


Feature :

1A, 30 V DC for Power
2 poles & 4 poles circuitry


Application :

Home electronic equipment
Industrial equipments
Audio system
ADSL modem
Wireless AP

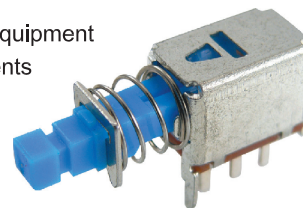




SWITCH SPECIFICATIONS	
POLE - POSITION	1P2T , 2P2T , 4P2T , Momentary and Lock Type are available
CONTACT RATING	30 V DC , 0.3 A ; 30 V DC , 1 A
CONTACT RESISTANCE	50 mΩ MAX. 1.5 V DC ; 100 mA , by Method of Voltage DROP
INSULATION RESISTANCE	100 MΩ MIN. 500 V DC
DIELECTRIC STRENGTH	Breakdown is not Allowable ; 500 V AC for 1 Minute
OPERATING FORCE	450 ± 150gf
OPERATING LIFE	10,000 cycles
OPERATING TEMPERATURE RANGE	-40°C ~ 85°C
TOTAL TRAVEL	3.5 ± 0.3 mm

▶ HOW TO ORDER



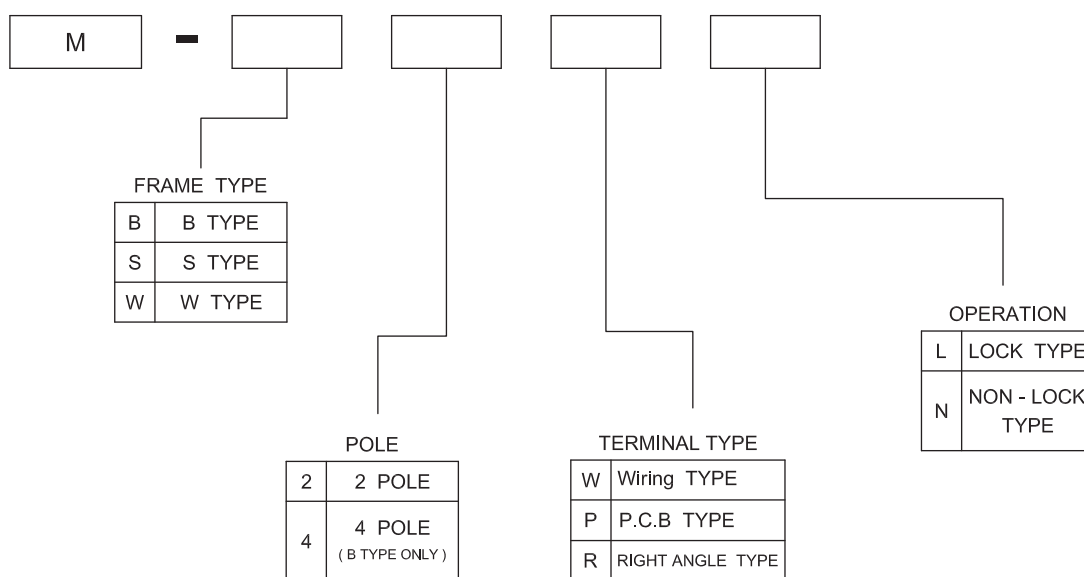


FRAME TYPE & TERMINAL TYPE



M - B2PN

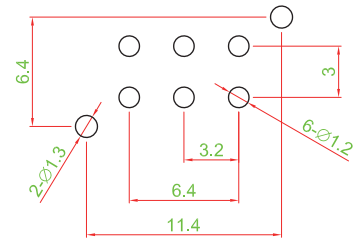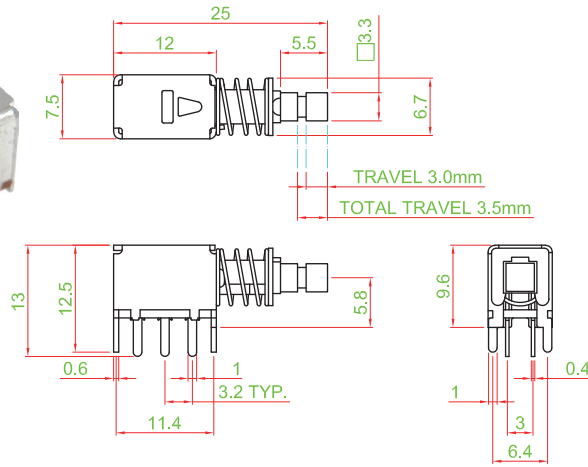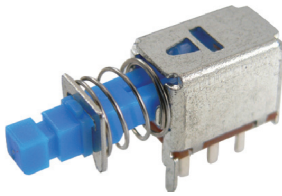

M - S2PN

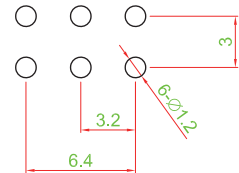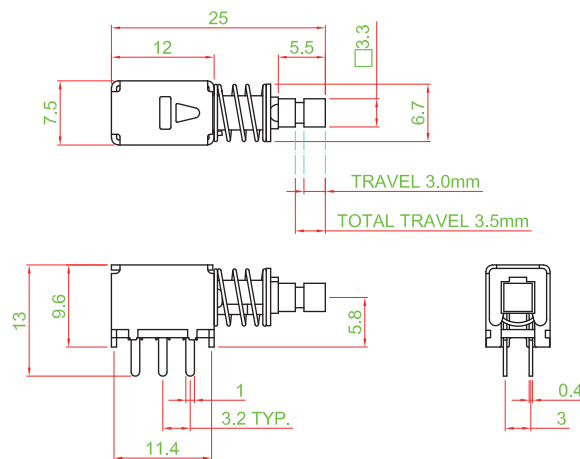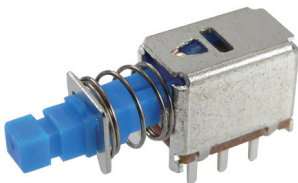

M - W2WL

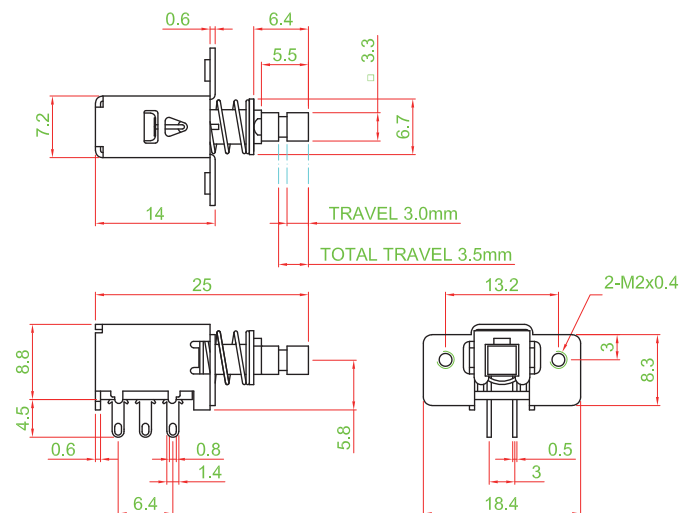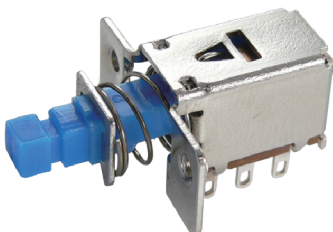
TACT
SWITCH

PUSH
BUTTON
SWITCH

LED TOUCH
SENSOR
SWITCH

5 DIRECTION
NAVIGATION
SWITCH
WITH LED

MEMBRANE
SWITCH

LED LIGHT
BAR

SLIDE
SWITCH

ROTARY
SWITCH

ROCKER
SWITCH

DETECT
SWITCH

ENCODER

INTERRUPTER

MINIATURE
MICRO
SWITCH

TELEPHONE
HOOK
SWITCH

DOOR
SWITCH

MINI SIZE
SOCKET





KNOB

CAP
SYMBOL







► FRAME TYPE & TERMINAL TYPE

M - S2RL

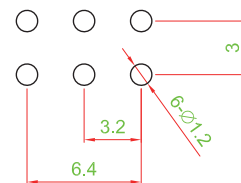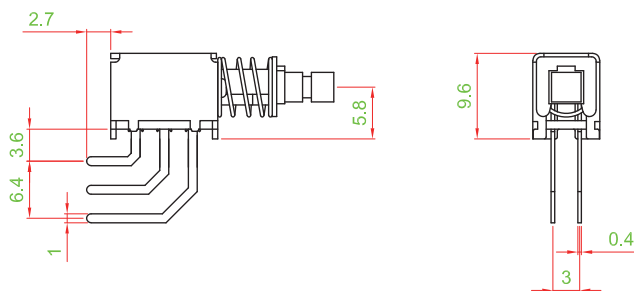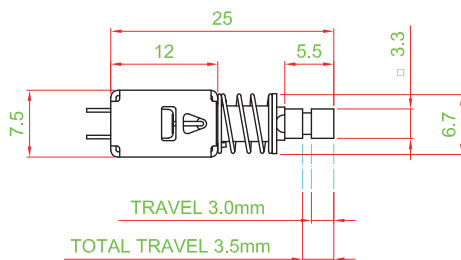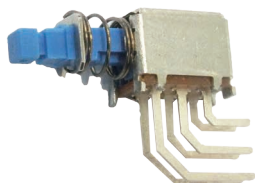


M - B4PL

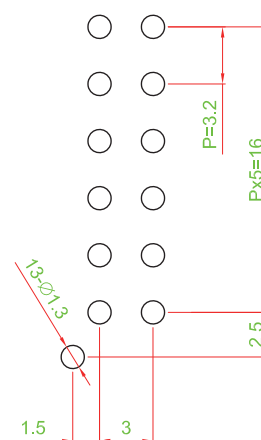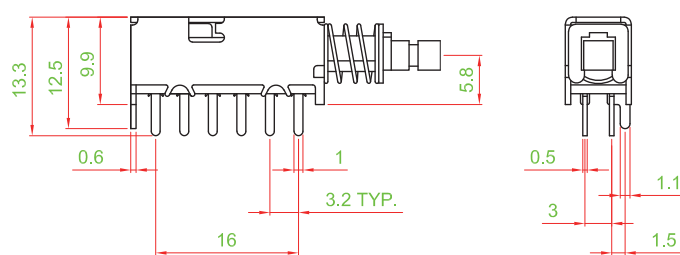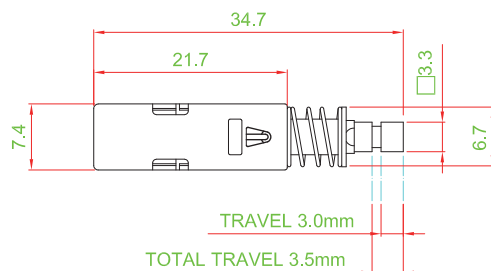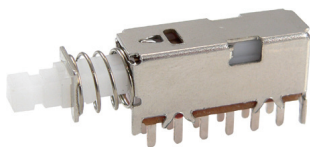


► CIRCUIT

2 POLE

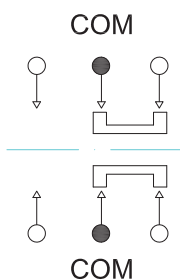

4 POLE

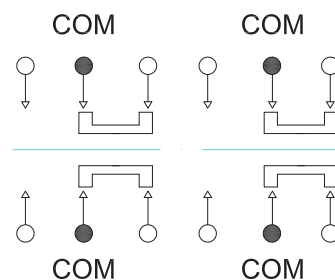

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Well Buying:](#)

[M-B2PL-74](#) [M-B2PL-10](#) [M-B2PL-19](#)