



### Feature :

Small dimension  
Max. 8 positions

### Application :


Power strip voltage selector  
Selection key on the application  
AV machine, video recorder  
Air cleaner



### SWITCH SPECIFICATIONS


POLE - POSITION	1POLE , 2 POSITION~8 POSITION ( STOP LESS ) are Available
CONTACT RATING	0.5A 24V DC ; 0.2A 48V DC
CONTACT RESISTANCE	2 Ω MAX. 1.5 V DC ; 100 mA , by Method of Voltage DROP
INSULATION RESISTANCE	100 MΩ MIN. 500 V DC
DIELECTRIC STRENGTH	Breakdown is not Allowable ; 500 V AC for 1 Minute
OPERATING FORCE	400 ± 250 gf.cm or 230 ± 100 gf.cm
OPERATING LIFE	2,000 cycles
OPERATING TEMPERATURE RANGE	-40°C ~ 85°C

### HOW TO ORDER

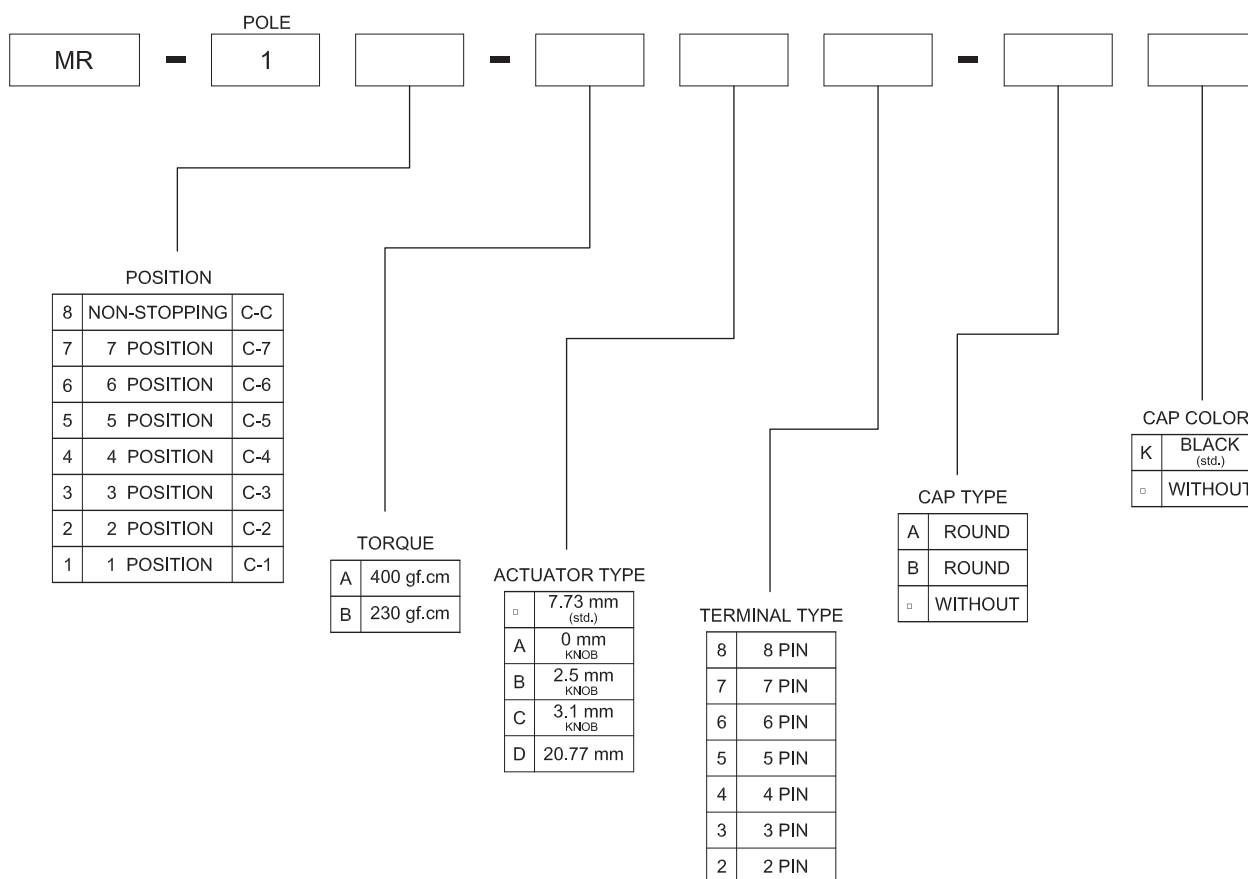


## ► DIMENSION

MR - 18 - A8

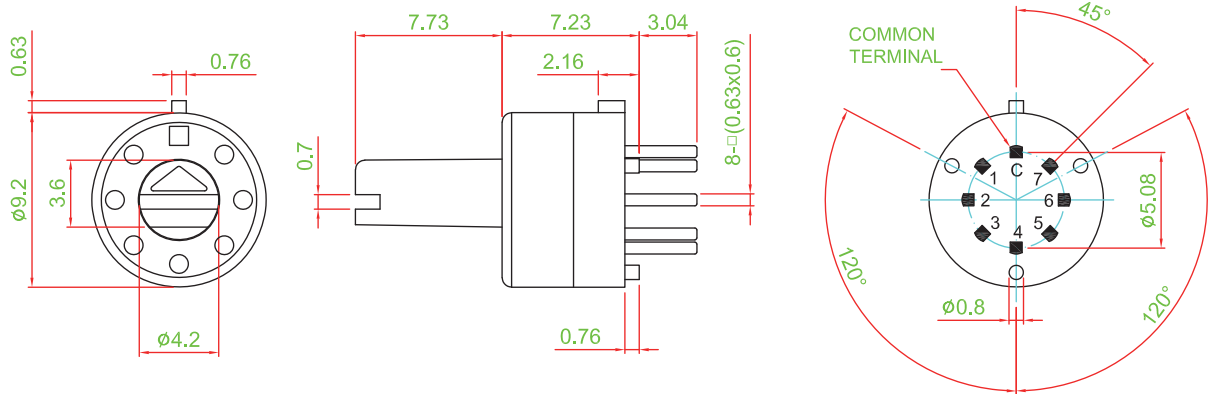


## ► ACTUATOR TYPE


A TYPE

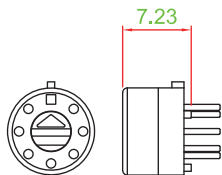


B TYPE

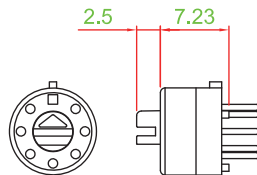

C TYPE

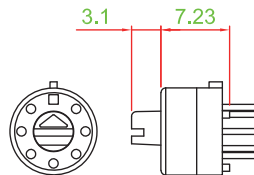


D TYPE

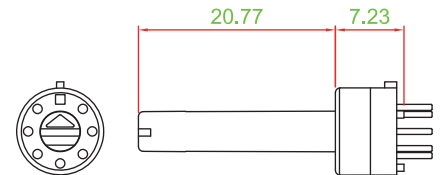


## ► CAP TYPE

A TYPE


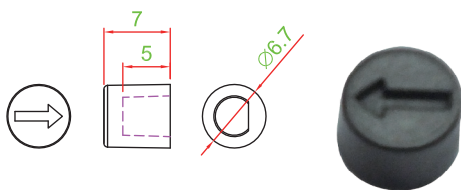


B TYPE

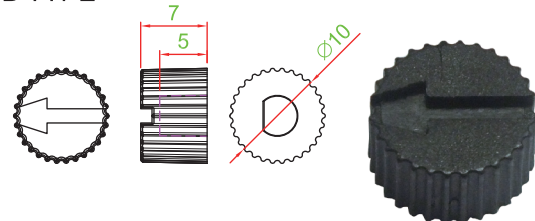

## ► CIRCUIT

TRAVEL	SWITCHING POSITION
0°	C - C (OFF)
45°	C - 1
90°	C - 2
135°	C - 3
180°	C - 4
225°	C - 5
270°	C - 6
315°	C - 7

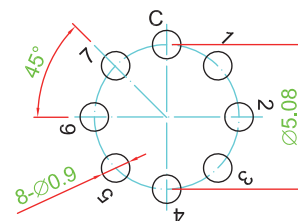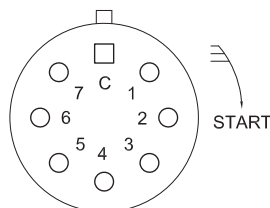

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Well Buying:](#)

[MR-12-A8](#) [MR-13-A4](#) [MR-18-A8](#)