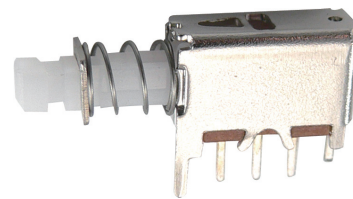


Feature :


0.3A, 30 V DC for Power
1 pole & 2 poles circuitry

Application :

Home electronic equipment
Industrial equipments
Audio system
ADSL modem
Wireless AP

**SWITCH SPECIFICATIONS**



POLE - POSITION	1P2T , 2P2T , Momentary and Lock Type are Available
CONTACT RATING	30 V DC , 0.3 A
CONTACT RESISTANCE	30 mΩ MAX. 1.5 V DC ; 100 mA , by Method of Voltage DROP
INSULATION RESISTANCE	100 MΩ MIN. 500 V DC
DIELECTRIC STRENGTH	Breakdown is not Allowable ; 500 V DC for 1 Minute
OPERATING FORCE	1P2T : 200 ± 100gf ; 2P2T : 250 ± 100gf
OPERATING LIFE	10,000 cycles
OPERATING TEMPERATURE RANGE	-40°C ~ 85°C
TOTAL TRAVEL	3.5 ± 0.3 mm

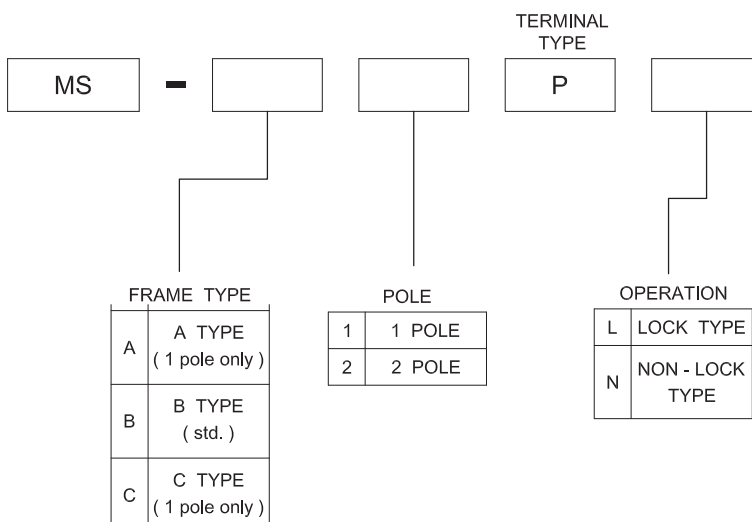► HOW TO ORDER





► DIMENSION



MS - A1PL

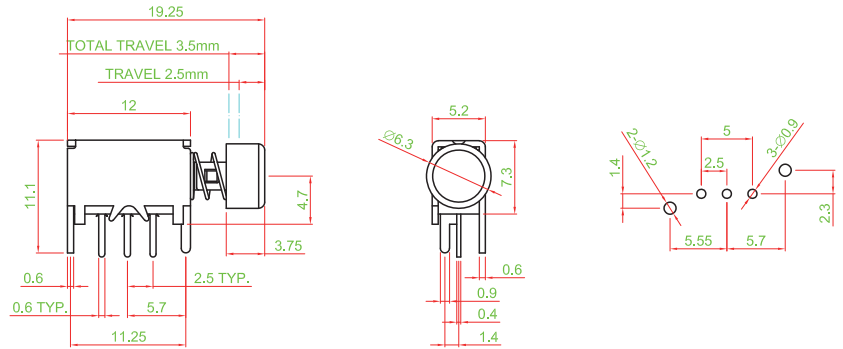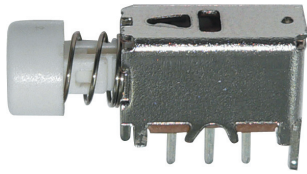



MS - B1PN

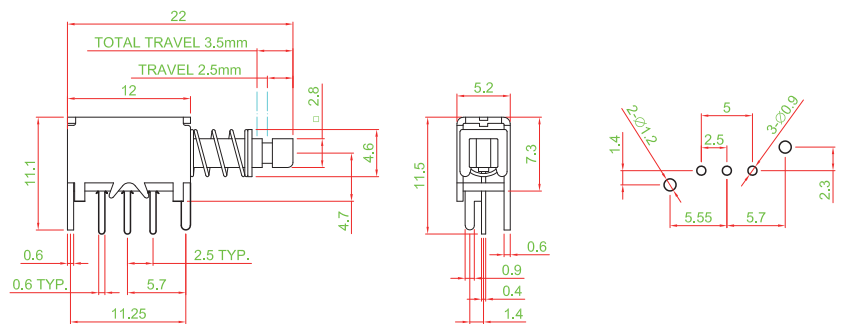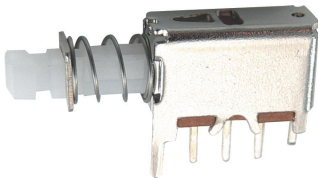



MS - C1PN

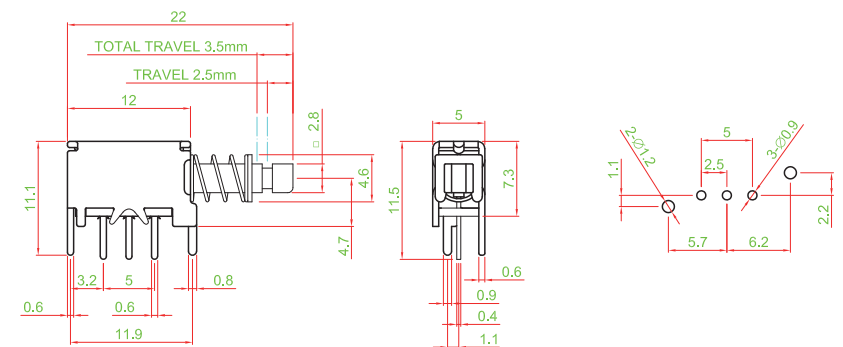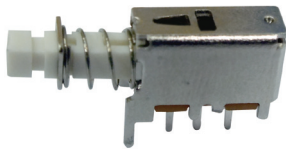

MS - B2PL

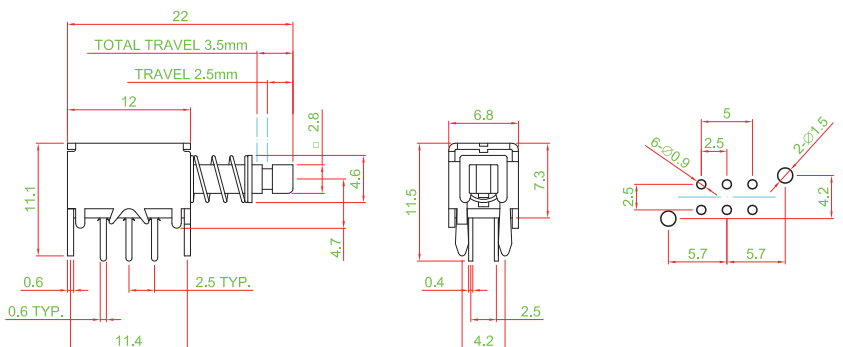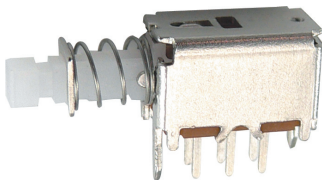

► CIRCUIT

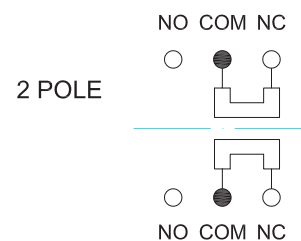 

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Well Buying:](#)

[MS-B2PL](#) [MS-B1PL-13](#) [MS-B2PL-6](#)