


Feature :

6A, 30VDC for power
SPST, lock / non-lock function

Application :


Home electronic equipments
Industrial electronic equipments
Audio system
ADSL modem ; Wireless AP

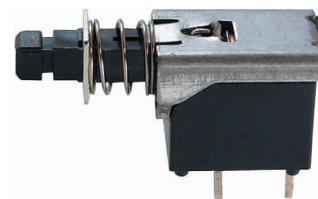

SWITCH SPECIFICATIONS



POLE - POSITION	1P1T
CONTACT RATING	30 V DC , 6 A ; 30 V DC , 2 A
CONTACT RESISTANCE	100 mΩ MAX. 1.5 V DC ; 100 mA , by method of voltage DROP
INSULATION RESISTANCE	100 MΩ MIN. 500 V DC
DIELECTRIC STRENGTH	Breakdown is not allowable ; 500 V AC for 1 minute
OPERATING FORCE	300 ± 150 gf
OPERATING LIFE	6,000 cycles
OPERATING TEMPERATURE RANGE	-40°C ~ 85°C
TOTAL TRAVEL	3.8 ± 0.3 mm

► HOW TO ORDER

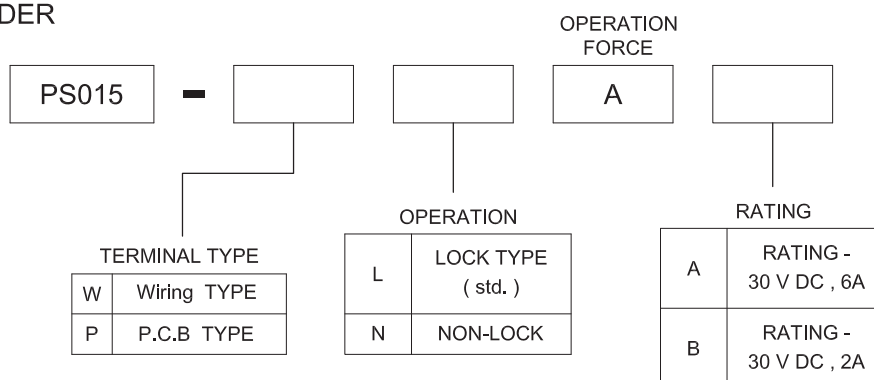


► DIMENSION

PS015-PLAA

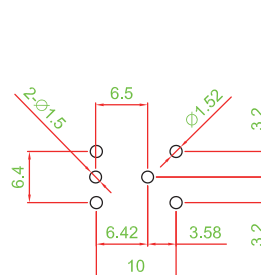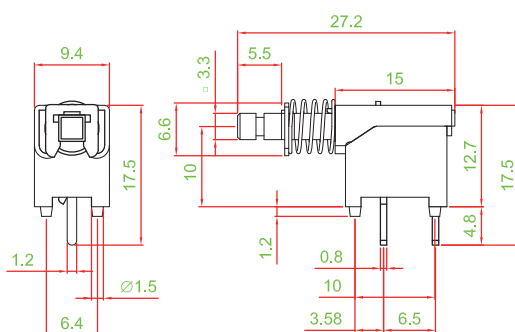

► CIRCUIT

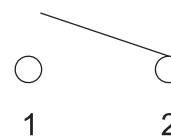

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Well Buying:](#)

[PS015-PLAA-2](#)