

Audio / video products.
Instrumentation
Communication equipments



LED SPECIFICATIONS								
 ATTENTION LEDs are Electrostatic Sensitive devices  (+) ○ — (LED) — ○ (-)	Unit	Value / LED Color						
		Blue	Pure Green	Red	Yellow	Orange	Green	White
LUMINOUS INTENSITY@20mA I _v	mcd	40	150	220	80	280	30	150
Dominant Wavelength λD	nm	470	525	630	590	601	568	/
FORWARD VOLTAGE@20mA V _f	V	3.3	3.3	1.95	2	2.1	3	3.3

■ A single bin cannot be ordered, please contact us in advance if you need a particular bin sorting before placing your order to clarify the lead time, MOQ and pricing

PS016	MOMENTARY N	POLE 1	POSITION 1							DIFFUSOR STATE w	CAP COLOR COLOR		See page 240
-------	----------------	-----------	---------------	--	--	--	--	--	--	---------------------	--------------------	--	--------------

OPERATING TRAVEL

A	2.9 ± 0.5mm
B	2.5 ± 0.5mm

CAP TYPE

A	A TYPE
B	B TYPE

LED BRIGHTNESS

U	ULTRA (std.)
X	WITHOUT

LED COLOR

B	BLUE
G	GREEN
R	RED
W	WHITE
Y	YELLOW
X	WITHOUT

LED BRIGHTNESS

U	ULTRA (std.)
X	WITHOUT

LED COLOR

B	BLUE
G	GREEN
R	RED
W	WHITE
Y	YELLOW
X	WITHOUT



CAP COLOR

□	TRANSPARENT(std.)
K	BLACK
S	SILVER
T	TRANSPARENT (When indicate the diffuser color)


CAP SYMBOL

For example

K3		PK3:Printing K3:Laser carving
E1		PE1:Printing E1:Laser carving
□		WITHOUT

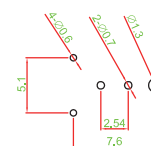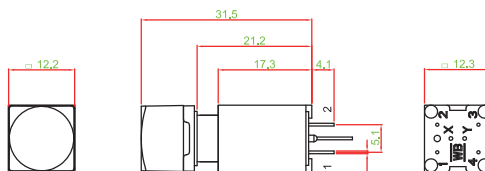PS016 - N11AA ☐ ☐ ☐ ☐

 
B TYPE



SINGLE COLOR



 TWO COLOR



Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Well Buying:

PS016-N11ABURPG PS016-N11AXURUG