


Feature -
small size push switch (6x6 mm)
lock / non-lock function

Application -
consumer products
computer products
instrumentation
communication equipments

► SPECIFICATIONS

SWITCH SPECIFICATIONS	
POLE - POSITION	SPDT , DPDT
CONTACT RATING	12 V DC , 50 mA
CONTACT RESISTANCE	100 mΩ MAX. 1.5 V DC ; 100 mA , by Method of Voltage DROP
INSULATION RESISTANCE	100 MΩ MIN. 500 V DC for 1 minute
DIELECTRIC STRENGTH	Breakdown is not Allowable ; 500 V AC for 1 Minute
OPERATING FORCE	250 ± 50 gf
OPERATING LIFE	50,000 cycles
OPERATING TEMPERATURE RANGE	-20°C ~ 70°C
TOTAL TRAVEL / OPERATING TRAVEL	2 ± 0.3 mm / 1.3 ± 0.3 mm

► HOW TO ORDER

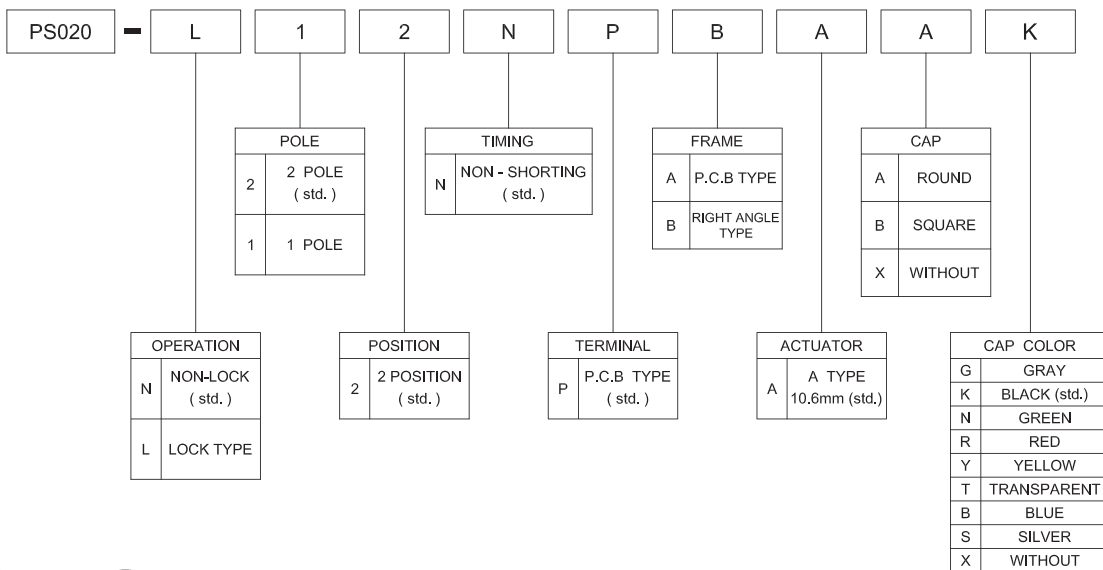

▶ DIMENSION	
<p>PS020-L22NPAAX</p>	<p>PS020-L22NPAAK</p>
<p>PS020-L12NPBAX</p>	<p>PS020-L12NPAABK</p>
▶ CIRCUIT	▶ P.C.B LAYOUT
<p>SINGLE POLE</p> <p>DOUBLE POLE</p>	<p>A TYPE</p> <p>B TYPE</p>
▶ MATERIAL	
<p>■ ACTUATOR : PA + GF</p> <p>■ TERMINAL : BRONZE SILVER PLATING</p>	<p>■ FRAME : PA + GF</p> <p>■ SPRING : STAINLESS STEEL</p>

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Well Buying:](#)

[PS020-L12NPBAX](#) [PS020-L22NPAAX](#)