




SWITCH SPECIFICATIONS	
POLE - POSITION	SPST
CONTACT RATING	POWER:1 Watt MAX CURRRNT:50uA MIN/300mA max VOLTAGE:DC24V MAX
CONTACT RESISTANCE	150mΩ MAX
BREAKDOWN VOLATAGE	150 VDC
INSULATION RESISTANCE	10 MΩ min. 500 V DC
OPERATING FORCE	140±50gf
OPERATING LIFE	50,000,000 cycles
TEMPERATURE RANGE	OPERATING:-5°C ~ 60°C STORAGE:-40°C ~ 90°C
TOTAL TRAVEL	2.8±0.3

u HOW TO ORDER

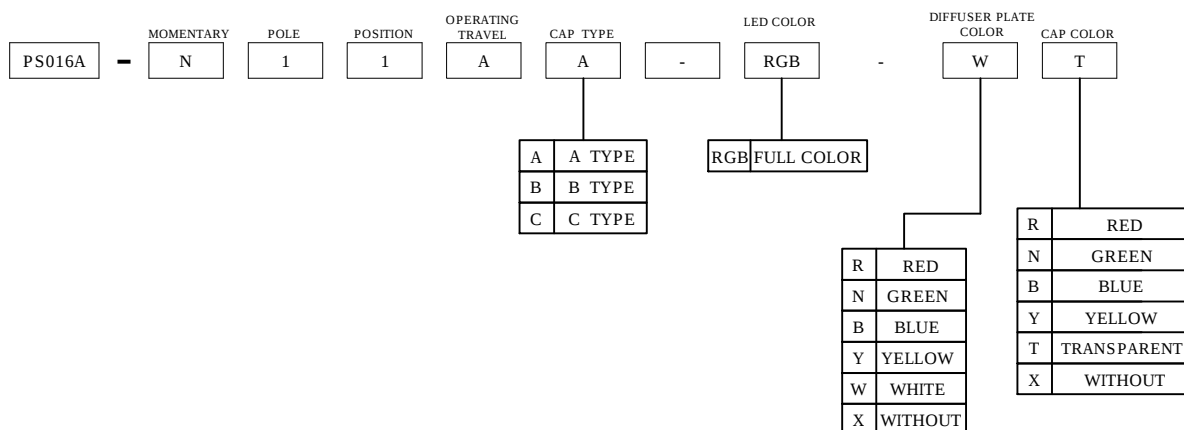

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Well Buying:](#)

[PS016A-N11AA-RGB-WT](#)