


Feature :

Water proof IP67 sealed
Full color LED illuminated available
Long electrical life cycles
SMD and vertical PCB terminal

Application :

Consumer products
Computer products
Instrumentation
Communication equipments

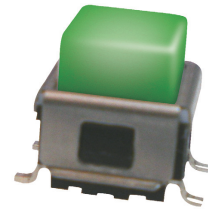


SWITCH SPECIFICATIONS	
POLE - POSITION	1P1T , with LED
CONTACT RATING	12 V DC , 50 mA
CONTACT RESISTANCE	100 mΩ MAX. 1.5 V DC ; 100 mA , by Method of Voltage DROP
INSULATION RESISTANCE	100 MΩ MIN. 500 V DC
DIELECTRIC STRENGTH	Breakdown is not Allowable ; 500 V AC for 1 Minute
OPERATING FORCE	300 ± 100 gf
OPERATING LIFE	500,000 cycles
OPERATING TEMPERATURE RANGE	-40°C ~85°C
TOTAL TRAVEL	0.4 ± 0.1 mm
SEALING	IP67

LED SPECIFICATIONS		Value / LED Color						
Unit		Blue (5mA)	Pure Green	Red	Yellow	Orange	Green	White
LUMINOUS INTENSITY@20mA I _v	mcd	25	180	200	200	250	55	250
Dominant Wavelength λ _D	nm	470	525	630	590	601	567	/
FORWARD VOLTAGE@20mA V _f	V	2.8	3.2	1.95	2	2.1	2.1	4

■ A single bin cannot be ordered, please contact us in advance if you need a particular bin sorting before placing your order to clarify the lead time, MOQ and pricing



► HOW TO ORDER

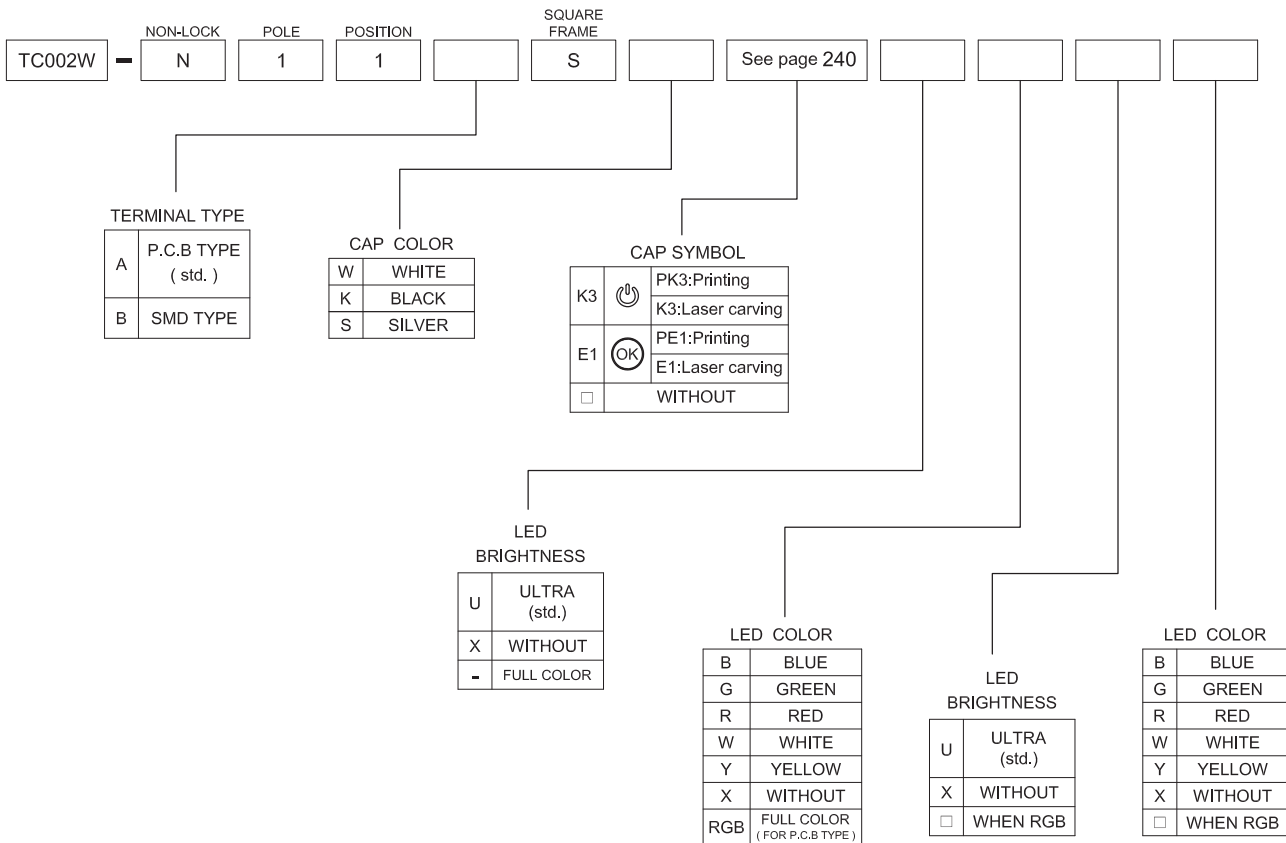




DIMENSION



TC002W-N11ASW

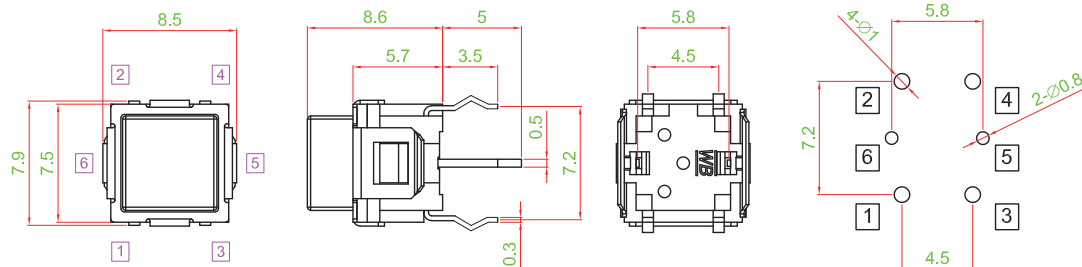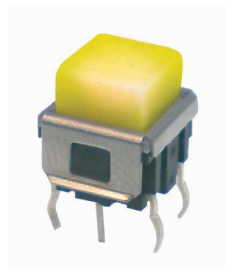


TC002W-N11ASW

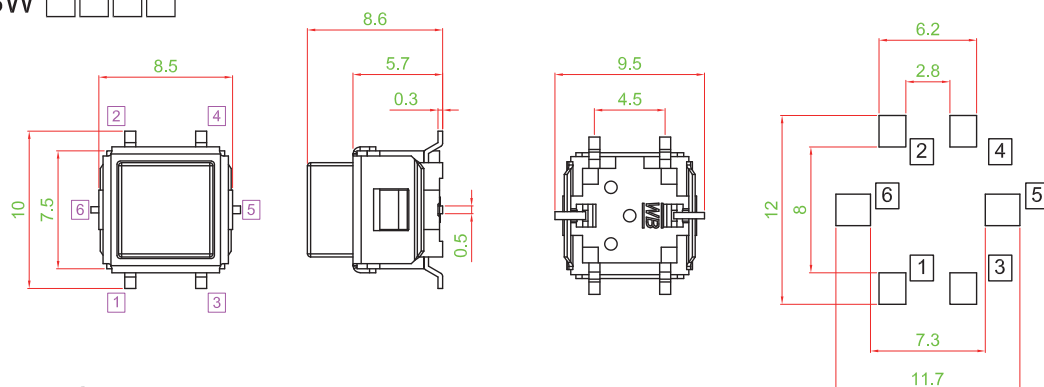

TC002W-N11ASW-RGB

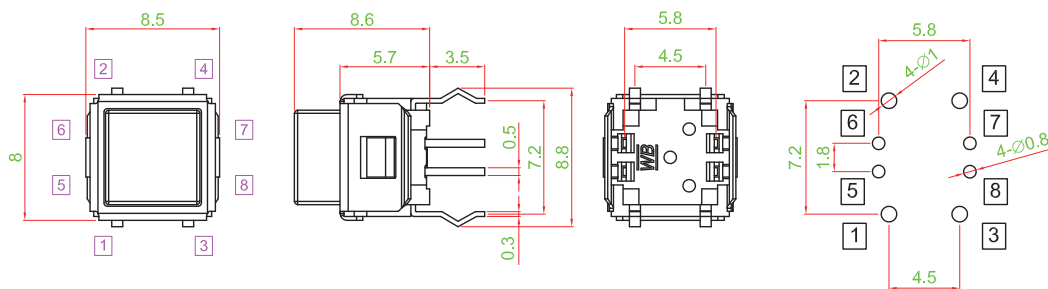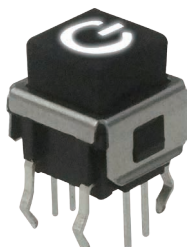


CIRCUIT

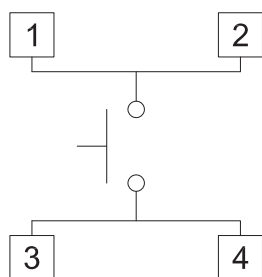


SINGLE
COLOR



 TWO
COLOR



FULL
COLOR

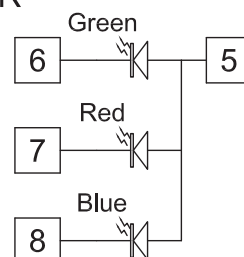

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Well Buying:

[TC002W-N11BSWURXX](#) [TC002W-N11BSSM8UBXX](#) [TC002W-N11BSKK3UBUR](#) [TC002W-N11ASSM8UBXX](#)
[TC002W-N11BSSM2UBXX](#) [TC002W-N11ASSM2UBXX](#) [TC002W-N11BSWUGUB](#)