
Feature -

SPST
mini in dimension
bi-color LED illuminated available
SMT, right angle, and vertical PCB terminal

Application -


consumer products
computer products
instrumentation
communication equipments

SPECIFICATIONS

SWITCH SPECIFICATIONS	
POLE - POSITION	Momentary action , SPST
CONTACT RATING	MAX. : 12 V DC , 50 mA MIN. : 1 V DC , 50 μ A
CONTACT RESISTANCE	500 m Ω MAX. 5 V DC ; 10 mA , by Method of Voltage DROP
INSULATION RESISTANCE	100 M Ω MIN. 100 V DC for 1 minute
DIELECTRIC STRENGTH	Breakdown is not Allowable ; 250 V AC for 1 Minute
OPERATING FORCE	160 $\pm$ 50 gf
OPERATING LIFE	100,000 cycles
OPERATING TEMPERATURE RANGE	-20°C ~ 70°C
TOTAL TRAVEL	0.2 $\pm$ 0.10 mm


LED SPECIFICATIONS		Value / LED Color			
	Unit				
		Blue	Green	Red	Yellow
FORWARD CURRENT	If	20	20	20	20
REVERSE VOLTAGE	Vr	5.0	5.0	5.0	5.0
REVERSE CURRENT	Ir	10	10	10	10
FORWARD VOLTAGE@20mA	Vf	3.5-3.8	2.0-2.5	2.0-2.5	2.0-2.5
LUMINOUS INTENSITY@20mA	Iv	45	20	80	80

Physical and electrical information of LED will be provided upon customer's request on switches .

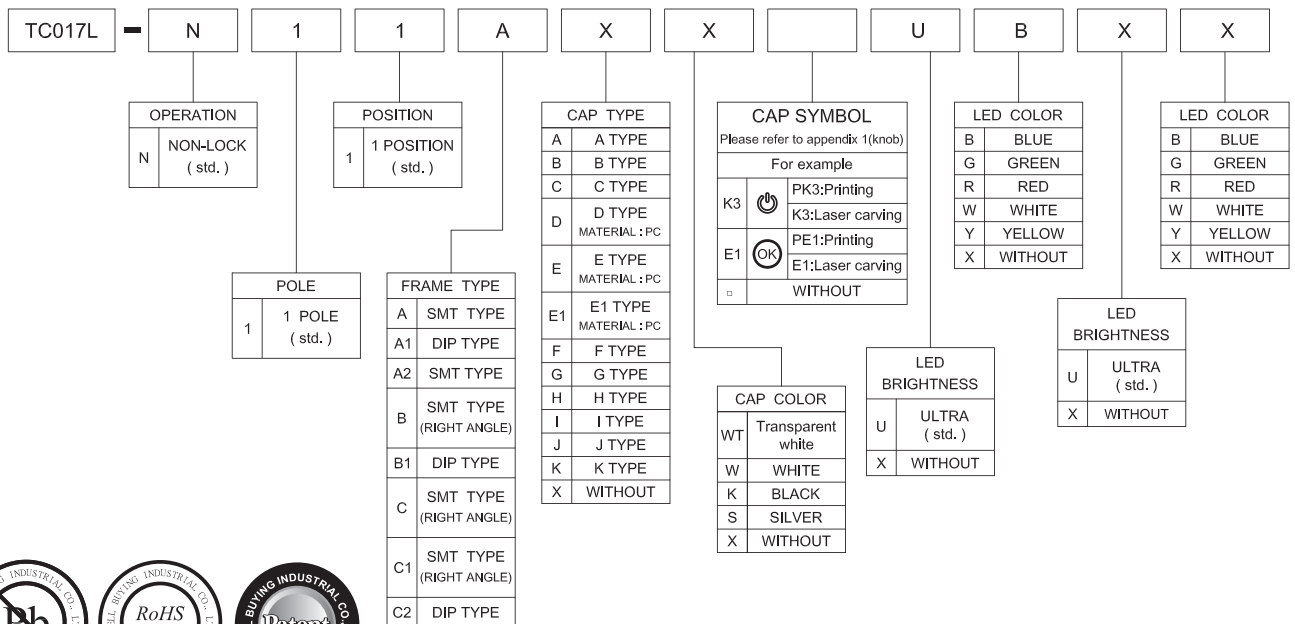
HOW TO ORDER


► DIMENSION


TC017L-N11AXX□□□□

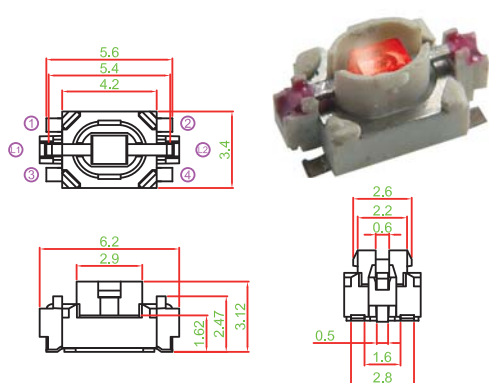


TC017L-N11A1XX□□□□

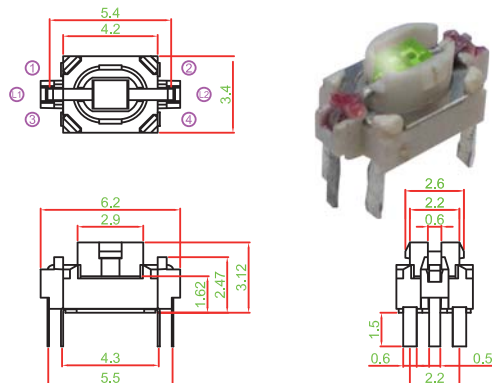


TC017L-N11A2XX□□□□

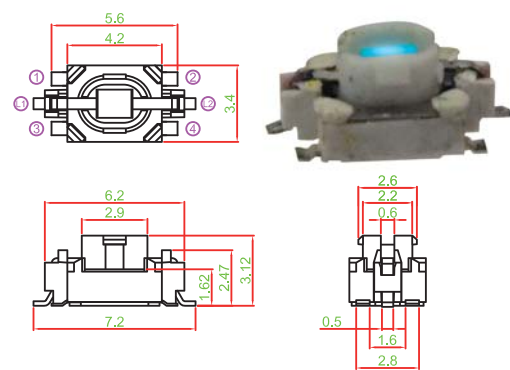



TC017L-N11CXX□□□□

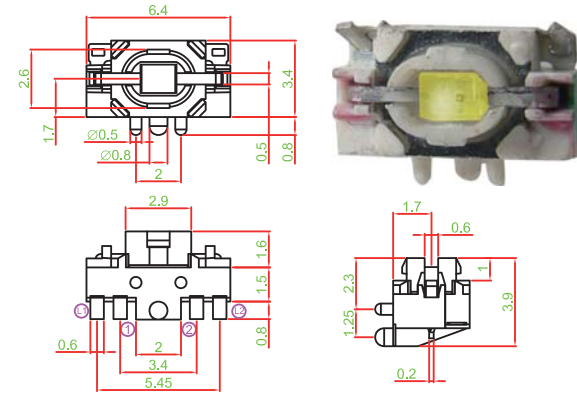


TC017L-N11C1XX□□□□

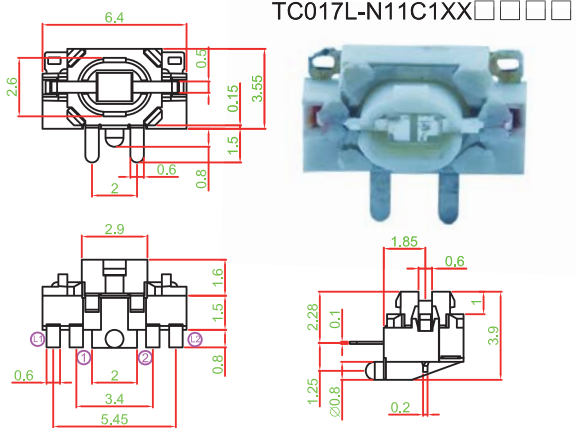

TC017L-N11C2XX□□□□

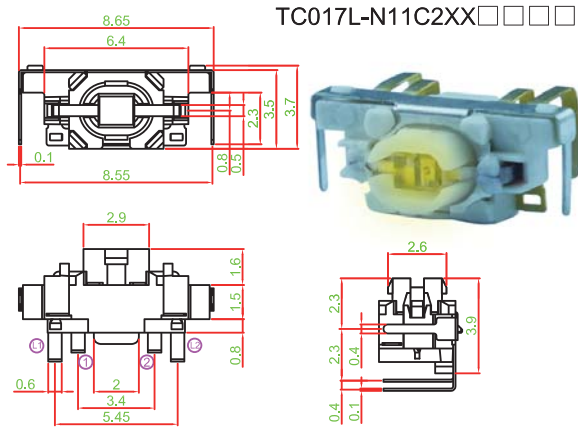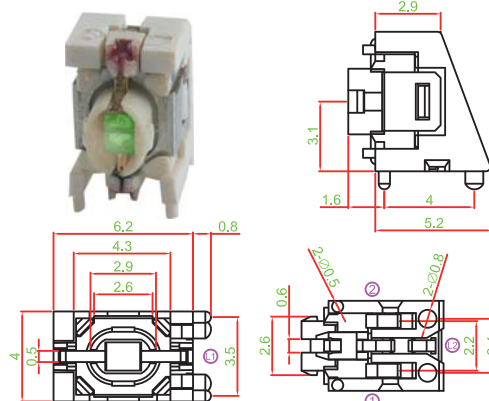
TC017L-N11BXX 

TC017L-N11B1XX□□□□

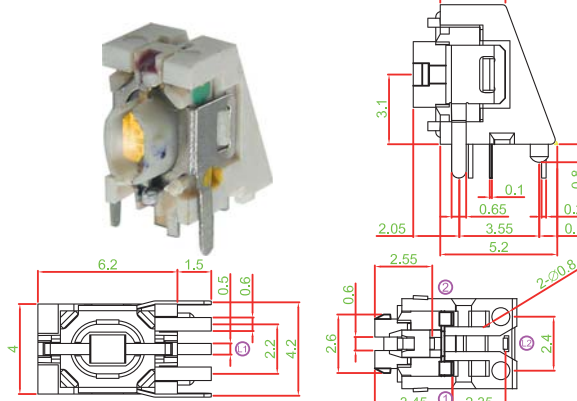


► KNOB TYPE OPTION


A TYPE

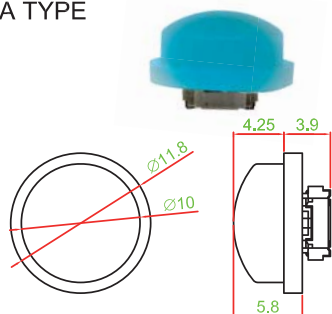


B TYPE

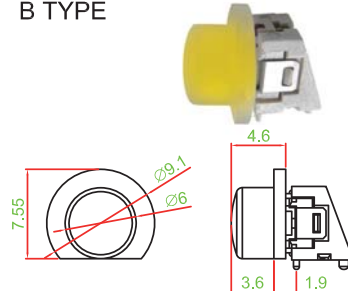


C TYPE

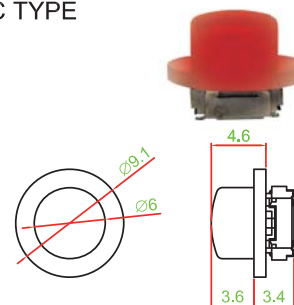


D&F TYPE

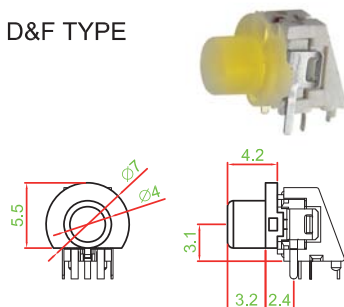


E&G TYPE

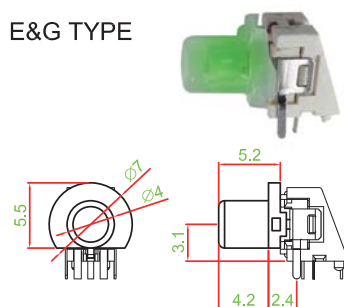


E1 TYPE

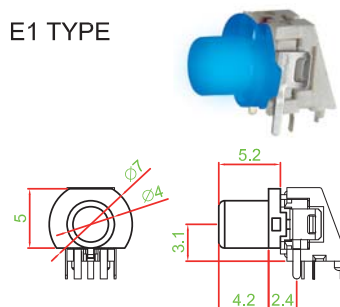


H TYPE

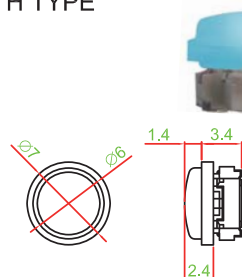


I TYPE

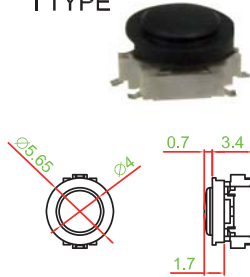

J TYPE

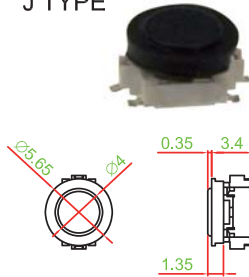


K TYPE

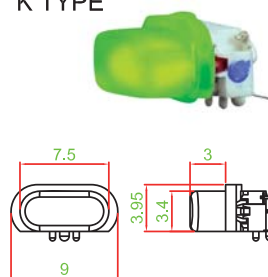


► CIRCUIT

FRAME : A

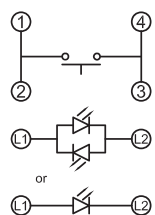

FRAME : B, C

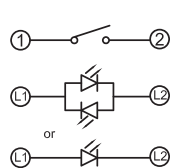


► MATERIAL

- COVER : SUS
- ACTUATOR : PA
- BASE : LCP
- CAP : PC、SILICONE
- TERMINAL : BRASS
SILVER PLATING

► P.C.B. LAYOUT


FRAME : A

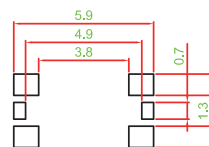


FRAME : A1




FRAME : A2

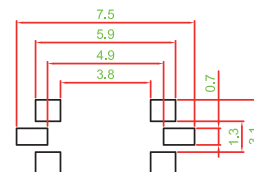


FRAME : B

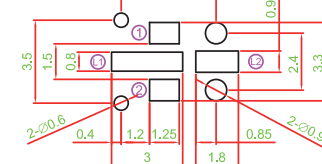


FRAME : C2

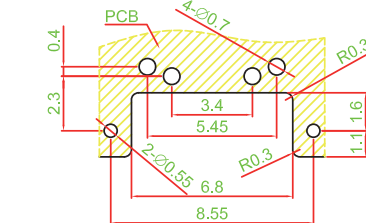


FRAME : B1

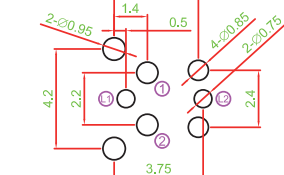

FRAME : C

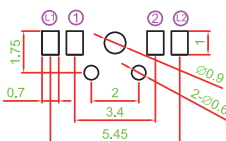

FRAME : C1

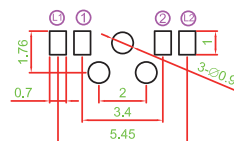

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Well Buying:

[TC017L-N11AAWURXX](#) [TC017L-N11AAWUWXX](#) [TC017L-N11AAWUYXX](#) [TC017L-N11AAWUGXX](#) [TC017L-N11AAWUBXX](#) [TC017L-N11B1XXUGUY-1-LF](#) [TC017L-N11B1XXUBXX-1-LF](#) [TC017L-N11B1XXUBXX-5](#) [TC017L-N11B1XXUGUY-1](#)