



Feature :

DPST
Two buttons in line
Vertical PCB mount


Applications :

Office equipment
Measuring instruments
Audio , TV , VCRs
Many types of electronic equipments

SWITCH SPECIFICATIONS


POLE - POSITION	DPST
CONTACT RATING	12 V DC , 50 mA
CONTACT RESISTANCE	100 mΩ MAX. 5 V DC ; 1 A , by Method of Voltage DROP
INSULATION RESISTANCE	100 MΩ MIN. 100 V DC for 1 minute
DIELECTRIC STRENGTH	Breakdown is not Allowable ; 100 V AC for 1 Minute
OPERATING FORCE	160 ± 50 gf
OPERATING LIFE	500,000 cycles
OPERATING TEMPERATURE RANGE	-40°C ~ 85°C
TOTAL TRAVEL	0.25 ± 0.10 mm

HOW TO ORDER


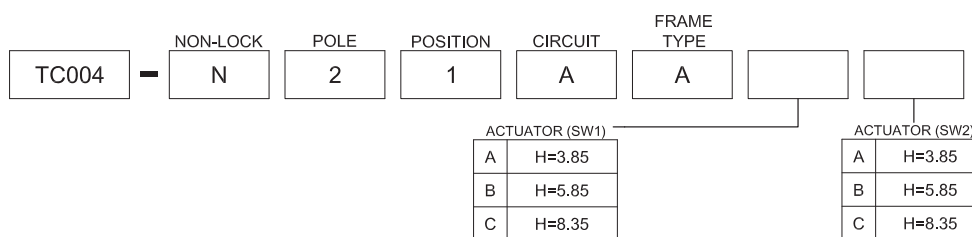


DIMENSION

TC004-N21AAAC

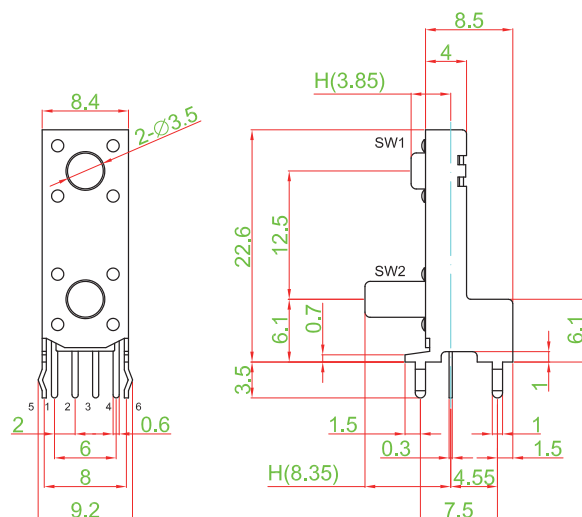

CIRCUIT

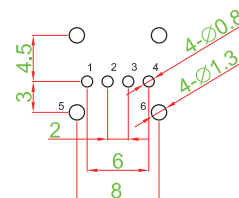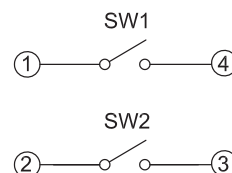

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Well Buying:](#)

[TS004-D11HAKKK3-F-W200](#) [TS004-DM11HAKKK3-F-W200](#)