


Feature :

Small size
Bi-color LED illuminated available
Good tactile feeling

Application :

Consumer products
Network products
Instrumentation
Communication equipments

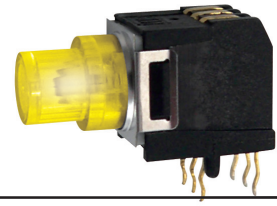


SWITCH SPECIFICATIONS	
POLE - POSITION	1P2T , Right Angle Push on-on momentary Type , with or w/o LED are Available
RATING	POWER MIN. / MAX. : 0.02VA / 1.0VA CURRENT MIN. / MAX. : 0.1mA ~ 100mA VOLTAGE MIN. / MAX. : DC 20mV ~ DC 32V
CONTACT RESISTANCE	250 mΩ max. 1.5 V DC : 100 mA , by Method of Voltage DROP
INSULATION RESISTANCE	100 MΩ min. 500 V DC
DIELECTRIC STRENGTH	Breakdown is not Allowable ; 250 V AC for 1 Minute
OPERATING FORCE	400 ± 125 gf
OPERATING LIFE	50,000 cycles
OPERATING TEMPERATURE RANGE	-40°C ~ 85°C
TOTAL TRAVEL	2.0 mm MAX.

LED SPECIFICATIONS		Value / LED Color						
ATTENTION LEDs are Electrostatic Sensitive devices (+)-O-(+)	Unit							
		Blue	Pure Green	Red	Yellow	Orange	Green	White
LUMINOUS INTENSITY@20mA Iv	mcd	1300	6500	1200	400	550	370	1200
Dominant Wavelength λD	nm	470	525	635	590	601	570	/
FORWARD VOLTAGE@20mA Vf	V	3.3	3.3	1.95	2	2.1	2.1	4

■ A single bin cannot be ordered, please contact us in advance if you need a particular bin sorting before placing your order to clarify the lead time, MOQ and pricing





► HOW TO ORDER

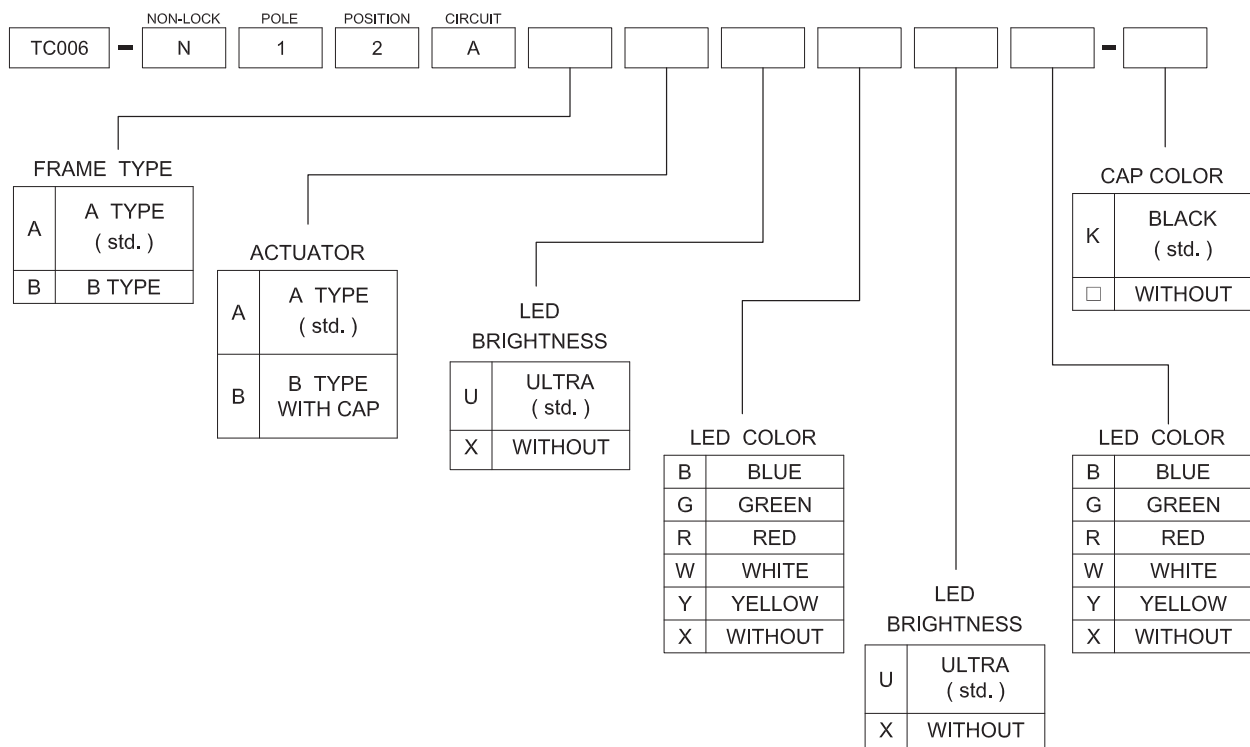







DIMENSION




TC006-N12AAA□□□□

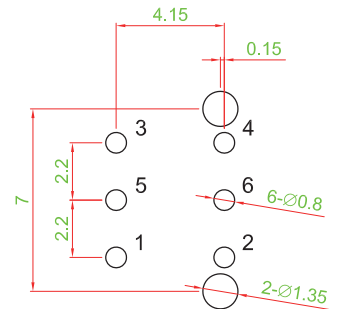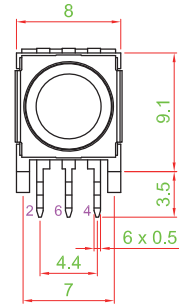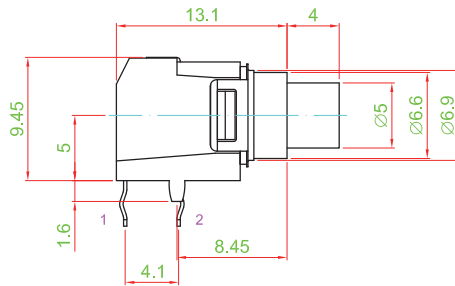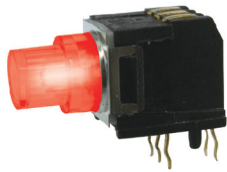


TC006-N12ABA□□□□

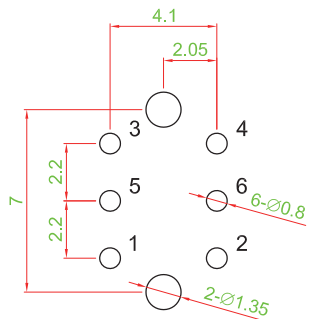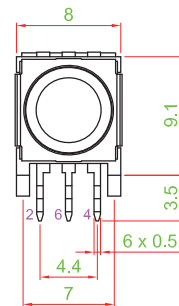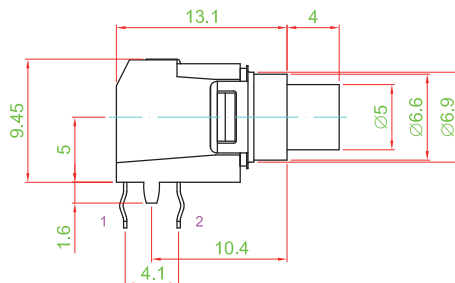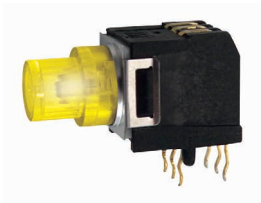

CAP TYPE

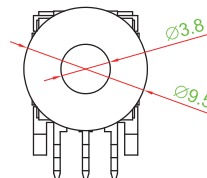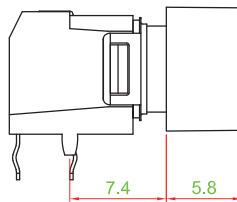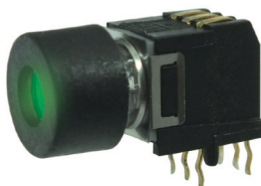

CIRCUIT

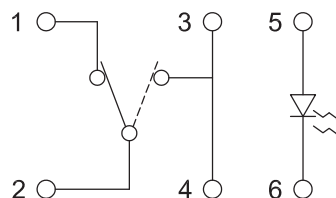

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Well Buying:](#)

[TS006-BTMKM4CRBYGB-W100](#) [TS006-ATMKM4CRBYGB-W100](#) [TS006-ADMKM4CRBYGB-W100](#)