

## Feature :

Water proof IP67 sealed  
Bi-color LED illuminated available  
Long electrical life cycles  
Good tactile feeling



## Application :

Consumer products  
Computer products  
Instrumentation  
Communication equipments




## DIMENSION

SWITCH SPECIFICATIONS	
POLE - POSITION	Momentary action , SPST
CONTACT RATING	20 V DC , 1 mA
CONTACT RESISTANCE	200Ω MAX. 5 V DC ; 1 mA , by Method of Voltage DROP
INSULATION RESISTANCE	100 MΩ MIN. 100 V DC for 1 minute
DIELECTRIC STRENGTH	Breakdown is not Allowable ; 250 V AC for 1 Minute
OPERATING FORCE	125 ± 50 gf
OPERATING LIFE	500,000 cycles
OPERATING TEMPERATURE RANGE	-40°C ~ 85°C
TOTAL TRAVEL	1.3 ± 0.1 mm
SEALING	IP67


LED SPECIFICATIONS								
 <div>ATTENTION LEDs are Electrostatic Sensitive devices</div> <div>(+) ○ (−)</div> 	Unit	Value / LED Color						
		Blue	Pure Green	Red	Yellow	Orange	Green	White
LUMINOUS INTENSITY@20mA I <sub>v</sub>	mcd	80	150	220	180	320	50	450
Dominant Wavelength λ <sub>D</sub>	nm	465	525	630	590	601	567	/
FORWARD VOLTAGE@20mA V <sub>f</sub>	V	3.3	3.2	1.95	2	2.1	2.1	3.3

■ A single bin cannot be ordered, please contact us in advance if you need a particular bin sorting before placing your order to clarify the lead time, MOQ and pricing


## HOW TO ORDER

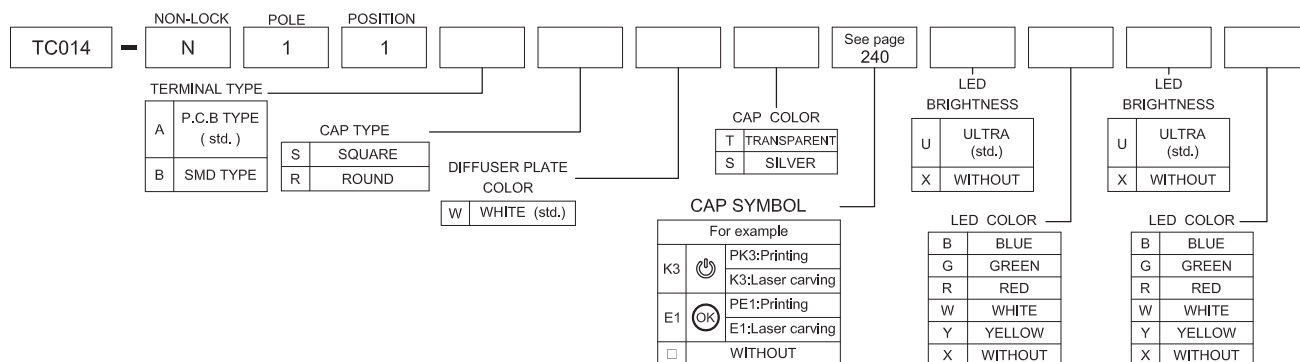

## CIRCUIT

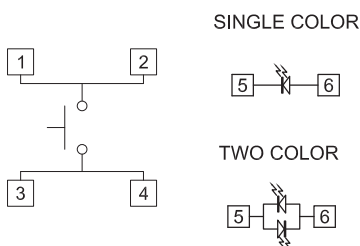

## DIMENSION

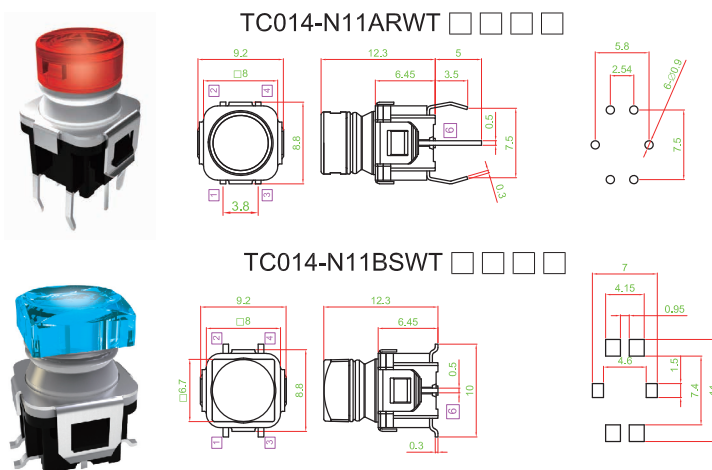

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Well Buying:](#)

[TC014-N11ARWTUWXX](#)