




SWITCH SPECIFICATIONS	
POLE - POSITION	SPST
CONTACT RATING	12VDC 50mA
CONTACT RESISTANCE	500mΩ MAX
INSULATION RESISTANCE	100 MΩ min. 500 V DC
DIELECTRIC STRENGTH	Breakdown is not Allowable ; 250 V AC for 1 Minute
OPERATING FORCE	160 ± 50 gf
OPERATING LIFE	100,000 cycles
OPERATING TEMPERATURE RANGE	-40°C ~ 85°C
TOTAL TRAVEL	0.2 ± 0.10 mm

► HOW TO ORDER

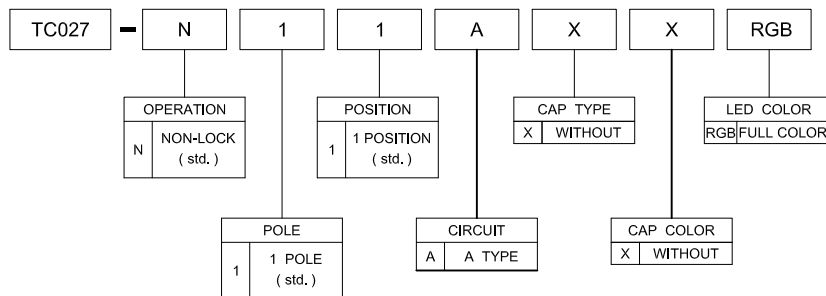

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Well Buying:](#)

[TC027-N11AAXX-RGB](#)