

**Feature -**

0.3A, 30 V DC for Power  
1 pole & 2 poles circuitry


**Application -**

home electronic equipment  
industrial electronic equipments  
audio system  
ADSL modem  
wireless AP

► **SPECIFICATIONS**


SWITCH SPECIFICATIONS	
POLE - POSITION	1P2T , 2P2T , Momentary and Lock Type are Available
CONTACT RATING	30 V DC , 0.3 A
CONTACT RESISTANCE	30 mΩ MAX. 1.5 V DC ; 100 mA , by Method of Voltage DROP
INSULATION RESISTANCE	100 MΩ MIN. 500 V DC
DIELECTRIC STRENGTH	Breakdown is not Allowable 500 V DC for 1 Minute
OPERATING FORCE	1P2T : 200 ± 100gf 2P2T : 250 ± 100gf
OPERATING LIFE	10,000 cycles
OPERATING TEMPERATURE RANGE	-20°C ~ 70°C
TOTAL TRAVEL	3.5 ± 0.3 mm

► **HOW TO ORDER**

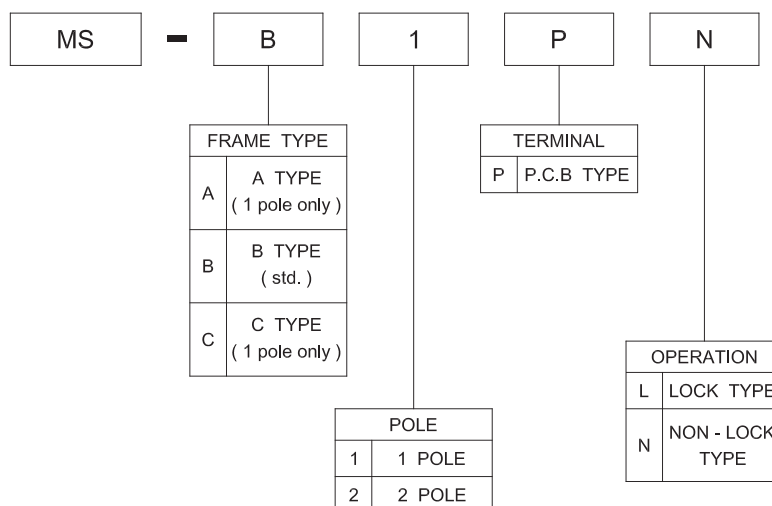


► DIMENSION


MS - A1PL

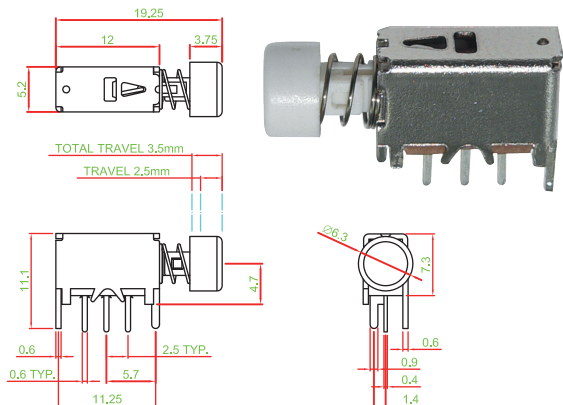


MS - B1PN

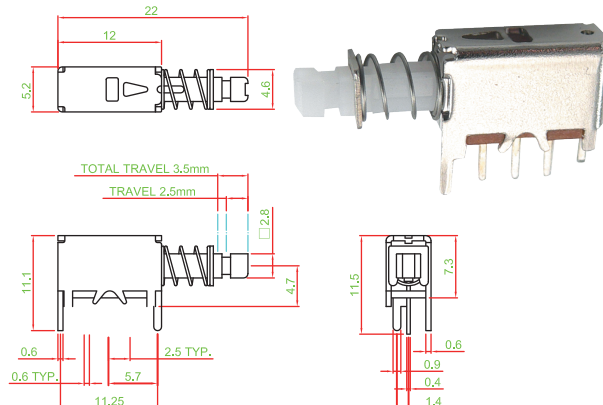



MS - C1PN

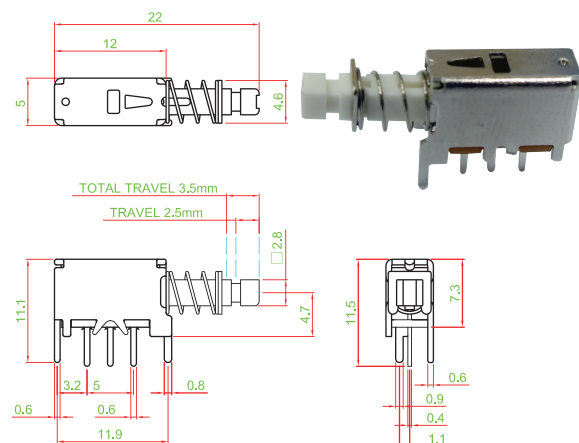

MS - B2PL

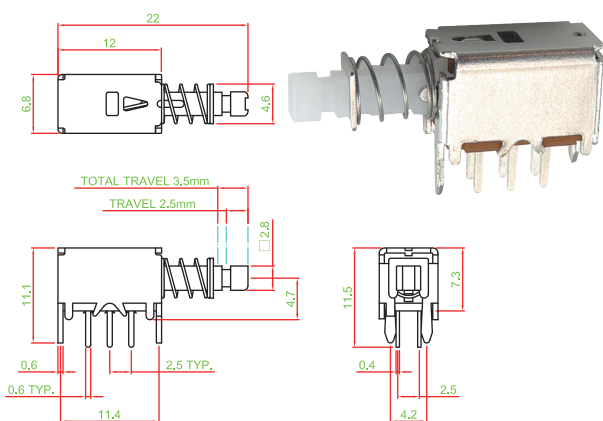


► CIRCUIT

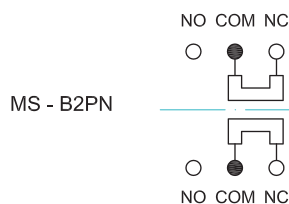 


► P.C.B LAYOUT


MS - B1PN

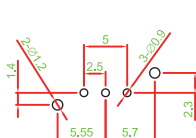

MS - B2PN

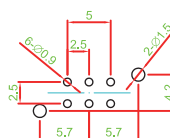

MS - C1PN

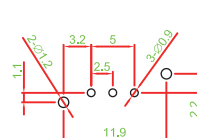

► MATERIAL

- ACTUATOR : PA + GF
- FRAME : STEEL PLATE
- TERMINAL : BRASS SILVER PLATING
- SPRING : STAINLESS STEEL

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Well Buying:](#)

[MS-B2PL](#) [MS-B1PL-13](#)