



Feature :

SPST
Mini in dimension

Application :

Consumer products
Computer products
Instrumentation
Communication equipments



SWITCH SPECIFICATIONS

POLE - POSITION	Momentary action , SPST
CONTACT RATING	MAX. : 12 V DC , 50 mA ; MIN. : 1 V DC , 50 μ A
CONTACT RESISTANCE	500 m Ω MAX. 5 V DC ; 10 mA , by Method of Voltage DROP
INSULATION RESISTANCE	100 M Ω MIN. 100 V DC for 1 minute
DIELECTRIC STRENGTH	Breakdown is not Allowable ; 250 V AC for 1 Minute
OPERATING FORCE	160 $\pm$ 50 gf
OPERATING LIFE	100,000 cycles
OPERATING TEMPERATURE RANGE	-40°C ~ 85°C
TOTAL TRAVEL	SHARP : 0.2 $\pm$ 0.10mm ; SOFT : 0.4 $\pm$ 0.10mm

HOW TO ORDER



FRAME TYPE

A	FLAT SMD (std.)
B	FLAT SMD
C	90° SMD
C1	90° DIP


 

ACTUATOR TYPE

A	SOFT FEELING
B	SHARP FEELING






FRAME TYPE




• TC017-N11AAA

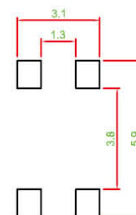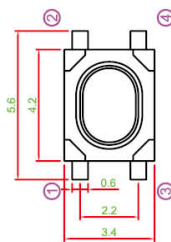




• TC017-N11ABB

 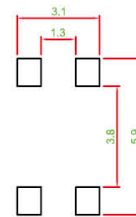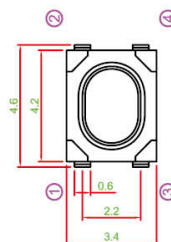


• TC017-N11ACA

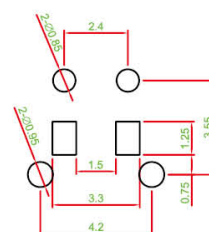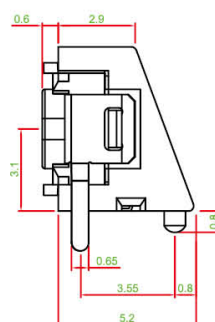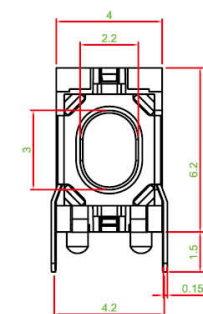

• TC017-N11AC1A

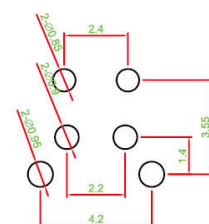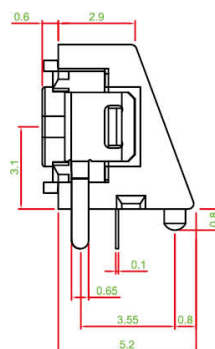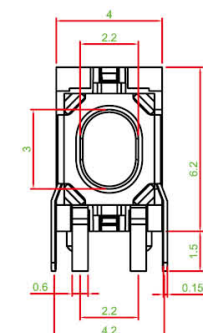

CIRCUIT

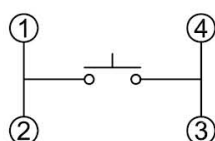TACT
SWITCHPUSH
BUTTON
SWITCHLED TOUCH
SENSOR
SWITCH5 DIRECTION
NAVIGATION
SWITCH
WITH LEDMEMBRANE
SWITCHLED LIGHT
BARSLIDE
SWITCHROTARY
SWITCHROCKER
SWITCHDETECT
SWITCH

ENCODER

INTERRUPTER

MINIATURE
MICRO
SWITCHTELEPHONE
HOOK
SWITCHDOOR
SWITCHMINI SIZE
SOCKET

KNOB

CAP
SYMBOL

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Well Buying:](#)

[TC017-N11AAA](#) [TC017-N11ACB](#) [TC017-N11AAB](#) [TC017-N11ABB](#)