

Feature :

DPST
Two buttons in line
Vertical PCB mount
LED illuminated available

Applications :

Office equipments
Measuring instruments
Audio, TV, VCRs
Many types of electronic equipments




SWITCH SPECIFICATIONS	
POLE - POSITION	DPST
CONTACT RATING	12 V DC , 50 mA
CONTACT RESISTANCE	100 mΩ MAX. 5 V DC ; 1 A , by Method of Voltage DROP
INSULATION RESISTANCE	100 MΩ MIN. 100 V DC for 1 minute
DIELECTRIC STRENGTH	Breakdown is not Allowable ; 100 V AC for 1 Minute
OPERATING FORCE	160 ± 50 gf
OPERATING LIFE	500,000 cycles
OPERATING TEMPERATURE RANGE	-40°C ~ 85°C
TOTAL TRAVEL	0.25 ± 0.10 mm

LED SPECIFICATIONS		Value / LED Color						
 ATTENTION LEDs are Electrostatic Sensitive devices 	Unit							
		Blue	Pure Green	Red	Yellow	Orange	Green	White
LUMINOUS INTENSITY@20mA Iv	mcd	330	1600	4000	2700	900	650	300
Dominant Wavelength λD	nm	465	525	630	590	601	/	567
FORWARD VOLTAGE@20mA Vf	V	3.3	3.3	1.95	2	2.1	4	2.1


■ A single bin cannot be ordered, please contact us in advance if you need a particular bin sorting before placing your order to clarify the lead time, MOQ and pricing

HOW TO ORDER

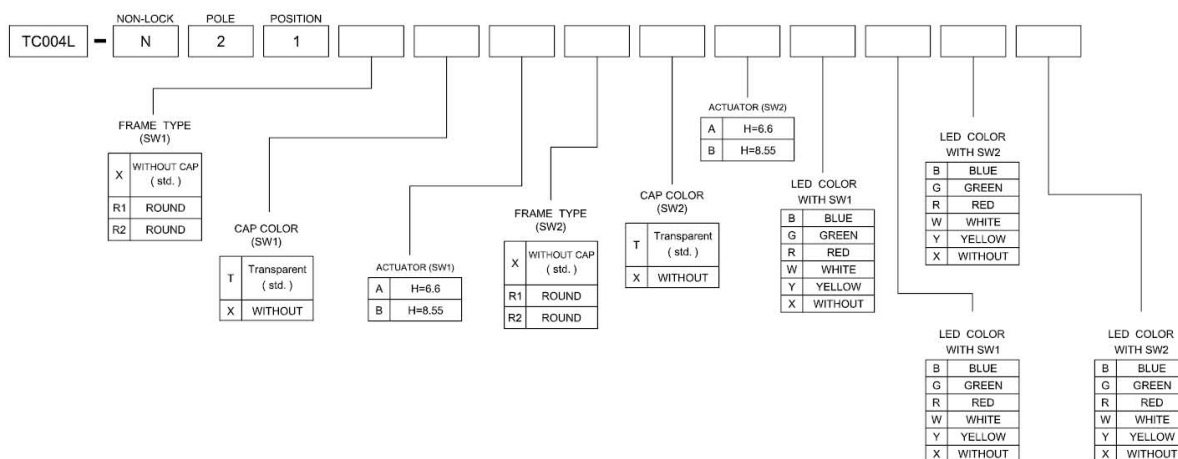


DIMENSION

• TC004L-N21XXBXXB □□□□

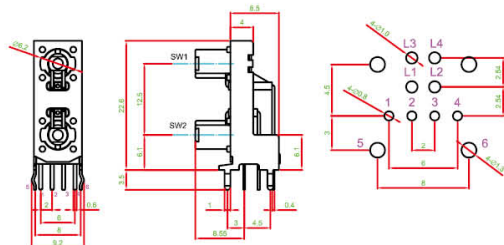


CAP TYPE


R1 TYPE

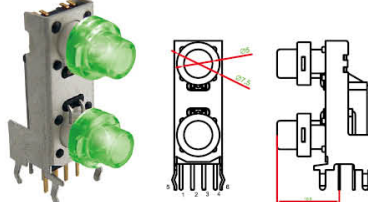


R2 TYPE

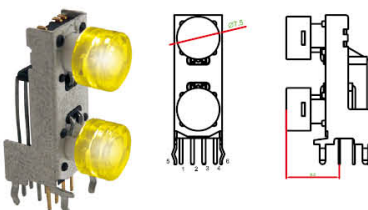

CIRCUIT

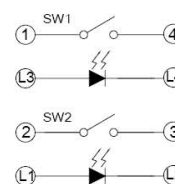

OR

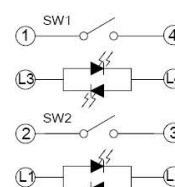

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Well Buying:](#)

[TC004L-N21R1TAR1TARGRG](#) [TC004L-N21R1TBR1TBGXGX](#) [TC004L-N21R2TAR2TARXRX](#) [TC004L-N21R2TBR2TBGXGX](#) [TC004L-N21XXAXXARXRX](#) [TC004L-N21XXBXXBGXGX](#)