


Feature -


 push / pull switch
 SPDT, DPDT, momentary function

Application -

 equipments
 game machines
 office appliances
 electrical home appliances


SPECIFICATIONS

SWITCH SPECIFICATIONS		
POLE - POSITION	Momentary type , SPDT , DPDT	
CONTACT RATING	250 V AC , 10(6) A	
CONTACT RESISTANCE	100 mΩ MAX. 1.5 V DC ; 100 mA , by method of voltage DROP	
INSULATION RESISTANCE	500 MΩ MIN. 500 V DC	
DIELECTRIC STRENGTH	Breakdown is not allowable ; 1000 V AC for 1 minute	
OPERATING FORCE	SPDT : PUSH : 400±100 PULL : 450±200	DPDT : PUSH : 500±200 PULL : 700±300
OPERATING LIFE	50,000 cycles	
OPERATING TEMPERATURE RANGE	-20°C ~ 70°C	
TOTAL TRAVEL	5.5 ± 0.3 mm	

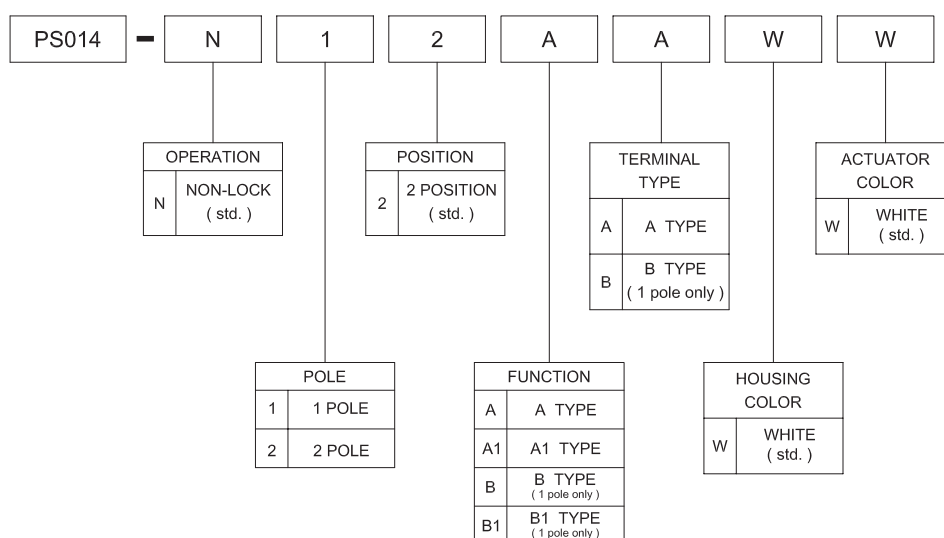
HOW TO ORDER


► DIMENSION


PS014-N12AAWW

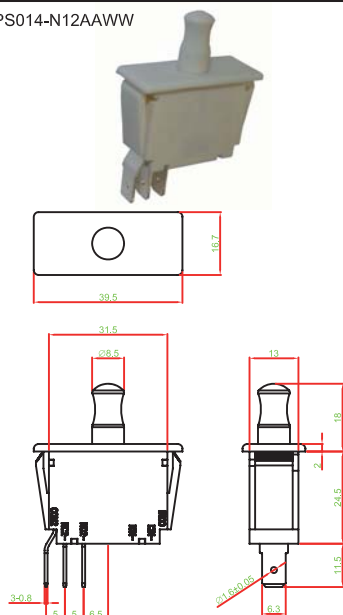

PS014-N22A1AWW

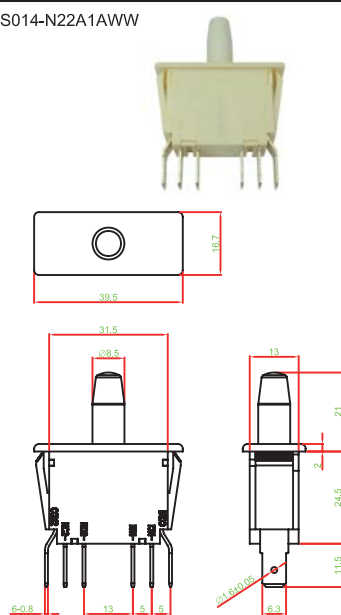


PS014-N12BBWW

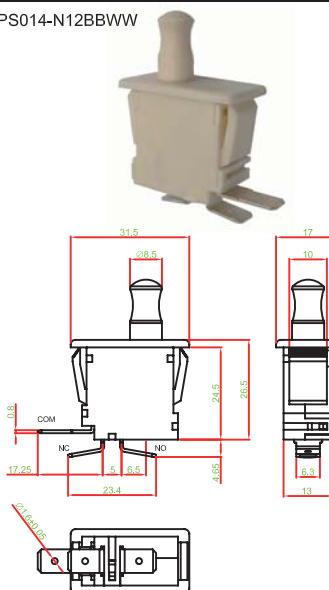


► FUNCTION


A TYPE

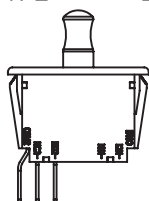


B TYPE

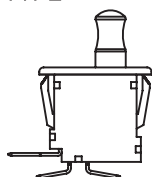

A1 TYPE

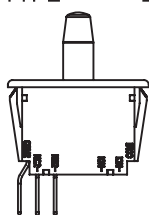


B1 TYPE

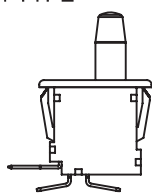


► CIRCUIT


PS014-N12AA□□

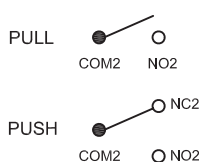


PS014-N22AA□□

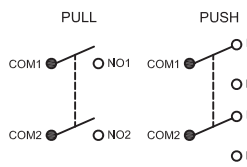


PS014-N12BB□□

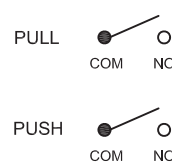

PS014-N12A1A□□

 

PS014-N22A1A□□

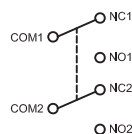

PS014-N12B1B□□



► MATERIAL

- ACTUATOR : PA66
- FRAME : PA66
- SPRING : STAINLESS STEEL
- TERMINAL : PHOSPHOR BRONZE SILVER PLATING
- MOVING CONTACT : PHOSPHOR BRONZE SILVER PLATING

► PANEL CUT OUT



PS014-N□2AA□□	
PANEL THICK	W
0.75 ~ 1.25	36
1.25 ~ 2.0	36.5
2.0 ~ 3.0	37

PS014-N12BB□□	
PANEL THICK	W
0.75 ~ 1.25	28
1.25 ~ 2.0	28.5
2.0 ~ 3.0	29

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Well Buying:

[PS014-N12AAWW](#) [PS014-N12BBWW](#)