
Feature -


 small dimension
 max. 8 positions

Application -

 high value toy
 power strip voltage selector
 selection key on the application
 AV machine, video recorder, air cleaner


SPECIFICATIONS

SWITCH SPECIFICATIONS	
POLE - POSITION	1P8T , 2P4T
CONTACT RATING	30 V DC , 0.5 A
CONTACT RESISTANCE	25 mΩ MAX. 1.5 V DC ; 100 mA , by Method of Voltage DROP
INSULATION RESISTANCE	100 MΩ MIN. 500 V DC
DIELECTRIC STRENGTH	Breakdown is not Allowable ; 500 V AC for 1 Minute
OPERATING FORCE	1P8T : 1000 ± 300 gf.cm
OPERATING LIFE	10,000 cycles
OPERATING TEMPERATURE RANGE	-20°C ~ 70°C

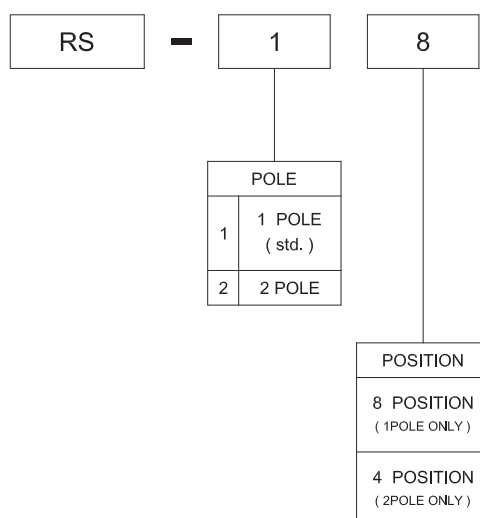HOW TO ORDER


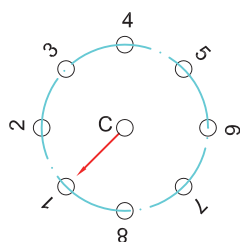
► DIMENSION

RS - 18

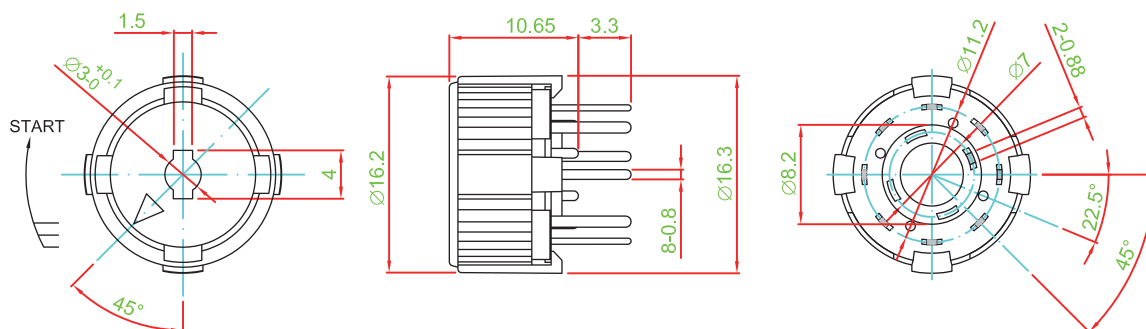


► CIRCUIT

RS-18




RS-24

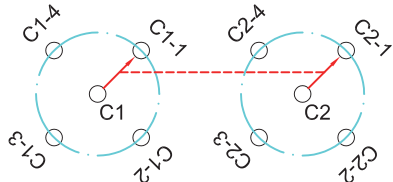


► P.C.B. LAYOUT

RS-18

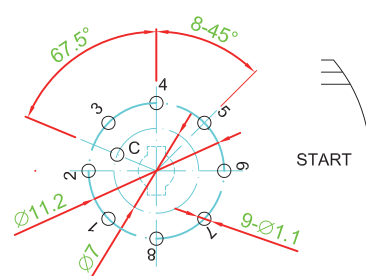

RS-24

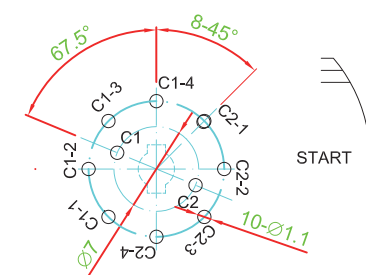

► MATERIAL

■ FRAME - PC

■ TERMINAL - BRASS SILVER PLATING

■ BASE FRAME - PA + GF

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Well Buying:](#)

[RS-18](#)