

2019




PROFESSIONAL HEX TOOLS

Inch & Metric








COMPLETE HEX TOOLS PROGRAM

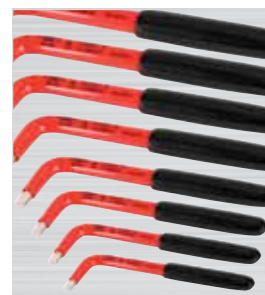


T-handles • PocketStars • L-keys • Insulated T-handles • Insulated L-keys
Insulated Sockets • Precision Screwdrivers • Insert & Power Bits • Sockets

     Wiha Hex Tools

	DESCRIPTION	Page
	T-handles	11
	PocketStar Fold Outs	13
	L-keys - Long/Short Nickel & Black Finish	14-15
	Insulated T-handle	16
	Insulated Hex Drivers	16
	Insulated L-keys	17
	Insulated Sockets	17
	Drive-Loc VI Blades	18
	ESD Safe Precision	23
	Precision	21
	PicoFinish	22
	SYSTEM 4 Blades	24
	SYSTEM 4 Micro Bits	25
	Insert/Power Bit Sets	26
	XSelectors	27
	Bit Insert & Power Bits	28-29
	Sockets	31-32



 
Wiha Security Hex Tools

	DESCRIPTION	Page
	SYSTEM 4 Micro Bits	25-26
	Insert Bits	28
	Sockets	32



90mm Security Hex Power Blades & Handle

	DESCRIPTION	Page
	Power Blades 90mm Security Hex Inch/Metric	18

   
Wiha Ball End Hex Tools

	DESCRIPTION	Page
	Ball End L-keys & Sets Chrome Finish	5
	Colored Coded L-keys Chrome Finish	6
	Ball End L-keys & Sets Long, Mid-Length & Short Black Finish	7
	Stainless Steel L-keys & Sets	6
	Soft Grip T-handles Chrome & Black Finish	10-11
	3K Series Screwdrivers	13
	Drive-Loc VI Blades	18
	Precision	21
	PicoFinish Soft Grip	22
	SYSTEM 4 Blades	24
	Stubby Bit Holder Sets	26
	Ball End Hex Insert Bit	29
	Ball End Hex Socket	32

  MagicRing Screw Holding Hex Tools

	DESCRIPTION	Page
	L-keys Screw Holding	4
	T-handles Screw Holding	9
	SoftFinish Screw Holding Cushion Grip	12
	PocketStars Screw Holding	9
	Insert Bits Screw Holding	27
	Power Bits Screw Holding	27
	Bit-Selectors Screw Holding Insert & Power Bits	27

 Wiha Drive-Loc VI

DESCRIPTION	Page
 Drive-Loc VI Handle SoftFinish® Cushion Grip	18
 Drive-Loc VI Handle ESD Safe Cushion Grip	18
 Drive-Loc VI Handle MicroFinish Non-Slip Grip	18
 Drive-Loc VI Blades Ball End Hex & Hex Inch/Metric	18
 Drive-Loc VI Blade Set	18

Wiha Power & Insert Hex Bits

DESCRIPTION	Page
 MagicRing Hex Inch & Metric Insert/Power Bits	27
 Hex Inch & Metric Insert/Power Bits	28
 Security Bits Inch & Metric Insert/Power Bits	28
 Ball End Hex Inch & Metric	29
 Stainless Steel Metric	29



Wiha TorqueControl Tools

DESCRIPTION	Page
 Insulated TorqueControl	20
 TorqueVario Handle	19
 Hex Inch/Metric Blades	19
 T-handle Torque Tools	20
 Hex Inch/Metric Blades	20


Terminator Impact Insert & Power Hex Bits

DESCRIPTION	Page
 Terminator Impact Bits	30

  Wiha Bit Sets

DESCRIPTION	Page
 Micro Bit Sets	24,26
 Stubby Bit Holder Sets	26
 XSelectors	26
 Bit Selector Sets	26-27
 Power Bit Belt Packs	27
 PokitPaks	27

 
Wiha Hex Sockets & Sets

DESCRIPTION	Page
 Insulated Sockets	17
 Hex Bit Sockets 1/4" Drive	31-32
 Hex Bit Sockets 3/8" Drive	31-32
 Ball End Sockets	32
 6" Bit Sockets 1/4" & 3/8" Drive	31
 Socket Sets	32

MagicRing Screw Holding Ball End Hex L-Keys



 Screw Holding Hex Tools!




669 MagicRing Ball End Metric Hex L-key

Long blade Chrome-V-Moly, hardened, hard chrome finish.

Item No.	mm	mm	mm	lbs.	pkg.
No Ring					
66904*	1.5	90	14	.01	10
66908*	2.0	99	16	.01	10
66912*	2.5	111	18	.01	10
MagicRing					
66916	3.0	125	20	.02	10
66920	4.0	138	25	.04	10
66924	5.0	158	28	.07	10
66928	6.0	178	32	.12	10
66936	8.0	198	36	.23	10
66944	10.0	221	40	.40	10

 * Standard Ball - No Ring



669 MagicRing Ball End Inch Hex L-key,

Long blade Chrome-V-Moly, hardened, hard chrome finish.

Item No.	Inch	Inch	Inch	lbs.	pkg.
No Ring					
66945*	.050	2.8	.5	.01	10
66946*	1/16	3.1	.6	.01	10
66947*	5/64	3.5	.7	.01	10
66950*	3/32	3.9	.7	.01	10
66952*	7/64	4.3	.7	.02	10
MagicRing					
66953	1/8	4.6	.8	.02	10
66955	9/64	5.2	.9	.03	10
66956	5/32	5.7	1.0	.04	10
66959	3/16	6.2	1.1	.06	10
66962	7/32	6.7	1.2	.09	10
66965	1/4	7.3	1.2	.13	10
66968	5/16	8.0	1.4	.22	10
66971	3/8	8.8	1.6	.36	10

* Standard Ball - No Ring



66991 13 Pc. MagicRing Long Inch Ball End Hex L-key Set, In ErgoStar Holder

Chrome-V-Moly, hardened, hard chrome finish.

Item No.	Inch	Inch	Inch	Inch	lbs.
66991	.050*	2.8	5/32	5.7	1.14
	1/16*	3.1	3/16	6.2	
	5/64*	3.5	7/32	6.7	
	3/32*	3.9	1/4	7.3	
	7/64*	4.3	5/16	8.0	
	1/8	4.6	3/8	8.8	
	9/64	5.2			

* Standard Ball - No Ring



66990 9 Pc. MagicRing Long Metric Ball End Hex L-key Set, In ErgoStar Holder

Blade Chrome-V-Moly, hardened, hard chrome finish.

Item No.	mm	mm	mm	mm	lbs.
66990	1.5*	90	5.0	158	1.07
	2.0*	99	6.0	178	
	2.5*	111	8.0	197	
	3.0	125	10.0	221	
	4.0	138			

* Standard Ball - No Ring



66992 22 Pc. Combination MagicRing L-key Set, In ErgoStar Holder

Item No. Set includes Inch & Metric:

66992	66990 Set - 1.5*, 2.0*, 2.5*, 3.0, 4.0, 5.0, 6.0, 8.0, 10.0mm
lbs.	66991 Set - .050*, 1/16*, 5/64*, 3/32*, 7/64*, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8"

* Standard Ball - No Ring

ErgoStar Ball End Hex Keys Chrome Finish

Fast Auto Open
Key Holder


66996 9 Piece ErgoStar Metric Ball End Hex Long L-key Set

lbs. 1.02

Item No. Metric: 1.5, 2.0, 2.5, 3.0, 4.0, 5.0,

66996 6.0, 8.0, 10.0mm

Fast Auto Open
Key Holder


66988 13 Piece ErgoStar Inch Ball End Hex Long L-key Set

lbs. 2.5

Item No. Inch: .050, 1/16, 5/64, 3/32, 7/64,

66988 1/8, 9/64, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8"

Fast Auto
Open Key
Holder


66982 22 Pc. ErgoStar Inch/Metric Ball End Hex Long L-key Set

Item No. Inch: .050, 1/16, 5/64, 3/32, 7/64, 1/8,

66982 9/64, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8"

lbs. Metric: 1.5, 2.0, 2.5, 3.0, 4.0, 5.0,

2.1 6.0, 8.0, 10.0mm

ErgoStar Inch Ball End L-key Set

- Patented ErgoStar auto open key holder
- Keys of chrome-vanadium-molybdenum steel
- 60HRC through hardened durability
- Hard chrome finish for best wear resistance

Metric & Inch Ball End Hex Keys Chrome Finish

Extra Long Hard Chromed



669 Ball End Metric Hex L-key, Long Arm

Chrome-V-Moly, hardened, hard chrome finish.

Item No.	mm	mm	mm	lbs.	pkg.
66904	1.5	90	14	.004	10
66908	2.0	99	16	.007	10
66912	2.5	111	18	.012	10
66918	3.0	125	20	.019	10
66922	4.0	138	25	.042	10
66926	5.0	158	28	.072	10
66930	6.0	178	32	.12	10
66937	8.0	198	36	.23	10
66938	10.0	221	40	.40	10

Extra Long Hard Chromed



369 Ball End Inch Hex L-key, Long Arm

Chrome-V-Moly, hardened, hard chrome finish.

Item No.	Inch	Inch	Inch	lbs.	pkg.
36949	1/8	4.6	.8	.021	10
36951	9/64	5.2	.9	.029	10
36954	5/32	5.7	1.0	.035	10
36957	3/16	6.2	1.1	.059	10
36958	7/32	6.7	1.2	.092	10
36960	1/4	7.3	1.2	.13	10
36961	5/16	8.0	1.4	.22	10
36963	3/8	8.8	1.6	.36	10



66994 9 Pc. Metric Ball End Hex Long L-key Set

lbs. .98

Item No. Metric: 1.5, 2.0, 2.5, 3.0, 4.0,

66994 5.0, 6.0, 8.0, 10.0mm



66995 6 Pc. Metric Ball End Hex Long L-key Set

lbs. .21

Item No. Metric: 1.5, 2.0, 2.5

66995 3.0, 4.0, 5.0mm



66998 11 Pc. Metric Ball End Hex Long L-key Set

lbs. 1.36

Item No. Metric: 1.5, 2.0, 2.5,

66998 3.0, 4.0, 5.0, 6.0, 7.0, 8.0, 9.0, 10.0mm



36998 13 Piece Inch Ball End Hex Long L-key Set, In Plastic Holder

Blade Chrome-V-Moly, hardened, hard chrome finish.

Item No. Inch: .050, 1/16, 5/64, 3/32, 7/64,

36998 1/8, 9/64, 5/32, 3/16, 7/32, 1/4, lbs. 1.0 5/16, 3/8"



66993 2 Pack Inch & Metric Ball End Hex L-key Sets

High alloy Chrome-V-Moly, hardened, hard chrome finish.

Item No. 2 Sets with 22 L-keys include:

66993 Metric: 1.5, 2.0, 2.5, 3.0, 4.0, 5.0,



6.0, 8.0, 10.0mm

lbs. 2.0 Inch: .050, 1/16, 5/64, 3/32, 7/64,

1/8, 9/64, 5/32, 3/16, 7/32, 1/4,

5/16, 3/8"

Inch & Metric Ball End Hex Keys Color Coded

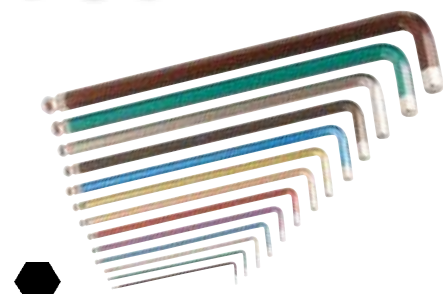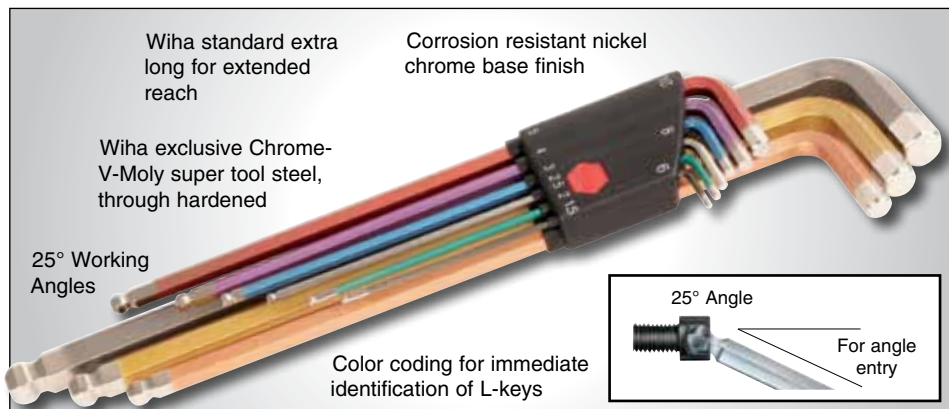

569 Ball End Inch Hex Long Arm L-key, Set With Color Coded Keys Blade Chrome-V-Moly, hardened.

Item No.	Color Key	Inch
56901	Brown	.050
56902	Green	1/16
56903	Chrome	5/64
56904	Blue	3/32
56905	Purple	7/64
56906	Red	1/8
56907	Copper	9/64
56908	Gold	5/32
56909	Blue	3/16
56910	Black	7/32
56911	Chrome	1/4
56912	Green	5/16
56913	Brown	3/8



36986 13 Pc. Inch Ball End Hex Long L-key Set With Color Coded Keys Chrome-V-Moly, hardened. lbs. .90

Item No.	Inch: .050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8"
36986	



569 Ball End Metric Hex Long Arm L-key, Set With Color Coded Keys Blade Chrome-V-Moly, hardened.

Item No.	Color Key	mm	mm	mm	lbs.
56914	brown	1.5	91	15	.005
56915	green	2.0	101	18	.009
56916	chrome	2.5	113	20	.017
56917	blue	3.0	128	23	.019
56918	purple	4.0	142	29	.04
56920	Copper	6.0	184	38	.10
56921	gold	8.0	206	44	.20
56922	grey	10.0	231	50	.38

Protturn Stainless Steel Ball End Hex L-Keys

Protturn Stainless Steel Made For Wiha



369 Stainless Steel Ball End Metric Hex L-key, Long Arm Hardened, hard chrome finish.

Item No.	mm	mm	mm	lbs.	pkg.
36911	1.5	91	14	.004	1
36913	2.0	101	18	.007	1
36914	2.5	113	20	.012	1
36915	3.0	128	23	.020	1
36917	4.0	142	29	.01	1
36918	5.0	163	33	.01	1
36919	6.0	184	38	.13	1
36921	8.0	206	44	.25	1
36922	10.0	231	50	.44	1



36988 9 Pc. Metric Ball End Hex Long L-key Set Stainless Steel lbs. 88

Item No.	Metric: 1.5, 2.0, 2.5, 3.0, 4.0, 5.0, 6.0, 8.0, 10.0mm
36988	

Stainless steel cannot be hardened to the same extent as high carbon tool steels. It will provide better protection against corrosion on fasteners and tools when used with stainless steel fasteners. Being softer, stainless steel will twist more & corners will round easier than other tool steels.



369 Stainless Steel Ball End Inch Hex L-key, Long Arm Hardened, hard chrome finish.


Item No.	Inch	mm	mm	lbs.	pkg.
36972	1/16	90	15	.01	1
36973	5/64	102	18	.01	1
36974	3/32	113	20	.01	1
36975	7/64	121	21	.01	1
36976	1/8	127	23	.02	1
36977	9/64	139	25	.04	1
36978	5/32	144	28	.04	1
36979	3/16	165	32	.06	1
36980	7/32	176	35	.10	1
36981	1/4	185	38	.14	1
36982	5/16	208	43	.22	1
36983	3/8	233	50	.36	1



36985 12 Pc. Inch Ball End Hex Long L-key Set Stainless Steel

Item No.	Inch: 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8"
36985	

Ball End Inch & Metric Hex L-Keys Black Finish

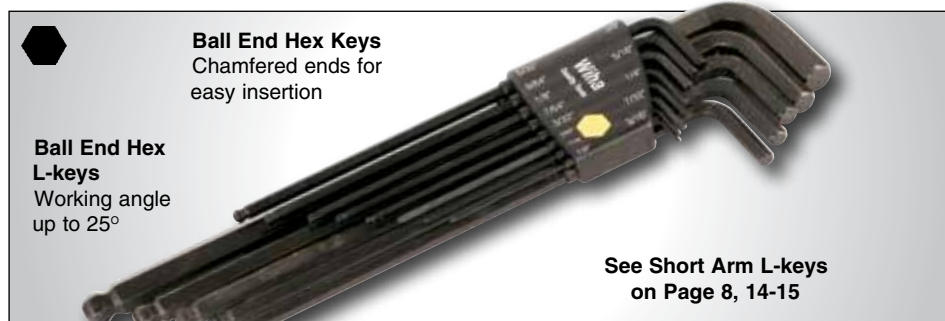

Ball End Hex Keys
Chamfered ends for
easy insertion

**Ball End Hex
L-keys**
Working angle
up to 25°

See Short Arm L-keys
on Page 8, 14-15



369 Ball End Hex Metric L-key, Long Arm
Blade Chrome-V-Moly, hardened, black finish.

Item No.	mm	mm	mm	lbs.	pkg.
36904	1.5	90	14	.004	10
36908	2.0	99	16	.007	10
36912	2.5	111	18	.012	10
36916	3.0	125	20	.019	10
36920	4.0	138	25	.042	10
36924	5.0	158	28	.072	10
36928	6.0	178	32	.12	10
36936	8.0	198	36	.23	10
36944	10.0	221	40	.40	10



36990 9 Pc. Metric Ball End Hex Long L-key Set Chrome-V-Moly, hardened, black finish.

Item No.	mm	mm	mm	mm	lbs.
36990	1.5	90	5.0	158	.98
	2.0	99	6.0	178	
	2.5	111	8.0	198	
	3.0	125	10.0	221	
	4.0	138			



36992 6 Pc. Metric Ball End Long Hex L-key Set Chrome-V-Moly, hardened, black finish.

Item No.	mm	mm	mm	mm	lbs.
36992	1.5	90	3.0	125	.30
	2.0	99	4.0	138	
	2.5	111	5.0	158	



369 Ball End Hex Inch L-key, Long Arm
Blade Chrome-V-Moly, hardened, black finish.

Item No.	Inch	Inch	Inch	lbs.	pkg.
36945	.050	2.8	.5	.002	10
36946	1/16	3.1	.6	.004	10
36947	5/64	3.5	.7	.007	10
36950	3/32	3.9	.7	.010	10
36952	7/64	4.3	.7	.016	10
36953	1/8	4.6	.8	.021	10
36955	9/64	5.2	.9	.029	10
36956	5/32	5.7	1.0	.035	10
36959	3/16	6.2	1.1	.059	10
36962	7/32	6.7	1.2	.092	10
36965	1/4	7.3	1.2	.13	10
36968	5/16	8.0	1.4	.22	10
36971	3/8	8.8	1.6	.36	10



36991 13 Pc. Inch Ball End Hex Long L-key Set Chrome-V-Moly, hardened, black finish.

Item No.	13 pc. set includes:
36991	.050, 1/16, 5/64, 3/32, 7/64,
lbs.	1/8, 9/64, 5/32, 3/16, 7/32,
1.0	1/4, 5/16, 3/8"



36993 8 Pc. Inch Ball End Hex Long L-key Set Chrome-V-Moly, hardened, black finish.

Item No.	8 pc. set includes:	lbs.
36993	5/64, 3/32, 1/8, 5/32, 3/16,	.62
	7/32, 1/4, 5/16"	

Inch &
Metric



36995 2 Pack Inch & Metric Ball End Hex L-key Sets High alloy Chrome-V-Moly, hardened, black finish.

Item No. 2 Sets with 22 L-keys include:

36995	Metric: 1.5, 2.0, 2.5, 3.0, 4.0, 5.0,
	6.0, 8.0, 10.0mm
lbs.	Inch: .050, 1/16, 5/64, 3/32, 7/64,
2.21	1/8, 9/64, 5/32, 3/16, 7/32, 1/4,
	5/16, 3/8"




Inch &
Metric

36696 3 Pack Inch & Metric Mid-Length Ball End Hex & TORX L-key Sets Blade Chrome-V-Moly, hardened, black finish.

Item No. 3 Sets Hex & TORX L-keys include:

36696	Metric: 1.5, 2.0, 2.5, 3.0, 4.0, 5.0,
	6.0, 8.0, 10.0mm
lbs.	Inch: .050, 1/16, 5/64, 3/32, 7/64, 1/8,
2.58	9/64, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8"
	TORX: T6, T7, T8, T9, T10, T15,
	T20, T25, T27, T30

 

**Ball End Hex
L-keys**
Working angle
up to 25°



369 Ball End Hex Inch Mid-Length

L-keys Chrome-V-Moly, hardened, black finish.

Item No.	 Inch	 Inch	 Inch	 lbs.	 pkg.
36901	.050	2.82	.45	.002	1
36902	1/16	3.05	.53	.004	1
36903	5/64	3.27	.63	.007	1
36905	3/32	3.43	.68	.010	1
36906	7/64	3.62	.76	.016	1
36907	1/8	3.84	.76	.021	1
36909	9/64	4.08	.87	.029	1
36910	5/32	4.36	.96	.035	1
36923	3/16	4.67	1.08	.059	1
36925	7/32	5.05	1.18	.092	1
36926	1/4	5.73	1.25	.13	1
36927	5/16	6.75	1.36	.22	1
36929	3/8	7.0	1.50	.36	1

10 Pack

Item No.	Inch	Inch	Inch	lbs.	pkg.
46701	.050	2.82	.45	.02	10
46703	1/16	3.05	.53	.04	10
46705	5/64	3.27	.63	.07	10
46707	3/32	3.43	.68	.10	10
46709	7/64	3.62	.76	.16	10
46711	1/8	3.84	.76	.21	10
46713	9/64	4.08	.87	.29	10
46717	5/32	4.36	.96	.35	10
46719	3/16	4.67	1.08	.59	10
46721	7/32	5.05	1.18	.92	10
46723	1/4	5.73	1.25	1.3	10
46727	5/16	6.75	1.36	2.2	10
46731	3/8	7.0	1.50	3.6	10



36937	13 Piece Inch Mid-Length Ball
-------	-------------------------------

End Hex L-key Set Blade Chrome-V-Moly, hardened, black finish.

Item No.	13 pc. set includes:	
36937	.050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8"	lbs. .88



369 Ball End Hex Metric Mid-Length

L-keys Chrome-V-Moly, hardened, black finish.

Item					
No.	mm	mm	mm	lbs.	pkg.
36930	1.5	79	13	.010	1
36931	2.0	84	15	.016	1
36932	2.5	90	17	.029	1
36933	3.0	100	19	.035	1
36934	4.0	113	24	.059	1
36935	5.0	123	26	.092	1
36938	6.0	144	31	.13	1
36939	8.0	159	35	.22	1
36966	10.0	181	37	.36	1

10 Pack

Item No.	mm	mm	mm	lbs.	pkg.
46732	1.5	79	13	.010	10
46733	2.0	84	15	.016	10
46734	2.5	90	17	.029	10
46735	3.0	100	19	.035	10
46736	4.0	113	24	.059	10
46737	5.0	123	26	.092	10
46738	6.0	144	31	.13	10
46739	8.0	159	35	.22	10
46741	10.0	181	37	.36	10



36999 9 Pc. **Metric** Mid-Length Ball End

Hex L-key Set Blade Chrome-V-Moly, hardened, black finish.	 lbs. .80
--	--

Item No.

36999 **Metric:** 1.5, 2.0, 2.5, 3.0,
4.0, 5.0, 6.0, 8.0, 10.0mm

Ball End Hex Keys Black Finish Short Arm



36989 9 Pc. Short Arm **Metric** Ball End Hex

L-key Set, In Plastic Holder Equipped with

1.5, 2.0, 2.5, 3.0, 4.0, 5.0, 6.0, 8.0, 10.0mm
 lbs. .59 pkg. 1

Notes:

Wiha PocketStar Fold-Ups

MagicRing



36997 9 Piece MagicRing Inch PocketStar Fold Outs High alloy CVM steel, hardened, molded ergonomic handle.  lbs. .46

Item No. 36997

Inch PocketStar: 5/64", 3/32", 7/64"
1/8, 9/64, 5/32, 3/16, 7/32, 1/4"

* Standard Ball - No Ring



36996 7 Piece MagicRing Metric PocketStar Fold Outs High alloy CVM steel, hardened, molded ergonomic handle.  lbs. .50

Item No. 36996 PocketStar

Metric: 2.0*, 2.5*, 3.0, 4.0, 5.0, 6.0, 8.0mm

* Standard Ball - No Ring



66997 2 Pack MagicRing PocketStar Fold Outs Inch & Metric High alloy CVM steel, hardened, molded ergonomic handle.  lbs. .98

Item No. 66997

Fold Outs Inch/Metric Includes:

36996 - 2.0*, 2.5*, 3.0, 4.0, 5.0, 6.0, 8.0mm
36997 - 5/64", 3/32", 7/64", 1/8, 9/64, 5/32, 3/16, 7/32, 1/4"

* Standard Ball - No Ring

Wiha MagicRing Screw Holding T-handle



Screw Holding Hex Tools

Hole for hanging

Proportioned ergonomic handle designed for high torque

Blade Wiha exclusive Chrome-V-Moly super tool steel, hardened, hard chrome finish

Smooth edges prevent injuries & eliminate pressure marks

Handle is molded directly onto blade

540 MagicRing Hex Metric Ball End, With Wiha T-handle Blade Chrome-V-Moly, hardened, hard chromed. Ball end for easy insertion. Wiha T-handle high quality plastic, impact resistant.

Item No.	mm	mm	mm	mm	lbs.	pkg.
54040	4.0	150	80	176	.08	10
54050	5.0	150	100	182	.14	10
54060	6.0	150	100	182	.17	10
54080	8.0	200	100	232	.29	10
54086	10.0	200	120	238	.49	10



54090 5 Piece MagicRing Ball End T-handle Set, Metric Sizes

Blade Chrome-V-Moly, hardened, hard chromed. Wiha T-handle high quality plastic, impact resistant.

Item No.	Metric:	lbs.
54090	4.0, 5.0, 6.0, 8.0, 10.0mm	1.37

540 MagicRing Hex Inch Ball End, With Wiha T-handle Blade Chrome-V-Moly, hardened, hard chromed. Ball end for easy insertion. Wiha T-handle high quality plastic, impact resistant.

Item No.	Inch	Inch	Inch	Inch	lbs.	pkg.
54012	5/32	5.8	2.8	6.9	.08	10
54014	3/16	5.8	4.0	7.2	.14	10
54016	7/32	5.8	4.0	7.2	.16	10
54018	1/4	5.8	4.0	7.2	.19	10
54022	5/16	7.8	4.0	9.3	.29	10
54024	3/8	7.8	4.7	9.3	.45	10



54091 6 Piece MagicRing Ball End T-handle Set, Inch Sizes

Blade Chrome-V-Moly, hardened, hard chromed. Wiha T-handle high quality plastic, impact resistant.

Item No.	Inch:	lbs.
54091	5/32, 3/16, 7/32, 1/4, 5/16, 3/8"	1.49

Wiha Soft Grip Dual Drive T-handle - Chrome Finish



540 Soft Grip Ball End Hex Metric Dual Drive T-handle

Item	Hex	mm	mm	Tip	lbs.	pkg.
No.		mm	mm	Tip	lbs.	pkg.
54020		2.0	150	Ball	.06	10
54025		2.5	150	Ball	.06	10
54030		3.0	150	Ball	.07	10
54042		4.0	150	Ball	.09	10
54052		5.0	150	Ball	.18	10
54062		6.0	150	Ball	.21	10
54082		8.0	200	Ball	.35	10
54088		10.0	200	Ball	.55	10

54095 8 Pc. Ball End Hex Metric Soft Grip T-handle Set- No stand

Item	Metric:	lbs.
No.	2.0, 2.5, 3.0, 4.0, 6.0,	lbs.
54095	5.0, 8.0, 10.0mm	1.90



54092 8 Piece Ball End Hex Metric Soft Grip T-handle Set

Blade Chrome-V-Moly, hardened, chrome finish. Wiha soft grips are molded on with through the handle side torque drive.

Item	Metric:	lbs.
No.	2.0, 2.5, 3.0, 4.0,	lbs.
54092	5.0, 6.0, 8.0, 10.0mm	3.34




540 Soft Grip Ball End Hex Inch Dual Drive T-handle Chrome-V-Moly, hardened, hard chrome finish. Ball tip for speed & easy insertion. Wiha soft grips are molded on with through the handle side torque drive.

Item					
No.	Inch	Inch	Tip	lbs.	pkg.
54007	3/32	5.9	Ball	.06	10
54008	7/64	5.9	Ball	.07	10
54009	1/8	5.9	Ball	.08	10
54010	9/64	5.9	Ball	.08	10
54001	5/32	5.9	Ball	.09	10
54002	3/16	5.9	Ball	.17	10
54003	7/32	5.9	Ball	.20	10
54004	1/4	5.9	Ball	.23	10
54005	5/16	7.9	Ball	.35	10
54006	3/8	7.9	Ball	.51	10

54097 10 Pc. Ball End Hex Inch Soft Grip T-handle Set- No stand

Item	Inch: 3/32, 7/64,	lbs.
No.	1/8, 9/64, 5/32, 3/16,	lbs.
54097	7/32, 1/4, 5/16, 3/8"	2.15

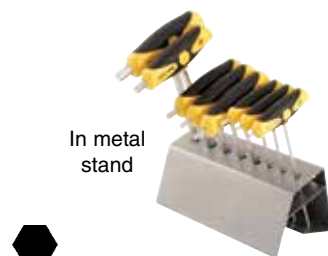

54094 8 Piece Ball End Hex Inch Soft Grip T-handle Set Blade Chrome-V-Moly, hardened, chrome finish. Wiha soft grips are molded on with through the handle side torque drive.

Item	Inch:	lbs.
No.	1/8, 9/64, 5/32, 3/16,	lbs.
54094	7/32, 1/4, 5/16, 3/8"	3.37

54094 8 Piece Ball End Hex Inch Soft Grip T-handle Set

Blade Chrome-V-Moly, hardened, chrome finish. Wiha soft grips are molded on with through the handle side torque drive.

Item	Inch:	lbs.
No.	1/8, 9/64, 5/32, 3/16,	lbs.
54094	7/32, 1/4, 5/16, 3/8"	3.37

Soft Grip Dual Drive T-handle Black Finish



334 Soft Grip Ball End Hex Metric Dual Drive T-handle Chrome-V-Moly, hardened, black finish. Ball tip for speed & easy insertion. Wiha soft grip are molded on with through the handle side torque drive.

Item	Hex	mm	mm	lbs.	pkg.
No.		mm	mm	lbs.	pkg.
33442*		2.0	150	.06	10
33444*		2.5	150	.06	10
33446*		3.0	150	.07	10
33448		4.0	150	.09	10
33450		5.0	150	.18	10
33452		6.0	150	.21	10
33454		8.0	200	.35	10
33458		10.0	200	.55	10

*No Ball - Standard Hex




33496 8 Pc. Ball End Hex Metric Soft Grip T-handle Set

Blade Chrome-V-Moly, hardened, black finish. Wiha soft grip are molded on with through the handle side torque drive.

Item	Metric:	lbs.
No.	2.0*, 2.5*, 3.0*, 4.0,	lbs.
33496	5.0, 6.0, 8.0, 10.0mm	2.04

*No Ball - Standard Hex

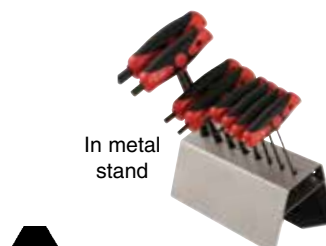


33489 8 Piece Hex & Ball End Hex Metric Soft Grip T-handle Set

Blade Chrome-V-Moly, hardened, black finish. Wiha soft grips are molded on with through the handle side torque drive.

Item	Metric:	lbs.
No.	2.0*, 2.5*, 3.0*, 4.0,	lbs.
33489	5.0, 6.0, 8.0, 10.0mm	3.33

*No Ball - Standard Hex

Soft Grip Dual Drive T-handle Black Finish

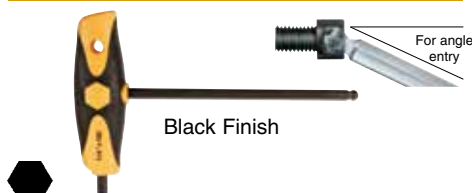

Black Finish

334 Soft Grip Ball End Hex Inch Dual

Drive T-handle Chrome-V-Moly, hardened, black finish. Ball tip for speed & easy insertion. Wiha soft grips are molded on with through the handle side torque drive.

Item	No.	Inch	Inch	lbs.	pkg.
33418*	5/64	5.9	.06	10	
33420*	3/32	5.9	.06	10	
33422*	7/64	5.9	.07	10	
33424*	1/8	5.9	.08	10	
33426*	9/64	5.9	.08	10	
33428	5/32	5.9	.09	10	
33430	3/16	5.9	.17	10	
33432	7/32	5.9	.20	10	
33433	1/4	5.9	.23	10	
33439	5/16	7.9	.35	10	
33440	3/8	7.9	.51	10	

*No Ball - Standard Hex

33494 11 Pc. Ball End Hex Inch Soft Grip Dual Drive T-handle Set

Item	No.	Inch: 5/64*, 3/32*, 7/64*, 1/8*, 9/64*, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8"	lbs.
33494			2.39

*No Ball - Standard Hex

33498 8 Pc. Ball End Hex Inch Soft Grip Dual Drive T-handle Set

Item	No.	Inch: 1/8*, 9/64*, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8"	lbs.
33498			2.15

*No Ball - Standard Hex


In metal
stand

33499 8 Piece Hex & Ball End Hex Inch Soft Grip T-handle Set

Blade Chrome-V-Moly, hardened, black finish. Wiha soft grips are molded on with through the handle side torque drive.

Item	No.	Inch: 1/8*, 9/64*, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8"	lbs.
33499			3.46

*No Ball - Standard Hex

Wiha T-handle Hex Tools

Ergonomic handle design for high torque

Hole for
hanging

Blade Wiha
exclusive
Chrome-V-Moly
super tool
steel hardened,
nickel-plated



Smooth edges prevent
injuries & eliminate
pressure marks

Yellow = Inch
Red = Metric

334 Hex Inch & Metric Drivers, With Wiha T-handle

Chamfered tip for easy insertion.

T-handle high quality plastic, impact resistant.

Item	No.	Inch	Inch	Inch	Inch	lbs.	pkg.
33453	3/32	6.0	2.8	7.0	.05	10	
33456	7/64	6.0	2.8	7.0	.05	10	
33459	1/8	6.0	2.8	7.0	.06	10	
33462	9/64	6.0	2.8	7.0	.07	10	
33465	5/32	6.0	2.8	7.0	.08	10	
33468	3/16	6.0	3.5	7.0	.13	10	
33471	7/32	6.0	3.5	7.0	.16	10	
33474	1/4	6.0	3.5	7.0	.18	10	
33477	5/16	6.0	3.5	7.0	.25	10	
33480	3/8	6.0	4.1	7.0	.39	10	
Item	No.	mm	mm	mm	mm	lbs.	pkg.
33401	2.0	100	80	126	.05	10	
33436	2.0	200	80	226	.05	10	
33402	2.5	100	80	126	.05	10	
33437	2.5	200	80	226	.08	10	
33403	3.0	100	80	126	.05	10	
33404	3.0	150	80	176	.08	10	
33405	3.0	200	80	226	.09	10	
33435	3.0	350	100	382	.22	10	
33406	4.0	100	80	126	.07	10	
33407	4.0	150	80	176	.10	10	
33408	4.0	200	80	226	.09	10	
33438	4.0	350	100	382	.26	10	
33409	5.0	100	100	132	.13	10	
33410	5.0	150	100	182	.17	10	
33411	5.0	200	100	232	.16	10	
33412	5.0	350	100	382	.26	10	
33413	5.0	450	120	488	.53	10	
33414	6.0	100	100	132	.14	10	
33415	6.0	150	100	182	.18	10	
33416	6.0	200	100	232	.20	10	
33417	6.0	350	100	382	.32	10	
33419	7.0	200	100	232	.22	10	
33421	8.0	100	100	132	.20	10	
33423	8.0	200	100	232	.29	10	
33434	8.0	350	100	372	.48	10	
33425	10.0	100	120	138	.34	10	
33427	10.0	200	120	238	.49	10	
33429	12.0	200	120	238	.58	10	



33492 10 Pc. Hex Driver T-handle Set, Inch Sizes

Item	No.	Inch: 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8"	lbs.
33492			1.74



33493 8 Pc. Hex Driver T-handle Set, Metric Sizes

Item	No.	Metric: 2.0, 2.5, 3.0, 4.0, 5.0, 6.0, 8.0, 10.0mm	lbs.
33493			1.64



33484 8 Pc. Hex Driver T-handle Set, Inch Sizes - In metal stand

Item	No.	Inch: 1/8, 9/64, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8"	lbs.
33484			3.07

33488 8 Pc. Hex Driver T-handle Set, Metric Sizes - In metal stand

Item	No.	Metric: 2.0, 2.5, 3.0, 5.0, 6.0, 8.0mm	lbs.
33488			3.07

Wiha MagicRing SoftFinish® Inch & Metric Hex Drivers

Screw Holding Hex Tools

Cushioned grip and extra large diameter to achieve high torque

Screw Holding



molded on handle for permanent bond

Flat surfaces give roll-off protection



Hard Chrome Finish

367 MagicRing Ball End Hex-Driver Inch, With Wiha-SoftFinish® Handle Hex blade, Chrome-V-Moly, hardened, hard chromed. Wiha-SoftFinish® handle, multi-component, cushion grip.

Item No.	Inch	Inch	mm	mm	lbs.	pkg.
36710*	.050	3.1	80	179	.06	10
36713*	1/16	3.1	80	204	.06	10
36716*	5/64	3.9	100	204	.07	10
36719*	3/32	3.9	100	204	.07	10
36723*	7/64	3.9	100	211	.07	10

With MagicRing

36726	1/8	3.9	100	243	.12	10
36728	9/64	3.9	100	243	.12	10
36732	5/32	5.0	125	271	.12	10
36734	3/16	6.0	150	271	.16	10
36736	7/32	6.0	150	271	.23	10
36738	1/4	6.0	150	271	.25	10
36742	5/16	8.0	200	271	.37	10
36744	3/8	8.0	200	271	.54	10

* Standard Ball - No Ring



36793 8 Pc. MagicRing Inch Ball End Screwdriver Set Hex blade Chrome-V-Moly, hardened, hard chromed. Wiha-SoftFinish® handle, multi-component, cushion grip.

Item No.	Inch: 1/8, 9/64, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8"	lbs.
36793		2.25

Don't Drop That Screw!
Save Valuable Time!
Improve Productivity!
Make The Job Easy!



36791 13 Piece MagicRing Inch Ball End Screwdriver Set Hex blade Chrome-V-Moly, hardened, hard chromed. Wiha-SoftFinish® handle, multi-component, cushion grip.

Item No.	Inch: .050*, 1/16*, 5/64*, 3/32*, 7/64*, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8"	lbs.
36791		2.58

* Standard Ball - No Ring



36794 6 Piece MagicRing Inch Ball End Screwdriver Set Hex blade Chrome-V-Moly, hardened, hard chromed. Wiha-SoftFinish® handle, multi-component, cushion grip.

Item No.	Inch: 1/8, 9/64, 5/32, 3/16, 7/32, 1/4"	lbs.
36794		1.34

Hardened spring steel retaining ring holds screws on

Hard chrome super durable corrosion resistant finish

Precision machined for exact fit

Made from Wiha exclusive Chrome-V-Moly hardened tool steel



Hard Chrome Finish

367 MagicRing Ball End Hex Driver Metric, With Wiha-SoftFinish® Handle

Hex blade, Chrome-V-Moly, hardened, hard chromed. Wiha-SoftFinish® handle, multi-component, cushion grip.

Item No.	mm	mm	mm	lbs.	pkg.
36715*	1.5	75	179	.06	10
36720*	2.0	100	204	.07	10
36725*	2.5	100	204	.07	10

With MagicRing

36730	3.0	100	204	.07	10
36740	4.0	125	211	.12	10
36750	5.0	150	243	.16	10
36760	6.0	150	243	.23	10
36780	8.0	200	268	.37	10
36786	10.0	200	271	.54	10

* Standard Ball - No Ring



36790 9 Piece MagicRing Metric Ball End Hex Screwdriver Set Hex blade Chrome-V-Moly, hardened, hard chromed. Wiha-SoftFinish® handle, multi-component, cushion grip.

Item No.	Metric: 1.5*, 2.0*, 2.5*, 3.0, 4.0, 5.0, 6.0, 8.0, 10.0mm	lbs.
36790		2.06


* Standard Ball - No Ring



36792 6 Pc. MagicRing Metric Ball End Hex Screwdriver Set Hex blade Chrome-V-Moly, hardened, hard chromed. Wiha-SoftFinish® handle, multi-component, cushion grip.

Item No.	Metric: 3.0, 4.0, 5.0, 6.0, 8.0, 10.0mm	lbs.
36792		1.86

 Wiha Ball End 3K Series Drivers & Sets



Inch / Soft Grip

467 Ball End Hex Inch Drivers, 3K Ergo


Soft Grip Handles Blades Chrome-V-Moly, hardened, black finish. Ergo soft grip handles.

Item					
No.	Inch	Inch	Inch	lbs.	pkg.
46702	.050	2.9	6.3	.07	10
46704	1/16	2.9	6.3	.07	10
46706	5/64	3.9	7.3	.07	10
46708	3/32	3.9	7.3	.07	10
46710	7/64	3.9	7.3	.07	10
46712	1/8	3.9	7.7	.09	10
46714	9/64	3.9	7.7	.10	10
46716	5/32	3.9	7.7	.11	10
46722	7/32	5.9	10.0	.19	10
46724	1/4	5.9	10.0	.22	10
46726	5/16	7.9	12.0	.34	10




**46794 6 Pc. 3K Ergo Inch Ball End Hex
Screwdriver set**

Item No.	Inch: 1/8, 9/64, 5/32,  lbs.
46794	3/16, 7/32, 1/4" .97

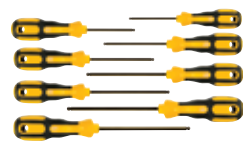

46793 8 Piece 3K Ergo Inch Ball End Hex Screwdriver Set

Item No.	Inch: .050, 1/16,	
46793	5/64, 3/32, 7/64,	lbs.
	1/8, 9/64, 5/32"	1.19

 

- Soft panel grip
- Fast angle entry
- Convenient hang hole
- Exact fit precision machined tips
- Wiha exclusive Chrome-V-Moly super tool steel



Metric / Soft Grip

467 Ball End Hex **Metric** Screwdriver,
With Wiha-3K Ergo Soft Grip Handle

Blades Chrome-V-Moly, hardened, black finish.

Item					
No.	mm	mm	mm	lbs.	pkg.
46715	1.5	75	161	.07	10
46720	2.0	100	186	.07	10
46725	2.5	100	186	.07	10
46730	3.0	100	186	.07	10
46740	4.0	100	197	.11	10
46750	5.0	100	197	.13	10
46760	6.0	150	257	.21	10
46780	8.0	200	307	.34	10
46786	10.0	200	319	.52	10

Wiha PocketStar Fold-Ups




35195 7 Pc. **Metric** Hex PocketStar Fold

Outs High alloy CVM steel, hardened, molded ergonomic handle.

Item No.	PocketStar	
35195	Metric: 2.0, 2.5, 3.0, 4.0, 5.0, 6.0, 8.0mm	lbs. .51

35196 7 Pc. **Metric** Hex PocketStar Fold Outs

Item No.	PocketStar	
35196	Metric: 1.5, 2.0, 2.5, 3.0, 4.0, 5.0, 6.0mm	lbs. .31

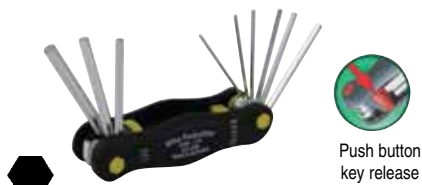

35197 9 Pc. Inch Hex PocketStar Fold

Outs High alloy CVM steel, hardened, molded ergonomic handle.

Item	Inch PocketStar: 5/64,
No.	3/32, 7/64, 1/8, 9/64, lbs.
35197	5/32, 3/16, 7/32, 1/4" .47

Notes:

Black Finish Long Arm Hex L-keys



Black Finish

High alloy CVM steel, hardened, black finish. Prec machined, burr free chamfered ends.

352 Inch L-key Hex, Long Arm

Item No.	Inch	mm	Inch	lbs.	pkg.
35200	.028	66	2.6	.01	10
35203	.035	68	2.7	.01	10
35213	.050	75	3.0	.01	10
35216	1/16	78	3.1	.01	10
35218	5/64	82	3.2	.01	10
35222	3/32	85	3.3	.01	10
35224	7/64	92	3.6	.02	10
35226	1/8	95	3.7	.02	10
35228	9/64	100	3.9	.03	10
35232	5/32	105	4.1	.04	10
35234	3/16	113	4.4	.05	10
35236	7/32	122	4.8	.07	10
35242	5/16	152	6.0	.18	10
35245	1/2	209	8.2	.75	1
35246	9/16	230	9.1	.99	1
35248	3/4	286	11.3	2.02	1
35249	1"	359	14.1	4.38	1

Item No.	mm	mm	mm	lbs.	pkg.
35200	0.7	66	5	.01	10
35203	0.9	68	8	.01	10
35205	1.3	72	12	.01	10
35215	1.5	76	14	.01	10
35220	2.0	99	16	.01	10
35225	2.5	110	18	.02	10
35230	3.0	124	20	.02	10
35240	4.0	138	25	.04	10
35250	5.0	158	28	.07	10
35260	6.0	178	32	.12	10
35270	7.0	187	34	.18	10
35280	8.0	196	36	.24	10
35282	10.0	219	40	.40	10
35284	12.0	245	45	.77	1
35286	17.0	316	63	1.80	1
35288	19.0	355	70	2.45	1



In Plastic Holder

Black Finish

35290 9 Pc. Metric Hex L-key Set

1.5, 2.0, 2.5, 3.0, 4.0, 5.0, 6.0, 8.0, 10.0mm

Item No.	lbs.	pkg.
35290	.97	1

Nickel-Plated Long Arm Hex L-keys



Nickel-Plated

• Ideal for use in clean rooms & other environments where non-oxidizing surfaces are specified or required.

352 Inch Inch & Metric Hex Long L-keys

Item No.	Inch	mm	Inch	lbs.	pkg.
35231	.050	75	3.0	.01	10
35233	1/16	78	3.1	.01	10
35235	5/64	82	3.2	.01	10
35237	3/32	85	3.3	.01	10
35239	7/64	92	3.6	.01	10
35241	1/8	95	3.7	.02	10
35243	9/64	100	3.9	.03	10
35251	5/32	105	4.1	.03	10
35252	3/16	113	4.4	.05	10
35253	7/32	122	4.8	.07	10
35254	1/4	135	5.3	.10	10
35255	5/16	152	6.0	.18	10
35256	3/8	173	6.8	.30	10
35257	1/2	209	8.2	.77	1
35258	9/16	230	9.1	1.04	1
35259	5/8	245	9.6	1.27	1
35261	3/4	286	11.3	2.01	1

Item No.	mm	mm	mm	lbs.	pkg.
35201	1.5	89	14	.01	10
35202	2.0	99	16	.01	10
35204	2.5	110	18	.02	10
35206	3.0	124	20	.02	10
35208	4.0	138	25	.04	10
35210	5.0	158	28	.07	10
35211	6.0	178	32	.12	10
35212	7.0	187	34	.17	10
35214	8.0	196	36	.23	10
35217	10.0	219	40	.40	10
35223	17.0	316	63	1.80	1
35227	19.0	355	70	2.46	1

Nickel-Plated



In Plastic Holder

35295 13 Pc. Inch Hex L-key Set

.050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8"

Item No.	lbs.	pkg.
35295	.90	1

Nickel-Plated



In Plastic Holder


35297 9 Pc. Metric Hex L-key Set

1.5, 2.0, 2.5, 3.0, 4.0, 5.0, 6.0, 8.0, 10.0mm

Item No.	lbs.	pkg.
35297	1.00	1

Short Arm Hex L-keys

 Nickel-Plated



• Ideal for use in clean rooms & other environments where non-oxidizing surfaces are specified or required.

351 Metric L-key Hex Metric, Short Arm

high alloy CVM steel, hardened, nickel plated. Precision machined, burr free chamfered ends.

Item No.	mm	mm	mm	lbs.	pkg.
35112	2.5	57	18	.01	10
35116	3.0	64	25	.02	10
35120	4.0	72	25	.03	10
35124	5.0	83	28	.04	10
35128	6.0	94	32	.07	10
35132	7.0	99	34	.10	10
35136	8.0	105	36	.13	10
35140	9.0	112	38	.18	10
35144	10.0	119	40	.23	10
35145	12.0	134	45	.40	1
35175	14.0	151	55	.61	1
35177	17.0	173	60	1.02	1
35179	19.0	195	70	1.40	1

351 Inch L-key Hex, Short Arm

Item No.	Inch	Inch	Inch	lbs.	pkg.
35143	.050	1.6	.39	.01	10
35146	1/16	1.8	.55	.01	10
35147	5/64	2.0	.63	.01	10
35150	3/32	2.1	.75	.01	10
35152	7/64	2.1	.75	.01	10
35153	1/8	2.3	.83	.02	10
35155	9/64	2.4	.91	.02	10
35156	5/32	2.7	.99	.02	10
35159	3/16	2.8	1.0	.04	10
35162	7/32	3.1	1.2	.05	10
35165	1/4	3.5	1.2	.08	10
35171	3/8	4.2	1.5	.20	10
35174	1/2	5.8	1.7	.46	1
35176	9/16	6.2	2.5	.64	1
35178	5/8	6.9	2.8	.85	1
35180	3/4	7.8	3.5	1.40	1



Nickel-Plated

35299 20 Pc. Inch Hex L-key Set -

Nickel Plated .050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8, 1/4, 5/16, 3/8, 1/2, 9/16, 5/8, 3/4"

Item No.	lbs.	pkg.
35299	5.96	1

Short Arm Hex L-keys

Nickel-Plated



35191 9 Piece Metric Hex L-key Set, In Plastic Holder Equipped with 1.5, 2.0, 2.5, 3.0, 4.0, 5.0, 6.0, 8.0, 10.0mm

 lbs. .59 pkg. 1

Nickel-Plated



35193 6 Piece **Metric** Hex L-key Set, In Plastic Holder Equipped with 1.5, 2.0, 2.5, 3.0, 4.0, 5.0mm

 lbs .20 pkg. 1

Nickel-Plated



35192 8 Piece Inch Hex L-key Set, In Plastic Holder Equipped with 5/64, 3/32, 1/8, 5/32, 3/16, 7/32, 1/4, 5/16"

 lbs. .41 pkg. 1

Nickel-Plated




35194 13 Piece Inch Hex L-key Set, In Plastic Holder Equipped with .050 - 3/8"

 lbs .72 pkg. 1

Short Arm Hex L-keys - Black Finish

Black Finish

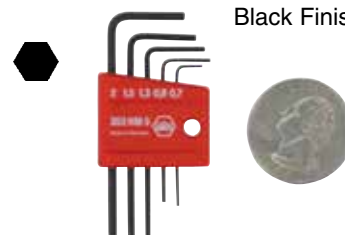

Black Finish

35390 9 Piece Metric Hex L-key Set

1.5, 2.0, 2.5, 3.0, 4.0, 5.0, 6.0, 8.0, 10.0mm

 lbs. .59 pkg. 1


Black Finish



35391 13 Piece Inch Hex L-key Set
.050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64.

5/32, 3/16, 7/32, 1/4, 5/16,
 lbs. .64  pkg. 1

Black Finish

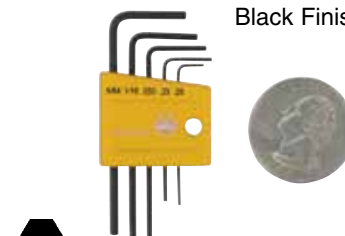

35393 5 Piece Mini Inch Hex L-key Set

Equipped with .028, .035, .050, 1/16, 5/64"

Notes:

Wiha Insulated T-handles

Insulation Test Standards:

Insulation according to EN/IEC 60900, ASTM F-1505-10, VDE 0682/part 201, DIN 7437, NFPA70E, CSA

Responds to OSHA's use specification 29 CFR1910

Insulation

Molded directly onto blade for permanent bonding

Blade CVM tool steel, hardened to average 58/60RC

1000V

Each tool individually tested to 10,000 volts and certified to 1000 Volt ac or 1500 Volt dc



1000V

334 Inch T-handle, With Wiha-Molded Handle Insulation According to ASTM F-1505-10, New VDE Specification 0682/part 201, EN/IEC 60900, NFPA70E and CSA, up to 1000 Volt. Individually Tested.

Blade CVM steel, hardened. Insulation molded directly onto blade. Wiha-SoftFinish® handle, multi-component.

Item						
No.	Inch	Inch	Inch	mm	lbs.	pkg.
33481	5/32	5.9	6.9	176	.09	10
33482	3/16	5.9	6.9	176	.15	10
33483	7/32	5.9	6.9	176	.19	10
33485	1/4	5.9	6.9	176	.20	10
33486	5/16	5.9	6.9	176	.26	10
33487	3/8	5.9	6.9	176	.44	10



1000V

334 Metric T-handle, With Wiha-Molded Handle. Insulation According to ASTM, VDE, EN/IEC, NFPA70E and CSA, up to 1000 Volt. Individually Tested.

Item						
No.	mm	mm	mm	lbs.	pkg.	
33441	4.0	150	176	.09	10	
33443	5.0	150	176	.15	10	
33445	6.0	150	176	.18	10	
33447	8.0	150	176	.26	10	
33449	10.0	150	176	.46	10	



1000V

33490 6 Piece Hex Inch T-handle Set

Item	Hex Inch:	
No.	5/32, 3/16, 7/32,	lbs.
33490	1/4, 5/16, 3/8"	1.66



1000V

33478 5 Piece Hex Metric T-handle Set

Item	Hex Metric:	
No.	4.0, 5.0, 6.0,	lbs.
33478	8.0, 10.0mm	1.20

Wiha Insulated Hex Metric Screwdrivers



1000V

323 Hex Metric Screwdriver, With Wiha-SoftFinish® Handle Insulation According to ASTM F-1505-10, New VDE Specification 0682/part 201 and EN/IEC 60900, NFPA70E & CSA, up to 1000 Volt. Individually Tested. Blade high alloy CVM steel, hardened, black finish. Insulation molded directly onto blade. Wiha-SoftFinish® handle, multi-component, cushion grip.

Item						
No.	Size	mm	mm	lbs.	pkg.	
32302	2.5	75	179	.06	10	
32303	3.0	75	179	.08	10	
32304	4.0	75	186	.12	10	
32305	5.0	75	186	.15	10	
32306	6.0	100	218	.21	10	
32308	8.0	100	218	.34	10	



1000V


32366 6 Piece Insulated Hex Metric Screwdriver Set

Item	Hex Metric:	
No.	2.5, 3.0, 4.0,	lbs.
32366	5.0, 6.0, 8.0mm	1.06

Wiha Insulated Inch & Metric Hex L-keys

Insulation Test Standards:

Insulation according to ASTM,
EN/IEC & CSA

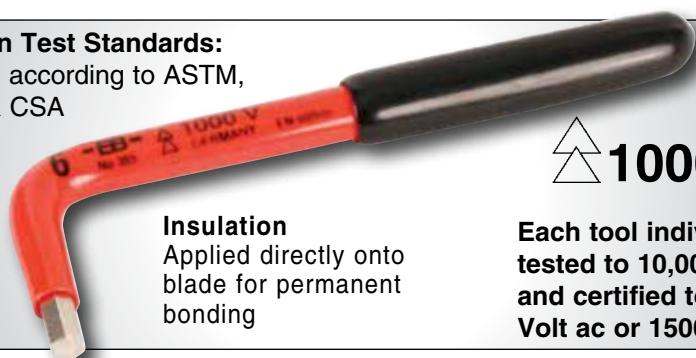

1000V

Insulation
Applied directly onto
blade for permanent
bonding

Each tool individually
tested to 10,000 volts
and certified to 1000
Volt ac or 1500 Volt dc

136 Inch Insulated Hex L-keys, With Insulated Handle Insulation According to IEC 60900 specification, up to 1000 Volt.

Individually Tested. Blade chrome-vanadium
steel, hardened.

Item						
No.	Inch	mm	Inch	mm	lbs.	
13670	1/16	79	3.1	.375	.05	
13671	5/64	84	3.3	.50	.05	
13672	3/32	89	3.5	.625	.05	
13673	7/64	94	3.7	.625	.06	
13663	1/8	104	4.1	1.0	.06	
13665	5/32	104	4.1	1.0	.06	
13666	3/16	134	5.3	1.25	.10	
13667	7/32	134	5.3	1.5	.12	
13668	1/4	134	5.3	1.5	.16	
13669	5/16	144	5.7	1.5	.24	
13662	3/8	234	9.2	1.63	.51	
13664	1/2	234	9.2	1.63	.77	



1000V

13690 8 Pc. Insulated Hex L-key Set - Inch

Item	Inch:	
No.	1/8, 5/32, 3/16, 7/32,	lbs.
13690	1/4, 5/16, 3/8, 1/2"	2.17



1000V

136 Metric Insulated Hex L-keys, With Insulated Handle Insulation According to IEC 60900 specification, up to 1000 Volt.

Individually Tested. Blade chrome-vanadium
steel, hardened.

Item						
No.	mm	mm	Inch	mm	lbs.	
13650	1.5	100	3.9	.50	.09	
13651	2.0	105	4.1	.50	.09	
13652	2.5	115	4.5	.625	.09	
13653	3.0	130	5.1	.75	.10	
13654	4.0	120	4.7	1.125	.10	
13655	5.0	140	5.5	1.375	.10	
13656	6.0	140	5.5	1.375	.13	
13658	8.0	150	5.9	1.375	.24	
13659	10.0	220	8.7	1.375	.51	
13657	12.0	260	10.2	1.625	.77	



1000V

13691 7 Pc. Insulated Hex L-key Set- Metric

Item	Metric:	
No.	3.0, 4.0, 5.0, 6.0,	lbs.
13691	8.0, 10.0, 12.0mm	2.07

13693 10 Piece Insulated Hex Metric L-key Set

Item	Metric: 1.5, 2.0, 2.5,	
No.	3.0, 4.0, 5.0, 6.0,	lbs.
13693	8.0, 10.0, 12.0mm	2.26

13694 12 Pc. Insulated Hex Inch L-key Set

Item	Inch: 1/16, 5/64,	
No.	3/32, 7/64, 1/8,	lbs.
13694	5/32, 3/16, 7/32,	lbs.
	1/4, 5/16, 3/8, 1/2"	2.40

Wiha Insulated 3/8" Bit Sockets & Set



1000V

318 Insulated 3/8" Drive Sockets - Insulation according to EN/IEC 60900, DIN 7448 specification, up to 1000 Volt.

Individually Tested. Chrome-vanadium steel,
forged, oil-hardened.

Item					
No.	Inch	OAL	lbs.	pkg.	
31805	3/16	3.1"	.13	1	
31807	7/32	3.1"	.14	1	
31809	1/4	3.1"	.14	1	
31811	5/16	3.1"	.16	1	
31813	3/8	3.1"	.18	1	
31815	7/16	3.1"	.20	1	
31817	1/2	3.1"	.22	1	

*Sockets must be used with insulated ratchets & extensions



1000V

31890 7 Pc. Insulated 3/8" Drive Socket

**Set - Inch CV steel, forged, oil-hardened
sockets. Insulated to EN/IEC 60900.**

Item	Inch:	
No.	3/16, 7/32, 1/4, 5/16,	lbs.
31890	3/8, 7/16, 1/2"	1.7

Wiha Insulated 1/2" Bit Sockets & Set



1000V

318 Insulated 1/2" Drive Sockets Chrome-vanadium steel, forged, oil-hardened.

Item					
No.	Inch	OAL	lbs.	pkg.	
31830	1/4	2.75	.22	1	
31832	5/16	2.75	.24	1	
31834	3/8	2.75	.25	1	
31836	7/16	3.63	.31	1	
31838	1/2	3.63	.34	1	
31840	9/16	3.63	.36	1	
31842	5/8	3.63	.42	1	
31844	3/4	3.63	.51	1	

*Sockets must be used with insulated ratchets & extensions

Wiha Power Blades



76000 CentroFix Cushion Grip Blade Holder

Wiha-SoftFinish® impact resistant, with roll off protection. Quick release bit holder with magnet.

Item					
No.	mm	mm	Inch	mm	Inch lbs.
76000	6.0	149	5.9	34.6	1.36 .26



760 Security Hex Metric Power Blades

S2 modified tool steel. Hardened & tempered to HRC 60. Blades fit CentroFix power blade handle. OAL 90mm/3.5".

Item				
No.	mm	lbs.	pkg.	
76001	2.5	.02	1	
76002	3.0	.02	1	
76003	4.0	.03	1	
76004	5.0	.04	1	



76090 4 Piece Security Hex Blade Set

Item		Set includes:
No.	lbs.	Metric: 2.5, 3.0,
76090	.12	4.0, 5.0 x 90mm



760 Security Hex Inch Power Blades

OAL 90mm/3.5".

Item				
No.	Inch	lbs.	pkg.	
76045	1/16*	.01	1	
76046	5/64	.01	1	
76047	3/32	.02	1	
76048	7/64	.02	1	
76049	1/8	.03	1	
76050	9/64	.03	1	
76051	5/32	.04	1	
76052	3/16	.04	1	
76053	7/32	.05	1	
76054	1/4	.06	1	

* 1/16" Standard Inch Hex Only



76096 10 Piece Security Hex Blade Set

Item		Set includes:
No.	lbs.	3/32, 7/64, 1/8, 9/64, 5/32,
76096	.32	3/16, 7/32, 1/4" x 90mm

* 1/16" Standard Inch Hex Only

Wiha Drive-Loc VI Handles

For Adjustable Length Locking Blades

Drive-Loc mechanism guarantees a secure hold & rapid blade exchange

Blades high quality CVM steel, hard chrome finish



Adjustable blade lengths 1.7" to 4.7" in 1/8" increments



28488 Drive-Loc VI Cushion Grip Handle

Ergonomic cushion grip, Drive-Loc mechanism guarantees secure hold & rapid blade exchange.

Item					
No.	mm	mm	Inch	mm	Inch lbs.
28488	6.0	115	4.5	36.0	1.41 .26

Adjustable blade lengths 1.7" to 4.7" in 1/8" increments



28487 Drive-Loc VI MicroFinish Non-Slip Grip Handle

Ergonomic handle shape for maximum comfort, Drive-Loc mechanism guarantees secure hold & rapid blade exchange.

Item					
No.	mm	mm	Inch	mm	Inch lbs.
28487	6.0	115	4.5	36.0	1.41 .20

Adjustable blade lengths 1.7" to 4.7" in 1/8" increments



28486 ESD Safe Drive-Loc VI Handle

Drive-Loc mechanism guarantees a secure hold and rapid blade exchange.


Item					
No.	mm	mm	Inch	mm	Inch lbs.
28486	6.0	115	4.5	36.0	1.41 .21



28189 15 Pc. Drive-Loc VI Interchangeable Blade Set, In Durable Pouch

Set includes Drive-Loc VI handle & 14 interchangeable blades.

Item No.	28189		lbs.	1.40
Slotted:	3.5+4.5, 5.5+6.5	Phillips:	1+2	
Security TORX®:	T6s+T8s, T7s+T9s, T10s+T15s, T20s+T25s, T30s+T40s			
Hex Inch:	3/32+7/64, 1/8+9/64, 5/32+3/16			
Hex Metric:	2.0+2.5, 3.0+4.0, 5.0+6.0mm			
Wiha SoftFinish® Cushion Grip Blade Lock Handle				

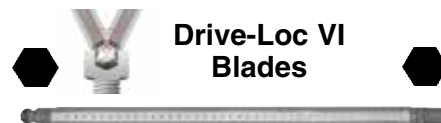

Drive-Loc VI Blades

281 Ball End Hex & Hex Metric Drive-Loc VI Interchangeable Blade

High alloy CVM steel, through hardened, hard chrome finish. Ball end enables the user to work at angles up to 25°. Over all blade length 150mm/5.9". Blades fit all Drive-Loc VI handles.

Item				
No.	mm + mm	lbs.	pkg.	
28116	2.5 2.5	.10	1	
28117	3 3	.10	1	
28118	4 4	.10	1	
28119	5 5	.10	1	
28120	6 6	.10	1	



28476 5 Piece Ball End & Hex Blade Set

Item		Set includes:
No.	lbs.	2.5, 3.0, 4.0,
28476	.36	5.0, 6.0mm



281 Hex Metric Drive-Loc VI Interchangeable Blade

High alloy CVM steel, through hardened, hard chrome finish. Over all blade length 150mm/5.9". Blades fit all Drive-Loc VI handles.

Item				
No.	mm + mm	lbs.	pkg.	
28149	2.0 2.5	.09	1	
28150	3.0 4.0	.10	1	
28151	5.0 6.0	.10	1	

281 Hex Inch Drive-Loc VI Interchangeable Blade

Over all blade length 150mm/5.9"

Item				
No.	Inch + Inch	lbs.	pkg.	
28122	3/32 7/64	.10	1	
28123	1/8 9/64	.10	1	
28124	5/32 3/16	.10	1	



28474 5 Pc. Hex Inch & Metric Blade Set

Item		Set includes:
No.	lbs.	3+4, 5+6mm
28474	.36	5/32+3/16"

TorqueControl Handles & Hex Interchangeable Blades

Wiha TorqueControl Screwdrivers

Cushion grips for maximum user comfort

Loosening torque 50% greater than the tightening torque

Automatically resets for next torque setting cycle

Audible & perceptible click alerts user that torque level has been attained



+/-6% accuracy tolerance
Certificate of calibration

285 TorqueFix, With Wiha-SoftFinish®

Handle Fixed Torque value pre-set. Tested in accordance with EN ISO 6789, BS EN 26789, ASME B107.14M, tolerance +/- 6%.

Item No.	Pre-Sets					
	oz.	lbs.	Nm	Inch	lbs.	pkg.
28503	80	5	0.56	4.4	.16	1
28505	120	7.5	0.84	4.4	.15	1
28507	160	10	1.12	4.7	.28	1
28509	200	12.5	1.41	4.7	.27	1
28511	240	15	1.69	4.7	.27	1
28513	320	20	2.25	4.7	.28	1
28515	400	25	2.82	4.9	.37	1
28517	480	30	3.39	4.9	.37	1
28518	560	35	3.95	4.9	.37	1
28519	640	40	4.52	4.9	.37	1
28521	800	50	5.65	5.2	.52	1
28523	960	60	6.78	5.2	.52	1
28525	1120	70	7.91	5.2	.52	1

Each tool has unique serial number and certificate of calibration

Direct Reading Scale



+/-6% accuracy tolerance
Certificate of calibration

285 Adjustable TorqueVario With Direct Reading Scale EN ISO 6789, BS EN 26789, ASME B107.14M. Ergonomic molded multi-component handle, light and compact. Handle sizes proportioned to optimize torque range. Audible and perceptible click when the torque setting has been attained, automatically resets for next torque cycle.

Item No.	Range					
	Inch	lbs.	Increments	mm	lbs.	pkg.
28501*	15 - 80	(in/oz)	2.5 In/oz	122-127	.22	1
28502	5 - 10		.5 In/lbs	122-127	.41	1
28506	10 - 50		2 In/lbs	133-138	.59	1

Above includes Micro Bit Holder 28583

* +/- 10% (This unit only)

* (1 Nm = 8.8507)

See 4mm

Micro Bits on Page 25



+/-6% accuracy tolerance
Certificate of calibration

285 Adjustable TorqueVario-S Handle - In Newton Meter Scale EN ISO 6789, BS EN 26789, ASME B107.14M.

Item No.	Newton					
	Meter Scale	Increments	mm	lbs.	pkg.	
28550*	0.1 - 0.6Nm	.02 Nm	122-127	.35	1	
28551	0.4 - 1.0Nm	.05 Nm	122-127	.35	1	
28552	0.5 - 2.0Nm	.05 Nm	126-131	.45	1	
28553	0.8 - 5.0Nm	.20 Nm	133-138	.55	1	
28655	2.0 - 7.0Nm	.25 Nm	137-142	.70	1	

* +/- 10% (This unit only)

* (1 Nm 8.8507)

Direct Reading Scale



+/-6% accuracy tolerance
Certificate of calibration

284 Adjustable TorqueVario With Direct Reading Scale

Item No.	Range					
	Inch	lbs.	Increments	mm	lbs.	pkg.
28404	5 - 18		.5 In/lbs	126-131	.50	1
28408	18 - 62		2 In/lbs	137-142	.74	1



285 Hex Metric Interchangeable Blades For TorqueFix & TorqueVario Hex tip blades on narrow 5/32 Hex shafts. High alloy CVM steel, hardened, satin hard chrome finish.

Item No.	mm	mm	lbs.	Nm	pkg.
28545	1.5	175	.07	0.9	1
28546	2.0	175	.07	1.8	1
28547	2.5	175	.07	3.8	1
28548	3.0	175	.07	8.0	1
28549	4.0	175	.07	8.0	1



285 Hex Inch Interchangeable Blades For TorqueFix & TorqueVario

Item No.	Inch	mm	lbs.	Nm	pkg.
28555	.050	175	.07	.4	1
28556	1/16	175	.07	.9	1
28557	5/64	175	.07	1.8	1
28558	3/32	175	.07	1.8	1
28559	7/64	175	.07	3.8	1
28560	1/8	175	.07	3.8	1
28587	9/64	175	.07	8.0	1
28588	5/32	175	.07	8.0	1

Whether it's TorqueVario-S or TorqueFix - Wiha has a torque screwdriver to cover almost every application

TorqueFix Key Wing Handles & Blades

EN ISO 6789,
BS EN 26789,
ASME B107.14M

+/- 6% Accuracy



Compact design specially used for hard to reach screws & confined spaces

Includes Calibration Certificate

283 TorqueFix Wing Handles

Audible & perceptible click when torque setting has been attained.

Item No.	Nm	mm	Inch	pkg.	lbs.
28349	0.5	68	2.7	1	.28
28351	0.6	68	2.7	1	.28
28352	0.9	68	2.7	1	.28
28353	1.1	68	2.7	1	.28
28354	1.2	68	2.7	1	.28
28355	1.4	68	2.7	1	.28
28356	2.0	68	2.7	1	.28
28357	2.5	68	2.7	1	.28
28358	3.0	68	2.7	1	.28
28359	3.8	68	2.7	1	.28
28360	4.0	68	2.7	1	.28



283 Hex Metric & Inch Blades For TorqueFix Wing Handles CVM steel, through-hardened, titanium silver

Item No.	mm	Nm	Inch	mm	pkg.	lbs.
28361	1.5	0.9	3.0	75	1	.03
28362	2.0	1.8	3.0	75	1	.03
28363	2.5	3.8	3.0	75	1	.03
28364	3.0	5.5	3.0	75	1	.03
28365	4.0	8.0	3.0	75	1	.03

T-handle TorqueControl Handles and Hex Interchangeable Blades



Includes Calibration Certificate

289 TorqueFix T-handle EN ISO 6789, BS EN 26789, ASME B107.14M, +/- 6% Accuracy Ergonomic multi-component handle, light & compact. With Certificate of calibration.

Item No.	Torque In-lbs.	Torque Nm	mm x mm	lbs.	pkg.
28931	53.1	6	56 x 120	.81	1
28933	70.8	8	56 x 120	.82	1
28935	88.5	10	56 x 120	.79	1
28937	106.2	12	56 x 120	.79	1
28938	110.6	12.5	56 x 120	.80	1
28939	123.9	14	56 x 120	.80	1

Each TorqueFix T-handle has unique serial number and certificate of calibration



Adjustable from Nm 5-14 or In-lbs. 44.3-123.9



Includes Calibration Certificate

28940 Adjustable TorqueVario STplus T-handle EN ISO 6789, BS EN 26789, ASME B107.14M, +/- 6% Accuracy Ergo multi-component handle, light & compact.

Item No.	Torque In-lbs.	Torque Nm	mm x mm	lbs.	pkg.
28940	44.3-123.9	5-14	56 x 120	.81	1

* (1 Nm 8.8507)



289 Hex Metric Interchangeable Blades For TorqueFix T-handle Hex tip blades on 6mm Hex shafts. High alloy CVM steel, hardened, satin hard chrome finish.

Item No.	mm	mm	Inch	lbs.	pkg.
28916	3.0	130	5.1	.11	1
28917	4.0	130	5.1	.11	1
28918	5.0	130	5.1	.11	1
28919	6.0	130	5.1	.11	1



289 Hex Inch Interchangeable Blades For TorqueFix T-handle Hex tip blades on 6mm Hex shafts. High alloy CVM steel, hardened, satin hard chrome finish.

Item No.	Inch	mm	Inch	lbs.	pkg.
28920	1/8	130	5.1	.11	1
28921	9/64	130	5.1	.11	1
28923	3/16	130	5.1	.11	1
28924	7/32	130	5.1	.11	1

Insulated TorqueControl Tools

Includes Certificate

⚡ 1000Volt



287 Insulated TorqueVario-S, With Window Scale Insulation ⚡ up to 1000 Volt. EN/IEC 60900 EN ISO 6789, BS EN 26789, ASME B107.14M & CSA, +/- 6% Accuracy. Ergonomic multi-component handle, light & compact. Handle sizes proportioned to optimize torque range. Audible & perceptible click when torque setting has been attained. Includes SlimLine blade holder.

Item No.	Range	Inch lbs.	Increments	mm	lbs.	pkg.
28750	5 - 18	.5	In/lbs	126-131	.43	1
28751	10 - 50	2	In/lbs	133-138	.40	1
28752	18 - 62	2	In/lbs	137-142	.69	1

⚡ 1000Volt



287 Insulated TorqueVario-S Handle - In Newton Meter Scale Includes SlimLine blade holder.

Item No.	Range	Nm	mm	lbs.	pkg.
28740	0.5 - 2.0	131	.45	1	
28741	0.8 - 5.0	138	.45	1	
28742	2.0 - 7.0	142	.72	1	

Each TorqueVario handle has unique serial number & certificate of calibration



283 Insulated Hex Metric SlimLine Blades SlimLine blades have up to 33% narrower insulation diameter than standard insulated tools.

Item No.	mm	Slim Dia.	Max Nm	Inch/ lbs.	lbs.	Pkg.
28332	1.5	4.0	0.9	7.9	.02	1
28333	2.0	4.0	1.8	15.9	.02	1
28334	2.5	4.0	3.8	33.6	.02	1
28335	3.0	4.0	5.5	48.7	.02	1
28336	4.0	6.0	5.5	48.7	.02	1
28337	5.0	6.0	5.5	48.7	.02	1
28338	6.0	6.0	5.5	48.7	.02	1

Wiha Hex Precision Series



263 Metric Metric Hex Driver, With Precision Handle Blade high alloy CVM steel.

Item	No.	mm	Inch	mm	Inch	mm	Inch	lbs.	pkg.
26307	0.7	0.028	40	1.6	120	4.7	.02	10	
26309	0.9	0.035	40	1.6	120	4.7	.02	10	
26313	1.3	0.05	40	1.6	120	4.7	.02	10	
26315	1.5	-	50	2.0	145	5.7	.03	10	
26320	2.0	5/64	50	2.0	145	5.7	.03	10	
26325	2.5	-	60	2.4	170	6.7	.04	10	
26330	3.0	-	60	2.4	170	6.7	.04	10	
26340	4.0	-	60	2.4	170	6.7	.05	10	

*Metric dimensions actual -
Inch dimensions approximate



26390 7 Pc. Precision Hex Driver Set - Metric Blade high alloy CVM steel.

Item	Metric:	lbs.
No.	0.7, 0.9, 1.3, 1.5,	
26390	2.0, 2.5, 3.0mm	.28



26399 8 Pc. Precision Hex Driver Set - Inch Blade high alloy CVM steel. Hard chrome finished. In canvas storage pouch

Item	Inch:	lbs.
No.	0.028, 0.035, 0.05,	
26399	3/32, 7/64, 1/8"	.55

Wiha Ball End Metric Hex Precision Series



264 Metric Ball End Hex Metric Screwdriver With Precision Handle Angle entry up to 30°

Item	No.	mm	Inch	mm	Inch	mm	Inch	lbs.	pkg.
26413	1.3	0.05	40	1.6	120	4.7	.02	10	
26415	1.5	-	50	2.0	145	5.7	.03	10	
26420	2.0	-	50	2.0	145	5.7	.03	10	
26425	2.5	-	60	2.4	170	6.7	.04	10	
26430	3.0	-	60	2.4	170	6.7	.05	10	
26440	4.0	-	60	2.4	170	6.7	.05	10	



263 Inch Inch Hex Driver, With Precision Handle Blade high alloy CVM steel.

Item	No.	Inch	mm	mm	Inch	mm	Inch	lbs.	pkg.
26307	.028	0.7	40	1.6	120	4.7	.02	10	
26309	.035	0.9	40	1.6	120	4.7	.02	10	
26313	0.05	1.3	40	1.6	120	4.7	.02	10	
26316	1/16	-	50	2.0	145	5.7	.03	10	
26320	5/64	2.0	50	2.0	145	5.7	.03	10	
26323	3/32	-	60	2.4	170	6.7	.04	10	
26327	7/64	-	60	2.4	170	6.7	.04	10	
26331	1/8	-	60	2.4	170	6.7	.04	10	
26333	9/64	60	2.4	170	6.7	.05	10		
26336	5/32	60	2.4	170	6.7	.05	10		

*Metric dimensions actual -
Inch dimensions approximate



26391 8 Pc. Precision Hex Driver Set - Inch Blade high alloy CVM steel.

Item	Inch:	lbs.
No.	0.028, 0.035, 0.05,	
26391	1/16, 5/64, 3/32,	.32
	7/64, 1/8"	



26491 5 Piece Ball End Hex Driver Set - Metric Angle entry up to 30°

Item	Metric:	lbs.
No.	1.3, 1.5, 2.0,	
26491	2.5, 3.0mm	.31

*Metric dimensions actual -
Inch dimensions approximate

Ball End Precision Series



264 Inch Ball End Hex Inch Screwdriver With Precision Handle Angle entry up to 30°. Blade high alloy CVM steel. Hard chrome finish.

Item	No.	Inch	mm	Inch	mm	Inch	lbs.	pkg.
26413	0.05	40	1.6	120	4.7	.02	10	
26416	1/16	50	2.0	145	5.7	.03	10	
26419	5/64	50	2.0	145	5.7	.03	10	
26423	3/32	50	2.0	145	5.7	.03	10	
26427	7/64	60	2.4	170	6.7	.03	10	
26431	1/8	60	2.4	170	6.7	.05	10	
26436	9/64	60	2.4	170	6.7	.05	10	
26439	5/32	60	2.4	170	6.7	.05	10	

*Metric dimensions actual -
Inch dimensions approximate



26490 8 Pc. Ball End Hex Driver Set - Inch Angle entry up to 30°. Blade high alloy CVM steel.

Item	Inch:	lbs.
No.	0.05, 1/16, 5/64, 3/32, 7/64,	
26490	1/8, 9/64, 5/32"	.40



26499 8 Pc. Ball End Hex Driver Set - Inch In canvas storage pouch

Item	Inch:	lbs.
No.	0.05, 1/16, 5/64, 3/32, 7/64,	
26499	1/8, 9/64, 5/32"	.62



91118 Rugged Polyester Canvas Storage Pouch Holds 8 Precision Tools up to 170mm in length. Folding pouch. Has security flaps and velcro closer.

Item	No.	Size	lbs.	pkg.
91118	14	1 1/2" W x 7 3/4" L	.13	1

Pico Soft Grip Ball End Inch & Metric



264 Ball End Hex Inch Screwdriver, With Precision Soft PicoFinish Handle Blade high alloy CVM tool steel, hardened, hard chrome finish.

Item						
No.	Inch	Inch	mm	Inch	mm	pkg
26455	1/16	2.0	50	5.9	150	10
26457	5/64	2.0	50	5.9	150	10
26459	3/32	2.0	50	5.9	150	10
26461	7/64	2.4	60	6.3	160	10
26463	1/8	2.4	60	6.3	160	10
26465	9/64	2.4	60	6.3	160	10
26467	5/32	2.4	60	6.3	160	10

*Metric dimensions actual -
Inch dimensions approximate



26493 7 Piece Inch Ball End Hex Precision Driver Set, With Soft PicoFinish Handle Blade high alloy CVM steel, hardened, hard chromed. ChromTop finish on tip for a perfect fit. In storage pouch

Item	Inch:	
No.	1/16, 5/64, 3/32, 7/64,	lbs.
26493	1/8, 9/64, 5/32"	.27



264 Ball End Hex Metric Screwdriver, With Precision Soft PicoFinish Handle. Blade high alloy CVM tool steel, hardened, hard chrome finish.

Item						
No.	mm	mm	Inch	mm	Inch	pkg.
26441	1.3	40	1.6	134	5.3	10
26443	1.5	50	2.0	150	5.9	10
26445	2.0	50	2.0	150	5.9	10
26447	2.5	60	2.4	160	6.3	10
26449	3.0	60	2.4	160	6.3	10

*Metric dimensions actual -
Inch dimensions approximate


Pico Soft Grip Hex Inch & Metric



263 Hex Inch Screwdriver, With Precision Soft PicoFinish Handle Blade high alloy CVM tool steel, hardened, hard chrome finish.

Item						
No.	Inch	mm	Inch	mm	Inch	pkg.
26341	0.028(0.7)	40	1.6	134	5.3	10
26343	0.035(0.9)	40	1.6	134	5.3	10
26345	0.05(1.3)	40	1.6	134	5.3	10
26349	5/64(2.0)	50	2.0	150	5.9	10
26363	1/16	50	2.0	144	5.7	10
26367	3/32	60	2.4	160	6.3	10
26369	7/64	60	2.4	160	6.3	10
26371	1/8	60	2.4	160	6.3	10

*Metric dimensions actual -
Inch dimensions approximate

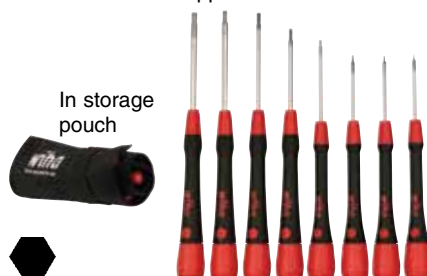

26392 8 Pc. Hex Inch Precision Driver Set

Item	Inch:	
No.	0.028, 0.035, 0.05,	lbs.
26392	5/64, 1/16, 3/32, 7/64, 1/8"	.24



263 Hex Metric Driver, With Precision Soft PicoFinish Handle Blade high alloy CVM tool steel, hardened, hard chrome finish.

Item						
No.	mm	mm	Inch	mm	Inch	pkg.
26341	0.7(0.028)	40	1.6	134	5.3	10
26343	0.9(0.035)	40	1.6	134	5.3	10
26345	1.3(0.05)	40	1.6	134	5.3	10
26347	1.5	50	2.0	144	5.7	10
26349	2.0(5/64)	50	2.0	150	5.9	10
26351	2.5	60	2.4	160	6.3	10
26353	3.0	60	2.4	160	6.3	10

*Metric dimensions actual -
Inch dimensions approximate



26393 7 Pc. Hex Metric Precision Driver Set In storage pouch

Item	Metric:	
No.	0.7, 0.9, 1.3, 1.5	lbs.
26393	2.0, 2.5, 3.0mm	.22

Wiha Ball End Protturn Precision Series



Set in canvas storage pouch

62994 14 Piece Inch/Metric Ball End Hex Work Tech Pack Protturn precision ball retainer handle & 13 Wiha interchangeable blades.

62994 Set includes the following blades:

Hex Inch: .050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32"

Hex Metric: 1.5, 2.0, 2.5, 3.0, 4.0mm
lbs. .66

Wiha Precision ESD Safe Hex Drivers

Wiha Precision ESD Static Dissipative Screwdrivers meet the requirements for tools used in static sensitive areas.



Rotating cap for precise turning & control with fingertip

Molded Precision handle
of impact resistant dissipative material

Tapered handle allows rapid rotation

Blade, CVM steel, hardened, hard chrome finish

Tip, precision ground for exact fit, Wiha Chromtop finish

ESD Standard IEC 61340-5-1

Surface resistance of handles is $10^6 - 10^9$ Ohms



275 Metric Hex Metric Driver, With Precision ESD Safe Dissipative Handle

Blade high alloy CVM steel. Hard chrome finished. Handle manufactured from impact resistant, dissipative material.

Item								
No.	mm	mm	Inch	mm	mm	Inch	lbs.	pkg.
27507	0.7	40	1.6	120	4.7	.02	10	
27509	0.9	40	1.6	120	4.7	.02	10	
27513	1.3	40	1.6	120	4.7	.03	10	
27515	1.5	50	2.0	145	5.7	.03	10	
27520	2.0	50	2.0	145	5.7	.04	10	
27525	2.5	60	2.4	170	6.7	.05	10	
27530	3.0	60	2.4	170	6.7	.05	10	
27535	4.0	60	2.4	170	6.7	.05	10	

*Metric dimensions actual -
Inch dimensions approximate

In Storage Pouch



ESD standard IEC 61340-5-1

27590 Set 8 Pcs. Hex Metric Precision ESD Safe Dissipative Handle Blade CVM steel, hardened, hard chromed. Handle impact resistant, dissipative material.

Item	Hex Metric:	
No.	.71, .89, 1.3, 1.5, 2.0,	lbs.
27590	2.5, 3.0, 4.0mm	.53



275 Inch Hex Driver, With Precision ESD Safe Dissipative Handle

Blade high alloy CVM steel. Hard chrome finished. Handle manufactured from impact resistant, dissipative material.

Item								
No.	Inch	mm	Inch	mm	Inch	lbs.	pkg.	
27505	0.028	40	1.6	120	4.7	.02	10	
27510	0.035	40	1.6	120	4.7	.02	10	
27513	0.05	40	1.6	120	4.7	.02	10	
27537	1/16	50	2.0	145	5.7	.03	10	
27539	5/64	50	2.0	145	5.7	.03	10	
27541	3/32	60	2.4	170	6.7	.04	10	
27543	7/64	60	2.4	170	6.7	.04	10	
27545	1/8	60	2.4	170	6.7	.04	10	
27547	9/64	60	2.4	170	6.7	.05	10	
27549	5/32	60	2.4	170	6.7	.05	10	

*Metric dimensions actual -
Inch dimensions approximate

In Storage Pouch



ESD standard IEC 61340-5-1

27591 8 Piece Hex Inch Precision Set, ESD Safe Dissipative Handle Blade CVM steel, hardened, hard chromed. Handle impact resistant, dissipative material.

Item	Hex Inch:	
No.	0.05, 1/16, 5/64, 3/32,	lbs.
27591	7/64, 1/8, 9/64, 5/32"	.57

SYS 4 Drive-Loc Precision Locking Tools



26961 ESD Safe Dissipative Precision Drive-Loc Handle Surface resistant 10^6-10^9 Ohms. 4 mm hex retainer for all SYSTEM 4 interchangeable blades. Ball retainer hold. 105mm/4.13" OAL

Item					
No.	mm	Inch	mm	Inch	lbs.
26961	4.0	.1574	23	.91	.08



280 SYSTEM 4 Metric Hex Drive-Loc Reversible Locking Blades

On 4mm Hex blades

Item			
No.	mm	mm	lbs.
28003	1.3 + 1.3		.02
28004	1.5 + 1.5		.02
28005	2.0 + 2.0		.02
28006	2.5 + 2.5		.02
28007	3.0 + 3.0		.02
28008	4.0 + 4.0		.02

SYS 4 Precision Handles



28000 ESD Safe Dissipative Precision Handle with rotating control cap. Surface resistant 10^6-10^9 Ohms. 4 mm hex retainer for all SYSTEM 4 interchangeable blades. Tapered handle, high quality plastic, impact resistant. Ball retainer hold. 110mm/4.3" OAL

Item					
No.	mm	Inch	mm	Inch	lbs.
28000	4.0	.1574	14.0	.55	.04



28001 ESD Safe Dissipative Precision Adjustable Handle with rotating control cap. **Advantages:**

- Use in ESD sensitive applications. Surface resistant 10^6-10^9 Ohms.
- Collet lock allows for quick & easy adjustment.
- Holds blade securely in place. Accepts all SYSTEM 4 blades. 110mm/4.3" OAL

Item					
No.	mm	Inch	mm	Inch	lbs.
28001	4.0	.1574	14.0	.55	.04

SYSTEM 4 Handles & Blades



26900 **SYS 4 Standard Precision Handle**, with rotating control cap. Accepts all SYSTEM 4 interchangeable blades. Wiha Precision handle, tapered, impact resistant. Ball retainer hold. 110mm/4.3" OAL

Item	No.	mm	Inch	mm	Inch	lbs.
26900		4.0	.1574	14.0	.55	.04



269 **SYSTEM 4 Metric Ball End & Standard Hex, Reversible Blade** Wiha vapor Chrome-Top finish on tips. One side hex, other side ball end hex.


Item	No.	mm	mm	mm	Inch	lbs.
26932		1.27 + 1.27	120	4.7	.05	
26935		2.5 + 2.5	120	4.7	.06	
26936		3.0 + 3.0	120	4.7	.06	
26937		4.0 + 4.0	120	4.7	.06	

269 **SYSTEM 4 Metric Hex, Interchangeable Blade** High alloy CVM steel, hardened, corrosion protected.

Item	No.	mm	mm	Inch	lbs.
26913		0.7	120	4.7	.06
26914		0.9	120	4.7	.06
26916		1.5	120	4.7	.06
26917		2.0	120	4.7	.06
26918		2.5	120	4.7	.06
26919		3.0	120	4.7	.06
26920		4.0	120	4.7	.06


269 **SYSTEM 4 Inch Hex, Interchangeable Blade**

Item	No.	Inch	mm	Inch	lbs.
26921		0.05	120	4.7	.06
26923		1/16	120	4.7	.06
26924		5/64	120	4.7	.06
26925		3/32	120	4.7	.06
26926		7/64	120	4.7	.06
26927		1/8	120	4.7	.06
26928		9/64	120	4.7	.06
26929		5/32	120	4.7	.06

 

280 **SYSTEM 4 Metric Ball End Hex Interchangeable Blade** Ball end works at 30° angle entry for easy access to fasteners.

Item	No.	mm	mm	Inch	lbs.	pkg.
28033		1.5	120	4.7	.06	1
28034		2.0	120	4.7	.06	1
28035		2.5	120	4.7	.06	1
28036		3.0	120	4.7	.06	1
28037		4.0	120	4.7	.06	1

 

280 **SYSTEM 4 Inch Ball End Hex Interchangeable Blade**

Item	No.	Inch	mm	Inch	lbs.
28021		.050	120	4.7	.06
28023		1/16	120	4.7	.06
28024		5/64	120	4.7	.06
28026		7/64	120	4.7	.06
28027		1/8	120	4.7	.06
28028		9/64	120	4.7	.06
28029		5/32	120	4.7	.06

Wiha SYSTEM 4 Micro Bits & Compact Bit Sets



75096 **16 Piece Precision Micro Bit Hex Inch & Metric Sets** ESD Safe precision handle, Bit Extension and 14 CVM steel Micro Bits.

Set includes the following Micro Bits:

Inch: 0.89/0.35", 1.3/.050", 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32"

Metric: 1.5, 2.0, 2.5, 3.0, 4.0mm
lbs. .14



75395 **18 Piece SYSTEM 4 Hex Inch & Metric Precision Interchangeable Bit Set, In Compact Fold Out Box** Wiha precision handle, bit extension & 16 interchangeable bits.

Item No. Combination Bit Set

75395 Set with Standard Precision Handle
Set includes the following bits:

Hex Metric: .71, .89, 1.3, 1.5, 2.0, 2.5, 3.0, 4.0mm

Hex Inch: .050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32"

100mm Bit Extension

lbs. .58

SYSTEM 4 Handles & Micro Bits

Tips
exact fit,
precision
machined

Rotating Cap
for precise
turning and
control

Tapered Handle
allows rapid rotation,
requires less clearance

Bits CVM steel,
hardened

Use bits directly in handle or with 4" bit extension



110mm/4.3" OAL

75800 SYSTEM 4 Standard Precision Bit

Handle with rotating control cap. Tapered, high quality plastic, impact resistant, ball retainer. Accepts all SYSTEM 4 Series bits.

Item				
No.	mm	Inch	mm	Inch lbs.
75800	4.0	.1574	14.0	.55 .06



110mm/4.3" OAL

75801 SYSTEM 4 ESD Safe Dissipative

Precision Bit Handle with rotating control cap. Tapered, high quality plastic, impact resistant. **Advantages:**

- For working in ESD sensitive applications Surface resistant 10^6 - 10^9 Ohms 
- Ball retainer holds bits securely in place
- Accepts all SYSTEM 4 Series bits

Item				
No.	mm	Inch	mm	Inch lbs.
75801	4.0	.1574	14.0	.55 .06



75901 Magnetic Bit Extension Blade For SYSTEM 4 Micro Bits Shaft CVM steel, hardened. Magnetic bit holder.

Item				
No.	Size	mm	mm	lbs.
75901	4.0	100	4.0	.04



75900 Extension Blade For SYSTEM 4 Micro Bits Shaft CVM steel, hardened, corrosion protected. Ball retainer bit extension for 4 mm bits.

Item				
No.	Size	mm	mm	lbs.
75900	4.0	100	4.0	.07



753 SYSTEM 4 Hex Metric Bits High alloy CVM steel, hardened, on 4 mm hex stock.

Item				
No.	mm	mm	Inch	lbs.
75307	.71	28	1.1	.01
75309	.89	28	1.1	.01
75313	1.3	28	1.1	.01
75315	1.5	28	1.1	.01
75320	2.0	28	1.1	.01
75325	2.5	28	1.1	.01
75330	3.0	28	1.1	.01
75340	4.0	28	1.1	.01



753 SYSTEM 4 Hex Inch Bits High alloy CVM steel, hardened, on 4 mm hex stock.

Item				
No.	Inch	mm	Inch	lbs.
75307	.028	28	1.1	.01
75309	.035	28	1.1	.01
75313	.050	28	1.1	.01
75350	1/16	28	1.1	.01
75352	5/64	28	1.1	.01
75354	3/32	28	1.1	.01
75356	7/64	28	1.1	.01
75358	1/8	28	1.1	.01
75360	9/64	28	1.1	.01
75340	5/32	28	1.1	.01



753 SYSTEM 4 Metric Security Hex Bits High alloy CVM steel, hardened, on 4 mm hex stock.

Item				
No.	mm	mm	Inch	lbs.
75322	2.0	28	1.1	.01
75332	3.0	28	1.1	.01
75342	4.0	28	1.1	.01



753 SYSTEM 4 Security Hex Inch Bits High alloy CVM steel, hardened, on 4 mm hex stock.

Item				
No.	Inch	mm	Inch	lbs.
75362	5/64	28	1.1	.01
75364	3/32	28	1.1	.01
75366	7/64	28	1.1	.01
75368	1/8	28	1.1	.01
75370	9/64	28	1.1	.01
75372	5/32	28	1.1	.01



10 Bit Pack

756 SYSTEM 4 Hex Metric Micro Bits

Item				
No.	mm	mm	Inch	lbs.
75616	.71	28	1.1	.06
75617	.89	28	1.1	.06
75618	1.3	28	1.1	.06
75619	1.5	28	1.1	.07
75620	2.0	28	1.1	.07
75621	2.5	28	1.1	.07
75622	3.0	28	1.1	.08
75623	4.0	28	1.1	.08



10 Bit Pack

756 SYSTEM 4 Hex Inch Micro Bits

Item				
No.	Inch	mm	Inch	lbs.
75628	.028	28	1.1	.06
75629	.035	28	1.1	.06
75630	.050	28	1.1	.06
75631	1/16	28	1.1	.06
75632	5/64	28	1.1	.06
75633	3/32	28	1.1	.07
75634	7/64	28	1.1	.07
75635	1/8	28	1.1	.07
75636	9/64	28	1.1	.08
75637	5/32	28	1.1	.08



10 Bit Pack

756 SYS 4 Metric Security Hex Micro Bits

Item				
No.	mm	mm	Inch	lbs.
75624	2.0	28	1.1	.06
75626	3.0	28	1.1	.07
75627	4.0	28	1.1	.08



10 Bit Pack

756 SYS 4 Security Hex Inch Micro Bits

Item				
No.	Inch	mm	Inch	lbs.
75638	5/64	28	1.1	.06
75639	3/32	28	1.1	.06
75640	7/64	28	1.1	.07
75641	1/8	28	1.1	.07
75642	9/64	28	1.1	.08
75643	5/32	28	1.1	.08

Wiha SYSTEM 4 Micro Bits & Compact Bit Sets



75983 Micro Bit Handle Storage Hex Inch Bit Set, 7 Pcs. Wiha precision storage handle & 6 interchangeable bits.

Item No. Precision Storage Handle Set
75983 **Hex Inch:** .050, 1/16, 5/64,
lbs. .08 3/32, 7/64, 1/8"



75982 SYSTEM 4 Hex Inch Micro Bit Replacement Pack, 10 Pcs.

CVM steel, hardened, on 4 mm hex stock.

Item No. SYSTEM 4 Micro Bit Set
75982 **Hex Inch:** .028, .035, .050, 1/16,
 5/64, 3/32, 7/64, 1/8, 9/64, 5/32"
lbs. .06

Wiha Blister Pack Bit Set



72596 Hex Inch Insert Blister Pack, 1"

CVM S2 modified tool steel. Extra hard with natural finish. Exact fit machined tips. 10 Pc. set

72596 Set includes the following bits:

Hex Inch: 1/16, 5/64, 3/32,
 7/64, 1/8, 9/64, 5/32, 3/16,
wt. .16 7/32, 1/4" x 1" (25mm)

Wiha Cushion Grip Pop-Up 1/4" Bit Holder

Bit holder stainless steel, magnetic



38049 Hex Inch & Metric Pop-Up Bit Screwdriver Set Cushion Grip handle, multi-component. Compact storage holds 12 bits.

Set includes:
lbs. **Inch:** 5/64, 3/32, 1/8, 5/32, 3/16, 1/4"
 .42 **Metric:** 2.0, 2.5, 3.0, 4.0, 5.0, 6.0mm

Wiha Cushion Grip Stubby Bit Holder

Stubby 6 in 1 Multi-Bit Driver Sets

Stainless steel bit holder

Just 2.5" over all length



Ergo soft grip handles

Bits hardened for extreme durability



38056 Ball End Hex SoftFinish® Cushion Grip Stubby Bit Holder CVM tool steel shaft.

Set includes the following 1/4" bits:
lbs. **Ball End Hex Inch:** 1/8, 9/64, 5/32,
 .21 3/16, 7/32, 1/4"



38057 Hex Metric SoftFinish® Cushion Grip Stubby Bit Holder CVM tool steel shaft.

Set includes the following 1/4" bits:
lbs. **Hex Metric:** 2.0, 2.5, 3.0,
 .18 4.0, 5.0, 6.0mm



38058 Hex Inch SoftFinish® Cushion Grip Stubby Bit Holder CVM tool steel shaft.

Set includes the following 1/4" bits:
lbs. **Hex Inch:** 3/32, 7/64, 1/8,
 .18 9/64, 5/32, 3/16"

Wiha Bit Selectors

Compact size & easy bit selection make the Bit Selector an ideal maintenance tool



Plastic storage box is compact, durable and light weight

Slide out drawer allows quick bit access & secure storage



Molded hex cavity in box end Magnetic adapter fits into opening so tool case can be used as a handle on quick fastening jobs

1/4" Magnetic Adapter fits all standard 1/4" bits

792 Sets Bit-Selector Sets

These handy sets include 10 hardened bits of CVM steel. Packaged in clear blister pack.



79276 Bit-Selector With Ball End Hex Inch Bits. Set Includes Magnetic 1/4" Bit Holder & The Following 8 Bits:

Ball End Hex Inch:
lbs. 3/32, 7/64, 1/8, 9/64,
 .30 5/32, 3/16, 7/32, 1/4"



Item #79246

79246 Bit-Selector With Hex Inch Bits. Set Includes Magnetic 1/4" Bit Holder & The Following 10 Bits:

Hex Inch: 1/16, 5/64,
lbs. 3/32, 7/64, 1/8, 9/64,
 .32 5/32, 3/16, 7/32, 1/4"

79256 Bit-Selector With Hex Metric Bits. Set Includes Magnetic 1/4" Bit Holder & The Following 8 Bits:

lbs. **Hex Metric:** 1.5, 2.0, 2.5,
 .30 3.0, 4.0, 5.0, 6.0, 8.0mm

Wiha XSelector Bit Set



79446 XSelector Bit Set With Hex Inch Bits Includes ClicFix quick release bit holder & 10 insert bits.

lbs. **Inch:** 1/16, 5/64, 3/32, 7/64,
 .27 1/8, 9/64, 5/32, 3/16, 7/32, 1/4"

Wiha MagicRing Insert Bits

Screw Holding
Hex Bits



713 MagicRing Metric Insert Bits, 1/4"

Item No.	mm	mm	pkg.	lbs.
71304	3.0	25	1	.01
71307	4.0	25	1	.01
71310	5.0	25	1	.01
71311	6.0	25	1	.01

713 MagicRing Inch Insert Bits, 1/4"

Item No.	Inch	mm	pkg.	lbs.
71343	1/8	25	1	.01
71346	9/64	25	1	.01
71349	5/32	25	1	.01
71352	3/16	25	1	.01
71354	7/32	25	1	.01

Wiha Security Hex Inch & Metric PokitPaks



71998 PokitPak - Security Hex Inch 1/4"

Insert Bits In Molded Case. Includes 6 Bits

Hex Inch Security Hex:

lbs.	3/32, 7/64, 1/8, 9/64,
.12	5/32, 3/16"



71995 PokitPak - Security Hex Metric 1/4"

Insert Bits In Molded Case - Includes 6 Bits

Hex Metric Security Hex:

lbs.	2.5, 3.0, 4.0, 5.0, 6.0, 8.0mm
.31	

Wiha Power Bit Belt Packs



74986 Power Bit Belt Pack With Inch

& Metric Hex Bits. Set Includes The

 
Following 10 Bits:

Hex Inch: 1/8, 9/64, 5/32, 3/16, 7/32, 1/4"

Hex Metric: 3.0, 4.0, 5.0, 6.0mm



Screw
Holding
Hex Bits



74999 Power Bit Belt Pack With Screw

Holding Inch & Metric Ball End Hex MagicRing Bits. Set Includes The Following 10 Bits:

Hex Inch: 1/8, 9/64, 5/32, 3/16, 7/32, 1/4"

Hex Metric: 3.0, 4.0, 5.0, 6.0mm

Wiha MagicRing Power Bits

Screw Holding
Hex Bits



743 MagicRing Metric Power Bits, 1/4"

Item No.	mm	mm	pkg.	lbs.
74301	3.0	50	1	.02
74305	4.0	50	1	.02
74307	5.0	50	1	.03
74319	6.0	50	1	.03

743 MagicRing Inch Power Bits, 1/4"

Item No.	mm	mm	pkg.	lbs.
74369	1/8	50	1	.02
74371	9/64	50	1	.02
74373	5/32	50	1	.02
74375	3/16	50	1	.03
74379	1/4	50	1	.03

Wiha Security Multi Bit Set



38014 Security Hex Inch Multi-Bit

Screwdriver, 6 Pc. Set With Wiha Powerhandle & CVM steel, hardened shaft.

Includes the following 1/4" Security bits:

3/32, 1/8, 5/32, 3/16, 7/32"

Wiha Security Bit Selector



79266 Bit-Selector With Security Hex Inch

Bits. Set Includes Magnetic 1/4" Bit Holder & The Following 9 Bits:

Hex Inch: 5/64, 3/32,

7/64, 1/8, 9/64, 5/32,

.31 3/16, 7/32, 1/4"

Hex Inch/Metric Bit Packs



71396 Hex Inch Insert Bit Packs, 1" CVM

S2 modified tool steel. Extra hard with natural finish. Exact fit machined tips. 6 pc. bit pack.

71396 Set includes the following bits:

Hex Inch:

1/16, 3/32, 1/8, 5/32

wt. .13 3/16, 1/4" x 1" (25mm)

71397 Hex Metric Insert Bit Packs, 1" CVM

S2 modified tool steel. Extra hard with natural finish. Exact fit machined tips. 6 pc. bit pack.

71397 Set includes the following bits:

Hex Metric:

wt. .21 2.0, 2.5, 3.0, 4.0, 5.0, 6.0

Wiha Bit Holders



714 ClicFix Bit Holder, Magnetic, For Insert Bits

Item No.	Size	Size	mm	Inch
71491	1/4"	1/4"	75	2.9



714 CentroFix Bit Holder For Power Bits

Item No.	Size	Size	mm	Inch
71480	1/4"	1/4"	60	2.3

Wiha Hex Inch & Metric Power Bits

10 bit pack


743 Hex Inch Power Bits

1/4" Hex Drive, Length 2.0"/50mm (10 Pk.)

Item				
No.	Inch	mm	pkg.	lbs.
74311	3/32	50	10	.30
74312	7/64	50	10	.30
74313	1/8	50	10	.30
74314	9/64	50	10	.30
74315	5/32	50	10	.30
74316	3/16	50	10	.30
74317	7/32	50	10	.30
74318	1/4	50	10	.30

10 bit pack


743 Hex Metric Power Bits

1/4" Hex Drive, Length 2.0"/50mm (10 Pk.)

Item				
No.	mm	mm	pkg.	lbs.
74325	2.5	50	10	.25
74330	3.0	50	10	.25
74340	4.0	50	10	.25
74350	5.0	50	10	.25
74360	6.0	50	10	.25
74380	8.0	50	10	.38



2 bit pack


743 Hex Inch Power Bit Packs, 2"

Item			
No.	Inch	mm	lbs.
74381	3/32	50	.07
74382	7/64	50	.07
74383	1/8	50	.07
74384	9/64	50	.07
74385	5/32	50	.07
74386	3/16	50	.07
74387	7/32	50	.07
74388	1/4	50	.07

743 Hex Metric Power Bit Packs, 2"

Item			
No.	mm	mm	lbs.
74361	2.5	50	.07
74362	3.0	50	.07
74363	4.0	50	.07
74364	5.0	50	.07
74365	6.0	50	.07
74366	8.0	50	.09

 
10 bit pack


743 Hex Inch Power Bits

1/4" Hex Drive, Length 2.75"/70mm (10 Pk.)

Item				
No.	Inch	mm	pkg.	lbs.
74342	3/32	70	1	.36
74343	7/64	70	1	.36
74344	1/8	70	1	.36
74345	9/64	70	1	.36
74346	5/32	70	1	.36
74348	7/32	70	1	.36
74349	1/4	70	1	.36

 10 bit pack


743 Hex Metric Power Bits

1/4" Hex Drive, Length 2.75"/70mm (10 Pk.)

Item				
No.	mm	mm	pkg.	lbs.
74351	2.0	70	1	.36
74352	2.5	70	1	.36
74353	3.0	70	1	.36
74354	4.0	70	1	.36
74355	5.0	70	1	.36
74356	6.0	70	1	.36
74357	8.0	70	1	.36


743 Hex Metric Power Bits

1/4" Hex Drive, Length 3.5"/90mm

Item				
No.	mm	mm	pkg.	lbs.
74332	2.0	90	1	.38
74333	2.5	90	1	.38
74334	3.0	90	1	.38
74335	4.0	90	1	.38
74336	5.0	90	1	.38
74337	6.0	90	1	.38

Stainless Steel Hex Metric Bits

701 Stainless Steel Hex Metric Insert Bits

Item			
No.	mm	mm	pkg.
70176	6.0	25	10

Hex Metric Long Insert Bit On 5/16"

72388 Hex Metric Bit On 5/16" Stock

Item					
No.	mm	mm	pkg.	lbs.	
72388	12.0	75	10	.14	

Wiha Ball End Hex Inch Insert Bits


10 bit pack

717 Ball End Hex Inch Insert Bits, 1/4"

Standard Hex Insert Bits, 1/4"					
Item					
No.	Inch	mm	pkg.	lbs.	
71701	3/32	25	10	.12	
71702	7/64	25	10	.12	
71703	1/8	25	10	.12	
71704	9/64	25	10	.12	
71705	5/32	25	10	.12	
71706	3/16	25	10	.13	
71707	7/32	25	10	.13	
71708	1/4	25	10	.13	

2 bit pack


717 Ball End Hex Inch Insert Bit Packs, 1"

Item			
No.	Inch	mm	lbs.
71711	3/32	25	.03
71712	7/64	25	.03
71713	1/8	25	.03
71714	9/64	25	.03
71715	5/32	25	.04
71716	3/16	25	.04
71717	7/32	25	.04
71718	1/4	25	.04

Ball End Hex Metric Power Bits

2 pc. bit pack


717 Ball End Hex Metric Power Bits

1/4" Hex Drive, Length 1.5"/38mm

Item			
No.	mm	mm	pkg.
71719	1.5	38	1
71720	2.0	38	1
71721	2.5	38	1
71722	3.0	38	1
71723	4.0	38	1
71724	5.0	38	1
71725	6.0	38	1

Wiha Terminator Hex Inch & Metric Impact Bits - Insert & Power

**Up To 30X
Performance Over
Standard
Screwdriver Bits**



Dual material
impact absorbing
torsion zone

Impact rated bits for long life in impact applications

Provide up to 30 times impact performance over standard bits

Standard 1/4" drive - No special adaptor required

Wiha enhanced bi-material torsion zone

Precision machined exact fit tips

Wiha exclusive CVM tool steel

Guaranteed to out perform impact imposters



765 Hex Inch Terminator Impact Bits, 1/4" Insert - 10 bit pack

Item	No.	Inch	mm	pkg.
76530	1/8	29	10	
76531	9/64	29	10	
76532	5/32	29	10	
76533	3/16	29	10	
76534	7/32	29	10	
76535	1/4	29	10	




768 Hex Inch Terminator Impact Bits, 1/4" Insert - 2 bit pack

Item	No.	Inch	mm	pkg.
76830	1/8	29	2	
76831	9/64	29	2	
76832	5/32	29	2	
76833	3/16	29	2	
76834	7/32	29	2	
76835	1/4	29	2	



1/4" Drive Insert & Power Bits

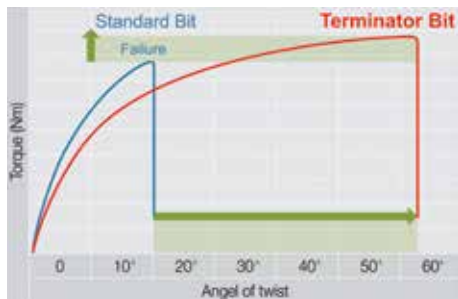

**Up To 30X Performance
Over Standard Screwdriver Bits**



765 Hex Metric Terminator Impact Bits, 1/4" Insert - 10 bit pack

Item	No.	mm	mm	pkg.
76523	3.0	29	10	
76524	4.0	29	10	
76525	5.0	29	10	
76526	6.0	29	10	



768 Hex Metric Terminator Impact Bits, 1/4" Insert - 2 bit pack

Item	No.	mm	mm	pkg.
76823	3.0	29	2	
76824	4.0	29	2	
76825	5.0	29	2	
76826	6.0	29	2	



76876 10 Pc. Set With Terminator Impact Insert Bits - 29mm

76876 Set includes the following bits:

- Hex Inch: 1/8, 9/64, 5/32, 3/16, 7/32, 1/4"
- Hex Metric: 3, 4, 5, 6mm



76893 7 Pc. Bit Buddy Set With Terminator Impact Insert Bits - 29mm

76893 Set includes the following bits:

- Hex Inch: 5/32, 3/16, 7/32, 1/4"
- Hex Metric: 4, 5, 6mm



765 Hex Inch Terminator Impact Bits, 1/4" Power - 10 bit pack

Item	No.	Inch	mm	pkg.
76570	1/8	49	10	
76571	9/64	49	10	
76572	5/32	49	10	
76573	3/16	49	10	
76574	7/32	49	10	
76575	1/4	49	10	



768 Hex Inch Terminator Impact Bits, 1/4" Power - 2 bit pack

Item	No.	Inch	mm	pkg.
76870	1/8	49	2	
76871	9/64	49	2	
76872	5/32	49	2	
76873	3/16	49	2	
76874	7/32	49	2	
76875	1/4	49	2	



765 Hex Metric Terminator Impact Bits, 1/4" Power - 10 bit pack

Item	No.	mm	mm	pkg.
76563	3.0	49	10	
76564	4.0	49	10	
76565	5.0	49	10	
76566	6.0	49	10	



768 Hex Metric Terminator Impact Bits, 1/4" Power - 2 bit pack

Item	No.	mm	mm	pkg.
76863	3.0	49	2	
76864	4.0	49	2	
76865	5.0	49	2	
76866	6.0	49	2	



76894 7 Pc. Bit Buddy Set With Terminator Impact Power Bits - 49mm

76894 Set includes the following bits:

- Hex Inch: 5/32, 3/16, 7/32, 1/4"
- Hex Metric: 4, 5, 6mm

Impact Bit Holding Sockets



720 Impact Bit Holding Socket With Retaining Ring For 1/4" drive bits.

Item	Bit	mm	Drive	lbs.
72001	1/4	25	1/4"	.05
72002	1/4	30	3/8"	.10
72003	1/4	35	1/2"	.21

72090 3 Piece Bit Holding Socket Set

for use with 1/4" Insert bits

Drive:  lbs.
1/4", 3/8", 1/2" .40

Long Blade Sockets & Sets




771 Hex Inch Sockets

Item	No.	Size	Inch	lbs.
77128	3/32	6.0	.12	
77130	7/64	6.0	.12	
77132	1/8	6.0	.12	
77134	9/64	6.0	.12	
77136	5/32	6.0	.12	
77138	3/16	6.0	.12	
77139	7/32	6.0	.12	
77141	1/4	6.0	.12	

77191 8 Piece Hex Inch Socket Blade Set

 Inch: 3/32, 7/64, 1/8, 9/64, 5/32,
3/16, 7/32, 1/4"  wt. .97



771 Hex Metric Sockets

1/4" Drive 6" Long Bit Socket

Item	No.	mm	mm	lbs.
77140	2.5	152	.13	
77142	3.0	152	.13	
77144	4.0	152	.13	
77146	5.0	152	.13	
77148	6.0	152	.13	

77192 5 Pc. Hex Metric Socket Blade Set

Metric: 2.5, 3.0, 4.0, 5.0, 6.0mm

 lbs. .70

Long Blade Sockets & Sets



771 Hex Inch Sockets

Item	No.	Size	Inch	lbs.
77165	3/32	6.0	.18	
77167	7/64	6.0	.18	
77169	1/8	6.0	.18	
77171	9/64	6.0	.18	
77173	5/32	6.0	.18	
77175	3/16	6.0	.18	
77177	7/32	6.0	.18	
77179	1/4	6.0	.18	



771 Hex Metric Sockets

3/8" Drive 6" Long Bit Socket

Item	No.	mm	mm	lbs.
77180	2.5	152	.18	
77182	3.0	152	.18	
77184	4.0	152	.18	
77186	5.0	152	.18	
77188	6.0	152	.18	



77198 22 Piece Hex & TORX® Long Blade

Socket Set, 1/4" Drive Inch Hex: 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4"

Metric Hex: 2.5, 3.0, 4.0, 5.0, 6.0mm

TORX®: T8, T9, T10, T15, T20, T25, T27, T30, T40

 lbs. 2.82

Wiha Sockets



713 Hex Sockets 3/8" Square drive socket.

Replaceable bit. 1/4" bits CVM steel.

Item	No.	Inch	mm	lbs.
71371	1/16	38	.05	
71370	5/64	38	.05	
71372	3/32	38	.05	
71374	7/64	38	.05	
71376	1/8	38	.05	
71378	9/64	38	.05	
71380	5/32	38	.05	
71382	3/16	38	.05	
71384	7/32	38	.05	
71386	1/4	38	.05	

Wiha Sockets



713 Hex Sockets 3/8" Square drive socket.

Replaceable bit. 1/4" bits CVM tool steel.

Item	No.	Inch	mm	lbs.
71375	1/8	42	.09	
71377	9/64	42	.09	
71379	5/32	42	.09	
71381	3/16	42	.09	
71383	7/32	42	.09	
71385	1/4	42	.09	
71388	5/16	42	.10	
71390	3/8	42	.10	



713 Hex Metric Sockets 1/4" Square drive

socket. Replaceable bit. 1/4" bits CVM steel.

Item	No.	mm	mm	lbs.
71301	1.5	38	.04	
71302	2.0	38	.04	
71305	2.5	38	.04	
71313	3.0	38	.04	
71314	4.0	38	.04	
71317	5.0	38	.05	
71319	6.0	38	.05	
71327	8.0	38	.05	
71340	10.0	38	.05	



3/8" Square drive socket

713 Hex Metric Sockets

Replaceable bit. 1/4" bits CVM steel.

Item	No.	mm	mm	lbs.
71300	2.0	42	.09	
71316	2.5	42	.09	
71341	3.0	42	.09	
71331	4.0	42	.09	
71323	5.0	42	.09	
71325	6.0	42	.09	
71320	8.0	42	.10	
71322	10.0	42	.11	



3/8" Square drive socket

71332 Hex Metric Sockets

Replaceable bit. 5/16" bits CVM steel.

Item	No.	mm	mm	lbs.
71332	12.0	75	.22	



Replaceable bit

761 Security Hex Inch Sockets

3/8" Square drive socket. 1/4" bits CVM steel.

Item No.	Inch	mm	lbs.
76164	5/64	42	.09
76165	3/32	42	.09
76166	7/64	42	.09
76167	1/8	42	.09
76168	9/64	42	.09
76169	5/32	42	.09
76170	3/16	42	.09
76171	7/32	42	.09
76172	1/4	42	.09

761 Security Hex Metric Sockets

3/8" Square drive socket. 1/4" bits CVM steel.

Item No.	mm	mm	lbs.
76132	2.0	42	.09
76133	2.5	42	.09
76134	3.0	42	.09
76135	4.0	42	.09
76136	5.0	42	.09
76137	6.0	42	.09
76138	8.0	42	.09

1/4" Square drive socket



717 Ball End Hex Sockets

Replaceable bit. 1/4" bits CVM steel.

Item No.	Inch	mm	lbs.
71761	3/32	38	.09
71762	7/64	38	.09
71763	1/8	38	.09
71764	9/64	38	.09
71765	5/32	38	.09
71766	3/16	38	.09
71767	7/32	38	.09
71768	1/4	38	.09



717 Ball End Hex Metric Sockets

1/4" Square drive socket. Replaceable bit.
1/4" bits CVM steel.

Item No.	mm	mm	lbs.
71771	1.5	51	.11
71772	2.0	51	.11
71773	2.5	51	.11
71774	3.0	51	.11
71775	4.0	51	.11
71776	5.0	51	.12
71777	6.0	51	.12

Wiha Socket Sets On Molded Rails

Bits CVM
tool steel



71391 10 Piece Hex Inch Socket Set

1/4" Square drive replaceable bit socket.

Item No.	lbs.	Set includes the following:
71391	.48	1/16, 5/64, 3/32, 7/64, 1/8 9/64, 5/32, 3/16, 7/32, 1/4"

Bits
CVM
tool steel



71798 8 Pc. Ball End Hex Inch Socket Set

1/4" Square Drive Replaceable Bit Socket.

Item No.	lbs.	Includes the following:
71798	.80	3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4"

Bits
CVM
tool steel



71398 7 Pc. Ball End Hex Inch Socket Set

1/4" Square Drive Replaceable Bit Socket.

Item No.	lbs.	Set includes the following:
71398	.48	3/32, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4"

Bits
CVM
tool steel



71797 7 Pc. Ball End Hex Metric Sockets

1/4" Square Drive Replaceable Bit Socket.

Item No.	lbs.	Set includes the following:
71797	.72	Hex Metric: 1.5, 2.0, 2.5, 3.0, 4.0, 5.0, 6.0mm

Bits
CVM
tool steel



71392 8 Piece Hex Inch Socket Set

3/8" Square Drive Replaceable Bit Socket.

Item No.	lbs.	Set includes the following:
71392	.78	1/8, 9/64, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8"

Bits CVM
tool steel



71393 5 Piece Hex Inch Socket Set

3/8" Square Drive Replaceable Bit Socket.

Item No.	lbs.	Set includes the following:
71393	.54	Hex Inch: 1/8, 3/16, 1/4, 5/16, 3/8"

Bits CVM
tool steel



71394 5 Piece Hex Metric Socket Set

3/8" Square Drive Replaceable Bit Socket.

Item No.	lbs.	Set includes the following:
71394	.56	Hex Metric: 4.0, 5.0, 6.0, 8.0, 10.0mm

Bits CVM
tool steel



71996 9 Piece Hex Metric Socket Set

1/4" & 3/8" Sq. Dr. Replaceable Bit Socket

Item No.	lbs.	Set includes the following:
71996	.66	1/4": 1.5, 2.0, 2.5, 3.0, 4.0mm 3/8": 5.0, 6.0, 8.0, 10.0mm

Bits CVM
tool steel



71999 9 Pc. Security Hex Inch Socket Set

3/8" Square Drive Replaceable Bit Socket.

Item No.	lbs.	Set includes the following:
71999	.86	5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4"

Bits CVM
tool steel



71989 7 Pc. Security Hex Metric Sockets

3/8" Square Drive Replaceable Bit Socket.

Item No.	lbs.	Set includes the following:
71989	.74	2.0, 2.5, 3.0, 4.0, 5.0, 6.0, 8.0mm

Item No. Page	Item No. Page	Item No. Page	Item No. Page	Item No. Page	Item No. Page
13650 17	26440 21	28024 24	28545 19	33407 11	33493 11
13651 17	26441 22	28026 24	28546 19	33408 11	33494 11
13652 17	26443 22	28027 24	28547 19	33409 11	33496 10
13653 17	26445 22	28028 24	28548 19	33410 11	33498 11
13654 17	26447 22	28029 24	28549 19	33411 11	33499 11
13655 17	26449 22	28033 24	28550 19	33412 11	35112 14
13656 17	26455 22	28034 24	28551 19	33413 11	35116 14
13657 17	26457 22	28035 24	28552 19	33414 11	35120 14
13658 17	26459 22	28036 24	28553 19	33415 11	35124 14
13659 17	26461 22	28037 24	28555 19	33416 11	35128 14
13662 17	26463 22	28116 18	28556 19	33417 11	35132 14
13663 17	26465 22	28117 18	28557 19	33418 11	35136 14
13664 17	26467 22	28118 18	28558 19	33419 11	35140 14
13665 17	26490 21	28119 18	28559 19	33420 11	35143 14
13666 17	26491 21	28120 18	28560 19	33421 11	35144 14
13667 17	26493 22	28122 18	28587 19	33422 11	35145 14
13668 17	26499 21	28123 18	28588 19	33423 11	35146 14
13669 17	26900 24	28124 18	28655 19	33424 11	35147 14
13670 17	26901 24	28149 18	28740 20	33425 11	35150 14
13671 17	26913 24	28150 18	28741 20	33426 11	35152 14
13672 17	26914 24	28151 18	28742 20	33427 11	35153 14
13673 17	26916 24	28189 18	28750 20	33428 11	35155 14
13690 17	26917 24	28332 20	28751 20	33429 11	35156 14
13691 17	26918 24	28333 20	28752 20	33430 11	35159 14
13693 17	26919 24	28334 20	28916 20	33432 11	35162 14
13694 17	26920 24	28335 20	28917 20	33433 11	35165 14
26307 21	26921 24	28336 20	28918 20	33434 11	35171 14
26309 21	26923 24	28337 20	28919 20	33435 11	35174 14
26313 21	26924 24	28338 20	28920 20	33436 11	35175 14
26315 21	26925 24	28349 19	28921 20	33437 11	35176 14
26316 21	26926 24	28351 19	28923 20	33438 11	35177 14
26320 21	26927 24	28352 19	28924 20	33439 11	35178 14
26323 21	26928 24	28353 19	28931 20	33440 11	35179 14
26325 21	26929 24	28354 19	28933 20	33441 16	35180 14
26327 21	26932 24	28355 19	28935 20	33442 10	35191 15
26330 21	26935 24	28356 19	28937 20	33443 16	35192 15
26331 21	26936 24	28357 19	28938 20	33444 10	35193 15
26333 21	26937 24	28358 19	28939 20	33445 16	35194 15
26336 21	26961 23	28359 19	28940 20	33446 10	35195 13
26340 21	27505 23	28360 19	31805 17	33447 16	35196 13
26341 22	27507 23	28361 19	31807 17	33448 10	35197 13
26343 22	27509 23	28362 19	31809 17	33449 16	35200 14
26345 22	27510 23	28363 19	31811 17	33450 10	35201 14
26347 22	27513 23	28364 19	31813 17	33452 10	35202 14
26349 22	27515 23	28365 19	31815 17	33453 11	35203 14
26351 22	27520 23	28404 19	31817 17	33454 10	35204 14
26353 22	27525 23	28408 19	31830 17	33456 11	35205 14
26363 22	27530 23	28474 18	31832 17	33458 10	35206 14
26367 22	27535 23	28476 18	31834 17	33459 11	35208 14
26369 22	27537 23	28486 18	31836 17	33462 11	35210 14
26371 22	27539 23	28487 18	31838 17	33465 11	35211 14
26390 21	27541 23	28488 18	31840 17	33468 11	35212 14
26391 21	27543 23	28501 19	31842 17	33471 11	35213 14
26392 22	27545 23	28502 19	31844 17	33474 11	35214 14
26393 22	27547 23	28503 19	31890 17	33477 11	35215 14
26399 21	27549 23	28505 19	32302 16	33478 16	35216 14
26413 21	27590 23	28506 19	32303 16	33480 11	35217 14
26415 21	27591 23	28507 19	32304 16	33481 16	35218 14
26416 21	28000 23	28509 19	32305 16	33482 16	35220 14
26419 21	28001 23	28511 19	32306 16	33483 16	35222 14
26420 21	28003 23	28513 19	32308 16	33484 11	35223 14
26423 21	28004 23	28515 19	32366 16	33485 16	35224 14
26425 21	28005 23	28517 19	33401 11	33486 16	35225 14
26427 21	28006 23	28518 19	33402 11	33487 16	35226 14
26430 21	28007 23	28519 19	33403 11	33488 11	35227 14
26431 21	28008 23	28521 19	33404 11	33489 10	35228 14
26436 21	28021 24	28523 19	33405 11	33490 16	35230 14
26439 21	28023 24	28525 19	33406 11	33492 11	35231 14

34 Tools that work for you

Item No. Page	Item No. Page	Item No. Page	Item No. Page	Item No. Page	Item No. Page
35232 14	36794 12	36976 6	46793 13	66926 5	71339 28
35233 14	36900 8	36977 6	46794 13	66928 4	71340 31
35234 14	36901 8	36978 6	54001 10	66930 5	71341 31
35235 14	36902 8	36979 6	54002 10	66936 4	71342 28
35236 14	36903 8	36980 6	54003 10	66937 5	71343 27
35237 14	36904 7	36981 6	54004 10	66938 5	71345 28
35239 14	36905 8	36982 6	54005 10	66944 4	71346 27
35240 14	36906 8	36983 6	54006 10	66945 4	71348 28
35241 14	36907 8	36985 6	54007 10	66946 4	71349 27
35242 14	36908 7	36986 6	54008 10	66947 4	71351 28
35243 14	36909 8	36988 6	54009 10	66950 4	71352 27
35245 14	36910 8	36989 8	54010 10	66952 4	71353 28
35246 14	36911 6	36990 7	54012 9	66953 4	71354 27
35248 14	36912 7	36991 7	54014 9	66955 4	71356 28
35249 14	36913 6	36992 7	54016 9	66956 4	71359 28
35250 14	36914 6	36993 7	54018 9	66959 4	71360 28
35251 14	36915 6	36995 7	54020 10	66962 4	71361 28
35252 14	36916 7	36996 9	54022 9	66965 4	71362 28
35253 14	36917 6	36997 9	54024 9	66968 4	71363 28
35254 14	36918 6	36998 5	54025 10	66971 4	71364 28
35255 14	36919 6	36999 8	54030 10	66982 5	71365 28
35256 14	36920 7	38014 27	54040 9	66988 5	71366 28
35257 14	36921 6	38049 26	54042 10	66990 4	71367 28
35258 14	36922 6	38056 26	54050 9	66991 4	71368 28
35259 14	36923 8	38057 26	54052 10	66992 4	71369 28
35260 14	36924 7	38058 26	54060 9	66993 5	71370 31
35261 14	36925 8	46701 8	54062 10	66994 5	71371 31
35270 14	36926 8	46702 13	54080 9	66995 5	71372 31
35280 14	36927 8	46703 8	54082 10	66996 5	71373 28
35282 14	36928 7	46704 13	54086 9	66997 9	71374 31
35284 14	36929 8	46705 8	54088 10	66998 5	71375 31
35286 14	36930 8	46706 13	54090 9	70172 29	71376 31
35288 14	36931 8	46707 8	54091 9	70176 29	71377 31
35290 14	36932 8	46708 13	54092 10	71300 31	71378 31
35295 14	36933 8	46709 8	54094 10	71301 31	71379 31
35297 14	36934 8	46710 13	54095 10	71302 31	71380 31
35299 14	36935 8	46711 8	54097 10	71303 28	71381 31
35390 15	36936 7	46712 13	56901 6	71304 27	71382 31
35391 15	36937 8	46713 8	56902 6	71305 31	71383 31
35392 15	36938 8	46714 13	56903 6	71306 28	71384 31
35393 15	36939 8	46715 13	56904 6	71307 27	71385 31
36696 7	36944 7	46716 13	56905 6	71308 28	71386 31
36710 12	36945 7	46717 8	56906 6	71309 28	71387 28
36713 12	36946 7	46718 13	56907 6	71310 27	71388 31
36715 12	36947 7	46719 8	56908 6	71311 27	71390 31
36716 12	36949 5	46721 8	56909 6	71312 28	71391 32
36719 12	36950 7	46722 13	56910 6	71313 31	71392 32
36720 12	36951 5	46723 8	56911 6	71314 31	71393 32
36723 12	36952 7	46724 13	56912 6	71315 28	71394 32
36725 12	36953 7	46725 13	56913 6	71316 31	71396 27
36726 12	36954 5	46726 13	56914 6	71317 31	71397 27
36728 12	36955 7	46727 8	56915 6	71318 28	71398 32
36730 12	36956 7	46730 13	56916 6	71319 31	71480 27
36732 12	36957 5	46731 8	56917 6	71320 31	71491 27
36734 12	36958 5	46732 8	56918 6	71321 28	71701 29
36736 12	36959 7	46733 8	56919 6	71322 31	71702 29
36738 12	36960 5	46734 8	56920 6	71323 31	71703 29
36740 12	36961 5	46735 8	56921 6	71324 28	71704 29
36742 12	36962 7	46736 8	56922 6	71325 31	71705 29
36744 12	36963 5	46737 8	62994 22	71326 28	71706 29
36750 12	36965 7	46738 8	66904 4,5	71327 31	71707 29
36760 12	36966 8	46739 8	66908 4,5	71328 28	71708 29
36780 12	36968 7	46740 13	66912 4,5	71329 28	71711 29
36786 12	36971 7	46741 8	66916 4	71330 28	71712 29
36790 12	36972 6	46750 13	66918 5	71331 31	71713 29
36791 12	36973 6	46760 13	66920 4	71332 31	71714 29
36792 12	36974 6	46780 13	66922 5	71333 28	71715 29
36793 12	36975 6	46786 13	66924 4	71336 28	71716 29

Item No.	Page	Item No.	Page	Item No.	Page	Item No.	Page	Item No.	Page	Item No.	Page
71717	29	72582	28	74384	29	76003	18	76876	30		
71718	29	72583	28	74385	29	76004	18	76893	30		
71719	29	72584	28	74386	29	76045	18	76894	30		
71720	29	72585	28	74387	29	76046	18	77128	31		
71721	29	72586	28	74388	29	76047	18	77130	31		
71722	29	72587	28	74986	27	76048	18	77132	31		
71723	29	72596	26	74999	27	76049	18	77134	31		
71724	29	73301	28	75096	24	76050	18	77136	31		
71725	29	73302	28	75307	25	76051	18	77138	31		
71761	32	73303	28	75309	25	76052	18	77139	31		
71762	32	73304	28	75313	25	76053	18	77140	31		
71763	32	73305	28	75315	25	76054	18	77141	31		
71764	32	73306	28	75320	25	76132	32	77142	31		
71765	32	73307	28	75322	25	76133	32	77144	31		
71766	32	73308	28	75325	25	76134	32	77146	31		
71767	32	73309	28	75330	25	76135	32	77148	31		
71768	32	74301	27	75332	25	76136	32	77165	31		
71771	32	74305	27	75340	25	76137	32	77167	31		
71772	32	74307	27	75342	25	76138	32	77169	31		
71773	32	74311	29	75350	25	76164	32	77171	31		
71774	32	74312	29	75352	25	76165	32	77173	31		
71775	32	74313	29	75354	25	76166	32	77175	31		
71776	32	74314	29	75356	25	76167	32	77177	31		
71777	32	74315	29	75358	25	76168	32	77179	31		
71797	32	74316	29	75360	25	76169	32	77180	31		
71798	32	74317	29	75362	25	76170	32	77182	31		
71930	28	74318	29	75364	25	76171	32	77184	31		
71932	28	74319	27	75366	25	76172	32	77186	31		
71934	28	74325	29	75368	25	76523	30	77188	31		
71936	28	74330	29	75370	25	76524	30	77191	31		
71938	28	74332	29	75372	25	76525	30	77192	31		
71939	28	74333	29	75395	24	76526	30	77198	31		
71940	28	74334	29	75616	25	76530	30	77719	28		
71941	28	74335	29	75617	25	76531	30	77720	28		
71942	28	74336	29	75618	25	76532	30	77721	28		
71943	28	74337	29	75619	25	76533	30	77723	28		
71944	28	74340	29	75620	25	76534	30	77724	28		
71945	28	74342	29	75621	25	76535	30	77725	28		
71946	28	74343	29	75622	25	76563	30	77726	28		
71955	28	74344	29	75623	25	76564	30	79246	26		
71956	28	74345	29	75624	25	76565	30	79256	26		
71960	28	74346	29	75626	25	76566	30	79266	27		
71970	28	74348	29	75627	25	76570	30	79276	26		
71971	28	74349	29	75628	25	76571	30	79446	26		
71972	28	74350	29	75629	25	76572	30	91118	21		
71973	28	74351	29	75630	25	76573	30				
71974	28	74352	29	75631	25	76574	30				
71975	28	74353	29	75632	25	76575	30				
71976	28	74354	29	75633	25	76823	30				
71977	28	74355	29	75634	25	76824	30				
71978	28	74356	29	75635	25	76825	30				
71979	28	74357	29	75636	25	76826	30				
71980	28	74360	29	75637	25	76830	30				
71981	28	74361	29	75638	25	76831	30				
71982	28	74362	29	75639	25	76832	30				
71983	28	74363	29	75640	25	76833	30				
71984	28	74364	29	75641	25	76834	30				
71985	28	74365	29	75642	25	76835	30				
71989	32	74366	29	75643	25	76863	30				
71995	27	74369	27	75800	25	76864	30				
71996	32	74371	27	75801	25	76865	30				
71998	27	74373	27	75900	25	76866	30				
71999	32	74375	27	75901	25	76870	30				
72001	31	74379	27	75982	26	76871	30				
72002	31	74380	29	75983	26	76872	30				
72003	31	74381	29	76000	18	76873	30				
72090	31	74382	29	76001	18	76874	30				
72388	29	74383	29	76002	18	76875	30				




Prop65 WARNING: This product could expose you to Chrome 6, DEHP & Phthalates. These chemicals are known to the state of California to cause cancer. For more information go to www.P65warnings.ca.gov/



PROFESSIONAL HEX TOOLS

Inch & Metric

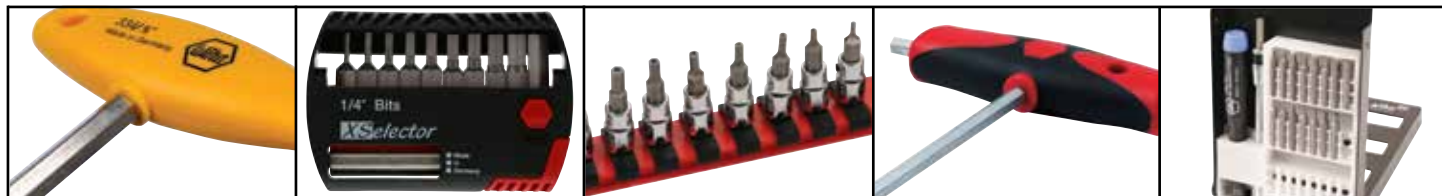

(800) 494-6104
fax: (800) 494-7456
cservice@wihatools.com



Wiha Quality Tools

1348 Dundas Circle
Monticello, MN 55362
tel: 763.295.6591
fax: 763.295.6598

Wiha Tools Canada Ltd.

www.wihatools.ca
Brampton, ONT L6T 4X4
tel: 866.494.0096 or 763.295.6591
fax: 763.295.6598



To:

Catalog Item No. 99934.wo
version - 3/1/19

Subject to change
without notice

©2019 Willi Hahn Corporation



99977.wo - Pliers/Crimpers Catalog



99914.wo - TORX Catalog




99001.wo - TorqueControl Catalog



99951.wo - Bits Catalog



99919.wo - Insulated Catalog

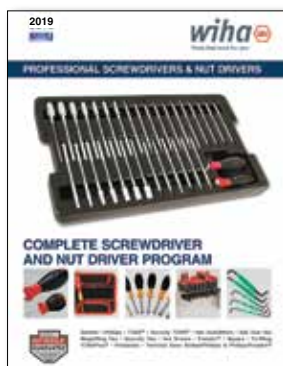

99002.wo - Screwdrivers Catalog




99004.wo - Shop Tools Catalog



99006.wo - Tech Tools Catalog



99945.wo - ESD Catalog

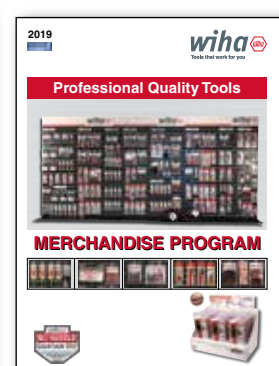

99007.wo - Merchandise Catalog

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Wiha:

33489	66993	71723	66988	54042	54092	36919	36922	36918	36915	66937	36921	36917	54088	54062
54020	54025	54082	66926	71702	66922	71701	54052	46794	36989	54030	36954	36988	36913	66998
66992	71722	54094	33429	36914	66995	66982	66930	33419	71329	66938	36911	36995	54097	54095
36987	66918	46701	46705	46733	46734	46735	46736	46737	46739	56911	56920	36905	36906	36909
36931	36932	36933	36966	56922	36903	36902	36901	46717	36975	76045	76048	28476	36938	36939
46703	46727	46731	46732	46738	46741	56902	56903	56904	56905	56906	56907	56908	56909	56910
56913	56915	56916	56917	56918	56919	56921	46721	56901	56914					