

PortaCrimp Dies



One piece die, held together to prevent mix up & loss. Easily interchangeable crimp dies are kept together with a special pin to simplify handling. Reliable crimping performance is consistent & accurate with a parallel action stroke, good to 50,000 cycles.



43150 PortaCrimp Open Barrel Non-Insulated Push On Terminals DIN 46247-1 .110" (2.8mm) Tab

Item				
No.	Crimps	AWG	lbs.	Pkg.
43150	0.5-1.0/0.25-0.5/0.1-0.25mm ²	26-18	1.2	1



43151 PortaCrimp Open Barrel Non-Insulated Push On Terminals DIN 46247-2 .187" (4.8mm) Tab

Item				
No.	Crimps	AWG	lbs.	Pkg.
43151	1.5-2.5 & 0.5-1.5mm ²	22-14	1.2	1



43143 PortaCrimp Weather Pack Open Barrel Terminals

Item				
No.	Crimps	AWG	lbs.	Pkg.
43143	3.0-0.5mm ²	12-20	1.2	1



43141 PortaCrimp Fiber Optic Die set for SMA, SMB, SFR, ST, SC fiber optic connectors (.178"/.213"/.151"/.128" hex)

Item				
No.	Crimps		lbs.	Pkg.
43141	4.52/5.41/3.84/3.25mm	(.178"/.213"/.151"/.128")	1.2	1

[SHOP](#)

43136 PortaCrimp Coaxial Network & Communications

Die set for RG58, RG59, RG62AU BNC/TNC Coaxial Connectors (.213"/.255"/.068" hex).

Item	Crimps			
No.	1.69/5.41/6.48mm	lbs.	Pkg.	
43136	(.213"/.255"/.068"hex)	1.2	1	



43138 PortaCrimp Coaxial Network & Communications, CATV, HDTV, Video Die set for RG6, Belden 1694A, Twinax BNC, CATV F Coaxial Connectors (.360"/.324" Hex).


Item				
No.	Crimps	lbs.	Pkg.	
43138	9.14 & 8.23mm (.360"/.324")	1.2	1	



43140 PortaCrimp Coaxial Network & Communications

Die set for RG174, RG179 BNC/TNC Coaxil Connectors (.178"/.128"/.068" Hex, .028"(0.7mm)Sq.

Item	Crimps			
No.	4.52/3.25/1.69mm hex 0.7mm sq.	lbs.	Pkg.	
43140	(.178"/.128"/.068" hex, .028" sq.)	1.2	1	

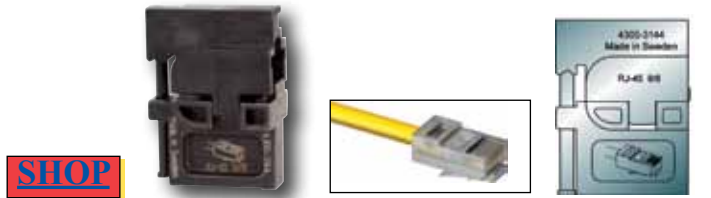

43144 PortaCrimp Datacom/Telecom Modular Plug Die set for 8-position 8-contact (RJ45).

Item No.	RJ45			
43144		1.2	1	



43132 PortaCrimp Datacom/Telecom Modular Plug

Die set for 6-position 6-contact (RJ11).

Item No.	RJ11			
43132		1.2	1	

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Wiha:](#)

[43138](#) [43140](#) [43141](#) [43150](#) [43151](#) [43144](#) [43132](#) [43143](#) [43136](#)