

2019





wiha 
Tools that work for you

PROFESSIONAL TECH TOOLS



COMPLETE TECHNICIAN'S PROGRAM

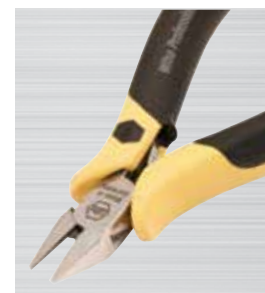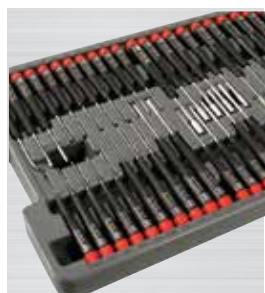

Precision Screwdrivers • PicoFinish Drivers • TorqueControl
Micro Bits • Blade Sets • Electronic Pliers • ESD Tweezers • Mirrors

Wiha Precision Screwdrivers

Description	Page
Precision Slotted Drivers	4
Precision Phillips Drivers	4
Precision Pozidriv® Drivers	5
Precision Hex Drivers	5
Precision Ball End Drivers	6
Precision Nut Drivers	7
Precision Torx® Drivers	6
Precision Pentalobe Drivers	7
Precision Chip Lifters	4

Wiha Magnetizer/Demagnetizer

Description	Page
Magnetizer/Demagnetizer	11

Wiha Precision Protturn Drivers

Description	Page
Protturn Drivers & Blade Sets	12
Slotted, Phillips, Torx, Chip Lifter	

Wiha TorqueControl Tools

Description	Page
Torque Cable Keys	8
TorqueControl Handle	8

Wiha ESD Safe Precision Handles/Blades

Description	Page
SYSTEM 4 Handles/Blades	13-15

Wiha Precision Screwdriver Accessories

Description	Page
Precision Master Tech Sets	8
Precision Pocket Clip	4
Precision Stand	4
Precision Pouch	11

Wiha ESD Safe Precision Handle & Blades

Description	Page
SYSTEM 4 Drive-Loc Handle & Blades	15
SYSTEM 4 Drive-Loc Set	15

Wiha Precision PicoFinish Drivers

Description	Page
PicoFinish Screwdrivers	9-12
Slotted, Phillips, Torx, TorxPlus, Hex, MagicSpring, Ball End Hex, Chip Lifter & Nut Drivers	
Tri-Wing Drivers	
Insulated PicoFinish Drivers	12

ESD Safe Micro Bit Handles, Bits & Sets

Description	Page
Micro Bit Handles/Bits/Sets	16-21
Micro Bit Storage Handle Sets	21
ESD Safe Micro Bit Sets	18-21

Precision Electronic Pliers/Cutters

	Description	Page
	Electronic Diagonal Cutters Wide Pointed Head	22
	Electronic Diagonal Cutters Wide Shape w/Wire Holding Spring	22
	Electronic Diagonal Cutters Narrow Shap	22
	Electronic Diagonal Cutters Full Flush Cutters w/Wire Trapping Spring	22
	Electronic Diagonal Cutters 48° Front Cutter/Long Nose Pliers	22
	Electronic Diagonal Cutters Oblique 30° Cutting Nippers	22
	Electronic Diagonal Cutters Short Nose Precision Pliers	22
	Electronic Stripping Pliers	22

Wiha Professional Tweezers

	Description	Page
	ESD Safe Tweezers	23-25
	Inspection Mirrors	25

Wiha ESD Safe Tech Tools

ESD Safe Precision Drivers
Slotted/Phillips/Torx®/
TorxPlus®/Hex/Nut Drivers/
Chip Lifter

ESD Safe Ceramic Drivers

ESD Safe SYSTEM 4
Handles/Blades/Sets

ESD Safe Drive-Loc
Handles/Blades/Sets

ESD Safe Pliers & Cutters



Catalog 99945.wo



The Comfortable Precision Screwdriver

Soft Grip Handle

CVM tool steel
blade, hardened,
hard chrome finish

Ergonomic multi-
component handle
with rotating cap for
maximum user comfort
and precise control

Sets In Roll-Up Pouch



New & Improved
PicoFinish
Screwdrivers On
Pages 9-12



Rotating cap
for precise turning and control with fingertip

Precision handle
high quality plastic, cadmium free

Molded on tapered handle
allows rapid rotation

High performance blades
CVM steel,
Hard chrome finished

Tip
precision ground for exact fit,
hard chromed non-slip surface



Wiha Precision Chip Lifter & Accessories

26810 Precision Chip Lifter

Blade CVM steel, hardened, chrome-plated. Precision handle high quality plastic, impact resistant. Standard handle

Item No.	mm	mm	mm	mm	Inch	lbs.	Pkg.
26810	1	3.5	50	145	5.7	.07	1

*Metric dimensions actual - Inch dimensions approximate



26001 Pocket Clip for Precision

Screwdrivers Tool clips turn Precision Screwdrivers into Pocket Screwdrivers.

Item No.	Fits all	lbs.	pkg.
26001	Precision handles	.01	1



26000 Plastic Precision Tool Rack

Rack holds 6 precision screwdrivers, can be set on workbench. Also has holes for hanging. Made from high quality plastic.

Item No.	Rack for 6	lbs.	Pkg.
26000	Precision screwdrivers	.08	1

Wiha Precision Slotted/Phillips Drivers



260 Slotted Screwdriver, With Precision

Handle Blade high alloy chrome-vanadium-molybdenum steel. Pkg. 10

Item No.	mm	Inch	mm	Inch	mm	mm	Inch	lbs.
26008	.80	1/32	40	1.6	0.16	120	4.7	.02
26010	1.0	.039	40	1.6	0.18	120	4.7	.02
26012	1.2	3/64	40	1.6	0.20	120	4.7	.02
26015	1.5	1/16	40	1.6	0.25	120	4.7	.02
26018	1.8	.070	40	1.6	0.30	120	4.7	.02
26020	2.0	5/64	40	1.6	0.40	120	4.7	.02
26022	2.0	5/64	50	2.0	0.40	145	5.7	.02
26023	2.0	5/64	100	3.9	0.40	180	7.1	.03
26025	2.5	3/32	50	2.0	0.40	145	5.7	.03
26027	2.5	3/32	100	3.9	0.40	195	7.7	.03
26028	2.5	3/32	150	6.0	0.40	245	9.6	.04
26030	3.0	1/8	50	2.0	0.50	145	5.7	.03
26032	3.0	1/8	60	2.4	0.50	170	6.7	.04
26033	3.0	1/8	100	3.9	0.50	210	8.3	.04
26034	3.0	1/8	150	5.9	0.50	260	10.2	.05
26035	3.5	9/64	60	2.4	0.60	170	6.7	.05
26040	4.0	5/32	60	2.4	0.80	170	6.7	.05
26041	4.0	5/32	100	3.9	0.80	210	8.3	.06
26042	4.0	5/32	150	5.9	0.80	260	10.2	.07

*Metric dimensions actual - Inch dimensions approximate



26090 6pc Precision Slotted Set

Blade high alloy chrome-vanadium-molybdenum steel. Hard chrome finished.

Item No.	Slotted:	lbs.
26090	1.5, 2.0 x 40mm	.27
	2.5, 3.0 x 50mm	
	3.5, 4.0 x 60mm	



26099 8pc Precision Slotted Set

Blade high alloy CVM steel. Hard chrome finished. In canvas storage pouch.

Item No.	Slotted:	lbs.
26099	1.0, 1.2, 1.5, 2.0 x 40mm	
	2.5, 3.0 x 50mm, 3.5, 4.0 x 60mm	.54



261 Phillips Screwdriver, With Precision

Handle Blade high alloy chrome-vanadium-molybdenum steel. Pkg. 10

Item No.	Size	mm	Inch	mm	Inch	mm	Inch	lbs.
26102	000	40	1.6	2.0	.08	120	4.7	.02
26100	00	40	1.6	2.0	.08	120	4.7	.02
26101	00	75	3.0	2.0	.08	155	6.1	.02
26105	0	50	2.0	3.0	.12	145	5.7	.02
26108	0	75	3.0	3.0	.12	170	6.7	.03
26107	0	100	3.9	3.0	.12	195	7.6	.05
26109	0	150	5.9	3.0	.12	245	9.6	.06
26110	1	60	2.4	4.0	.16	170	6.7	.05
26113	1	80	3.1	4.0	.16	190	7.5	.05
26114	1	100	3.9	4.0	.16	210	8.2	.06
26115	1	150	5.9	4.0	.16	260	10.2	.07

*Metric dimensions actual - Inch dimensions approximate



26190 8pc Precision Slotted & Phillips

Screwdrivers and Industrial Long Nose Pliers Set

Item No.	Slotted: 1.5 x 40mm
26190	2.0, 2.5 x 50mm, 3.0 x 60mm
	Phillips: 00 x 40mm
lbs. .72	0 x 50mm, 1 x 60mm
	Industrial Long Nose Pliers
	6.3"/160mm OAL



26197 7pc Precision Slotted &

Phillips Set Blade high alloy CVM steel.

Item No.	Slotted: 1.5 x 40mm
26197	2.0, 2.5 x 50mm, 3.0 x 60mm
	Phillips: 00 x 40mm
lbs. .31	0 x 50mm, 1 x 60mm



26199 8pc Precision Slotted/Phillips Set

Item No.	Slotted: 1.0, 2.0 x 40mm, 3.0 x 50mm, 4.0 x 60mm	lbs.
26199	Phillips: 000, 00 x 40mm, 0 x 50mm, 1 x 60mm	.55



In canvas storage pouch

Wiha Precision Slotted/Phillips Drivers



26092 7pc Precision Slotted & Phillips

Set Blade high alloy chrome-vanadium-molybdenum steel.

Item No. 

26092	Slotted:	lbs.
	2.5 x 50mm,	.30
	2.5, 3.0, 4.0 x 100mm	
	3.0, 4.0 x 150mm	
	Phillips:	
	0 x 75mm	



26194 4pc Precision Phillips Set

Blade high alloy chrome-vanadium-molybdenum steel. Hard chrome finished.

Item **Phillips:** 

No.	000, 00 x 40mm	lbs.
26194	0 x 50mm, 1 x 60mm	.18



26192 5pc Precision Slotted & Phillips

Set Blade high alloy chrome-vanadium-molybdenum steel.

Item **Slotted:** 

No.	2.5, 3.0, 4.0 x 150mm	lbs. .44
26192	Phillips:	
	0, 1 x 150mm	

Wiha Pozidriv® Precision Series



262 Pozidriv® Screwdriver, With

Precision Handle Blade high alloy chrome-vanadium-molybdenum steel.  Pkg. 10

Item								
No.	Size	mm	Inch	mm	Inch	mm	Inch	lbs.
26205	0	50	2.0	3.0	.12	145	5.7	.03
26210	1	60	2.4	4.0	.16	170	6.7	.05

*Metric dimensions actual - Inch dimensions approximate

Wiha Hex Inch & Metric Precision Series



263 Inch **Inch Hex Driver, With Precision Handle** Inch sizes. Blade high alloy chrome-vanadium-molybdenum steel.  Pkg. 10

Item							
No.	Inch	mm	mm	Inch	mm	Inch	lbs.
26307	0.028	0.7	40	1.6	120	4.7	.02
26309	0.035	0.9	40	1.6	120	4.7	.02
26313	0.05	1.3	40	1.6	120	4.7	.02
26316	1/16	-	50	2.0	145	5.7	.03
26320	5/64	2.0	50	2.0	145	5.7	.03
26323	3/32	-	60	2.4	170	6.7	.04
26327	7/64	-	60	2.4	170	6.7	.04
26331	1/8	-	60	2.4	170	6.7	.04
26333	9/64	-	60	2.4	170	6.7	.05
26336	5/32	-	60	2.4	170	6.7	.05

*Metric dimensions actual - Inch dimensions approximate



26391 8pc Precision Hex Driver Set - Inch Blade high alloy chrome-vanadium-molybdenum steel.

Item No.	
26391	Hex Inch:
	.028, .035, .050 x 1.6"
	1/16, 5/64 x 2.0"
	3/32, 7/64, 1/8 x 2.4"



26399 8pc Precision Hex Driver Set - Inch Blade high alloy CVM steel. Hard chrome finished. In canvas storage pouch

Item No.	Hex Inch:	
26399	.028, .035, .050 x 1.6"	lbs. .55
	1/16, 5/64 x 2.0", 3/32, 7/64, 1/8 x 2.4"	



263 Metric **Metric Hex Driver, With Precision Handle** Metric sizes. Blade high alloy chrome-vanadium-molybdenum steel.

Item								
No.	mm	Inch	mm	Inch	mm	Inch	lbs.	pkg.
26307	.7	.028	40	1.6	120	4.7	.02	10
26309	.9	.035	40	1.6	120	4.7	.02	10
26313	1.3	.050	40	1.6	120	4.7	.02	10
26315	1.5	-	50	2.0	145	5.7	.03	10
26320	2.0	5/64	50	2.0	145	5.7	.03	10
26325	2.5	-	60	2.4	170	6.7	.04	10
26330	3.0	-	60	2.4	170	6.7	.04	10
26340	4.0	-	60	2.4	170	6.7	.05	10

*Metric dimensions actual - Inch dimensions approximate



26390 7pc Precision Hex Driver Set - Metric Blade high alloy chrome-vanadium-molybdenum steel.

Item No.	
26390	Hex Metric:
	.7, .9, 1.3 x 40mm
	1.5, 2.0 x 50mm
	2.5, 3.0 x 60mm

Y-Type Precision Driver

Y-Type

(Used in iPhone 7 or higher series)



26601 Y-Type Precision Screwdriver Blade high alloy CVM steel.

Hard chrome finished.

Item							
No.	Size	mm	Inch	mm	Inch	mm	Inch
26601	000	40	1.6	2.0	.08	120	4.75

Wiha Ball End Precision Series



264 Inch Ball End Hex Inch Screwdriver

With Precision Handle Angle entry up to 30°. Blade high alloy chrome-vanadium-molybdenum steel. Hard chrome finish.

Item	No.	Inch	mm	Inch	mm	Inch	lbs.	Pkg.
26413	.050	40	1.6	120	4.7	.02	10	
26416	1/16	50	2.0	145	5.7	.03	10	
26419	5/64	50	2.0	145	5.7	.03	10	
26423	3/32	50	2.0	145	5.7	.03	10	
26427	7/64	60	2.4	170	6.7	.03	10	
26431	1/8	60	2.4	170	6.7	.05	10	
26436	9/64	60	2.4	170	6.7	.05	10	
26439	5/32	60	2.4	170	6.7	.05	10	

*Metric dimensions actual - Inch dimensions approximate



264 Metric Ball End Hex Metric Screwdriver

With Precision Handle Angle entry up to 30°. Blade high alloy CVM steel.

Item	No.	mm	Inch	mm	Inch	mm	Inch	lbs.	Pkg.
26413	1.3	.050	40	1.6	120	4.7	.02	10	
26415	1.5	-	50	2.0	145	5.7	.03	10	
26420	2.0	-	50	2.0	145	5.7	.03	10	
26425	2.5	-	60	2.4	170	6.7	.04	10	
26430	3.0	-	60	2.4	170	6.7	.05	10	
26440	4.0	-	60	2.4	170	6.7	.05	10	

*Metric dimensions actual - Inch dimensions approximate



26491 5pc Ball End Hex Driver Set - Metric

Angle entry up to 30°.

Blade high alloy chrome-vanadium-molybdenum-steel.

Item	No.	Ball End Hex Metric:	lbs.
26491	1.3 x 40mm		.25
	1.5, 2.0 x 50mm		
	2.5, 3.0 x 60mm		



26490 8 Piece Ball End Hex Driver Set - Inch

Angle entry up to 30°.

Blade high alloy chrome-vanadium-molybdenum steel.

Item	No.	Hex Inch:	lbs.
26490	1/16, 5/64, 3/32 x 2.0,		.28
	7/64, 1/8, 9/64,		
	5/32 x 2.4"		



26499 8pc Ball End Hex Driver Set - Inch

Blade high alloy chrome-vanadium-molybdenum steel. Hard chrome finished.

Item	No.	Ball End Hex Inch:	lbs.
26499	.050 x 1.6"		.62
	1/16, 5/64, 3/32 x 2.0"		
	7/64, 1/8, 9/64, 5/32 x 2.4"		

Wiha TORX® Precision Series



26792 7pc TORX® Screwdriver Set

Blade high alloy chrome-vanadium-molybdenum steel.

Item	No.	TORX®:	lbs.
26792	T5, T6, T7, T8 x 40mm		.33
	T9, T10 x 50mm		
	T15 x 60mm		

Wiha TORX® Precision Series



267 TORX® Screwdriver, With Precision

Handle Blade high alloy chrome-vanadium-molybdenum steel.

Item	No.	Size	mm	Inch	mm	Inch	lbs.	pkg.
26701	T1	40	1.6	120	4.7	.01	10	
26702	T2	40	1.6	120	4.7	.02	10	
26703	T3	40	1.6	120	4.7	.02	10	
26704	T4	40	1.6	120	4.7	.02	10	
26705	T5	40	1.6	120	4.7	.02	10	
26706	T6	40	1.6	120	4.7	.02	10	
26707	T7	40	1.6	120	4.7	.02	10	
26708	T8	40	1.6	120	4.7	.03	10	
26709	T9	50	2.0	145	5.7	.03	10	
26710	T10	50	2.0	145	5.7	.03	10	
26715	T15	60	2.4	170	6.7	.05	10	
26720	T20	60	2.4	170	6.7	.05	10	

*Metric dimensions actual - Inch dimensions approximate



26790 6pc TORX® Screwdriver Set

Blade high alloy chrome-vanadium-molybdenum steel.

Item	No.	TORX®:	lbs.
26790	T6, T7, T8 x 40mm		.30
	T9, T10 x 50mm		
	T15 x 60mm		

26791 8pc TORX® Screwdriver Set

Item No.	T1, T2, T3, T4,
26791	T5, T6, T7, T8



26799 8pc TORX® Screwdriver Set

Blade high alloy chrome-vanadium-molybdenum steel. Hard chrome finished. In canvas storage pouch

Item	No.	TORX®:	lbs.
26799	T3, T4, T5, T6, T7, T8 x 40mm		.50
	T9 x T10 x 50mm		

Wiha Pentalobe Precision Series

Wiha Pentalobe drivers will fit fasteners used in "Apple" brand products including iPhone, Mac Book & Mac Air

- Exact fit precision machined tips
- High performance CRM72 tool steel
- Hard chromed finish blades & tips
- Tapered ergonomic handle
- Easy spin finger tip control cap



267 Pentalobe Screwdrivers, With

Precision Handle Blade high alloy chrome-vanadium-molybdenum steel.

Item No.	Size	mm	Inch	mm	Inch	lbs.	pkg.
26761	PL1	40	1.6	120	4.7	.01	1
26762	PL2	40	1.6	120	4.7	.02	1
26763	PL3	40	1.6	120	4.7	.02	1
26764	PL4	40	1.6	120	4.7	.02	1
26765	PL5	40	1.6	120	4.7	.02	1
26766	PL6	40	1.6	120	4.7	.02	1

*Metric dimensions actual - Inch dimensions approximate



26794 6pc Precision Pentalobe

Screwdriver Set Blade high alloy CVM steel. Hard chrome finished. Super hardened best wear resistance long life.

Item No.	Pentalobe Drivers:	lbs.
26794	PL1, PL2, PL3, PL4, PL5, PL6	.35

Wiha Nut Driver Precision Series



265 Metric Metric Nut Driver With Precision Handle Metric sizes. Blade CVM steel. Hard chrome finished.

Item No.	mm	mm	Inch	mm	Inch	mm	mm	lbs.	Pkg.
26510	1.5	60	2.4	140	5.5	2.5	3.0	.03	10
26515	1.8	60	2.4	140	5.5	2.9	3.5	.03	10
26520	2.0	60	2.4	140	5.5	3.2	4.0	.04	10
26525	2.5	60	2.4	155	6.1	4.0	4.0	.04	10
26530	3.0	60	2.4	155	6.1	5.0	5.0	.05	10
26532	3.2	60	2.4	155	6.1	5.0	5.0	.05	10
26535	3.5	60	2.4	155	6.1	5.3	6.0	.05	10
26540	4.0	60	2.4	155	6.1	5.5	6.0	.05	10
26545	4.5	60	2.4	155	6.1	6.2	7.0	.05	10
26550	5.0	60	2.4	155	6.1	6.8	7.0	.05	10
26555	5.5	60	2.4	170	6.7	7.6	8.0	.06	10
26560	6.0	60	2.4	170	6.7	8.2	9.0	.06	10
26570	7.0	60	2.4	170	6.7	9.6	10.0	.06	10

*Metric dimensions actual - Inch dimensions approximate



26590 8pc Precision Nut Driver Set - Metric Blade CVM steel.

Item No.	Metric Nut Drivers:	lbs.
26590	2.5, 3.0, 3.5, 4.0, 4.5, 5.0, 5.5, 6.0 x 60mm	.48

26592 7pc Nut Driver Set - Metric

Item No.	Metric Nut Drivers:
26592	1.5, 1.8, 2.0, 2.5, 3.0, 3.5, 4.0mm



26598 8pc Precision Nut Driver Set - Metric Blade high alloy CVM steel. Hard chrome finished. In canvas storage pouch

Item No.	Metric Nut Drivers:	lbs.
26598	2.5, 3.0, 3.5, 4.0, 4.5, 5.0, 5.5, 6.0 x 60mm	.70



265 Inch Inch Nut Driver With Precision Handle Inch sizes. Blade CVM steel. Hard chrome finished.

Item No.	Inch	mm	Inch	mm	Inch	mm	mm	lbs.	Pkg.
26523	3/32	60	2.4	155	6.1	.16	.16	.04	10
26527	7/64	60	2.4	155	6.1	.20	.20	.05	10
26531	1/8	60	2.4	155	6.1	.20	.20	.05	10
26536	9/64	60	2.4	155	6.1	.21	.24	.05	10
26539	5/32	60	2.4	155	6.1	.22	.24	.05	10
26547	3/16	60	2.4	155	6.1	.25	.28	.05	10
26556	7/32	60	2.4	170	6.7	.30	.32	.06	10
26563	1/4	60	2.4	170	6.7	.34	.36	.06	10

*Metric dimensions actual - Inch dimensions approximate



26591 8pc Precision Nut Driver Set - Inch Blade CVM steel.


Item No.	Inch Nut Drivers:	lbs.
26591	3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4" x 2.4"	.47



26599 8pc Precision Nut Driver Set - Inch Blade high alloy CVM steel. Hard chrome finished. In canvas storage pouch

Item No.	Inch Nut Drivers:	lbs.
26599	3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4" x 2.4"	.72

Wiha Precision Screwdriver Set

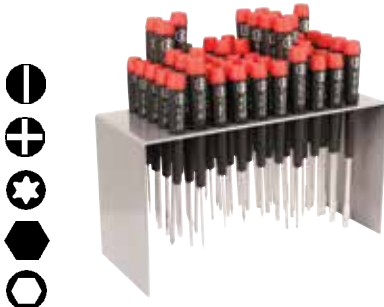

92189 Master Technicians Bench Top Set
Metal frame. Equipped with 50 precision drivers.

Item No.	Slotted: .8, 1.0, 1.2, 1.5, 1.8, 2.0, 2.5, 3.0, 3.5, 4.0
92189	Phillips: #000, #00, #0, #1
	Pentalobe: PL1, PL2, PL3, PL4
	TORX®: T1, T2, T3, T4, T5, T6, T7, T8, T9, T10
	Metric Hex: 1.27, 1.5, 2.0, 2.5, 3.0
	Inch Hex: .028, .035, .050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32"
	Metric Nut Drivers: 1.5, 1.8, 2.0, 2.5, 3.0, 3.5, 4.0, 4.5, 5.0, 5.5
	26810 Chip Lifter



92191 51pc Precision Tool Tray Set
Tool box tray. Equipped with 51 precision drivers.

Item No.	Slotted: .8, 1.0, 1.2, 1.5, 1.8, 2.0, 2.5, 3.0, 3.5, 4.0
92191	Phillips: #000, #00, #0, #1
	Torx®: T1, T2, T3, T4, T5, T6, T7, T8, T9, T10
	Metric Hex: 1.27, 1.5, 2.0, 2.5, 3.0, 4.0
	Inch Hex: .028, .035, .050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32"
	Metric Nut Drivers: 1.5, 1.8, 2.0, 2.5, 3.0, 3.5, 4.0, 4.5, 5.0, 5.5
	26810 Chip Lifter



92190 Master Technicians Bench Top Set
Metal frame. Equipped with 50 precision drivers.

Item No.	Slotted: .8, 1.0, 1.2, 1.5, 1.8, 2.0, 2.5, 3.0, 3.5, 4.0
92190	Phillips: #000, #00, #0, #1
	TORX®: T1, T2, T3, T4, T5, T6, T7, T8, T9, T10
	Metric Hex: 1.27, 1.5, 2.0, 2.5, 3.0
	Inch Hex: .028, .035, .050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32"
	Metric Nut Drivers: 1.5, 1.8, 2.0, 2.5, 3.0, 3.5, 4.0, 4.5, 5.0, 5.5
	26810 Chip Lifter

Wiha Magnetizer/ Demagnetizer

Magnetize or Demagnetize tools and small parts instantly

Shatterproof Box is made from high quality plastic

Uses 2 C8 industrial permanent magnets



(+) to Magnetize

(-) to Demagnetize

40010 Magnetizer and Demagnetizer
To magnetize and demagnetize steel screwdriver blades, tweezers and similar tools. Box high quality plastic, shock-resistant, green, cadmium free.

Application:

To magnetize, lead tool slowly through the (+) opening, to demagnetize guide tool slowly through the (-) opening.

Item	Dimensions	lbs.
40010	2.1" x 2.0" x 1.1"	.30

(Parts under 1" Length or 1/8" Diameter may not demagnetize)

Wiha Torque Cable Keys



286 Torque Cable Key For Threaded

Hex Connectors For torque controlled fastening of cable plug connectors with Hex heads. Used with Wiha-TorqueControl Screwdrivers.

Item No.	Size	mm	mm	mm	Max Nm	lbs.	Pkg.
28620	8mm	4.0	78	218	1.0	.06	1
28622	9mm	4.0	78	218	1.0	.06	1
28626	12mm	4.0	78	218	1.5	.06	1
28627	13mm	4.0	78	218	1.5	.06	1
28629	14mm	4.0	78	218	1.5	.06	1
28633	18mm	4.0	78	218	1.5	.06	1

28644 Torque Cable Key For Threaded

Item No.	Size	mm	mm	mm	Max Nm	lbs.	Pkg.
28644	1/2"	4.0	78	218	1.5	.06	1



+/-6% accuracy tolerance
Certificate of calibration

28552 Adjustable TorqueVario-S Handle -

In Newton Meter Scale EN ISO 6798, BS EN 26789, ASME B107.14M. Ergonomic molded multi-component handle, light and compact. Handle sizes proportioned to optimize torque range. Audible and perceptible click when the torque setting has been attained, automatically resets for next torque cycle.

Item No.	Newton Meter Scale	Increments	mm	lbs.	Pkg.
28552	0.8 - 2.0Nm	.10 Nm	126 - 131	.45	1

Wiha Soft Grip PicoFinish Precision Screwdrivers

The Comfortable Precision Screwdriver

Soft Grip Handle

CVM tool steel blade, hardened, hard chrome finish

Ergonomic multi-component handle with rotating cap for maximum user comfort and precise control

Sets In Roll-Up Pouch



Ergonomic multi-component handle with rotating cap for maximum user comfort and precise control



26195 5pc Precision Screwdrivers With Precision Soft PicoFinish Handle

Item	Slotted:	
No.	1.5, 2.5, 3.5mm	lbs.
26195	Phillips: #0, #1	.25

* No Pouch - In clamshell



26196 5pc Precision Screwdrivers With Precision Soft PicoFinish Handle

Item	Phillips: #0, #1	
No.	Pentalobe: PL1	lbs.
26196	Tri-Wing: #000	.25
	Tweezers: 2a SA ESD Flat Round Tip	

* No Pouch - In clamshell



26198 11pc Smartphone Precision Screwdrivers With Precision Soft PicoFinish Handle

Item	Slotted: 1.8mm	
No.	Phillips: #000, #00, #0	
26198	TORX®: T3, T4, T5, T6	
	Pentalobe: PL1	
lbs.	Tri-Wing: #000	
.59	Tweezers: PSF SA ESD Long Flat Tip	



260 Slotted Precision Screwdriver, With PicoFinish Handle Blade CVM steel, hardened, hard chromed.

Item	Slotted:						
No.	mm	Inch	mm	Inch	mm	Inch	Pkg.
26050	0.8	.03	40	1.6	134	5.3	10
26051	1.0	.04	40	1.6	134	5.3	10
26052	1.2	.05	40	1.6	134	5.3	10
26053	1.5	.06	40	1.6	134	5.3	10
26055	1.8	.07	40	1.6	134	5.3	10
26060	2.0	.08	40	1.6	140	5.5	10
26061	2.0	.08	60	2.4	160	6.3	10
26065	2.5	.09	50	2.0	150	5.9	10
26066	2.5	.09	75	3.0	175	6.9	10
26068	2.5	.09	100	3.9	200	7.9	10
26070	3.0	.13	50	2.0	150	5.9	10
26072	3.0	.13	100	3.9	200	7.9	10
26073	3.0	.13	150	5.9	250	9.8	10
26074	3.5	.14	60	2.4	160	6.3	10
26076	4.0	.16	60	2.4	160	6.3	10
26079	4.0	.16	100	3.9	200	7.9	10
26080	4.0	.16	150	5.9	250	9.8	10

*Metric dimensions actual - Inch dimensions approximate



261 Phillips Precision Screwdriver, With Soft PicoFinish Precision Handle Blade high alloy CVM steel. Hard chrome finished.

Item	Phillips:						
No.	Size	mm	Inch	mm	Inch	mm	Pkg.
26130	000	40	1.6	2.0	.08	134	5.3
26132	00	40	1.6	2.0	.08	134	5.3
26135	0	50	2.0	3.0	.12	150	5.9
26136	0	75	3.0	3.0	.12	175	6.9
26140	1	60	2.4	4.0	.16	160	6.3
26142	1	80	3.1	4.0	.16	180	7.1
26145	1	150	5.9	4.0	.16	250	9.8

*Metric dimensions actual - Inch dimensions approximate




In Roll-Up Pouch



26193 8pc Slotted & Phillips Precision Driver Set, With Soft PicoFinish Handle Blade high alloy CVM steel, hardened, hard chromed. ChromTop finish on tip for a perfect fit. In storage pouch

Item	Slotted:	
No.	1.0, 1.5, 2.0 x 40mm	lbs.
26193	2.5 x 50mm, 3.5 x 60mm	.55
	Phillips: 00 x 40mm	
	0 x 50mm, 1 x 60mm	

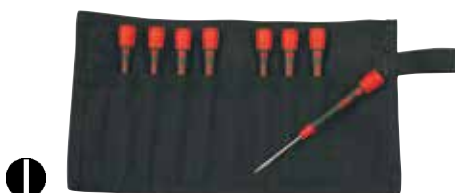

26093 8pc Slotted Precision Screwdriver Set, With Soft PicoFinish Handle

In storage pouch

Item	Slotted:	
No.	.8, 1.2, 1.5, 2.0 x 40mm	lbs.
26093	2.5, 3.0 x 50mm, 3.5, 4.0 x 60mm	.54

Wiha Pico Soft Grip TORX®



267 TORX® Screwdriver, With Precision Soft PicoFinish Handle Blade high alloy CVM tool steel, hardened, hard chrome finish.

Item No.	Size	mm	Inch	mm	Inch	Pkg.
26732	T1	40	1.6	134	5.3	10
26733	T2	40	1.6	134	5.3	10
26735	T3	40	1.6	134	5.3	10
26736	T4	40	1.6	134	5.3	10
26737	T5	40	1.6	134	5.3	10
26739	T6	40	1.6	140	5.5	10
26741	T7	40	1.6	140	5.5	10
26743	T8	40	1.6	140	5.5	10
26745	T9	50	2.0	150	5.9	10
26747	T10	50	2.0	150	5.9	10
26749	T15	60	2.4	160	6.3	10
26751	T20	60	2.4	160	6.3	10

*Metric dimensions actual - Inch dimensions approximate

In storage pouch



26793 8pc TORX® Precision Driver Set, With Soft PicoFinish Handle Blade high alloy CVM steel, hardened, hard chromed. ChromTop finish on tip for a perfect fit.

Item No.	TORX®:	lbs.
26793	T1, T2, T3, T4, T5, T6, T7, T8	.50

In storage pouch



26796 8pc TORX® Precision Driver Set, Soft PicoFinish Handle Blade high alloy CVM steel, hardened, hard chromed. ChromTop finish on tip for a perfect fit.

Item No.	TORX®:	lbs.
26796	T5, T6, T7, T8 x 40mm, T9, T10 x 50mm, T15, T20 x 60mm	.57

Pico Soft Grip Hex Inch & Metric



263 Hex Inch Screwdriver, With Precision Soft PicoFinish Handle Blade high alloy CVM tool steel, hardened, hard chrome finish.

Item No.	Inch	mm	Inch	mm	Inch	Pkg.
26341	0.028(0.7)	40	1.6	134	5.3	10
26343	0.035(0.9)	40	1.6	134	5.3	10
26345	0.05(1.3)	40	1.6	134	5.3	10
26349	5/64(2.0)	50	2.0	150	5.9	10
26363	1/16	50	2.0	144	5.7	10
26367	3/32	60	2.4	160	6.3	10
26369	7/64	60	2.4	160	6.3	10
26371	1/8	60	2.4	160	6.3	10

*Metric dimensions actual - Inch dimensions approximate



In storage pouch

26392 8pc Hex Inch Precision Driver Set, Soft PicoFinish Handle Blade high alloy CVM steel, hardened, hard chromed.


Item No.	Hex Inch:	lbs.
26392	.028, .035, .050 x 1.6" 5/64, 1/16 x 2.0", 3/32, 7/64, 1/8 x 2.4"	.24



263 Hex Metric Driver, With Precision Soft PicoFinish Handle

Item No.	mm	mm	Inch	mm	Inch	Pkg.
26341	.7(.028)	40	1.6	134	5.3	10
26343	.9(.035)	40	1.6	134	5.3	10
26345	1.3(.050)	40	1.6	134	5.3	10
26347	1.5	50	2.0	144	5.7	10
26349	2.0(5/64)	50	2.0	150	5.9	10
26351	2.5	60	2.4	160	6.3	10
26353	3.0	60	2.4	160	6.3	10

*Metric dimensions actual - Inch dimensions approximate

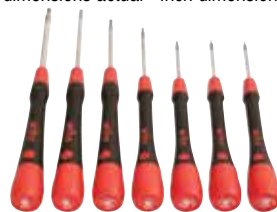

In storage pouch

26393 7pc Hex Metric Precision Driver Set, Soft PicoFinish Handle Blade high alloy CVM steel, hardened, hard chromed.

Item No.	Hex Metric:	lbs.
26393	.7, .9, 1.3 x 40mm 1.5, 2.0 x 50mm, 2.5, 3.0 x 60mm	.22

Pico Soft Grip Ball End Inch & Metric



264 Ball End Hex Inch Screwdriver, With Precision Soft PicoFinish Handle Blade high alloy CVM tool steel, hardened, hard chrome finish.

Item No.	Inch	Inch	mm	Inch	mm	pkg.
26455	1/16	2.0	50	5.9	150	10
26457	5/64	2.0	50	5.9	150	10
26459	3/32	2.0	50	5.9	150	10
26461	7/64	2.4	60	6.3	160	10
26463	1/8	2.4	60	6.3	160	10
26465	9/64	2.4	60	6.3	160	10
26467	5/32	2.4	60	6.3	160	10

*Metric dimensions actual - Inch dimensions approximate



26493 7pc Inch Ball End Hex Precision Driver Set, With Soft PicoFinish Handle Blade high alloy CVM steel, hardened, hard chromed. ChromTop finish on tip for a perfect fit. In storage pouch

Item No.	Ball End Hex Inch:	lbs.
26493	1/16, 5/64, 3/32 x 2.0" 7/64, 1/8, 9/64, 5/32 x 2.4"	.27



264 Ball End Hex Metric Screwdriver, With Precision Soft PicoFinish Handle. Blade high alloy CVM tool steel, hardened, hard chrome finish.

Item No.	mm	mm	Inch	mm	Inch	pkg.
26441	1.3	40	1.6	134	5.3	10
26443	1.5	50	2.0	150	5.9	10
26445	2.0	50	2.0	150	5.9	10
26447	2.5	60	2.4	160	6.3	10
26449	3.0	60	2.4	160	6.3	10

*Metric dimensions actual - Inch dimensions approximate

Pico Soft Grip Nut Drivers Inch & Metric



265 Inch Nut Drivers, With Precision Soft PicoFinish Handle Blade high alloy chrome-vanadium-molybdenum tool steel, hardened, hard chrome finish.

Item						
No.	Inch	Inch	mm	Inch	mm	pkg.
26571	3/32	2.4	60	6.3	160	10
26572	7/64	2.4	60	6.3	160	10
26573	1/8	2.4	60	6.3	160	10
26574	9/64	2.4	60	6.3	160	10
26575	5/32	2.4	60	6.3	160	10
26576	3/16	2.4	60	6.3	160	10
26577	7/32	2.4	60	6.3	160	10
26578	1/4	2.4	60	6.3	160	10

*Metric dimensions actual - Inch dimensions approximate



265 Metric Nut Drivers, With Precision PicoFinish Handle Blade high alloy CVM tool steel, hardened, hard chrome finish.

Item						
No.	mm	mm	Inch	mm	Inch	pkg.
26579	1.5	60	2.4	160	6.3	10
26581	2.0	60	2.4	160	6.3	10
26582	2.5	60	2.4	160	6.3	10
26583	3.0	60	2.4	160	6.3	10
26584	3.5	60	2.4	160	6.3	10
26585	4.0	60	2.4	160	6.3	10
26586	4.5	60	2.4	160	6.3	10
26587	5.0	60	2.4	160	6.3	10
26588	5.5	60	2.4	160	6.3	10
26589	6.0	60	2.4	160	6.3	10

*Metric dimensions actual - Inch dimensions approximate



26593 8pc Inch Nut Driver Set, With Precision Soft PicoFinish Handle Blade high alloy CVM tool steel, hardened, hard chrome finish. Chrom-Top finish on tip for a perfect fit. In storage pouch

Item	Inch Nut Drivers:		lbs.	
No.	3/32, 7/64, 1/8, 9/64,			
26593	5/32, 3/16, 7/32, 1/4" x 2.4"			



26596 8pc Metric Nut Driver Set, With Precision Soft PicoFinish Handle

Item	Metric Nut Drivers:	
No.	2.0, 2.5, 3.0, 3.5, 4.0,	lbs.
26596	4.5, 5.0, 5.5 x 60mm	.66

Pico Soft Grip Pentalobe



267 Pentalobe Screwdriver, With Precision Soft PicoFinish Handle Blade high alloy CVM tool steel, hardened, hard chrome finish.

Item						
No.	Size	Inch	mm	Inch	mm	pkg.
26771	PL1	1.6	40	5.5	140	10
26772	PL2	1.6	40	5.5	140	10
26773	PL3	1.6	40	5.5	140	10
26774	PL4	1.6	40	5.5	140	10
26775	PL5	1.6	40	5.5	140	10
26776	PL6	1.6	40	5.5	140	10

*Metric dimensions actual - Inch dimensions approximate



26795 6pc Precision Pentalobe Driver Set, Soft PicoFinish Handle Blade high alloy CVM steel. Hard chrome finished.

Item No.	Pentalobe Drivers:	
26795	PL1, PL2, PL3, PL4, PL5, PL6	lbs.
		.40

Pico Soft Grip Precision Chip Lifter



26815 Soft PicoFinish Precision Chip Lifter Blade CVM steel, hardened, hard chromed.

Item	mm	mm	mm	mm	Inch	lbs.	Pkg.
No.	1	3.5	50	150	5.9	.03	1
26815	Standard Soft PicoFinish handle						

Pico Soft Grip Y-Type Precision Driver

Y-Type

(Used in iPhone 7 or higher series)



266 Y-Type Precision Screwdriver, With Soft PicoFinish Precision Handle Blade high alloy CVM steel. Hard chrome finished.

Item							
No.	Size	mm	Inch	mm	Inch	mm	Inch
26631	000	40	1.6	2.0	.08	140	5.5



75973 23pc Micro Bit Set, With Soft PicoFinish Handle CVM steel Micro Bits, hardened, on 4 mm hex stock. Ergonomic multi-component handle with rotating cap for maximum user comfort and precise control.

Item	Slotted: 1.5, 2.0, 2.5, 3.0, 3.5mm
No.	Phillips: 000, 00, 0, 1, 2
75973	TORX®: T1, T2, T3, T4, T5, T6, T7, T8, T9, T10
lbs.	PicoFinish® Precision Handle
.82	Micro Bit Holder - 100mm
	Micro Bit Socket Adapter 1/4"

PicoFinish MagicSpring Precision Screwdrivers



267 MagicSpring Screw Holding TORX® Screwdriver, With Wiha-Precision Soft PicoFinish Handle Blade high alloy CVM steel, hardened, hard chromed. Molded on ergonomic Wiha-PicoFinish precision handle, molded on, soft grips.

Item							
No.	Size	mm	Inch	mm	Inch	lbs.	Pkg.
26721	T6	40	1.6	140	5.5	.03	10
26723	T7	40	1.6	140	5.5	.03	10
26725	T8	40	1.6	140	5.5	.03	10
26727	T9	50	2.0	150	5.9	.04	10
26729	T10	50	2.0	150	5.9	.04	10
26731	T15	60	2.4	160	6.3	.04	10

*Metric dimensions actual - Inch dimensions approximate



26798 6pc MagicSpring Screw Holding TORX® Screwdriver Set, With Wiha-Precision Soft PicoFinish Handle

Blade high alloy CVM steel, hardened, hard chromed. Molded on ergonomic Wiha-PicoFinish precision handle, molded on, soft grips. In storage pouch

Item		
No.	MagicSpring TORX®:	lbs.
26798	T6, T7, T8 x 40mm T9, T10, T15 x 50mm	.45



91118 Rugged Polyester Canvas Storage Pouch Holds 8 Precision Tools up to 170mm in length. Folding pouch. Has security flaps and velcro closer.

Item			
No.	Size	lbs.	pkg.
91118	14 1/2" W x 7 3/4" L	.13	1

Insulated PicoFinish Precision Screwdrivers

1000Volt



320 Insulated Slotted PicoFinish Screwdrivers. Individually Tested Protective Insulation 1000Volt AC, VDE & GS Tested.

High quality CV steel, through hardened, black finish. Rotating cap for precise turning and control with fingertip.

Item						
No.	mm	Inch	mm	mm	lbs.	Pkg.
32000	1.5	.06	40	154	.05	1
32001	2.0	.08	40	154	.07	1
32002	2.5	.10	60	160	.07	1
32003	3.0	.12	60	160	.08	1
32004	3.5	.14	60	160	.08	1

1000Volt



321 Insulated Phillips PicoFinish Screwdrivers. Individually Tested Protective Insulation 1000Volt AC, VDE & GS Tested.

Item					
No.	Size	mm	mm	lbs.	Pkg.
32106	00	40	154	.05	1
32107	0	60	160	.07	1
32108	1	60	160	.08	1

1000Volt



32088 8pc Slotted/Phillips PicoFinish Set

Item	Slotted: 1.5, 2.0,	
No.	2.5, 3.0, 3.5mm	lbs.
32088	Phillips: #00, #0, #1	.35


1000Volt



32085 5pc Slotted/Phillips PicoFinish Set

Item	Slotted: 1.5,	
No.	2.5, 3.5mm	lbs.
32085	Phillips: #0, #1	.26

Wiha Protturn Precision Screwdrivers

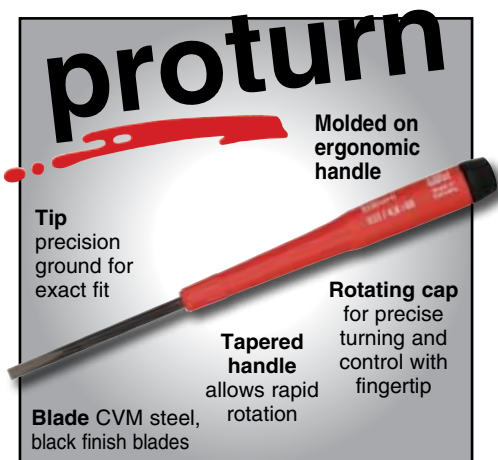

62994 14pc Inch/Metric Ball End Hex

Work Tech Pack Protturn precision ball retainer handle & 13 Wiha interchangeable blades.

62994 Set includes the following blades:

Hex Inch: .050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32"

Hex Metric: 1.5, 2.0, 2.5, 3.0, 4.0mm
lbs. .66

Set in canvas storage pouch



96800 Protturn Precision Chip Lifter

Molded on precision handle. Blade CVM tool steel, hardened, black finish.

Item					
No.	Size	mm	mm	Inch	lbs. pkg.
96800	1.0	50	145	5.7	.07 1

Wiha SYSTEM 4 Precision Handles and Blades

Rotating Cap

for precise turning & control

Tapered Handle
allows rapid rotation, requires less clearance

Blades

chrome-vanadium-molybdenum steel, hardened, hard chromed. On 4mm Hex shafts

Tips

Exact fit, precision machined

Precision Handle
high quality plastic, cadmium free. ESD Safe or Standard styles

15mm

Collet Lock Handle adjustable blade length from 15 to 95mm/.6" to 3.75"

95mm



26900 SYS 4 Standard Precision Handle, with rotating control cap. Accepts all SYSTEM 4 interchangeable blades. Wiha Precision handle, tapered, impact resistant. Ball retainer hold. 110mm/4.3" OAL

Item					
No.	mm	Inch	mm	Inch	lbs.
26900	4.0	.1574	14.0	.55	.04



28000 ESD Safe Dissipative Precision Handle with rotating control cap. Surface resistant 10^6 - 10^9 Ohms. 4 mm hex retainer for all SYSTEM 4 interchangeable blades. Tapered handle, high quality plastic, impact resistant. Ball retainer hold. 110mm/4.3" OAL

Item					
No.	mm	Inch	mm	Inch	lbs.
28000	4.0	.1574	14.0	.55	.04



269 SYSTEM 4 Slotted Reversible Blade
High alloy CVM steel, hardened, hard chromed. Wiha vapor Chrome-Top finish on tips.

Item					
No.	mm	mm	mm	Inch	lbs.
26903	1.5 + 3.0	120	4.7	.05	
26904	2.0 + 3.5	120	4.7	.05	
26905	2.5 + 4.0	120	4.7	.06	



269 SYSTEM 4 Pozidriv Reversible Blade
High alloy CVM steel, hardened, hard chromed. Wiha vapor Chrome-Top finish on tips.

Item					
No.	Size	Size	mm	Inch	lbs.
26922	0 + 1	120	4.7	.03	

Notes:



269 SYSTEM 4 Phillips Reversible Blade
High alloy CVM steel, hardened, hard chromed. Wiha vapor Chrome-Top finish on tips.

Item					
No.	Size	Size	mm	Inch	lbs.
26911	000 + 00	120	4.7	.03	
26912	0 + 1	120	4.7	.03	



269 SYS 4 TORX Reversible Blade
High alloy CVM steel, hardened, vapor chrome protected, Wiha vapor Chrome-Top finish on tips. 120mm/4.7" OAL.

Item			
No.	Size	Size	lbs.
26951	T6 + T8	.03	
26952	T7 + T9	.03	
26953	T10 + T15	.03	
26954	T15 + T20	.03	



269 SYSTEM 4 Combined Slotted/Phillips Reversible Blade High alloy CVM steel, hardened, hard chromed.

Item					
No.	mm	Size	mm	Inch	lbs.
26971	1.5+ 000	120	4.7	.05	
26972	2.0+ 00	120	4.7	.05	
26973	3.0+ 0	120	4.7	.05	
26974	4.0+ 1	120	4.7	.06	



269 SYSTEM 4 TORX Interchangeable Blade High alloy CVM steel, hardened, Wiha vapor Chrome-Top finish on tips. 120mm/4.7" OAL

Item		
No.	Size	lbs.
26955	T3	.03
26956	T4	.03
26957	T5	.03

Wiha SYSTEM 4 Precision Blades



269 SYSTEM 4 Inch Hex Sizes,

Interchangeable Blade High alloy CVM steel, hardened, corrosion protected.

Item					
No.	Inch	mm	Inch	lbs.	
26921	.050	120	4.7	.06	
26923	1/16	120	4.7	.06	
26924	5/64	120	4.7	.06	
26925	3/32	120	4.7	.06	
26926	7/64	120	4.7	.06	
26927	1/8	120	4.7	.06	
26928	9/64	120	4.7	.06	
26929	5/32	120	4.7	.06	




269 SYSTEM 4 Metric Hex Sizes,

Interchangeable Blade High alloy CVM steel, hardened, corrosion protected.

Item					
No.	mm	mm	Inch	lbs.	
26913	0.7	120	4.7	.06	
26914	0.9	120	4.7	.06	
26916	1.5	120	4.7	.06	
26917	2.0	120	4.7	.06	
26918	2.5	120	4.7	.06	
26919	3.0	120	4.7	.06	
26920	4.0	120	4.7	.06	

Notes:

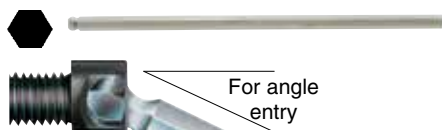

280 SYSTEM 4 Inch Ball End Hex

Interchangeable Blade High alloy tool steel, hardened, corrosion protected. Ball end works at 30° angle entry for easy access to fasteners.

Item					
No.	Inch	mm	Inch	lbs.	
28021	.050	120	4.7	.06	
28023	1/16	120	4.7	.06	
28024	5/64	120	4.7	.06	
28026	7/64	120	4.7	.06	
28027	1/8	120	4.7	.06	
28028	9/64	120	4.7	.06	
28029	5/32	120	4.7	.06	



280 SYSTEM 4 Metric Ball End Hex

Interchangeable Blade High alloy tool steel, hardened, corrosion protected. Ball end works at 30° angle entry for easy access to fasteners.

Item						
No.	mm	mm	Inch	lbs.	pkg.	
28033	1.5	120	4.7	.06	1	
28034	2.0	120	4.7	.06	1	
28035	2.5	120	4.7	.06	1	
28036	3.0	120	4.7	.06	1	
28037	4.0	120	4.7	.06	1	



269 SYS 4 Metric Ball End & Standard

Hex, Reversible Blade CVM steel, hardened, hard chromed. Wiha vapor Chrome-Top finish on tips. One side hex, other side ballpoint hex.

Item						
No.	mm	mm	mm	Inch	lbs.	
26932	1.3 + 1.3	120	4.7	.05		
26934	2.0 + 2.0	120	4.7	.06		
26935	2.5 + 2.5	120	4.7	.06		
26936	3.0 + 3.0	120	4.7	.06		
26937	4.0 + 4.0	120	4.7	.06		



269 SYSTEM 4 Nut Driver Inch,

Interchangeable Blade High alloy chrome-vanadium-molybdenum steel, hardened, corrosion protected. 120mm/4.7" OAL

Item					
No.	Inch	Inch	Inch	lbs.	
26962	3/32	.16	.16	.04	
26963	7/64	.20	.20	.04	
26964	1/8	.20	.20	.04	
26965	9/64	.21	.24	.04	
26966	5/32	.22	.24	.04	
26968	7/32	.30	.32	.04	
26969	1/4	1.34	.36	.04	



269 SYSTEM 4 Nut Driver Metric,

Interchangeable Blade High alloy chrome-vanadium-molybdenum steel, hardened, corrosion protected. 120mm/4.7" OAL

Item					
No.	mm	mm	Inch	Inch	lbs.
26940	1.5 + 1.8	.12	.12	.03	
26941	2.0 + 2.5	.16	.16	.03	
26938	1.5 -	.11	.11	.04	
26939	1.8 -	.12	.12	.04	
26949	2.0 -	.13	.13	.06	
26950	2.5 -	.16	.16	.06	
26942	3.0 -	.20	.20	.06	
26943	3.2 -	.20	.20	.06	
26944	3.5 -	.22	.24	.06	
26945	4.0 -	.22	.24	.06	
26946	4.5 -	.25	.28	.06	
26947	5.0 -	.27	.28	.06	
26948	5.5 -	.30	.32	.06	

Notes:

Wiha SYSTEM 4 Drive-Loc Precision Locking Tools



26906 SoftFinish® Cushion Grip

Drive-Loc Handle 4 mm hex retainer for all SYSTEM 4 interchangeable blades. Ball retainer hold. 105mm/4.13" OAL

Item					
No.	mm	Inch	mm	Inch	lbs.
26906	4.0	.1574	23	.91	.08



26961 ESD Safe Dissipative Precision

Drive-Loc Handle Surface resistant 10^6 - 10^9 Ohms. 4 mm hex retainer for all SYSTEM 4 interchangeable blades. Ball retainer hold. 105mm/4.13" OAL

Item					
No.	mm	Inch	mm	Inch	lbs.
26961	4.0	.1574	23	.91	.08



269 SYSTEM 4 Slotted Drive-Loc Reversible Locking Blades

On 4mm Hex blades

Item				
No.	mm	mm	lbs.	
26958	1.5	+	3.0	.02
26959	2.0	+	3.5	.02
26960	2.5	+	4.0	.02



269 SYSTEM 4 Phillips Drive-Loc Reversible Locking Blades

On 4mm Hex blades

Item				
No.	Size	Size	lbs.	
26975	000	+	00	.02
26976	0	+	1	.02



280 SYSTEM 4 Pozidriv® Drive-Loc Reversible Locking Blades

On 4mm Hex blades

Item			
No.	Size	Size	lbs.
28002	0 +	1	.02



269 SYSTEM 4 TORX® Drive-Loc Reversible Locking Blades

On 4mm Hex blades

Item				
No.	Size	Size	lbs.	
26977	T1	+	T2	.02
26978	T3	+	T4	.02
26979	T5	+	T6	.02
26980	T6	+	T8	.02
26981	T7	+	T9	.02
26982	T10	+	T15	.02
26983	T15	+	T20	.02



280 SYSTEM 4 Metric Hex Drive-Loc Reversible Locking Blades

On 4mm Hex blades

Item			
No.	mm	mm	lbs.
28003	1.3	+	1.3
28004	1.5	+	1.5
28005	2.0	+	2.0
28006	2.5	+	2.5
28007	3.0	+	3.0
28008	4.0	+	4.0



280 SYSTEM 4 Metric Nut Drivers Drive-Loc Reversible Locking Blades

On 4mm Hex blades

Item			
No.	mm	mm	lbs.
28012	3.2	+ -	.02



26985 12pc Drive-Loc IV Precision

ESD Safe Set In storage pouch

Item No.

26985 **ESD Safe Drive-Loc Handle**

 **Slotted:** 1.5x3.0, 2.0x3.5, 2.5x4.0

lbs. .44 **Phillips:** 000x00, 0x1

TORX®: T1xT2, T3xT4, T5xT6, T6xT8, T7xT9, T10xT15



26930 7pc Drive-Loc IV TORX® Precision

ESD Safe Set In storage pouch

Item No.


26930 **ESD Safe Drive-Loc Handle**

 **TORX®:** T3xT4, T5xT6,

lbs. .56 T6xT8, T7xT9, T10xT15, T15xT20

Micro Bits Made in Germany

Wiha SYSTEM 4 Micro Bits - 10 Bit Packs

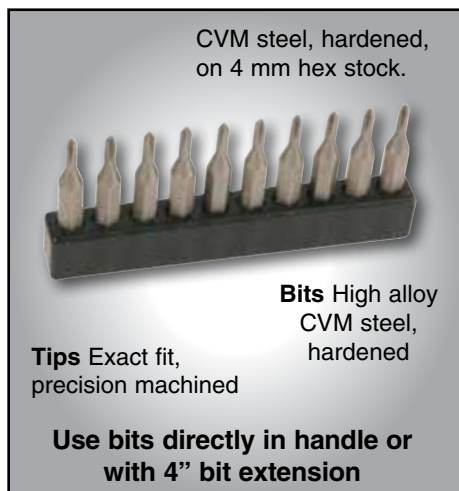

756 SYSTEM 4 Hex Metric Micro Bits

Item No.	mm	mm	Inch	lbs.
75616	.7	28	1.1	.06
75617	.9	28	1.1	.06
75618	1.3	28	1.1	.06
75619	1.5	28	1.1	.07
75620	2.0	28	1.1	.07
75621	2.5	28	1.1	.07
75622	3.0	28	1.1	.08
75623	4.0	28	1.1	.08



756 SYSTEM 4 Slotted Micro Bits

Item No.	mm	mm	Inch	lbs.
75602	0.8	28	1.1	.06
75603	1.2	28	1.1	.06
75604	1.5	28	1.1	.06
75605	1.8	28	1.1	.06
75606	2.0	28	1.1	.07
75607	2.5	28	1.1	.07
75608	3.0	28	1.1	.07
75609	3.5	28	1.1	.07
75610	4.0	28	1.1	.08



756 SYSTEM 4 Hex Inch Micro Bits

Item No.	Inch	mm	Inch	lbs.
75628	.028	28	1.1	.06
75629	.035	28	1.1	.06
75630	.050	28	1.1	.06
75631	1/16	28	1.1	.06
75632	5/64	28	1.1	.06
75633	3/32	28	1.1	.07
75634	7/64	28	1.1	.07
75635	1/8	28	1.1	.07
75636	9/64	28	1.1	.08
75637	5/32	28	1.1	.08



756 SYSTEM 4 Phillips Micro Bits

Item No.	Size	mm	Inch	lbs.
75611	000	28	1.1	.06
75612	00	28	1.1	.06
75613	0	28	1.1	.06
75614	1	28	1.1	.07
75615	2	28	1.1	.07



756 SYS 4 Metric Security Hex Micro Bits

Item No.	mm	mm	Inch	lbs.
75624	2.0	28	1.1	.06
75626	3.0	28	1.1	.07
75627	4.0	28	1.1	.08



756 SYSTEM 4 Pentalobe Micro Bits

Item No.	Size	mm	Inch	lbs.
75672	PL1	28	1.1	.06
75673	PL2	28	1.1	.06
75674	PL3	28	1.1	.07
75675	PL4	28	1.1	.07
75676	PL5	28	1.1	.07



756 SYS 4 Security Hex Inch Micro Bits

Item No.	Inch	mm	Inch	lbs.
75638	5/64	28	1.1	.06
75639	3/32	28	1.1	.06
75641	1/8	28	1.1	.07



756 SYSTEM 4 TORX Micro Bits

Item No.	Size	mm	Inch	lbs.
75660	T1	28	1.1	.06
75661	T2	28	1.1	.06
75662	T3	28	1.1	.06
75663	T4	28	1.1	.06
75664	T5	28	1.1	.06
75665	T6	28	1.1	.06
75666	T7	28	1.1	.06
75667	T8	28	1.1	.07
75668	T9	28	1.1	.07
75669	T10	28	1.1	.07
75670	T15	28	1.1	.08
75671	T20	28	1.1	.08



756 SYSTEM 4 Security TORX Micro Bits

Item No.	Size	mm	Inch	lbs.
75681	T10s	28	1.1	.07
75683	T20s	28	1.1	.08



756 SYSTEM 4 Inch Nut Setters

Item No.	Inch	mm	Inch	lbs.
75644	5/64	30	1.2	.07
75645	3/32	30	1.2	.07
75646	7/64	30	1.2	.07
75647	1/8	30	1.2	.07
75648	9/64	30	1.2	.08
75649	5/32	30	1.2	.08
75650	3/16	30	1.2	.08
75651	7/32	30	1.2	.09



756 SYSTEM 4 Metric Nut Setters

Item No.	mm	mm	Inch	lbs.
75652	2.0	30	1.2	.07
75653	2.5	30	1.2	.07
75654	3.0	30	1.2	.07
75655	3.5	30	1.2	.07
75656	4.0	30	1.2	.08
75657	4.5	30	1.2	.08
75658	5.0	30	1.2	.08
75659	5.5	30	1.2	.09

Wiha SYSTEM 4 Micro Bits

SYSTEM 4 Handles & Micro Bits

Rotating Cap
for precise
turning and
control

Tips
Exact fit,
precision
machined

Tapered Handle
allows rapid
rotation, requires
less clearance

Bits High alloy
CVM steel, hardened

Use bits directly in handle or with 4" bit extension



75800 SYSTEM 4 Standard Precision Bit

Handle Accepts all SYSTEM 4 Series bits.
110mm/4.3" OAL

Item					
No.	mm	Inch	mm	Inch	lbs.
75800	4.0	.1574	14.0	.55	.06



75801 SYSTEM 4 ESD Safe Dissipative

Precision Bit Handle 110mm/4.3" OAL

Advantages:

- For working in ESD sensitive applications
Surface resistant 10^6 - 10^9 Ohms
- Ball retainer holds bits securely in place
- Accepts all SYSTEM 4 Series bits

Item					
No.	mm	Inch	mm	Inch	lbs.
75801	4.0	.1574	14.0	.55	.06

SYSTEM 4 Micro Bit Extension Blades



75900 Extension Blade For SYS 4 Micro Bits

Shaft CVM steel, hardened, corrosion protected.
Ball retainer bit extension for 4mm bits.

Item					
No.	Size	mm	mm	lbs.	
75900	4.0	100	4.0	.07	



75901 Magnetic Bit Extension Blade For
SYS 4 Micro Bits Shaft CVM steel, hardened,
corrosion protected. Magnetic bit holder.

Item					
No.	Size	mm	mm	lbs.	
75901	4.0	100	4.0	.04	



750 SYSTEM 4 Slotted Micro Bits

CVM steel, hardened, on 4 mm hex stock.

Item					
No.	mm	mm	Inch	lbs.	
75008	0.8	28	1.1	.01	
75012	1.2	28	1.1	.01	
75015	1.5	28	1.1	.01	
75018	1.8	28	1.1	.01	
75020	2.0	28	1.1	.01	
75025	2.5	28	1.1	.01	
75030	3.0	28	1.1	.01	
75035	3.5	28	1.1	.01	
75040	4.0	28	1.1	.01	



751 SYSTEM 4 Phillips Micro Bits

CVM steel, hardened, on 4 mm hex stock.

Item					
No.	Size	mm	Inch	lbs.	
75105	000	28	1.1	.01	
75110	00	28	1.1	.01	
75115	0	28	1.1	.01	
75120	1	28	1.1	.01	
75125	2	28	1.1	.02	



753 SYSTEM 4 Hex Metric Micro Bits

CVM steel, hardened, on 4 mm hex stock.

Item					
No.	mm	mm	Inch	lbs.	
75307	.7	28	1.1	.01	
75309	.9	28	1.1	.01	
75313	1.3	28	1.1	.01	
75315	1.5	28	1.1	.01	
75320	2.0	28	1.1	.01	
75325	2.5	28	1.1	.01	
75330	3.0	28	1.1	.01	
75340	4.0	28	1.1	.01	



753 SYSTEM 4 Hex Inch Micro Bits

CVM steel, hardened, on 4 mm hex stock.

Item					
No.	Inch	mm	Inch	lbs.	
75307	.028	28	1.1	.01	
75309	.035	28	1.1	.01	
75313	.050	28	1.1	.01	
75350	1/16	28	1.1	.01	
75352	5/64	28	1.1	.01	
75354	3/32	28	1.1	.01	
75356	7/64	28	1.1	.01	
75358	1/8	28	1.1	.01	
75360	9/64	28	1.1	.01	
75340	5/32	28	1.1	.01	



757 SYSTEM 4 TORX® Micro Bits

CVM steel, hardened, on 4 mm stock.

Item					
No.	Size	mm	Inch	lbs.	
75701	T1	28	1.1	.01	
75702	T2	28	1.1	.01	
75703	T3	28	1.1	.01	
75704	T4	28	1.1	.01	
75705	T5	28	1.1	.01	
75706	T6	28	1.1	.01	
75707	T7	28	1.1	.01	
75708	T8	28	1.1	.01	
75709	T9	28	1.1	.01	
75710	T10	28	1.1	.01	
75715	T15	28	1.1	.01	
75720	T20	28	1.1	.01	



757 SYSTEM 4 Security TORX® Micro Bits

Item					
No.	Size	mm	Inch	lbs.	
75735	T10s	28	1.1	.01	
75742	T20s	28	1.1	.01	



753 SYS 4 Metric Security Hex Micro Bits

CVM steel, hardened, on 4 mm hex stock.

Item					
No.	mm	mm	Inch	lbs.	
75322	2.0	28	1.1	.01	
75332	3.0	28	1.1	.01	
75342	4.0	28	1.1	.01	

753 SYS 4 Security Hex Inch Micro Bits

Item					
No.	Inch	mm	Inch	lbs.	
75362	5/64	28	1.1	.01	
75364	3/32	28	1.1	.01	
75366	7/64	28	1.1	.01	
75368	1/8	28	1.1	.01	
75370	9/64	28	1.1	.01	
75372	5/32	28	1.1	.01	

Micro Bit 1/4" Drive Power Tool Adapter For 4mm Bits



75902 Micro Bit 1/4" Drive Power Tool Adapter
CVM steel, hardened, corrosion protected.

Item					
No.	Size	mm	mm	lbs.	
75902	4.0	60	4.0	.07	

Wiha SYSTEM 4 Micro Bits



757 SYSTEM 4 Pentalobe Micro Bits CVM steel, hardened, on 4 mm hex stock.


Item No.	Size	mm	Inch	lbs.
75743	PL1	28	1.1	.01
75744	PL2	28	1.1	.01
75745	PL3	28	1.1	.01
75746	PL4	28	1.1	.01
75747	PL5	28	1.1	.01
75748	PL6	28	1.1	.01



758 SYSTEM 4 Metric & Inch Nut Setters CVM steel, hardened, on 4 mm hex stock.

Item No.	Metric	mm	Inch	lbs.
75820	2.0	30	1.2	.01
75821	2.5	30	1.2	.01
75822	3.0	30	1.2	.01
75823	3.5	30	1.2	.01
75824	4.0	30	1.2	.01
75825	4.5	30	1.2	.01
75826	5.0	30	1.2	.01
75827	5.5	30	1.2	.01
Inch	Inch	mm	Inch	lbs.
75810	5/64	30	1.2	.01
75811	3/32	30	1.2	.01
75812	7/64	30	1.2	.01
75813	1/8	30	1.2	.01
75814	9/64	30	1.2	.01
75815	5/32	30	1.2	.01
75816	3/16	30	1.2	.01
75817	7/32	30	1.2	.01

Micro Bit Replacement Packs On 4mm Hex Stock

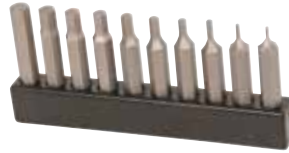

75982 10pc SYSTEM 4 Hex Inch Micro Bit Replacement Pack

CVM steel, hardened, on 4 mm hex stock.

Item No.

75982 SYSTEM 4 Micro Bit Set

Hex Inch: .028, .035, .050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32"

lbs. .06



75984 10pc SYSTEM 4 Slotted Micro Bit Replacement Pack

CVM steel, hardened, on 4 mm hex stock.

Item No.

75984 SYSTEM 4 Micro Bit Set

Slotted: 0.8, 1.2, 1.5, 1.8, 2.0, 2.5, 3.0, 3.5, 4.0mm

lbs. .06



75986 10pc SYSTEM 4 Phillips & Pentalobe Micro Bit Replacement Pack

CVM steel, hardened, on 4 mm hex stock.


Item No.

75986 SYSTEM 4 Micro Bit Set

Phillips: #000, 00, 0, 1

Pentalobe: PL1, PL2, PL3, PL4, PL5, PL6

lbs. .06

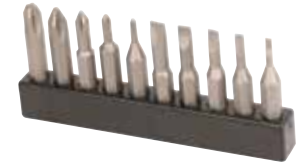

75987 10pc SYSTEM 4 Slotted & Phillips Micro Bit Replacement Pack

CVM steel, hardened, on 4 mm hex stock.


Item No.

75987 SYSTEM 4 Micro Bit Set

Slotted: 1.5, 2.0, 2.5, 3.0, 3.5mm

Phillips: #000, 00, 0, 1

lbs. .06

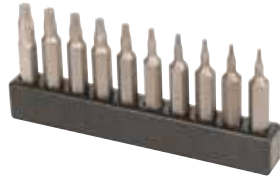

75988 10pc SYSTEM 4 TORX Micro Bit Replacement Pack

CVM steel, hardened, on 4 mm hex stock.

Item No.

75988 SYSTEM 4 Micro Bit Set

TORX: T1, T2, T3, T4, T5, T6, T7, T8, T9, T10

lbs. .06

1/4" Drive Micro Bit Tool Adapters



75802 Micro Bit To 1/4" Drive Insert Bit Adapter magnets to hold 4mm Micro Bits

Item No.	Size	mm	mm	lbs.
75802	4.0	25	4.0	.01



75803 Long Micro Bit To 1/4" Drive Insert Bit Adapter Uses spring clip non-magnetic to hold 4mm Micro Bits

Item No.	Size	mm	mm	lbs.
75803	4.0	38	4.0	.02




Micro Bit 4mm To 1/4" Socket Adapter



75806 Micro Bit 4mm to 1/4" Socket Adapter CVM steel, hardened.

Item No.	mm	Inch	lbs.
75806	28	1.125	.02

 Wiha SYS 4 Micro Bits & Compact Bit Sets

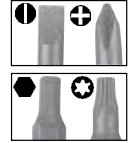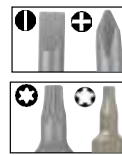

75999 26pc SYS 4 Slotted, Phillips, Hex Inch & Metric Precision Interchangeable Bit Set. In Compact Fold Out Box. Precision handle, bit extension & 24 interchangeable bits.

Item No. Combination Bit Set

75999 Set with Standard Precision Handle

Set includes the following bits:

- ↓  **Slotted:** 1.5, 2.0, 3.0, 4.0mm
- ⊕ **Phillips:** 000, 00, 0, 1
- ⬢ **Hex Metric:** .7, .9, 1.3, 1.5, 2.0, 2.5, 3.0, 4.0mm
- ⬢ **Hex Inch:** .050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32"
- **100mm Bit Extension**
- ↔ **lbs.** .64

75995 26pc SYSTEM 4 Precision Interchangeable Bit Set. In Compact Fold Out Box Sets includes Wiha precision handle, bit extension & 24 Wiha interchangeable bits.

Item SYSTEM 4 Micro Bit Set

No. Set with ESD Safe Precision Handle

75995 and the following bits:

- ⊕ **TORX®:** T1, T2, T3, T4, T5, T6, T7, T8, T9, T10
- ⊕ **Pentalobe:** PL1, PL2, PL3, PL4, PL5, PL6
- ↓  **Slotted:** 1.5, 2.0, 2.5, 3.0mm
- ⊕ **Phillips:** #000, 00, 0, 1
- **100mm Bit Extension**
- ↔ **lbs.** .54

75994 27pc SYSTEM 4 Slotted/Phillips/Hex Metric/ TORX® Precision Interchangeable Bit Set. In Compact Fold Out Box. Set includes Wiha precision handle, bit extension and 25 Wiha interchangeable bits.



Item SYSTEM 4

No. Combination Bit Set

75994 Set with ESD Safe Precision Handle

Set includes the following bits:

- ↓  **Slotted:** 1.5, 2.0, 3.0, 4.0mm
- ⊕ **Phillips:** 000, 00, 0, 1
- ⊕ **TORX®:** T3, T4, T5, T6, T7, T8, T9, T10, T15
- ⬢ **Hex Metric:** .7, .9, 1.3, 1.5, 2.0, 2.5, 3.0, 4.0mm
- **100mm Bit Extension**
- ↔ **lbs.** .64

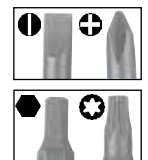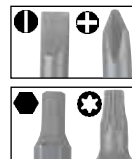

75395 18pc SYS 4 Hex Inch & Metric Precision Interchangeable Bit Set. In Compact Fold Out Box. Wiha precision handle, bit extension and 16 Wiha interchangeable bits.

Item No. Combination Bit Set

75395 Set with Standard Precision Handle

Includes the following bits:

- ⬢ **Hex Metric:** .7, .9, 1.3, 1.5, 2.0, 2.5, 3.0, 4.0mm
- ⬢ **Hex Inch:** .050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32"
- **100mm Bit Extension**
- ↔ **lbs.** .58

759 sets 27pc SYSTEM 4 Slotted/Phillips/Hex Inch/ TORX® Precision Interchangeable Bit Set. In Compact Fold Out Box. Sets include your choice of Wiha precision handle, bit extension & 25 Wiha interchangeable bits.

Item Handle Options for SYSTEM 4

No. Combination Bit Sets

75991 Set with Standard Precision Handle

75992 Set with ESD Safe Precision Handle

Sets include the following bits:

- ↓  **Slotted:** 1.5, 2.0, 3.0, 4.0mm
- ⊕ **Phillips:** 000, 00, 0, 1
- ⊕ **TORX®:** T3, T4, T5, T6, T7, T8, T9, T10, T15
- ⬢ **Hex Inch:** .050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32"
- **100mm Bit Extension**
- ↔ **lbs.** .64

75996 40pc SYSTEM 4 Interchangeable Bit Set. Includes Wiha precision handle, bit extension & 38 interchangeable bits.

Item SYSTEM 4

No. Combination Bit Set

75996 Set with ESD Safe Precision Handle

Set includes the following bits:

- ↓  **Slotted:** 0.8, 1.2, 1.5, 1.8, 2.0, 2.5, 3.0, 3.5, 4.0mm
- ⊕ **Phillips:** 000, 00, 0, 1
- ⊕ **TORX®:** T3, T4, T5, T6, T7, T8, T9, T10, T15
- ⬢ **Hex Metric:** 1.3, 1.5, 2.0, 2.5, 3.0, 4.0mm
- ⬢ **Hex Inch:** .028, .035, .050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32"
- **100mm Bit Extension**
- ↔ **lbs.** 1.04

Technicians MicroBit Sets

- Micro Precision Bits on 4mm Hex Drive
- Bits of Exclusive CRM-72 Tool Steel
- Handle uses non-magnetic ball retainer
- Use bits in extension only
- Standard extension adds 4" to length
- Non-magnetic bit extension

Surface resistance of handles is $10^6 - 10^9$ Ohms

Rotation cap

Light weight & compact

Handle tapered for precise control

Bits hardened for extreme durability



75093 16pc SYSTEM 4 Slotted, Phillips, TORX® Compact ESD Precision Interchangeable Bit Set

Item No. Combination Bit Set

 
75093 Set with ESD Safe Precision Handle

↓ Slotted: 1.5, 2.0, 2.5, 3.0mm

⊕ Phillips: 00, 0, 1

lbs. ⚙ TORX: T6, T7, T8, T9, T10, T15, T20

.17 ○ 100mm Bit Extension



75094 16pc SYSTEM 4 Slotted, Phillips, Hex Inch Compact ESD Precision Interchangeable Bit Set

Item No. Combination Bit Set

75094 Set with ESD Safe Precision Handle

 
↓ Slotted: 1.5, 2.0, 2.5, 3.0mm

⊕ Phillips: 00, 0, 1

⚙ Hex Inch: .035, .050, 1/16, 5/64,

lbs. 3/32, 7/64, 1/8"

.17 ○ 100mm Bit Extension



75095 16pc SYSTEM 4 Slotted, Phillips, Hex Metric Compact ESD Precision Interchangeable Bit Set

Item No. Combination Bit Set

75095 Set with ESD Safe Precision Handle

↓ Slotted: 1.5, 2.0, 2.5, 3.0mm

⊕ Phillips: 00, 0, 1

⚙ Hex Metric: .9, 1.3, 1.5, 2.0, 2.5,

lbs. 3.0, 4.0mm

.17 ○ 100mm Bit Extension



75096 16pc SYSTEM 4 Hex Inch & Metric Compact ESD Precision Interchangeable Bit Set

Item No. Combination Bit Set

75096 Set with ESD Safe Precision Handle

⚙ Hex Inch: 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32"

⚙ Hex Metric: .9, 1.3, 1.5, 2.0, 2.5, lbs. 3.0, 4.0mm

.17 ○ 100mm Bit Extension



75097 16pc SYSTEM 4 Slotted, Phillips, Pentalobe Compact ESD Precision Interchangeable Bit Set

Item No. Combination Bit Set

75097 Set with ESD Safe Precision Handle

↓ Slotted: 1.2, 1.5, 2.0, 2.5, 3.0mm

⊕ Phillips: 000, 00, 0, 1, 2

⚙ Pentalobe: PL1, PL2, PL3, PL4

.17 ○ 100mm Bit Extension



91109 Black Cartridge Holder

Holds 14 Micro bits 4mm. 1" OAL

Item No.	mm	mm	lbs.
91109	4.0	25.4	.01



75965 65pc SYSTEM 4 Master Tech ESD & Ratchet With Micro Bits. In Storage Box.

Includes Wiha precision ESD Safe handle, micro bit extension, 72 tooth ratchet & 62 interchangeable micro bits.

Item No. lbs. 1.16

75965 Includes the following micro bits:

Slotted: 0.8, 1.2, 1.5, 1.8, 2.0, 2.5, 3.0, 3.5, 4.0mm

Phillips: 000, 00, 0, 1

TORX: T3, T4, T5, T6, T7, T8, T9, T10, T15, T20

Hex Metric: .7, .9, 1.3, 1.5, 2.0, 2.5, 3.0, 4.0mm

Hex Inch: .050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32"

Nut Drivers Metric: 2.0 - 5.5mm

Nut Drivers Inch: 5/64 - 7/32"

 
Pentalobe: PL1, PL2, PL3, PL4, PL5, PL6

Magnetic 1/4" to 4mm Adapter

SYSTEM 4 Interchangeable Bit Sets



Includes Dust Cover



75968 68pc SYSTEM 4 Micro Bit Set

Includes ESD handle, Micro bit storage handle, micro bit extension & 65 micro bits.

Item No.

75968 Includes the following micro bits:

↓ Slotted: 0.8, 1.2, 1.5, 1.8, 2.0, 2.5, lbs. 3.0, 3.5, 4.0mm

.70 ⊕ Phillips: 000, 00, 0, 1, 2

⚙ TORX: T1, T2, T3, T4, T5, T6, T7, T8, T9, T10, T15, T20

⚙ Hex Metric: .7, .9, 1.3, 1.5, 2.0, 2.5, 3.0, 4.0mm

 
⚙ Hex Inch: .050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32"

○ Nut Drivers Metric: 2.0, 2.5, 3.0, 3.5, 4.0, 4.5, 5.0, 5.5mm

○ Nut Drivers Inch: 5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32"

⚙ Pentalobe: PL1, PL2, PL3, PL4, PL5, PL6
Magnetic 1/4" to 4mm Adapter

* Does not include storage box



75971 68pc SYSTEM 4 Micro Bit Set

Includes ESD handle, Micro bit storage handle, micro bit extension & 65 micro bits.

Item No. Set In Zipper Case

75971 Includes the following micro bits:

↓ Slotted: 0.8, 1.2, 1.5, 1.8, 2.0, 2.5, lbs. 3.0, 3.5, 4.0mm

.96 ⊕ Phillips: 000, 00, 0, 1, 2

⚙ TORX: T1, T2, T3, T4, T5, T6, T7, T8, T9, T10, T15, T20

⚙ Hex Metric: .7, .9, 1.3, 1.5, 2.0, 2.5, 3.0, 4.0mm

⚙ Hex Inch: .050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32"

○ Nut Drivers Metric: 2.0, 2.5, 3.0, 3.5, 4.0, 4.5, 5.0, 5.5mm

○ Nut Drivers Inch: 5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32"

⚙ Pentalobe: PL1, PL2, PL3, PL4, PL5, PL6
Magnetic 1/4" to 4mm Adapter

SYSTEM 4 Interchangeable Bit Sets



75980 68pc SYSTEM 4 Master Tech Micro Bit Set. Includes Wiha ESD Safe Precision Handle, 1/4" to 4mm Adapter, 100mm Bit Extension & 36 Micro Bits.

Item No. SYSTEM 4 Micro Bit Set

75980 Includes The Following Bits:

↓  **Slotted:** 0.8, 1.2, 1.5, 1.8, 2.0, 2.5, 3.0, 3.5, 4.0mm

 **Phillips:** 000, 00, 0, 1, 2

 **TORX®:** T1, T2, T3, T4, T5, T6, T7, T8, T9, T10

 **Hex Metric:** 1.3, 1.5, 2.0, 2.5, 3.0, 4.0mm

 **Pentalobe:** PL1, PL2, PL3, PL4, PL5, PL6

 **lbs.** .38



75993 28pc SYSTEM 4 Premium ESD Safe Micro Bit Set. Includes Wiha ESD Safe Precision Handle, 1/4" to 4mm Adapter, 100mm Bit Extension, ESD Safe Tweezers & 21 Micro Bits.

Item No. SYSTEM 4 Micro Bit Set

75993 Micro Bits:

↓  **Slotted:** 0.8, 1.5, 2.0, 2.5, 3.0, 3.5mm

 **Phillips:** 000, 00, 0, 1, 2

 **TORX®:** T1, T2, T3, T4, T5, T6, T7, T8, T9, T10

ESD Safe Tweezers:

5SA ESD, 7aSA ESD, 2ASA ESD, AASA ESD, OOSA ESD

 **lbs.** .95

Micro Bit Handle Storage Sets



Micro precision bits on 4mm hex drive

Bits of exclusive CRM-72 tool steel

Storage handle

Bits hardened for extreme durability



75981 7pc Micro Bit Handle Storage Slotted & Phillips Bit Set

Wiha precision storage handle & 6 Micro Bit interchangeable 4mm bits.

Item Set with Micro Bit Precision
No. Storage Handle

75981 ↓  **Slotted:** 1.2, 1.5, 2.0mm
 **Phillips:** 000, 00, 0

 **lbs.** .08



75985 7pc Micro Bit Handle Storage TORX® Bit Set

Wiha precision storage handle & 6 Micro Bit interchangeable 4mm bits.

Item Set with Micro Bit Precision
No. Storage Handle

75985  **TORX®** T3, T4, T5, T6, T7, T8
 **lbs.** .08



75805 SYSTEM 4 Micro Bit Storage

Handle Accepts all SYSTEM 4 Series bits.
108mm / 4.25" OAL

Item   
No. mm Inch lbs.

75805 4.0 .1574 .05



75983 7pc Micro Bit Handle Storage Hex Inch Bit Set

Wiha precision storage handle & 6 Micro Bit interchangeable 4mm bits.

Item Set with Micro Bit Precision
No. Storage Handle

75983  **Hex Inch:** .050, 1/16, 5/64, 3/32, 7/64, 1/8"

 **lbs.** .08

The Comfortable Precision Pliers & Cutters

Electronics pliers with cutting edges are designed especially for cutting soft to medium hard wires.

Precision ground cutting edges for smooth cuts

Glare free black finish

Lay-on, riveted precision joint

Light weight design for maximum user comfort in production work

C70 tool steel HR60 hardness

Electronic Diagonal Cutters



Full Flush

56818 Precision Electronic Diagonal Cutters, Wide Pointed Head Cutting edge - full flush. With return spring. C70 special tool steel. For an absolutely flush cut of copper wire.

Item No.	mm	Inch	Cut Capacity	lbs.	Pkg.
56818	138	5.5	1.3mm/16AWG	.22	1

Electronic Diagonal Cutters



Semi Flush

56815 Precision Electronic Diagonal Cutters, Wide Pointed Head Cutting edge - semi flush. With return spring. C70 special tool steel. Universal small diagonal cutter for cutting copper wires.

Item No.	mm	Inch	Cut Capacity	Hard Wire	Pkg.
56815	138	5.5	2.0mm/16AWG	0.8	1

Electronic Pointed Pliers



Electronic Diagonal Cutters



56812 Precision Electronic Diagonal Cutters, Narrow Shape Extra narrow, short head for working in particularly restricted spaces. Cutting edge - full flush. With return spring. For absolutely flush cutting of copper wires in difficult to access locations.

Item No.	mm	Inch	Cut Capacity	lbs.	Pkg.
56812	118	4.5	0.8mm/16AWG	.19	1

Electronic Diagonal Cutters



56813 Precision Electronic Diagonal Full Flush Cutters With Wire Trapping Spring Extra narrow, short head for working in particularly restricted spaces. Cutting edge - full flush. With return spring. C70 special tool steel. For absolutely flush cutting of copper wires in difficult to access locations.

Item No.	mm	Inch	Cut Capacity	lbs.	Pkg.
56813	128	5.0	1.0mm/16AWG	.19	1

Electronic Diagonal Cutters




56825 Precision Electronic Diagonal Cutters, Wide Shape With Wire Holding Spring Wide, Pointed head. Cutting edge - full flush. With return spring & fixture for holding ends of wires that have been cut off. For an absolutely flush cut of copper wire.

Item No.	mm	Inch	Cut Capacity	lbs.	Pkg.
56825	138	5.5	1.3mm/16AWG	.23	1

56801 Electronic Short Nose Precision Pliers Narrow, short head. Smooth jaws. Width at tip is only 1.2mm. C70 special tool steel. For holding small components as well as for holding and angling wires.

Item No.	mm	Inch	Pkg.	lbs.
56801	138	5.5	1	.23

Electronic Oblique 48° Cutter

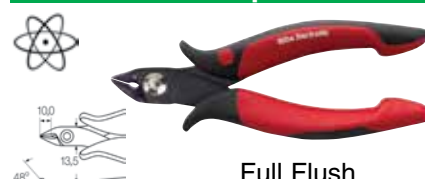


Full Flush

56833 Electronic Oblique 48° Cutter Wide pointed head. Cutting edge - full flush. With cutting edge at 48° for cutting obliquely from above or from the side. C70 special tool steel. For absolutely flush cutting of copper wires in difficult to access locations.

Item No.	mm	Inch	Cut Capacity	lbs.	Pkg.
56833	138	5.5	1.3mm/16AWG	.22	1

Narrow Front Cutter/Long Nose Pliers

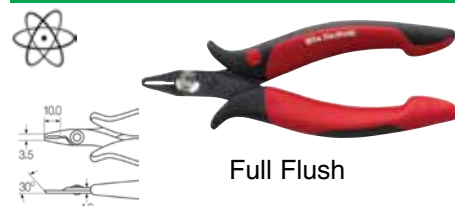

Full Flush

56830 Electronic Narrow 30° Front Cutter / Long Nose Pliers Extremely narrow, short head for working in particularly restricted spaces. Cutting edge - full flush. Edge at 30° to face end of pliers for cutting obliquely from above or from the side. C70 special tool steel. For absolutely flush cutting of copper wires in difficult to access locations.

Item No.	mm	Inch	Cut Capacity	lbs.	Pkg.
56830	118	4.5	0.6mm/16AWG	.19	1

Electronic Stripping Pliers



56871 Electronic Stripping Pliers Wide long head with ridged gripping surface, shears blade and firm wire stripping stations. With opening spring and locking mechanism. Wire stripping stations 0.81 / 1.0 / 1.3 / 1.6 / 2.0 / 2.59mm, AWG 20 / 18 / 16 / 14 / 12 / 10.

#56871	mm	Inch	Ø	AWG	lbs.	Pkg.
	180	7.0	0.81-2.59	20-10	.15	1



Professional Quality ESD Tweezers

ESD SAFE • STATIC DISSIPATIVE • HYPO ALLERGENIC COATED • TEXTURED GRIPPING SURFACE



Universal Fine Point Tweezers

Item No.	Description	wt.
44501	AA SA ESD - 130mm	.09

Static dissipative, ESD Safe hypo allergenic tweezers made from Vommaloy. Special stainless steel, anti-magnetic and acid resistant.



Very Fine Points/Tapered To Tip

Item No.	Description	wt.
44508	4 SA ESD - 110mm	.08

Static dissipative, ESD Safe hypo allergenic tweezers made from Vommaloy. Special stainless steel, anti-magnetic and acid resistant.



Angled 3.5 to 7mm Diameter

Item No.	Description	wt.
44515	54 SA ESD - 120mm	.08

Static dissipative, ESD Safe hypo allergenic tweezers made from Vommaloy. Special stainless steel, anti-magnetic and acid resistant.



Long Narrow Body Low Force

Item No.	Description	wt.
44503	SS SA ESD - 135mm	.08

Static dissipative, ESD Safe hypo allergenic tweezers made from Vommaloy. Special stainless steel, anti-magnetic and acid resistant.



Extra Fine Points/Tapered To Tip

Item No.	Description	wt.
44509	5 SA ESD - 110mm	.08

Static dissipative, ESD Safe hypo allergenic tweezers made from Vommaloy. Special stainless steel, anti-magnetic and acid resistant.



Narrow Rounded Tip Serrated, Guide Pin

Item No.	Description	wt.
44518	22 SA ESD - 150mm	.10

Static dissipative, ESD Safe hypo allergenic tweezers made from Vommaloy. Special stainless steel, anti-magnetic and acid resistant.



Reduced Body To Medium Point

Item No.	Description	wt.
44504	2 SA ESD - 120mm	.08

Static dissipative, ESD Safe hypo allergenic tweezers made from Vommaloy. Special stainless steel, anti-magnetic and acid resistant.



Curved Extra Fine Rounded Tips

Item No.	Description	wt.
44510	7a SA ESD - 120mm	.08

Static dissipative, ESD Safe hypo allergenic tweezers made from Vommaloy. Special stainless steel, anti-magnetic and acid resistant.



Universal Blunt Tip Serrated

Item No.	Description	wt.
44520	40 SA ESD - 145mm	.11

Static dissipative, ESD Safe hypo allergenic tweezers made from Vommaloy. Special stainless steel, anti-magnetic and acid resistant.



Flat Round Tip Smooth Sides

Item No.	Description	wt.
44505	2a SA ESD - 120mm	.08

Static dissipative, ESD Safe hypo allergenic tweezers made from Vommaloy. Special stainless steel, anti-magnetic and acid resistant.



Holds 0.8 to 2mm Diameter

Item No.	Description	wt.
44511	50 SA ESD - 120mm	.08

Static dissipative, ESD Safe hypo allergenic tweezers made from Vommaloy. Special stainless steel, anti-magnetic and acid resistant.



MicroTip 45° Hook 1x1x2mm

Item No.	Description	wt.
44521	12 SA-SMD ESD-120mm	.09

Static dissipative, ESD Safe hypo allergenic tweezers made from Vommaloy. Special stainless steel, anti-magnetic and acid resistant.



Fine Round Points For Assembly

Item No.	Description	wt.
44506	3 SA ESD - 120mm	.08

Static dissipative, ESD Safe hypo allergenic tweezers made from Vommaloy. Special stainless steel, anti-magnetic and acid resistant.



Holds 1.5 to 3mm Diameter

Item No.	Description	wt.
44512	51 SA ESD - 130mm	.08

Static dissipative, ESD Safe hypo allergenic tweezers made from Vommaloy. Special stainless steel, anti-magnetic and acid resistant.



Fine Round Points Shorter

Item No.	Description	wt.
44507	3c SA ESD - 110mm	.08

Static dissipative, ESD Safe hypo allergenic tweezers made from Vommaloy. Special stainless steel, anti-magnetic and acid resistant.



Holds 6.5 to 10mm Diameter

Item No.	Description	wt.
44514	53 SA ESD - 120mm	.08

Static dissipative, ESD Safe hypo allergenic tweezers made from Vommaloy. Special stainless steel, anti-magnetic and acid resistant.



10pc ESD Safe Tweezers Set

Item No.	Description	wt.
44593	10pc Set Includes:	1.05

AA SA Fine Point, 2a SA Flat Round Tip, 3 SA Round Point, 3c SA Fine Round Points Shorter, 4 SA Very Fine Points, 7a SA Curved Extra Fine, PSF SA Flat-1.0mm Wide, 7abb SA Curved Extra Fine, 5bb SA Extra Fine Bent, 4b SA Very Fine Point 40°

Wiha Professional Quality ESD Safe Tweezers



MicroTip For Chips Angled 1.6 x 1 x 1mm

Item No.	Description	wt.
44522	13 SA ESD - 120mm	.08
Static dissipative, ESD Safe hypo allergenic tweezers made from Vommaloy. Special stainless steel, anti-magnetic and acid resistant.		



Flat Bent 35° - 2mm Diameter Grip Radius

Item No.	Description	wt.
44530	59 SA-SMD ESD-117mm	.08
Static dissipative, ESD Safe hypo allergenic tweezers made from Vommaloy. Special stainless steel, anti-magnetic and acid resistant.		



Narrow Body, Bent, Long Guide Pin, Serrated

Item No.	Description	wt.
55532	22b SA ESD - 155mm	.10
Static dissipative, ESD Safe hypo allergenic tweezers made from Vommaloy. Special stainless steel, anti-magnetic and acid resistant.		



Long Flat to 1.0mm Wide No Serration

Item No.	Description	wt.
44523	PSF SA ESD-125mm	.09
Static dissipative, ESD Safe hypo allergenic tweezers made from Vommaloy. Special stainless steel, anti-magnetic and acid resistant.		



ESD Safe General Purpose Fine Point

Item No.	Description	wt.
44531	1 SA ESD - 120mm	.08
Static dissipative, ESD Safe hypo allergenic tweezers made from Vommaloy. Special stainless steel, anti-magnetic and acid resistant.		



Blunt Tips - 1.0mm Wide Serrated

Item No.	Description	wt.
55533	PSF SA ESD S -125mm	.09
Static dissipative, ESD Safe hypo allergenic tweezers made from Vommaloy. Special stainless steel, anti-magnetic and acid resistant.		



Curved Extra Fine, 3mm Long Straight Tip

Item No.	Description	wt.
44525	7abb SA ESD - 120mm	.08
Static dissipative, ESD Safe hypo allergenic tweezers made from Vommaloy. Special stainless steel, anti-magnetic and acid resistant.		



Heavy Duty Strong Tweezers Tapered To Strong Point

Item No.	Description	wt.
44532	00 SA ESD - 120mm	.09
Static dissipative, ESD Safe hypo allergenic tweezers made from Vommaloy. Special stainless steel, anti-magnetic and acid resistant.		



Flat and Broad Tips 3mm Wide

Item No.	Description	wt.
55534	F SA ESD - 120mm	.08
Static dissipative, ESD Safe hypo allergenic tweezers made from Vommaloy. Special stainless steel, anti-magnetic and acid resistant.		



Angled Extra Fine Points Bent 30° - 3mm Long Tips

Item No.	Description	wt.
44527	5abb SA ESD - 117mm	.08
Static dissipative, ESD Safe hypo allergenic tweezers made from Vommaloy. Special stainless steel, anti-magnetic and acid resistant.		



Angled & Slightly Bent With Extra Fine Tips

Item No.	Description	wt.
44533	7 SA ESD - 120mm	.08
Static dissipative, ESD Safe hypo allergenic tweezers made from Vommaloy. Special stainless steel, anti-magnetic and acid resistant.		



MicroTip Straight & 0.5mm Slot Milled

Item No.	Description	wt.
55535	8ab SA-SMD ESD-120mm	.08
Static dissipative, ESD Safe hypo allergenic tweezers made from Vommaloy. Special stainless steel, anti-magnetic and acid resistant.		



Extra Fine Points Bent 30° - 3mm Long Tips

Item No.	Description	wt.
44528	5bb SA ESD-107mm	.08
Static dissipative, ESD Safe hypo allergenic tweezers made from Vommaloy. Special stainless steel, anti-magnetic and acid resistant.		



MicroTip 30° Bend & 0.5mm Slot Milled

Item No.	Description	wt.
55531	11SA-SMD ESD-117mm	.08
Static dissipative, ESD Safe hypo allergenic tweezers made from Vommaloy. Special stainless steel, anti-magnetic and acid resistant.		



MicroTip 30° Bent & Angled With 0.5 Slot

Item No.	Description	wt.
55536	19 SA-SMD ESD-120mm	.08
Static dissipative, ESD Safe hypo allergenic tweezers made from Vommaloy. Special stainless steel, anti-magnetic and acid resistant.		

Wiha Professional Quality ESD Safe Tweezers



Chip Holding Curved Fine MicroTip

Item No.	Description	wt.
55537	R10 SA SMD ESD - 117mm	.07

Static dissipative, ESD Safe hypo allergenic tweezers made from Vomalloy. Special stainless steel, anti-magnetic and acid resistant.



Very Fine Points 40° Tapered To Tip

Item No.	Description	wt.
55539	4b SA ESD - 110mm	.08

Static dissipative, ESD Safe hypo allergenic tweezers made from Vomalloy. Special stainless steel, anti-magnetic and acid resistant.



Wafer Tweezer

Item No.	Description	wt.
55538	72a SA ESD -	.07

Static dissipative, ESD Safe hypo allergenic tweezers made from Vomalloy. Special stainless steel, anti-magnetic and acid resistant.



9mm Wide With Back Stop Pins - Wafer

Item No.	Description	wt.
55546	89 SA ESD - 125mm	.08

Static dissipative, ESD Safe hypo allergenic tweezers made from Vomalloy. Special stainless steel, anti-magnetic and acid resistant.



Angled 12mm Wide Flat, Back Stop - Wafer

Item No.	Description	wt.
55547	91 SA ESD - 125mm	.08

Static dissipative, ESD Safe hypo allergenic tweezers made from Vomalloy. Special stainless steel, anti-magnetic and acid resistant.

Inspection Mirrors All Stainless Detachable & Boilable

Inspection Mirrors - Detachable All Stainless

For Visual Checks and Fault
Finding at Inaccessible
Locations

Natural Finish,
Stainless Steel



40410 - #0

Inspection Mirror - Stainless 10mm

Item No.	Description	wt.
40410	#0 IM - 216mm	.09



40414 - #0

Inspection Mirror - Stainless 14mm

Item No.	Description	wt.
40414	#0 IM - 216mm	.09



40420 - #3

Inspection Mirror - Stainless 20mm

Item No.	Description	wt.
40420	#3 IM - 224mm	.09



40422 - #4

Inspection Mirror - Stainless 22mm Short Stem

Item No.	Description	wt.
40422	#4 IM - 224mm	.10



40424 - #5

Inspection Mirror - Stainless 24mm Short Stem

Item No.	Description	wt.
40424	#5 IM - 225mm	.10



40426 - #6

Inspection Mirror - Stainless 26mm

Item No.	Description	wt.
40426	#6 IM - 229mm	.10



40430 - #8

Inspection Mirror - Stainless 30mm

Item No.	Description	wt.
40430	#8 IM - 232mm	.10



7pc Inspection Mirror Set

Item No.	Description	wt.
40490	7pc Set Includes: 10mm, 14mm, 20mm, 22mm 24mm, 26mm, 30mm	.67



Disposable Inspection Mirrors

Item No.	Description	wt.
40425	5 Pack - Plastic	.10

Set includes: White disposable inspection mirror #5
Inspection Mirrors - 24mm x 146mm

Item No. Page	Item No. Page	Item No. Page	Item No. Page	Item No. Page	Item No. Page
26000 4	26145 9	26449 10	26631 11	26911 13	26975 15
26001 4	26190 4	26455 10	26701 6	26912 13	26976 15
26008 4	26192 5	26457 10	26702 6	26913 14	26977 15
26010 4	26193 9	26459 10	26703 6	26914 14	26978 15
26012 4	26194 5	26461 10	26704 6	26916 14	26979 15
26015 4	26195 9	26463 10	26705 6	26917 14	26980 15
26018 4	26196 9	26465 10	26706 6	26918 14	26981 15
26020 4	26197 4	26467 10	26707 6	26919 14	26982 15
26022 4	26198 9	26490 6	26708 6	26920 14	26983 15
26023 4	26199 4	26491 6	26709 6	26921 14	26985 15
26025 4	26205 5	26493 10	26710 6	26922 13	28000 13
26027 4	26210 5	26499 6	26715 6	26923 14	28002 15
26028 4	26307 5	26510 7	26720 6	26924 14	28003 15
26030 4	26309 5	26515 7	26721 12	26925 14	28004 15
26032 4	26313 5	26520 7	26723 12	26926 14	28005 15
26033 4	26315 5	26523 7	26725 12	26927 14	28006 15
26034 4	26316 5	26525 7	26727 12	26928 14	28007 15
26035 4	26320 5	26527 7	26729 12	26929 14	28008 15
26040 4	26323 5	26530 7	26731 12	26930 15	28012 15
26041 4	26325 5	26531 7	26732 10	26932 14	28021 14
26042 4	26327 5	26532 7	26733 10	26934 14	28023 14
26050 9	26330 5	26535 7	26735 10	26935 14	28024 14
26051 9	26331 5	26536 7	26736 10	26936 14	28026 14
26052 9	26333 5	26539 7	26737 10	26937 14	28027 14
26053 9	26336 5	26540 7	26739 10	26938 14	28028 14
26055 9	26340 5	26545 7	26741 10	26939 14	28029 14
26060 9	26341 10	26547 7	26743 10	26940 14	28033 14
26061 9	26343 10	26550 7	26745 10	26941 14	28034 14
26065 9	26345 10	26555 7	26747 10	26942 14	28035 14
26066 9	26347 10	26556 7	26749 10	26943 14	28036 14
26068 9	26349 10	26560 7	26751 10	26944 14	28037 14
26070 9	26351 10	26563 7	26761 7	26945 14	28552 8
26072 9	26353 10	26570 7	26762 7	26946 14	28620 8
26073 9	26363 10	26571 11	26763 7	26947 14	28622 8
26074 9	26367 10	26572 11	26764 7	26948 14	28624 8
26076 9	26369 10	26573 11	26765 7	26949 14	28626 8
26079 9	26371 10	26574 11	26766 7	26950 14	28627 8
26080 9	26390 5	26575 11	26771 11	26951 13	28629 8
26090 4	26391 5	26576 11	26772 11	26952 13	28632 8
26092 5	26392 10	26577 11	26773 11	26953 13	28633 8
26093 9	26393 10	26578 11	26774 11	26954 13	28637 8
26099 4	26399 5	26579 11	26775 11	26955 13	28644 8
26100 4	26413 6	26581 11	26776 11	26956 13	32000 12
26101 4	26415 6	26582 11	26790 6	26957 13	32001 12
26102 4	26416 6	26583 11	26791 6	26958 15	32002 12
26105 4	26419 6	26584 11	26792 6	26959 15	32003 12
26107 4	26420 6	26585 11	26793 10	26960 15	32004 12
26108 4	26423 6	26586 11	26794 7	26961 15	32085 12
26109 4	26425 6	26587 11	26795 11	26962 14	32088 12
26110 4	26427 6	26588 11	26796 10	26963 14	32106 12
26113 4	26430 6	26589 11	26798 12	26964 14	32107 12
26114 4	26431 6	26590 7	26799 6	26965 14	32108 12
26115 4	26436 6	26591 7	26810 4	26966 14	40010 8
26130 9	26439 6	26592 7	26815 11	26968 14	40410 25
26132 9	26440 6	26593 11	26900 13	26969 14	40414 25
26135 9	26441 10	26596 11	26903 13	26971 13	40420 25
26136 9	26443 10	26598 7	26904 13	26972 13	40422 25
26140 9	26445 10	26599 7	26905 13	26973 13	40424 25
26142 9	26447 10	26601 5	26906 15	26974 13	40425 25

Item No.	Page	Item No.	Page	Item No.	Page	Item No.	Page	Item No.	Page	Item No.	Page
40426	25	75093	20	75628	16	75735	17	75994	19		
40430	25	75094	20	75629	16	75742	17	75995	19		
40490	25	75095	20	75630	16	75743	18	75996	19		
44501	23	75096	20	75631	16	75744	18	75999	19		
44503	23	75097	20	75632	16	75745	18	91109	20		
44504	23	75105	17	75633	16	75746	18	91118	11		
44505	23	75110	17	75634	16	75747	18	92189	8		
44506	23	75115	17	75635	16	75748	18	92190	8		
44507	23	75120	17	75636	16	75800	17	92191	8		
44508	23	75125	17	75637	16	75801	17	96800	12		
44509	23	75307	17	75638	16	75802	18				
44510	23	75309	17	75639	16	75803	18				
44511	23	75313	17	75641	16	75805	21				
44512	23	75315	17	75644	16	75806	18				
44514	23	75320	17	75645	16	75810	18				
44515	23	75322	17	75646	16	75811	18				
44518	23	75325	17	75647	16	75812	18				
44520	23	75330	17	75648	16	75813	18				
44521	23	75332	17	75649	16	75814	18				
44522	24	75340	17	75650	16	75815	18				
44523	24	75342	17	75651	16	75816	18				
44525	24	75350	17	75652	16	75817	18				
44527	24	75352	17	75653	16	75820	18				
44528	24	75354	17	75654	16	75821	18				
44530	24	75356	17	75655	16	75822	18				
44531	24	75358	17	75657	16	75823	18				
44532	24	75360	17	75658	16	75824	18				
44533	24	75362	17	75659	16	75825	18				
44593	23	75364	17	75660	16	75826	18				
55531	24	75366	17	75661	16	75827	18				
55532	24	75368	17	75662	16	75900	17				
55533	24	75370	17	75663	16	75901	17				
55534	24	75372	17	75664	16	75902	17				
55535	24	75395	19	75665	16	75965	20				
55536	24	75602	16	75666	16	75968	20				
55537	25	75603	16	75667	16	75971	20				
55538	25	75604	16	75668	16	75973	11				
55539	25	75605	16	75669	16	75980	21				
55546	25	75606	16	75670	16	75981	21				
55547	25	75607	16	75671	16	75982	18				
56801	22	75608	16	75672	16	75983	21				
56812	22	75609	16	75673	16	75993	21				
56813	22	75610	16	75674	16	75984	18				
56815	22	75611	16	75675	16	75985	21				
56818	22	75612	16	75676	16	75986	18				
56825	22	75613	16	75681	16	75987	18				
56830	22	75614	16	75683	16	75988	18				
56833	22	75615	16	75701	17	75991	19				
56871	22	75616	16	75702	17	75992	19				
62994	12	75617	16	75703	17						
75008	17	75618	16	75704	17						
75012	17	75619	16	75705	17						
75015	17	75620	16	75706	17						
75018	17	75621	16	75707	17						
75020	17	75622	16	75708	17						
75025	17	75623	16	75709	17						
75030	17	75624	16	75710	17						
75035	17	75626	16	75715	17						
75040	17	75627	16	75720	17						



Prop65 WARNING: This product could expose you to chemicals including Vinyl Chloride, Ethylene Glycol, Ni or CrVI, which are known to the state of California to cause cancer or reproductive harm. For more information go to www.P65warnings.ca.gov/



PROFESSIONAL TECH TOOLS



(800) 494-6104
fax: (800) 494-7456
cservice@wihatools.com
www.wihatools.com

Catalog Item No. 99006 .wo
version - 9/1/19

Subject to change without notice

©2019 Willi Hahn Corporation

®Torx is a registered trademark of
Acument Intellectual Properties LLC.



Wiha Quality Tools

1348 Dundas Circle
Monticello, MN 55362
tel: 763.295.6591
fax: 763.295.6598

Wiha Tools Canada Ltd.

www.wihatools.ca
Brampton, ONT L6T 4X4
tel: 866.494.0096 or 763.295.6591
fax: 763.295.6598



To:



99934.wo - Hex Tools Catalog



99914.wo - TORX Catalog



99001.wo - TorqueControl Catalog



99951.wo - Bits Catalog



99919.wo - Insulated Catalog



99002.wo - Screwdrivers Catalog




99004.wo - Shop Tools Catalog



99977.wo - Pliers/Crimpers Catalog



99945.wo - ESD Catalog

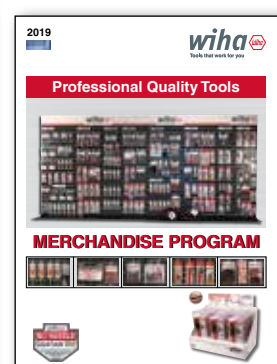

99007.wo - Merchandise Catalog

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Wiha:

[75989](#) [75095](#) [75094](#) [75093](#) [75990](#)