

2019



wiha 
Tools that work for you

PROFESSIONAL TORX® TOOLS

 
 
 
 


COMPLETE TORX® FOR TOOLING PROGRAM





TorqueFix • TorqueVario • TorqueControl Blades • TorqueFix Wing
EasyTorque • iTorque • Adapters • Cable Keys • Insulated TorqueVario
ESD Safe TorqueVario • T-handle Torque • TorqueControl Sets • Micro Bits

Torx® Index


	DESCRIPTION	Page
	SoftFinish® Cushion Grip	5
	ESD Safe SoftFinish® Cushion Grip	6
	Insulated Cushion Grip	7
	MicroFinish Non-Slip Grip	7
	Powerhandle	8
	Protturn	8
	3K Series	9
	Drive-Loc VI Blades	10
	T-handle & ComfortGrip	13
	L-Keys Offset Screwdrivers	12-13 11
	PocketStar Fold Outs	11
	Wing Handle	14
	Flag Handle	14
	TorqueControl Blades	20-22
	Precision Tools	
	Standard	23
	PicoFinish	23
	ESD Safe	24
	SYSTEM 4 Blades	24
	SYSTEM 4 Micro Bits	25
	Bit Sets	26-27
	Insert & Power Bits	29-32
	Bit Sockets & Sets	35-36

* Standard TORX® are not for use in TORXPlus® fasteners

  TorxPlus® Index

	DESCRIPTION	Page
	Wing Handle	16
	Flag Handle	16
	PocketStar Fold Outs	16
	SoftFinish® Cushion Grip	17
	T-handles	17
	L-Keys Short/Long Arm	18
	TorqueControl Blade	20-22
	ESD Safe Precision	24
	Bit-Selectors	27
	Insert Bits	34
	Power Bits	34
	Bit Sockets & Sets	35,37


 
Ball End Torx® Index

	DESCRIPTION	Page
	SoftFinish Drivers Cushion Grip	15
	L-Keys	15
	Power Bits	15



Security Torx® Index

	DESCRIPTION	Page
	SoftFinish® Cushion Grip & Insulated	6,11
	Drive-Loc VI Blades	10
	L-Keys	12
	PocketStar Fold Outs	11
	SYSTEM 4 Micro Bits	25
	Bit Sets	26-27
	Insert Bits - 1/4" & 5/16"	33
	Power Bits	33
	Bit Sockets	35,37


 
 
MagicSpring Screw Holding

	DESCRIPTION	Page
	SoftFinish® Screw Holding Cushion Grip	19
	PicoFinish Soft Grip Screw Holding	19
	L-keys Screw Holding	18
	Wing Handle Screw Holding	19
	TorqueControl Blades Screw Holding	20
	Power Bits	34

  
Wing/Flag & L-keys Index

DESCRIPTION	Page
	L-Keys 12-13
	Offset Screwdrivers 11
	Wing Handle 14,16,19 Torx®, TorxPlus® & MagicSpring
	Flag Handle 14,16 Torx® & TorxPlus®

   Screwdrivers Index

	DESCRIPTION	Page
	SoftFinish® CushionGrip Torx®, Security Torx®, TorxPlus®, MagicSpring	5-6,15,17,19
	ESD Safe SoftFinish® Cushion Grip - Torx®	6
	Insulated Torx® & Security Torx®	7,11
	MicroFinish Non-Slip Grip - Torx®	7
	Powerhandle- Torx®	8
	Protturn - Torx®	8
	3K Series - Torx®	8
	Offset Screwdrivers	11
	T-handle/ComfortGrip Torx® & TorxPlus®	13,17
	Precision Tools	
	Standard	23
	PicoFinish	23
	ESD Safe	24


 
Drive-Loc VI Interchangeable

DESCRIPTION	Page
	Drive-Loc VI Handle SoftFinish® Cushion Grip 10
	Drive-Loc VI Handle ESD Safe Cushion Grip 10
	Drive-Loc VI Handle MicroFinish Non-Slip Grip 10
	Drive-Loc VI Blades Torx® / Security Torx® 10

Fold Outs Index

DESCRIPTION	Page
	PocketStars 11,16 Torx, Security Torx, TorxPlus

  TorqueControl Index

DESCRIPTION	Page
 TorqueVario Handle	20
 Torx® / TorxPlus® Blades	20
 Insulated Torque Tools	21
 Easy Torque Tools	21
 ESD Safe TorqueControl	22
 ESD Safe Torx® Blades	22
 T-handle Torque Tools	22
 Interchangeable Blades For Torque T-handle	22
 TorqueControl Sets	22


Standard Bits Index

DESCRIPTION	Page
 Torx® Insert/Power Bits	30-32

Specialty Bits Index

DESCRIPTION	Page
  Ball End Torx®	15
  Torx® Align Bits Insert/Power Bits	32
  Security Torx® Insert/Power Bits	33
  TorxPlus® Bits Insert/Power Bits	34
  Security Pentalobe	34

 Bit Sets Index



DESCRIPTION	Page
 Six-in-One Bit Sets	26
 Bit Selector Sets	27
 Power Bit Belt Packs	27
 SYSTEM 4 Sets Micro Bits & Interchangeable Blades	25
 XSelectors	27

 See Bit Holders on Pg. 26-28

ESD Blade Set Index

DESCRIPTION	Page
 Interchangeable Blade Set	24-25

  Sockets Index

DESCRIPTION	Page
 Torx® 1/4" Drive	35-37
 Torx® 3/8" Drive	35-37
 Torx® 3/8" - 5/16" Bits	35-37
 Security Torx® 3/8", 1/2"	35,37
 External Torx® Sockets 1/4", 3/8", 1/2"	36
 6" Bit Sockets 1/4" & 3/8" Drive	36
 Bit Socket Sets	36-37

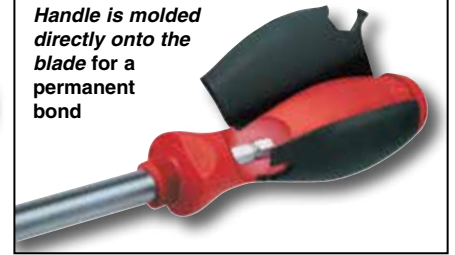
Wiha TORX® SoftFinish® Screwdrivers - Ergonomic Cushion Grip Handle
TORX®

Extra large
diameter to achieve
high torque

Improved torque zone.
For all working conditions
with molded on soft
cushion grips

Flat surfaces give
roll-off protection

Handle is molded
directly onto the
blade for a
permanent
bond


362 TORX® Screwdriver, With Wiha-SoftFinish® Handle

Round blade high alloy chrome-vanadium-molybdenum steel, hardened, hard chromed. Wiha-Chromtop finish on tips. Wiha-SoftFinish® handle, multi-component, cushion grips.

Item No.	Size	mm	Inch	mm	Inch	mm	Inch	lbs.	pkg.
36264	T5	60	2.4	2.5	.098	164	6.5	.05	10
36266	T6	60	2.4	3.5	.139	164	6.5	.06	10
36268	T7	60	2.4	3.5	.139	164	6.5	.06	10
36270	T8	60	2.4	3.5	.139	164	6.5	.06	10
36272	T9	60	2.4	4.0	.157	171	6.7	.10	10
36274	T10	80	3.1	4.0	.157	191	7.5	.11	10
36276	T15	80	3.1	4.0	.157	191	7.5	.11	10
36278	T20	100	3.9	4.0	.157	211	8.3	.11	10
36280	T25	100	3.9	4.5	.177	211	8.3	.12	10
36282	T27	115	4.5	5.5	.216	233	9.2	.19	10
36284	T30	115	4.5	6.0	.236	233	9.2	.20	10
36286	T40	130	5.1	7.0	.275	254	10.0	.27	10
36288	T45	130	5.1	8.0	.315	254	10.0	.31	10


36294 8 Pcs. TORX® Set

Round blade high alloy CVM steel, hardened, hard chromed. Wiha-Chromtop finish on tips. Wiha-SoftFinish® handle, multi-component, cushion grips.

Item No.	Size	mm	Size	mm	lbs.
36294	T6	60	T20	100	1.24
	T8	60	T25	100	
	T10	80	T27	115	
	T15	80	T30	115	


36291 6 Pcs. TORX® Set

Round blade high alloy CVM steel, hardened, hard chromed. Wiha-Chromtop finish on tips. Wiha-SoftFinish® handle, multi-component, cushion grips.

Item No.	Size	mm	Size	mm	lbs.
36291	T6	60	T9	60	.77
	T7	60	T10	80	
	T8	60	T15	80	


36201 6 Pcs. TORX® Set

Round blade high alloy CVM steel, hardened, hard chromed. Wiha-Chromtop finish on tips. Wiha-SoftFinish® handle, multi-component, cushion grips.

Item No.	Size	mm	Size	mm	lbs.
36201	T6	60	T15	80	.83
	T8	60	T20	100	
	T10	80	T25	100	


36267 Set 12 Pcs. TORX® Round

blade high alloy CVM steel, hardened, hard chromed. Wiha-Chromtop finish on tips. Wiha-SoftFinish® handle, multi-component, cushion grips.

Item No.	Size	mm	Size	mm	lbs.
36267	T5	60	T15	80	2.03
	T6	60	T20	100	
	T7	60	T25	100	
	T8	60	T27	115	
	T9	60	T30	115	
	T10	80	T40	130	

Wiha Security TORX® Drivers



362 Security TORX® Screwdriver With Wiha-SoftFinish® Handle

Round blade high alloy CVM steel, hardened, hard chromed. Wiha-Chromtop finish on tips.

Wiha-SoftFinish® handle, multi-component, cushion grips.

Item	Size	mm	Inch	mm	Inch	mm	Inch	lbs.	pkg.
No.									
36269	T7s	60	2.4	3.5	.139	164	6.5	.06	10
36271	T8s	60	2.4	3.5	.139	164	6.5	.06	10
36273	T9s	60	2.4	4.0	.157	171	6.7	.10	10
36275	T10s	80	3.1	4.0	.157	191	7.5	.11	10
36277	T15s	80	3.1	4.0	.157	191	7.5	.11	10
36279	T20s	100	3.9	4.0	.157	211	8.3	.11	10
36281	T25s	100	3.9	4.5	.177	211	8.3	.11	10
36283	T27s	115	4.5	5.5	.216	233	9.2	.19	10
36285	T30s	115	4.5	6.0	.236	233	9.2	.20	10
36287	T40s	130	5.1	7.0	.275	254	10.0	.28	10



36298 7 Pcs. Security TORX® Set

Item	Size	mm	Size	mm	lbs.
No.					
36298	T7s	60	T15s	80	.95
	T8s	60	T20s	100	
	T9s	60	T25s	100	
	T10s	80			



36259 10 Pcs. Security TORX® Set

Item	Size	mm	Size	mm	lbs.
No.					
36259	T7s	60	T20s	100	1.5
	T8s	60	T25s	100	
	T9s	60	T27s	115	
	T10s	80	T30s	115	
	T15s	80	T40s	130	

Wiha SoftFinish® ESD Safe Handle



ESD Safe (10⁶-10⁹ Ohm)

362 ESD Safe TORX® Driver, Wiha-SoftFinish® Handle DIN EN 61340-5-1/61340-5-2

Round blade, CVM steel, hardened, hard chromed. Offers protection against electrostatic

discharge. Dissipative SoftFinish® cushion grip handle, multi-component.

Item	Size	mm	Inch	mm	Inch	mm	Inch	lbs.	pkg.
No.									
36260	T3	60	2.4	3.5	.139	164	6.5	.06	10
36204	T4	60	2.4	3.5	.139	164	6.5	.06	10
36200	T5	60	2.4	3.5	.139	164	6.5	.06	10
36206	T6	60	2.4	3.5	.139	164	6.5	.06	10
36208	T8	60	2.4	3.5	.139	164	6.5	.06	10
36209	T9	60	2.4	4.0	.157	171	6.7	.10	10
36218	T10	80	3.1	4.0	.157	191	7.5	.11	10
36219	T15	80	3.1	4.0	.157	191	7.5	.11	10
36224	T20	100	3.9	4.0	.157	211	8.3	.11	10



ESD Safe
(10⁶-10⁹ Ohm)



36289 Set 6 Pcs. ESD Safe TORX® Screwdrivers

Item No.	TORX®	lbs.
36289	T6, T8, T9, T10, T15, T20	.81

Wiha ESD Safe Interchangeable Blade Set

In Durable Pouch



10893 ESD Safe 5 Piece TORX®

Interchangeable Blade Set Includes ESD Safe handle & 4 interchangeable blades.

Item	lbs.
No. 10893	.75
TORX®: T6, T7, T8, T9, T10, T15, T20, T25	
Wiha ESD Safe Handle	

Wiha Insulated **TORX**® Screwdrivers

  **1000Volt**


325 TORX® Screwdriver, With Wiha-SoftFinish® Handle Insulation According to ASTM F-1505-10, New VDE Specification 0682/part 201 and EN/IEC 60900, NFPA70E,  up to 1000 Volt. Individually Tested.

Blade high alloy cvm steel, hardened, black finish. Insulation molded directly onto blade.

Item No.	Size	mm	Inch	mm	Inch	lbs.	pkg.
32505	T5	60	2.4	164	6.5	.06	10
32511	T6	60	2.4	164	6.5	.06	10
32516	T7	60	2.4	164	6.5	.06	10
32521	T8	60	2.4	164	6.5	.06	10
32526	T9	60	2.4	164	6.5	.06	10
32531	T10	60	2.4	164	6.5	.06	10
32536	T15	80	3.1	191	7.5	.12	10
32541	T20	80	3.1	191	7.5	.12	10
32546	T25	80	3.1	198	7.8	.17	10
32551	T27	100	3.9	218	8.6	.20	10
32556	T30	100	3.9	218	8.6	.20	10
32561	T40	150	5.9	274	10.8	.30	10
32566	T45	150	5.9	274	10.8	.35	10

  **1000Volt**


32590 Set 6 Pcs. TORX®

Item No.	Size	mm	Size	mm	lbs.
32590	T8	60	T15	80	.83
	T9	60	T20	80	
	T10	60	T25	80	


  **1000Volt**

32592 Set 10 Pcs. TORX®

Item No.	Size	mm	Size	mm	lbs.
32592	T6	60	T15	80	1.2
	T7	60	T20	80	
	T8	60	T25	80	
	T9	60	T27	100	
	T10	60	T30	100	

Wiha **TORX**® MicroFinish Handle Non-Slip Grip

Wiha MicroFinish handle has a patented non-slip surface - it won't peel, crack or deteriorate when exposed to petroleum solvents. Oil and moisture flow away from the handle surface for a powerful, non-slip grip. You get maximum force and comfort with dry, oily or wet hands.

Exact
fit precision
ground tips



Blades are hardened
& hard chromed

MicroFinish Handle
with patented non-slip surface. Ergo handle shape
for maximum comfort & exceptional torque transfer

Safe, high density material,
eliminates risk of sharp
objects becoming embedded
in the handle



527 TORX® Screwdriver, With Wiha-MicroFinish Handle

Blade high alloy chrome-vanadium-molybdenum steel, hardened, hard chromed. Wiha-MicroFinish handle, cellulose-acetate, impact resistant, non-slip, oil and grease resistant. Round blades.

Item No.	Size	mm	Inch	mm	Inch	mm	Inch	lbs.	pkg.
52711	T9	60	2.4	4.0	.157	171	6.7	.15	10
52713	T10	80	3.1	4.0	.157	191	7.5	.15	10
52716	T15	80	3.1	4.0	.157	191	7.5	.15	10
52719	T20	100	3.9	4.0	.157	211	8.3	.15	10
52722	T25	100	3.9	4.5	.177	211	8.3	.16	10
52726	T27	115	4.5	5.5	.216	233	9.2	.25	10
52729	T30	115	4.5	6.0	.236	233	9.2	.27	10
52732	T40	130	5.1	7.0	.275	254	10.0	.40	10




52790 Set 5 Pcs. TORX®

Item No.	Size	mm	Size	mm	lbs.
52790	T10	80	T25	100	1.0
	T15	80	T30	115	
	T20	100			




52791 Set 8 Pcs. TORX®

Item No.	Size	mm	Size	mm	lbs.
52791	T9	60	T25	100	1.89
	T10	80	T27	115	
	T15	80	T30	115	
	T20	100	T40	130	

Wiha Powerhandle TORX®



362 TORX® Screwdriver, With Wiha-Powerhandle

CVM steel blade, hardened, hard chromed. Wiha-powerhandle cellulose-acetate.

Item No.	Size	mm	Inch	mm	Inch	mm	Inch	lbs.	pkg.
36205	T5	50	2.0	2.5	.098	110	4.3	.03	10
36210	T6	50	2.0	3.5	.139	125	4.9	.06	10
36212	T7	50	2.0	3.5	.139	125	4.9	.06	10
36215	T8	60	2.4	3.5	.139	135	5.3	.06	10
36220	T9	60	2.4	4.0	.157	140	5.5	.09	10
36225	T10	80	3.1	4.0	.157	170	6.7	.13	10
36230	T15	80	3.1	4.0	.157	170	6.7	.13	10
36235	T20	100	3.9	4.0	.157	200	7.9	.17	10
36240	T25	100	3.9	4.5	.177	200	7.9	.18	10
36245	T27	115	4.5	5.5	.216	215	8.5	.20	10
36250	T30	115	4.5	6.0	.236	225	8.9	.28	10



36292 8 Pc. Set TORX® With Wiha-Powerhandle

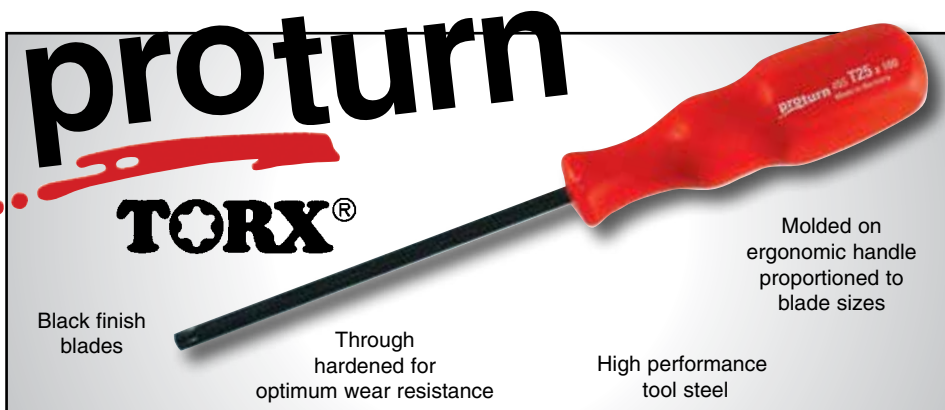
Item No.	TORX® T6, T8, T10, T15, T20, T25, T27, T30	lbs.
36292		1.45



36293 6 Pc. Set TORX® With Wiha-Powerhandle

Item No.	TORX® T6, T7, T8, T9, T10, T15	lbs.
36293		.78

Wiha TORX® Protturn Screwdrivers



455 TORX® Screwdriver, With Wiha-Protturn Handle Blade high alloy CVM steel, hardened, black finish. Molded on ergonomic Wiha-Protturn handle, impact resistant.

Item No.	Size	mm	Inch	mm	Inch	mm	Inch	lbs.	pkg.
45505	T6	50	2.0	3.5	.139	129	5.1	.05	10
45506	T7	50	2.0	3.5	.139	129	5.1	.05	10
45511	T8	60	2.4	3.5	.139	139	5.5	.06	10
45516	T9	60	2.4	4.0	.157	149	5.8	.08	10
45521	T10	80	3.1	4.0	.157	170	6.7	.10	10
45526	T15	80	3.1	4.0	.157	170	6.7	.10	10
45531	T20	100	3.9	4.0	.157	190	7.5	.11	10
45536	T25	100	3.9	4.5	.177	190	7.5	.11	10
45541	T27	115	4.5	5.5	.216	215	8.4	.11	10
45546	T30	115	4.5	6.0	.236	215	8.4	.20	10
45551	T40	130	5.1	7.0	.275	240	9.4	.28	10
45561	T50	130	5.1	9.0	.354	240	9.4	.31	10



45591 6 Pcs. TORX® Set

Item No.	TORX® T7, T8, T9, T10, T15, T20	lbs.
45591		.72



45592 8 Pcs. TORX® Set

Item No.	TORX® T8, T9, T10, T15, T20, T25, T27, T30	lbs.
45592		1.07



45589 11 Pcs. TORX® Set

Item No.	TORX® T6, T7, T8, T9, T10x80, T15, T20, T25, T27, T30, T40	lbs.
45589		2.2

Wiha TORX® 3K Series Drivers and Sets

3K Series

Blade high alloy
CVM steel, hardened

Hole for
hanging

Precision
black tip

Molded on soft grip
ergonomic handle,
impact resistant



455 TORX® Screwdriver, With Wiha-3K Series Handle Blade high alloy CVM steel, hardened, precision black tip. Molded on ergonomic Wiha-3K Series handle, impact resistant.

Item										
No.	Size	mm	Inch	mm	Inch	mm	Inch	lbs.	pkg.	
45504	T6	60	2.4	3.2	9/64	145	5.7	.06	10	
45508	T8	60	2.4	3.5	9/64	139	5.5	.06	10	
45509	T9	60	2.4	4.0	5/32	149	5.8	.08	10	
45525	T25	100	3.9	6.0	1/4	215	8.4	.20	10	
45527	T27	115	4.5	7.0	9/32	240	9.4	.28	10	
45530	T30	115	4.5	6.0	1/4	233	9.1	.21	10	
45540	T40	130	5.1	7.0	9/32	248	9.7	.25	10	
45550	T50	130	5.1	9.0	3/8	249	9.8	.33	10	



45593 Set 5 Pcs. TORX® Blade CVM steel, hardened, precision black tip. Wiha-3k Ergo handle, cushion grip.

Item No.	TORX®	lbs.
45593	T8, T10, T15, T20, T25	.86

Wiha Bit Holders



48401 1/4" Bit holding Screwdriver, With Wiha-Ergo 3K Handle Magnetic, holds bit & screw. Retainer out of stainless steel. CVM tool steel, nickel plated.

Item							
No.	Size	mm	Inch	mm	Inch	lbs.	pkg.
48401	1/4"	125	5.0	211	8.3	.24	1



48400 1/4" Bit holding Screwdriver, With Wiha-Protturn Handle Magnetic, holds bit & screw. Retainer out of stainless steel. Shaft CVM tool steel, nickel plated.

Item							
No.	Size	mm	Inch	mm	Inch	lbs.	pkg.
48400	1/4"	125	5.0	243	9.6	.24	10

Wiha Drive-Loc VI Handles, Blades & Sets



28488 Drive-Loc VI Cushion Grip Handle

Wiha-SoftFinish® impact resistant, with roll off protection. Ergonomic cushion grip, Drive-Loc mechanism guarantees a secure hold & rapid blade exchange.

Item No.	mm	mm	Inch	mm	Inch	lbs.
28488	6.0	115	4.5	36.0	1.41	.20



28486 ESD Safe Drive-Loc VI Cushion Grip Handle

Wiha-SoftFinish® impact resistant, with roll off protection. Ergonomic cushion grip, Drive-Loc mechanism guarantees a secure hold and rapid blade exchange. Static Dissipative

Item No.	mm	mm	Inch	mm	Inch	lbs.
28486	6.0	115	4.5	36.0	1.41	.20



28487 Drive-Loc VI MicroFinish Non-Slip Grip Handle

Wiha-MicroFinish handle, won't peel, crack or deteriorate when exposed to petroleum solvents. Ideal for Hex, TORX® & Nut Drivers. Ergonomic handle shape for maximum comfort, mechanism guarantees a secure hold & rapid blade exchange.

Item No.	mm	mm	Inch	mm	Inch	lbs.
28487	6.0	115	4.5	36.0	1.41	.20



10810 Drive-Loc VI Standard Narrow Profile Tech Handle

Dynamic non-locking, impact resistant, friction hold. Fits all Drive-Loc blades. Does not have locking feature.

Item No.	mm	mm	Inch	mm	Inch	lbs.
10810	6.0	135	5.3	15.2	.60	.16



Drive-Loc VI

For Adjustable Length Locking Blades

Locking mechanism allows blade length to be adjusted from 40mm-120mm. (1.7 to 4.7" In 1/8" increments)

Blades high quality CVM steel, hard chrome finish.

Ergonomic handles in ESD Safe, cushioned & non-slip grip.



281 TORX® Drive-Loc VI

Interchangeable Blade High alloy CVM steel, through hardened, hard chrome finish. Over all blade length 150mm/5.9". Blades fit all Drive-Loc VI handles.

Item No.	Size + Size	lbs.	pkg.
28126	T6 T8	.09	1
28127	T7 T9	.09	1
28128	T10 T15	.10	1
28129	T20 T25	.10	1
28130	T30 T40	.10	1



281 Security TORX® Drive-Loc VI

Over all blade length 150mm/5.9". Blades fit all Drive-Loc VI handles.

Item No.	Size + Size	lbs.	pkg.
28132	T6s T8s	.09	1
28133	T7s T9s	.09	1
28134	T10s T15s	.10	1
28135	T20s T25s	.10	1
28136	T30s T40s	.10	1



28485 5 Pack Drive-Loc VI

Interchangeable Blade Set

Over all blade length 150mm/5.9"

Item No.	TORX®	lbs.
28485	T6+T8, T7+T9, T10+T15, T20+T25, T30+T40	.35



28477 5 Pack Drive-Loc VI

Interchangeable Blade Set

Item No.	TORX®	lbs.
28477	T6s+T8s, T7s+T9s, T10s+T15s, T20s+T25s, T30s+T40s	.35



28197 Drive-Loc VI Interchangeable

Blade Set, 6 Pcs. in Durable Pouch

Set includes Drive-Loc VI handle & 5 interchangeable blades.

Item No.	Security TORX®
28197	T6s+T8s, T7s+T9s, T10s+T15s, T20s+T25s, T30s+T40s
lbs.	SoftFinish® Cushion Grip Blade
.83	Lock Handle



28189 15Pc. Drive-Loc VI

Interchangeable Blade Set, in Durable Pouch

Set includes Drive-Loc VI handle & 14 interchangeable blades.

Item No.	28189	lbs.
	Slotted: 3.5+4.5, 5.5+6.5	1.28
	Phillips: 1+2	
	Security TORX®: T6s+T8s, T7s+T9s, T10s+T15s, T20s+T25s, T30s+T40s	
	Hex Inch: 3/32+7/64, 1/8+9/64, 5/32+3/16	
	Hex Metric: 2.0+2.5, 3.0+4.0, 5.0+6.0mm	
	Wiha SoftFinish® Cushion Grip Blade Lock Handle	


Wiha SlimLine Security **TORX**® SoftFinish® Screwdrivers



  1000Volt

325 Insulated Security **TORX**® SlimLine Drivers Insulation According to ASTM, New VDE Specification 0682/part 201 and EN/IEC 60900, NFPA70E & CSA,  up to 1000 Volt. Individually Tested to 10,000Volts.

Item					
No.	Size	mm	mm	lbs.	Pkg.
32512	T10s	100	204	.08	1
32513	T15s	100	211	.12	1
32514	T20s	100	211	.12	1
32515	T25s	125	243	.18	1
32517	T27s	125	243	.21	1
32518	T30s	125	243	.21	1
32519	T40s	150	268	.26	1

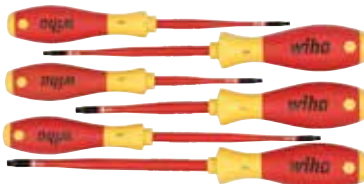

  1000Volt

32596 6 Pc. Insulated SlimLine Security **TORX**® Screwdrivers. Insulation According to ASTM F-1505, New VDE Specification 0682/part 201 and EN/IEC 60900, NFPA70E & CSA,  up to 1000 Volt. Individually Tested to 10,000Volts. High quality CV steel, through hardened. SlimLine blades have up to 33% narrower insulation diameter than standard insulated tools.

Item	Security TORX ®	T10s, T15s, T20s, T25s, T27s, T30s
32596	 lbs.	1.18

Wiha Insulated SlimLine Tools

Insulation according to EN/IE, ASTM, VDE, DIN, NFPA70E & CSA specification



28301 SlimLine Blade Holder, With Wiha-SoftFinish® Handle Insulation Chrome-vanadium steel, through-hardened. Insulation molded directly onto blade. Friction hold blade holder. Wiha-SoftFinish® handle, multi-component, cushion grip.

Item						
No.	Size	mm	Inch	mm	Inch	lbs. pkg.
28301	1/4"	50	2.0	160	6.3	.15 1

Wiha SlimTECHNOLOGY

Achieves blade diameters up to 33% narrower utilizing integrated insulation



283 Insulated **TORX**® SlimLine Blades High quality CV steel, through hardened.

Item		Slim	Max	Inch/		
No.	Size	Dia.	Nm	lbs.	lbs.	Pkg.
28339	T8	4.0	1.3	11.5	.02	1
28344	T9	4.0	1.3	11.5	.02	1
28340	T10	4.0	3.8	33.6	.02	1
28341	T15	6.0	5.5	48.7	.02	1
28342	T20	6.0	5.5	48.7	.02	1
28343	T25	6.0	5.5	48.7	.02	1

Wiha PocketStar Fold Outs




36396 **TORX**® PocketStar Fold Outs, 7 Pc. Set High alloy CVM steel, hardened, molded ergonomic handle. OAL 3.8"

Item No.			lbs.	pkg.
36396	TORX ®		.22	
		T7, T8, T9, T10, T15, T20, T25		




36395 Security **TORX**® PocketStar Fold Outs, 7 Pc. Set High alloy CVM steel, hardened, molded ergonomic handle. OAL 3.8"

Item No.	TR TORX ®		lbs.	pkg.
36395	T7s, T8s, T9s, T10s, T15s, T20s, T25s		.22	

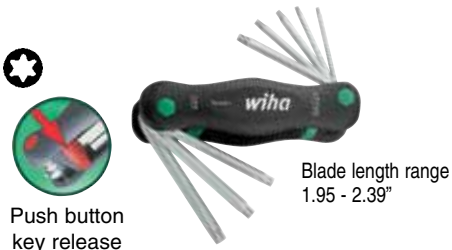

36398 **TORX**® PocketStar Fold Outs, 8 Pc. Set High alloy CVM steel, hardened, molded ergonomic handle. OAL 4.74"

Item No.	TORX ®		lbs.	pkg.
36398	T9, T10, T15, T20, T25, T27, T30, T40		.24	

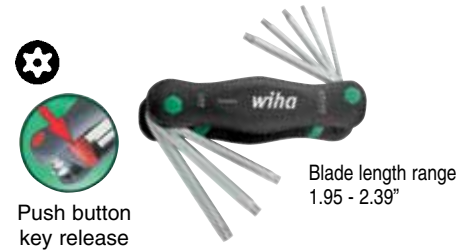

36397 Security **TORX**® PocketStar Fold Outs, 8 Pc. Set High alloy CVM steel, hardened, molded ergonomic handle. OAL 4.74"

Item No.	TR TORX ®		lbs.	pkg.
36397	T9s, T10s, T15s, T20s, T25s, T27s, T30s, T40s		.24	

Wiha Offset Screwdrivers



207 **TORX**® Offset Screwdriver With Molded Handle For working in confined spaces. Blade CVM special steel, hardened, black finish.

Item			
No.	Size	lbs.	pkg.
20756	T6 + T8	.02	1
20757	T7 + T9	.02	1
20758	T10 + T15	.02	1
20759	T20 + T25	.07	1
20760	T27 + T30	.10	1



20799 **TORX**® Offset Screwdriver Set, 5 Pcs. With Molded Handle Blade CVM special steel, hardened, black finish.

Item	Set Includes: T6+T8, T7+T9, T10+T15, T20+T25, T27+T30		
No.		lbs.	pkg.
20799		.24	1


TORX® Short Arm L-keys



363 TORX® L-key, Short Arm

High alloy CVM steel, hardened, black finish.

Item						
No.	Size	mm	Inch	mm	Inch	lbs.
36305	T5	37	1.5	16	.6	.01
36306	T6	39	1.5	16	.6	.01
36307	T7	42	1.7	16	.6	.01
36308	T8	45	1.8	16	.6	.01
36309	T9	48	1.9	16	.6	.01
36310	T10	51	2.0	17	.7	.01
36315	T15	54	2.1	19	.7	.01
36320	T20	58	2.3	19	.7	.01
36325	T25	63	2.5	21	.8	.02
36327	T27	67	2.6	22	.9	.03
36330	T30	73	2.9	24	.9	.05
36340	T40	79	3.1	26	1.0	.06
36345	T45	82	3.2	28	1.1	.09
36350	T50	95	3.7	32	1.3	.13
36355	T55	108	4.3	35	1.4	.27
36360	T60	120	4.7	38	1.5	.40

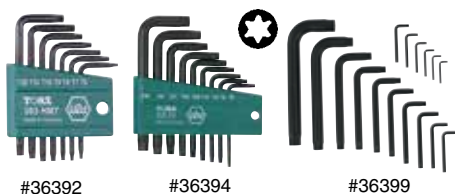

#36392

#36394

#36399

36392 TORX® Set, 7 Pc. In Plastic Holder

Equipped with T6, T7, T8, T9, T10, T15, T20

Item			
No.	lbs.	pkg.	
36392	.10	1	

36394 TORX® Set, 9 Pc. In Plastic Holder

T8, T9, T10, T15, T20, T25, T27, T30, T40

Item			
No.	lbs.	pkg.	
36394	.30	1	

36399 TORX® Set, 16 Pc.

Equipped with T5, T6, T7, T8, T9, T10, T15, T20, T25, T27, T30, T40, T45, T50, T55, T60

Item			
No.	lbs.	pkg.	
36399	1.14	1	



36390 TORX® Set, 9 Pc. In Metal Stand

Equipped with T10, T15, T20, T25, T30, T40, T50, T55, T60

Item No.	lbs.	pkg.	
36390	1.86	1	



TORX® Long Arm L-keys



366 TORX® L-key, Long Arm

High alloy CVM steel, hardened, black finish.

Item						
No.	Size	mm	Inch	mm	Inch	lbs.
36645	T5	71	2.8	12	.5	.06
36646	T6	78	3.1	13	.5	.07
36647	T7	87	3.4	16	.6	.10
36648	T8	99	3.9	18	.7	.13
36649	T9	106	4.2	18	.7	.17
36650	T10	118	4.6	21	.8	.23
36651	T15	131	5.2	23	.9	.33
36652	T20	144	5.7	25	1.0	.44
36653	T25	158	6.2	28	1.1	.65
36654	T27	169	6.7	30	1.2	.98
36655	T30	184	7.2	32	1.3	1.27
36659	T40	201	7.9	35	1.4	2.09
36660	T45	222	8.7	40	1.6	2.70
36661	T50	213	8.4	40	1.6	3.14



36699 Long Arm TORX® Set, 13 Pc. in Molded Holder

Equipped with T5, T6, T7, T8, T9, T10, T15, T20, T25, T27, T30, T40, T50

Item No.	lbs.	pkg.	
36699	1.13	1	



36698 Long Arm TORX® Set, 10 Pc. In Molded Holder

Equipped with T6, T7, T8, T9, T10, T15, T20, T25, T27, T30

Item No.	lbs.	pkg.	
36698	1.04	1	



36694 26 Piece Combo Pack Long Arm TORX® And Hex Inch L-key Sets, In Pouch

Set includes: 36699-13pc set T5-T50 and 36991-13pc set .050 - 3/8"

Item No.	lbs.	pkg.	
36694	2.13	1	



Wiha Security TORX® L-keys



Security Torx® L-Keys

363 Security TORX® L-key, Short Arm

High alloy CVM steel, hardened, black finish.

Item						
No.	Size	mm	Inch	mm	Inch	lbs.
36323	T8s	45	1.8	16	.6	.01
36326	T9s	48	1.9	16	.6	.01
36328	T10s	51	2.0	17	.7	.01
36329	T15s	54	2.1	19	.7	.01
36332	T20s	58	2.3	19	.7	.02
36335	T25s	63	2.5	21	.8	.02
36337	T27s	67	2.6	22	.9	.03
36339	T30s	73	2.9	24	.9	.04
36342	T40s	79	3.1	26	1.0	.06
36346	T45s	82	3.2	28	1.1	.09
36352	T50s	95	3.7	35	1.3	.13
36357	T55s	108	4.3	38	1.4	.27



Security Torx® L-Key Sets



36393 Security TORX® Set, 9 Pcs. In Plastic Holder

Equipped with T8s, T9s, T10s, T15s, T20s, T25s, T27s, T30s, T40s

Item No.	lbs.	pkg.	
36393	.30	1	



36391 Security TORX® Set, 6 Pcs.

T10s, T15s, T20s, T25s, T27s, T30s

Item No.	lbs.	pkg.	
36391	.16	1	

Wiha "Rust Free" Finish TORX® L-keys

Pacified Zinc
Chromate Finish

96 hour salt bath tested for best
corrosion protection



CVM tool steel through
hardened and tempered for
maximum tool life

36693 TORX® Long Arm Set, 13 Pc.

In ErgoStar Molded Holder Equipped with
T5, T6, T7, T8, T9, T10, T15, T20, T25, T27,
T30, T40, T45

Item No.		lbs.		pkg.
36693		1.10		1

Wiha TORX® Soft Grip T-handles & Set

Two Tools In One!



Through the handle
side driver

Short and Long
Arm In One
Powerful Tool

Two
component
soft grip
handle

Torx - Blades of
CVM tool steel,
through hardened
durability, hard
chrome finish

Maximum Comfort
& Maximum Power



Soft grips are molded on & include
through the handle side torque drive

364 Soft Grip TORX® T-handle

Item No.		Size		mm		lbs.		pkg.
36480		T10		100		.08		10
36481		T15		100		.08		10
36482		T20		100		.13		10
36483		T25		150		.16		10
36484		T27		150		.19		10
36486		T30		150		.20		10
36487		T40		150		.24		10

Wiha TORX® T-handle

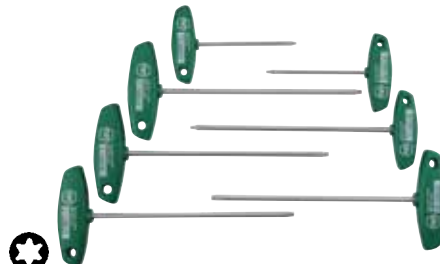
Blade high alloy CVM steel,
hardened, hard chrome finish.

Wiha T-handle high quality plastic,
impact resistant



364 TORX® with Wiha T-handles

Item No.		Size		mm		Inch		mm		Inch		lbs.		pkg.
36409		T9		100		3.9		4.0		5/32		80	3.1	.07 10
36410		T10		100		3.9		4.0		5/32		80	3.1	.07 10
36415		T15		100		3.9		4.0		5/32		80	3.1	.07 10
36417		T15		200		7.9		5.5		7/32		80	3.1	.13 10
36420		T20		100		3.9		4.0		5/32		100	3.9	.10 10
36422		T20		200		7.9		5.5		7/32		100	3.9	.17 10
36425		T25		100		3.9		4.0		5/32		100	3.9	.11 10
36427		T25		200		7.9		5.5		7/32		100	3.9	.17 10
36430		T27		100		3.9		5.5		7/32		100	3.9	.14 10
36432		T27		200		7.9		5.5		7/32		100	3.9	.17 10
36435		T30		100		3.9		7.9		6.0		100	3.9	.14 10
36437		T30		200		7.9		6.0		1/4		100	3.9	.19 10
36440		T40		100		3.9		7.0		9/32		100	3.9	.16 10
36442		T40		200		7.9		7.0		9/32		100	3.9	.23 10
36445		T45		150		5.9		8.0		5/16		120	4.7	.29 10
36450		T50		150		5.9		9.0		3/8		120	4.7	.30 10
36452		T50		250		9.8		9.0		3/8		120	4.7	.45 10



36492 TORX® T-handle Set, 7 Pc.

Includes T9, T10, T15, T20, T25, T27, T30

Item No.		lbs.		pkg.
36492		1.24		1



36490 TORX® T-handle Set, 7 Pc.

In Metal Stand Equipped with T10, T15, T20,
T25, T30, T40, T50

Item No.		lbs.		pkg.
36490		2.65		1



36494 TORX® T-handle Set, 8 Pc. In

Metal Stand Equipped with T9, T10, T15,
T20, T25, T27, T30, T40

Item No.		lbs.		pkg.
36494		3.10		1



36497 7 Piece TORX® Set Soft Grip T-handles

Item No.		lbs.
36497	T10, T15, T20, T25, T27, T30, T40	1.53

Wiha TORX® Tools Wing Handle 10 Packs & 2 Packs

Ideal for use with indexable carbide tooling and also for working in confined spaces



365 TORX® Screwdriver, With Wing Handle - 10 Pack Blade high alloy CVM steel, hardened, black finish. Wing handle high quality plastic, impact resistant.

Item No.	Size	mm	Inch	mm	Inch	mm	Inch	lbs.	pkg.
36511	T6	35	1.4	70	2.7	40	1.6	.02	10
36513	T7	35	1.4	70	2.7	40	1.6	.02	10
36514	T8	40	1.6	75	2.9	40	1.6	.02	10
36534	T9	40	1.6	75	2.9	40	1.6	.02	10
36536	T10	40	1.6	75	2.9	40	1.6	.02	10
36537	T15	45	1.8	80	3.1	40	1.6	.02	10
36538	T20	45	1.8	80	3.1	40	1.6	.02	10

365 TORX® Screwdriver, With Wing Handle - 2 Pack

Item No.	Size	mm	Inch	mm	Inch	mm	Inch	lbs.	pkg.
36516	T6	35	1.4	70	2.7	40	1.6	.02	2
36517	T7	35	1.4	70	2.7	40	1.6	.02	2
36518	T8	40	1.6	75	2.9	40	1.6	.02	2
36519	T9	40	1.6	75	2.9	40	1.6	.02	2
36521	T10	40	1.6	75	2.9	40	1.6	.02	2
36522	T15	45	1.8	80	3.1	40	1.6	.02	2
36523	T20	45	1.8	80	3.1	40	1.6	.02	2

Wiha TORX® Tools Flag Handle 10 Packs & 2 Packs

Ideal for use with indexable carbide tooling and also for working in confined spaces



370 TORX® Screwdriver, With Flag Handle - 10 Pack Blade high alloy CVM steel, hardened, black finish. Flag handle high quality plastic, impact resistant.

Item No.	Size	mm	Inch	mm	Inch	mm	Inch	lbs.	pkg.
37055	T5	35	1.4	63	2.6	15.0	.75	.01	10
37056	T6	35	1.4	63	2.6	15.0	.75	.01	10
37057	T7	35	1.4	67	2.6	19.0	.75	.01	10
37058	T8	40	1.6	72	2.8	19.0	.75	.01	10
37059	T9	40	1.6	74	2.9	23.5	.93	.01	10
37060	T10	40	1.6	74	2.9	23.5	.93	.01	10
37061	T15	45	1.8	80	3.1	28.0	1.10	.02	10
37062	T20	45	1.8	80	3.1	28.0	1.10	.02	10

370 TORX® Screwdriver, With Flag Handle - 2 Pack

Item No.	Size	mm	Inch	mm	Inch	mm	Inch	lbs.	pkg.
37005	T5	35	1.4	63	2.6	15.0	.75	.01	2
37006	T6	35	1.4	63	2.6	15.0	.75	.01	2
37007	T7	35	1.4	67	2.6	19.0	.75	.01	2
37008	T8	40	1.6	72	2.8	19.0	.75	.01	2
37009	T9	40	1.6	74	2.9	23.5	.93	.01	2
37010	T10	40	1.6	74	2.9	23.5	.93	.01	2
37011	T15	45	1.8	80	3.1	28.0	1.10	.02	2
37012	T20	45	1.8	80	3.1	28.0	1.10	.02	2



36591 Wing Handle TORX® Set, 7 Pc.

Set includes: T6, T7, T8, T9, T10, T15, T20

wt. .16



36590 Wing Handle TORX® Set, 7 Pc. In Metal Stand

Set includes: T6, T7, T8, T9, T10, T15, T20

wt. .32



37091 Flag Handle TORX® Set, 7 Pc.

Set includes: T6, T7, T8, T9, T10, T15, T20

wt. .14



37090 Flag Handle TORX® Set, 7 Pc. In Metal Stand

Set includes: T6, T7, T8, T9, T10, T15, T20

wt. .31

Wiha Ball End TORX® Screwdrivers

25°

- Ball End For 25° Angle Driving
- Precision Machined Exact Fit Tips
- Through Hardened For Maximum Durability
- WIHA High Performance CRM-72 Tool Steel
- Guaranteed Quality Made By Wiha



362 Ball End TORX® Screwdriver, With Wiha-SoftFinish® Handle

Blade high alloy chrome-vanadium-molybdenum steel, hardened, hard chromed. Wiha-Chromtop finish on tips. Wiha-SoftFinish® handle, multi-component, cushion grips.

Item No.	Size	mm	Inch	mm	Inch	mm	Inch	lbs.	pkg.
36216	T9	60	2.4	4.0	.157	164	6.5	.10	10
36217	T10	60	2.4	4.0	.157	184	7.2	.11	10
36221	T15	80	3.1	4.0	.157	191	7.5	.11	10
36222	T20	80	3.1	4.0	.157	211	8.3	.11	10
36226	T25	100	3.9	4.5	.177	218	8.6	.12	10
36227	T27	115	4.5	5.5	.216	233	9.2	.19	10
36236	T30	115	4.5	6.0	.236	233	9.2	.20	10



36237 Set 7 Pcs. TORX® Blade high alloy CVM steel, hardened, hard chromed. Wiha-Chromtop finish on tips. SoftFinish® handle, multi-component, cushion grips.

Item No.	Size	mm	Size	mm	lbs.
36237	T9	60	T25	100	1.24
	T10	60	T27	115	
	T15	80	T30	115	
	T20	80			

Wiha Ball End TORX® L-keys

25°

366 Ball End TORX® L-key, Long Arm

High alloy CVM steel, hardened, black finish.

Item No.	Size	mm	Inch	mm	Inch	lbs.	pkg.
36631	T9	111	4.4	21	.83	.17	10
36632	T10	121	4.8	23	.91	.23	10
36633	T15	136	5.4	27	1.1	.33	10
36634	T20	148	5.8	29	1.1	.44	10
36635	T25	163	6.4	33	1.3	.65	10
36636	T27	176	6.9	36	1.4	.98	10
36637	T30	191	7.5	38	1.5	1.27	10
36638	T40	210	8.3	43	1.7	2.09	10
36639	T45	232	9.1	50	2.0	2.34	10

25°

36692 Ball End TORX® L-key Set, 8 Pc. in Plastic Holder Equipped with T9, T10, T15, T20, T25, T27, T30, T40

Item No.	lbs.	pkg.
36692	6.16	1

Wiha ErgoStar Ball End TORX® Long L-keys

25°

36689 ErgoStar TORX® Long Arm Set, 13 Pc. In Molded Holder Equipped with T5, T6, T7, T8, T9, T10, T15, T20, T25, T27, T30, T40, T45

Item No.	lbs.	pkg.
36689	1.08	1

Ball End TORX® Power Bits

25°

745 Ball End TORX® Power Bits

1/4" Hex Drive, Length 2.0"/50mm

Item No.	Size	mm	pkg.	lbs.
74524	T9	50	10	.18
74526	T10	50	10	.18
74528	T15	50	10	.18
74532	T20	50	10	.18
74534	T25	50	10	.18
74537	T27	50	10	.18
74539	T30	50	10	.18
74541	T40	50	10	.18

25°

2 bit pack


25°

745 Ball End TORX® Power Bit Packs, 1"

Item No.	Size	mm	lbs.
74505	T9	50	.05
74520	T10	50	.05
74522	T15	50	.05
74543	T20	50	.05
74545	T25	50	.06
74547	T27	50	.06
74549	T30	50	.08
74550	T40	50	.08

The TORXPlus® Advantage

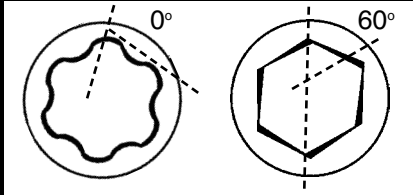The TorxPlus® Drive System offers 100% improvement in driver bit fatigue & 25% average improvement in driver bit torsional strength. In addition its unique design provides optimum torque transfer & eliminates the need for excessive end load pressure while driving the fastener. The TorxPlus® configuration also virtually eliminates tool "camout" & slippage that can damage the head of the fastener and cause reduced tool life.



Not for use in standard Torx fasteners

- Broad Surface For Driving
- Features 0° Drive Angle Between The Fastener & Driver
- Greater Engagement Depth



Wiha TORXPlus® Tools 2 Packs & 10 Packs

TORXPlus®

Not for use in standard Torx fasteners

370 TORXPlus® Screwdriver, With Flag Handle - 2 & 10 Packs

Ideal for use with indexable carbide tooling and also for working in confined spaces. Blade high alloy CVM steel, hardened, black finish. Flag handle high quality plastic, impact resistant.

Item No.	Size	mm	Inch	mm	Inch	mm	Inch	lbs.	pkg.
37063	IP5	35	1.4	63	2.6	15.0	.75	.01	10
37064	IP6	35	1.4	63	2.6	15.0	.75	.01	10
37065	IP7	35	1.4	67	2.6	19.0	.75	.01	10
37066	IP8	40	1.6	72	2.8	19.0	.75	.01	10
37067	IP9	40	1.6	74	2.9	23.5	.93	.01	10
37068	IP10	40	1.6	74	2.9	23.5	.93	.01	10
37069	IP15	45	1.8	80	3.1	28.0	1.10	.02	10
37070	IP20	45	1.8	80	3.1	28.0	1.10	.02	10



37092 Flag Handle TORXPlus® Set, 7 Pc. in Metal Stand

Set includes: lbs. .31
IP6, IP7, IP8, IP9, IP10, IP15, IP20



36592 TORXPlus® 7 Pc. Wing Handle

Set In Metal Stand. Equipped with IP6, IP7, IP8, IP9, IP10, IP15, IP20

Item No.	lbs.	pkg.
36592	.38	1

TORXPlus®

Not for use in standard Torx fasteners

365 TORXPlus® Screwdriver, With Wing Handle - 2 & 10 Packs

Blade high alloy CVM steel, hardened, black finish. Wing handle high quality plastic, impact resistant.

Item No.	Size	mm	Inch	mm	Inch	mm	Inch	lbs.	pkg.
36539	IP5	35	1.4	70	2.7	40	1.6	.02	10
36541	IP6	35	1.4	70	2.7	40	1.6	.02	10
36543	IP7	35	1.4	70	2.7	40	1.6	.02	10
36545	IP8	40	1.6	75	3.0	40	1.6	.02	10
36547	IP9	40	1.6	75	3.0	40	1.6	.02	10
36549	IP10	40	1.6	75	3.0	40	1.6	.02	10
36551	IP15	45	1.8	80	3.1	40	1.6	.02	10
36553	IP20	45	1.8	80	3.1	40	1.6	.02	10



Wiha PocketStar Fold Out



Push button key release

36697 TORXPlus® PocketStar Fold

Outs, 8 Pc. Set High alloy CVM steel, hardened, molded ergonomic handle.

Item No. lbs. .31

36697 : IP6, IP7, IP8, IP9, IP10, IP15, IP20, IP25

Wiha TORXPlus® Cushion Grip Drivers



 Not for use in standard Torx fasteners

362 TORXPlus® Screwdriver With Wiha SoftFinish Handle

Round blade high alloy CVM tool steel, hardened, hard chromed. Wiha-Chromtop finish on tips.

Item No.	Size	mm	Inch	mm	Inch	mm	Inch	lbs.	pkg.
36211	IP6	60	2.4	3.5	.139	164	6.5	.06	10
36223	IP7	60	2.4	3.5	.139	164	6.5	.06	10
36228	IP8	60	2.4	4.0	.157	171	6.7	.10	10
36229	IP9	60	2.4	4.0	.157	171	6.7	.11	10
36233	IP10	80	3.1	4.0	.157	191	7.5	.11	10
36238	IP15	80	3.1	4.0	.157	191	7.5	.11	10
36239	IP20	100	3.9	4.5	.177	211	8.3	.11	10
36243	IP25	100	3.9	5.5	.216	211	8.3	.19	10
36248	IP27	115	4.5	6.0	.236	233	9.2	.20	10
36253	IP30	115	4.5	7.0	.275	233	9.2	.28	10
36255	IP40	130	5.1	7.0	.275	254	10.0	.28	10

362 TORXPlus® Screwdriver With Wiha SoftFinish Handle In Clamshell

Round blade high alloy CVM tool steel, hardened, hard chromed. Wiha-Chromtop finish on tips.

Item No.	Size	mm	Inch	mm	Inch	mm	Inch	lbs.	pkg.
36214	IP6	60	2.4	3.5	.139	164	6.5	.06	1
36231	IP7	60	2.4	3.5	.139	164	6.5	.06	1
36232	IP8	60	2.4	4.0	.157	171	6.7	.10	1
36241	IP9	60	2.4	4.0	.157	171	6.7	.11	1
36242	IP10	80	3.1	4.0	.157	191	7.5	.11	1
36246	IP15	80	3.1	4.0	.157	191	7.5	.11	1
36247	IP20	100	3.9	4.5	.177	211	8.3	.11	1
36252	IP25	100	3.9	5.5	.216	211	8.3	.19	1
36262	IP27	115	4.5	6.0	.236	233	9.2	.20	1
36263	IP30	115	4.5	7.0	.275	233	9.2	.28	1
36265	IP40	130	5.1	7.0	.275	254	10.0	.28	1

Wiha T-handle TORXPlus®

Not for use in standard
Torx fasteners



364 TORXPlus® Screwdriver, With Wiha T-handle

Blade high alloy chrome-vanadium-molybdenum steel, hardened, hard chromed.

Wiha T-handle high quality plastic, impact resistant.

Item No.	Size	mm	Inch	mm	Inch	mm	Inch	lbs.	pkg.
36461	IP9	100	3.9	4.0	.157	80	3.1	.07	10
36463	IP10	100	3.9	4.0	.157	80	3.1	.07	10
36466	IP15	100	3.9	4.0	.157	80	3.1	.07	10
36469	IP20	100	3.9	4.0	.157	80	3.1	.10	10
36472	IP25	150	5.9	8.0	.315	120	4.7	.13	10
36474	IP27	150	5.9	8.0	.315	120	4.7	.14	10
36476	IP30	150	5.9	8.0	.315	120	4.7	.16	10
36478	IP40	150	5.9	8.0	.315	120	4.7	.20	10



36296 Set 6 Pcs. TORXPlus® Blade high alloy CVM steel, hardened, hard chromed. Wiha-SoftFinish handle, multi-component.

Item No.	TORXPlus®	lbs.
36296	IP6, IP7, IP8, IP9 IP10, IP15	.72



36299 Set 7 Pcs. TORXPlus® Blade high alloy CVM steel, hardened, hard chromed. Wiha-SoftFinish handle, multi-component.

Item No.	TORXPlus®	lbs.
36299	IP8, IP10, IP15, IP20, IP25, IP30, IP40	1.23



36297 Set 8 Pcs. TORXPlus® Blade high alloy CVM steel, hardened, hard chromed. Wiha-SoftFinish handle, multi-component.

Item No.	TORXPlus®	lbs.
36297	IP6, IP7, IP8, IP9 IP10, IP15, IP20, IP25	1.35




36496 Set 6 Pc. TORXPlus® T-handles Blade CVM steel, hardened, hard chromed. Chromtop blade tips. Wiha T-handle high quality plastic, impact resistant.

Item No.	Size	mm	Size	mm	lbs.
36496	IP10	100	IP25	150	1.01
	IP15	100	IP27	150	
	IP20	100	IP30	150	


TORXPlus®

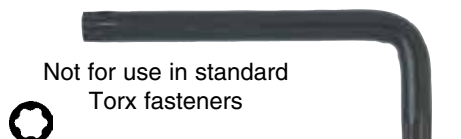For Improved Torque and Longer Tool Life



Not for use in standard Torx fasteners

361 TORXPlus® L-key, Short Arm						
High alloy CVM steel, hardened, black finish.						
Item No.	Size	mm	Inch	mm	Inch	lbs.
36106	IP6	39	1.5	16	.6	.01
36107	IP7	42	1.7	16	.6	.01
36108	IP8	45	1.8	16	.6	.01
36109	IP9	48	1.9	16	.6	.01
36110	IP10	51	2.0	17	.7	.01
36115	IP15	55	2.2	19	.7	.01
36120	IP20	58	2.3	19	.7	.01
36125	IP25	63	2.5	21	.8	.01
36127	IP27	68	2.7	22	.9	.02
36130	IP30	73	2.9	24	.9	.03
36140	IP40	81	3.2	26	1.0	.05

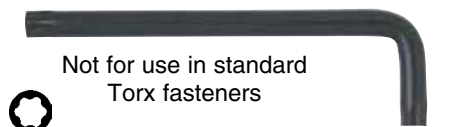

Not for use in standard Torx fasteners

366 TORXPlus® L-key, Long Arm						
High alloy CVM steel, hardened, black finish.						
Item No.	Size	mm	Inch	mm	Inch	lbs.
36606	IP6	64	2.5	14	.6	.01
36607	IP7	68	2.7	14	.6	.01
36608	IP8	74	2.9	15	.6	.01
36609	IP9	78	3.1	16	.6	.01
36610	IP10	83	3.3	18	.7	.01
36615	IP15	88	3.5	18	.7	.02
36620	IP20	94	3.7	18	.7	.02
36625	IP25	98	3.9	19	.7	.03
36627	IP27	107	4.2	23	.9	.05
36630	IP30	114	4.5	24	.9	.06
36640	IP40	118	4.6	27	1.0	.09



36197 TORXPlus® L-key, Short Arm, 7 Pc. Set In Holder			
High alloy CVM steel, hardened, black finish.			
Item No.	lbs.	Set includes the following L-keys:	
36197	.10	IP6, IP7, IP8, IP9, IP10, IP15, IP20	



36690 TORXPlus® L-key, Long Arm, 7 Pc. Set In Holder			
High alloy CVM steel, hardened, black finish.			
Item No.	lbs.	Set includes the following L-keys:	
36690	.22	IP6, IP7, IP8, IP9, IP10, IP15, IP20	



36199 TORXPlus® L-key, Short Arm, 9 Pc. Set In Holder			
Set includes the following L-keys:			
Item No.	lbs.	Set includes the following L-keys:	
36199	.30	IP8, IP9, IP10, IP15, IP20, IP25, IP27, IP30, IP40	




36691 TORXPlus® L-key, Long Arm, 9 Pc. Set In Holder			
Set includes the following L-keys:			
Item No.	lbs.	Set includes the following L-keys:	
36691	.35	IP8, IP9, IP10, IP15, IP20, IP25, IP27, IP30, IP40	

MagicSpring TORX® Tools



371 MagicSpring Screw Holding TORX® L-key, Long Arm	
High alloy CVM steel, hardened, black finish.	
Item No.	Size
37106	T6 14 .55 80 3.1 .001
37107	T7 16 .63 88 3.5 .002
37108	T8 18 .71 101 4.0 .003
37109	T9 19 .75 111 4.4 .005
37110	T10 21 .83 121 4.8 .007
37115	T15 22 .87 136 5.4 .009
37120	T20 25 .98 148 5.8 .01
37125	T25 28 1.1 163 6.4 .02
37127	T27 30 1.2 176 6.9 .03
37130	T30 34 1.3 191 7.5 .04
37140	T40 36 1.4 210 8.3 .07

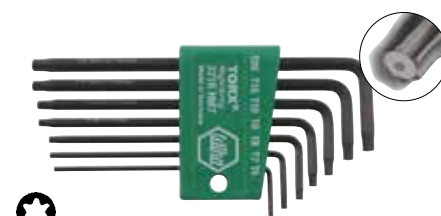

37190 MagicSpring Long Arm Screw Holding TORX® Set, 7 Pc. in Plastic Holder		
Equipped with T6, T7, T8, T9, T10, T15, T20		
Item No.	lbs.	pkg.
37190	.20	1



37192 MagicSpring Long Arm Screw Holding TORX® Set, 10 Pc. in Plastic Holder		
T6, T7, T8, T9, T10, T15, T20, T25, T27, T30		
Item No.	lbs.	pkg.
37192	.35	1

Laser Welded MagicSpring Assembly



Wiha MagicSpring TORX® Tools

- Laser welded assembly
- Holds screws securely
- Won't damage screws
- Doesn't weaken tool
- Exact fit tips
- Hardened tool steel blades
- Holds standard Torx screws*

Screw Holding TORX®

Stainless Rotary Spring

Wiha-Chromtop finish on tips

Wiha-SoftFinish® handle, multi-component, cushion grips



362 MagicSpring Screw Holding TORX® Driver, With Wiha-SoftFinish® Handle

Round blade high alloy CVM steel, hardened, hard chromed.

Item No.	Size	mm	Inch	mm	Inch	mm	Inch	lbs.	pkg.
36202	T6	60	2.4	3.5	.139	164	6.5	.07	10
36203	T7	60	2.4	3.5	.139	164	6.5	.07	10
36207	T8	60	2.4	3.5	.139	164	6.5	.07	10
36234	T9	60	2.4	4.0	.157	171	6.7	.11	10
36244	T10	80	3.1	4.0	.157	191	7.5	.11	10
36249	T15	80	3.1	4.0	.157	191	7.5	.11	10
36254	T20	100	3.9	4.0	.157	211	8.3	.16	10
36256	T25	100	3.9	4.5	.177	211	8.3	.17	10
36257	T27	115	4.5	5.5	.216	233	9.2	.20	10
36258	T30	115	4.5	6.0	.236	233	9.2	.21	10



Stainless Rotary Spring



365 MagicSpring Screw Holding TORX® driver, With Wing Handle Ideal for use with indexable carbide tooling and also for working in confined spaces. Blade high alloy CVM steel, hardened, black finish. Wing handle high quality plastic, impact resistant. Molded on.

Item No.	Size	mm	Inch	mm	Inch	mm	Inch	lbs.	pkg.
36556	T6	35	1.4	70	2.7	40	1.6	.01	10
36557	T7	35	1.4	70	2.7	40	1.6	.02	10
36558	T8	40	1.6	75	3.0	40	1.6	.02	10
36559	T9	40	1.6	75	3.0	40	1.6	.02	10
36560	T10	40	1.6	75	3.0	40	1.6	.02	10
36561	T15	45	1.8	80	3.1	40	1.6	.02	10
36562	T20	45	1.8	80	3.1	40	1.6	.02	10



Screw Holding Tools



36598 MagicSpring Screw Holding TORX® Wing Handle Set, Pc. in Metal Stand
Equipped with T6, T7, T8, T9, T10, T15, T20
⚖️ .36 lbs.



36290 Set 6 Pcs. MagicSpring Screw Holding TORX® SoftFinish Screwdrivers

Round blade high alloy CVM steel, hardened, hard chromed. Wiha-Chromtop finish on tips. Wiha-SoftFinish® handle, multi-component, cushion grips. Molded on.

Item No.	Size	mm	Size	mm	lbs.
36290	T8	60	T20	100	.98
	T10	80	T25	100	
	T15	80	T30	115	

*MagicSpring tools will hold Torx® screws made to CamCar Textron Torx® specifications



267 MagicSpring Screw Holding TORX® Driver, With Wiha-Precision PicoFinish Handle

Blade high alloy CVM steel, hardened, hard chromed. Molded on ergo Wiha-Pico Finish precision handle, molded on, soft grips.

Item No.	Size	mm	Inch	mm	Inch	lbs.	pkg.
26721	T6	40	1.6	140	5.5	.03	10
26723	T7	40	1.6	140	5.5	.03	10
26725	T8	40	1.6	140	5.5	.03	10
26727	T9	50	2.0	150	5.9	.04	10
26729	T10	50	2.0	150	5.9	.04	10
26731	T15	60	2.4	160	6.3	.04	10



26798 Set 6 Pcs. MagicSpring Screw Holding TORX® Screwdriver, With Wiha-Precision PicoFinish Handle

Blade high alloy CVM steel, hardened, hard chromed. Molded on ergonomic Wiha-Pico Finish precision handle, molded on, soft grips.

Item No.	Size	mm	Size	mm	lbs.
26798	T6	40	T9	50	.45
	T7	40	T10	50	
	T8	40	T15	60	

Wiha TorqueControl Screwdrivers

Molded cushion grip two component handles allow for maximum achievable torque to be reached with comfort

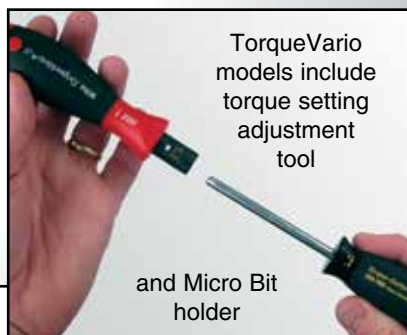
Precise repeatability!

All TorqueVario tools are tested and comply with:

- EN ISO 6789
- BS EN 26789
- ASME B107.14M

Each tool has unique serial number and certificate of calibration

See 4mm Micro Bits on Page 25



TorqueVario models include torque setting adjustment tool

and Micro Bit holder

Direct Reading Scale



+/-6% accuracy tolerance
Certificate of calibration

285 Adjustable TorqueVario With

Direct Reading Scale EN ISO 6789, BS EN 26789, ASME B107.14M. Ergonomic molded multi-component handle, light and compact. Handle sizes proportioned to optimize torque range. Audible and perceptible click when the torque setting has been attained, automatically resets for next torque cycle. Pkg. 1

Item No.	Range	Inch lbs.	Increments	mm
28501	15 - 80(in/oz)		2.5 In.oz.	127
28502	5 - 10		.5 In.lbs.	127
28506	10 - 50		2 In.lbs.	138

* 28501 +/- 10% (This unit only)*

Item No.	Range	Inch lbs.	Increments	mm
28404	5 - 18		.5 in/lbs.	131
28408	18 - 62		2 In.lbs.	142

+/-6% accuracy tolerance
Certificate of calibration



285 Adjustable TorqueVario-S Handle

In Newton Meter Scale EN ISO 6789, BS EN 26789, ASME B107.14M. Ergo molded multi-component handle, light & compact. Handle sizes proportioned to optimize torque range. Audible & perceptible click when the torque setting has been attained, automatically resets for next torque cycle. Pkg. 1

Item No.	Newton Meter Scale	Increments	mm
28550	0.1 - 0.6Nm	.02 Nm	127
28551	0.4 - 1.0Nm	.05 Nm	127
28552	0.5 - 2.0Nm	.10 Nm	131
28553	0.8 - 5.0Nm	.20 Nm	138
28655	2.0 - 7.0Nm	.25 Nm	142

* +/- 10% (This unit only)



285 TORX® Interchangeable Blades For TorqueFix & TorqueVario

TORX® tip blades on narrow 5/32 Hex shafts. High alloy CVM steel, hardened, satin hard chrome finish.

Item No.	Size	mm	mm	lbs.	Nm	pkg.
28561	T5	175	4.0	.07	0.4	1
28562	T6	175	4.0	.07	0.6	1
28563	T7	175	4.0	.07	0.9	1
28564	T8	175	4.0	.07	1.3	1
28565	T9	175	4.0	.07	2.5	1
28566	T10	175	4.0	.07	3.8	1
28567	T15	175	4.0	.07	5.5	1
28568	T20	175	4.0	.07	8.0	1
28569	T25	175	4.0	.07	8.0	1



285 TORXPlus® Blades For TorqueFix & TorqueVario

TORXPlus® tip blades on narrow 5/32 Hex shafts. High alloy CVM steel, hardened, satin hard chrome finish.

Item No.	Size	mm	mm	lbs.	Nm	pkg.
28571	IP5	175	4.0	.07	0.5	1
28572	IP6	175	4.0	.07	0.8	1
28573	IP7	175	4.0	.07	1.3	1
28574	IP8	175	4.0	.07	2.0	1
28575	IP9	175	4.0	.07	3.0	1
28576	IP10	175	4.0	.07	4.5	1
28577	IP15	175	4.0	.07	6.6	1
28578	IP20	175	4.0	.07	8.0	1
28579	IP25	175	4.0	.07	8.0	1



Screw Holding



285 MagicSpring TORX® Blades

For TorqueFix & TorqueVario blades on narrow 5/32 Hex shafts. High alloy CVM steel, hardened, satin hard chrome finish.

Item No.	Size	mm	mm	lbs.	Nm	pkg.
28512	T6	175	4.0	.07	0.6	1
28527	T7	175	4.0	.07	0.9	1
28528	T8	175	4.0	.07	1.3	1
28529	T9	175	4.0	.07	2.5	1
28530	T10	175	4.0	.07	3.8	1
28531	T15	175	4.0	.07	5.5	1
28532	T20	175	4.0	.07	8.0	1
28533	T25	175	4.0	.07	8.0	1



Screw Holding



286 MagicSpring TORXPlus® Interchangeable Blades For TorqueFix & TorqueVario

blades on narrow 5/32 Hex shafts. High alloy CVM steel, hardened, satin hard chrome finish.

Item No.	Size	mm	mm	lbs.	Nm	pkg.
28611	IP6	175	4.0	.07	0.8	1
28612	IP7	175	4.0	.07	1.3	1
28613	IP8	175	4.0	.07	2.0	1
28614	IP9	175	4.0	.07	3.0	1
28616	IP10	175	4.0	.07	4.5	1
28617	IP15	175	4.0	.07	6.6	1
28618	IP20	175	4.0	.07	8.0	1
28619	IP25	175	4.0	.07	8.0	1

*None of the blades featured on this page will function in a TorqueVario Insulated Handle

Wiha Easy Torque Handles



292 easyTorque Screwdriver Handle

With TORX® Blades easyTorque value pre-set. Release accuracy +/- 10%. Internal mechanism clicks when torque value has been attained. Cushion grip comfortable handle for good power transfer.

Item No.	Pre-Sets Size	Inch/lbs.	Nm	lbs.	pkg.
29232	T5	4.4	0.5	.24	1
29233	T6	5.3	0.6	.24	1
29234	T7	8.0	0.9	.24	1
29236	T8	10.6	1.2	.25	1
29237	T9	12.4	1.4	.25	1
29239	T10	17.7	2.0	.26	1
29242	T15	26.6	3.0	.26	1
29243	T20	35.4	4.0	.26	1
29244	T25	44.2	5.0	.28	1

* No Calibration Certificates



292 easyTorque Screwdriver Handle

With TORXPlus® Blades easyTorque value pre-set. Release accuracy +/- 10%. Internal mechanism clicks when torque value has been attained. Cushion grip comfortable handle for good power transfer.

Item No.	Pre-Sets Size	Inch/lbs.	Nm	lbs.	pkg.
29246	IP5	4.4	0.5	.24	1
29247	IP6	5.3	0.6	.24	1
29248	IP7	8.0	0.9	.24	1
29249	IP8	10.6	1.2	.25	1
29252	IP9	12.4	1.4	.25	1
29253	IP10	17.7	2.0	.26	1
29254	IP15	26.6	3.0	.26	1
29255	IP20	35.4	4.0	.26	1
29256	IP25	44.2	5.0	.28	1

* No Calibration Certificates

TorqueFix Key Wing Handles & Blades

EN ISO 6789,
BS EN 26789, ASME
B107.14M

+/- 6% Accuracy



Includes Calibration Certificate

283 TorqueFix Wing Handles

Audible & perceptible click when torque setting has been attained.

Item No.	Nm	mm	Inch	pkg.	lbs.
28349	0.5	68	2.7	1	.28
28351	0.6	68	2.7	1	.28
28352	0.9	68	2.7	1	.28
28353	1.1	68	2.7	1	.28
28354	1.2	68	2.7	1	.28
28355	1.4	68	2.7	1	.28
28356	2.0	68	2.7	1	.28
28357	2.5	68	2.7	1	.28
28358	3.0	68	2.7	1	.28
28359	3.8	68	2.7	1	.28
28360	4.0	68	2.7	1	.28



Compact design specially used for hard to reach screws and confined spaces

CVM steel, through-hardened,
titanium silver blades



283 TORX® Blades For TorqueFix Wing Handles

Item No.	Size	Max Nm	Inch	pkg.
28374	T6	0.6	3.0	1
28375	T7	0.9	3.0	1
28376	T8	1.3	3.0	1
28377	T9	2.5	3.0	1
28378	T10	3.8	3.0	1
28379	T15	5.5	3.0	1
28380	T20	8.0	3.0	1
28381	T25	8.0	3.0	1



283 TORXPlus® Blades For TorqueFix Wing Handles

Item No.	Size	Max Nm	Inch	pkg.
28382	IP6	0.8	3.0	1
28383	IP7	1.3	3.0	1
28384	IP8	2.0	3.0	1
28385	IP9	3.0	3.0	1
28386	IP10	4.5	3.0	1
28387	IP15	6.6	3.0	1
28388	IP20	8.0	3.0	1
28389	IP25	8.0	3.0	1

Wiha Insulated TorqueControl Tools



* Includes Certificate

* Includes SlimLine blade holder #28350

* Requires SlimLine Blades

1000Volt



287 Insulated TorqueVario-S, With Window Scale Insulation up to 1000Volt

EN ISO, BS EN, ASME, VDE, ASTM & NFPA70E standards, +/- 6% Accuracy. Handle sizes proportioned to optimize torque range. Audible and perceptible click when torque setting has been attained. Includes SlimLine blade holder.

Item	Range				
No.	Inch	lbs.	Increments	mm	lbs. pkg.
28750	5	- 18	.5 In.lbs.	131	.43 1
28751	10	- 50	2 In.lbs.	138	.40 1
28752	18	- 62	2 In.lbs.	142	.69 1

Each TorqueVario handle has unique serial number and certificate of calibration

287 Insulated TorqueVario-S Handle - In Newton Meter Scale

Includes SlimLine blade holder

Item No.	Range Nm	mm	lbs.	pkg.
28740	0.5 - 2.0	131	.45	1
28741	1.0 - 5.0	138	.45	1
28742	2.0 - 7.0	142	.72	1



283 Insulated TORX® SlimLine Blades

High quality CV steel, through hardened. SlimLine blades have up to 33% narrower insulation diameter than standard insulated tools.

Item No.	Size	Slim Dia.	Max Nm	Inch/ lbs.	lbs.	pkg.
28339	T8	4.0	1.3	11.5	.02	1
28344	T9	4.0	1.3	11.5	.02	1
28340	T10	4.0	3.8	33.6	.02	1
28341	T15	6.0	5.5	48.7	.02	1
28342	T20	6.0	5.5	48.7	.02	1
28343	T25	6.0	5.5	48.7	.02	1

Wiha TorqueControl Tool Sets



28597 8 Pc. TorqueControl Set With

TORX® Blades Certified to EN ISO 6789, BS EN 26789, ASME B107.14M

28597 lbs. 1.01

TORX®: T7, T8, T9, T10, T15, T20

28506 - Handle Range 10 - 50 In/lbs.

With Certificate of Calibration



28598 8 Piece TorqueControl Set With

TORXPlus® Blades Certified to EN ISO 6789, BS EN 26789, ASME B107.14M

28598 lbs. 1.00

TORXPlus®: IP7, IP8, IP9, IP10, IP15, IP20

28506 - Handle Range 10 - 50 In/lbs.

With Certificate of Calibration



28599 14 Piece TorqueControl Set With

TORX® & TORXPlus® Blades Certified to EN ISO 6789, BS EN 26789, ASME B107.14M.

Set includes Ergonomic multi-component adjustable TorqueVario-S handle, 12 blades & Torque adjustment tool. Packed in a durable canvas pouch.

TORXPlus®: lbs. 1.25

IP7, IP8, IP9, IP10, IP15, IP20

TORX®: T7, T8, T9, T10, T15, T20

28506 - Handle Range 10 - 50 In/lbs.

With Certificate of Calibration

T-handle TorqueControl Tools

Each TorqueFix T-handle has unique serial number and certificate of calibration



Includes Calibration Certificate

289 TorqueFix T-handle EN ISO 6789, BS EN 26789, ASME B107.14M, +/- 6%

Item No.	Torque In-lbs.	Torque Nm	mm x mm	lbs.	pkg.
28931	53.1	6	56 x 120	.81	1
28933	70.8	8	56 x 120	.82	1
28935	88.5	10	56 x 120	.79	1
28937	106.2	12	56 x 120	.79	1
28938	110.6	12.5	56 x 120	.80	1
28939	123.9	14	56 x 120	.80	1



289 TORX® Interchangeable Blades For TorqueFix T-Handle **TORX®** tip blades on 6mm Hex shafts. High alloy CVM steel, hardened, hard chromed.

Item No.	Size	mm	Inch	mm	lbs.	pkg.
28903	T15	130	5.1	6.0	.10	1
28904	T20	130	5.1	6.0	.10	1
28905	T25	130	5.1	6.0	.11	1
28906	T27	130	5.1	6.0	.11	1
28907	T30	130	5.1	6.0	.11	1
28908	T40	130	5.1	6.0	.11	1



Accuracy Ergonomic multi-component handle, light & compact

Includes Calibration Certificate

28940 Adjustable TorqueVario STplus T-handle EN ISO 6789, BS EN 26789, ASME B107.14M, +/- 6%

Item No.	Torque Nm	Torque In-lbs.	mm x mm	lbs.	pkg.
28940	5-14	44.3-123.9	56 x 120	.81	1

* (1 Nm 8.8507) (Scale is shown in Nm only)



289 TORXPlus® Interchangeable Blades For TorqueFix T-Handle **TORXPlus®** tip blades on 6mm Hex shafts. High alloy CVM steel, hardened, hard chromed.

Item No.	Size	mm	Inch	mm	lbs.	pkg.
28910	IP15	130	5.1	6.0	.10	1
28911	IP20	130	5.1	6.0	.10	1
28912	IP25	130	5.1	6.0	.11	1
28913	IP27	130	5.1	6.0	.11	1
28914	IP30	130	5.1	6.0	.11	1
28915	IP40	130	5.1	6.0	.11	1

ESD Safe Adjustable TorqueControl Tools

Each TorqueVario handle has unique serial number and certificate of calibration



Includes Certificate

285 ESD Safe TorqueVario-S, With Window Scale EN ISO 6789, BS EN 26789, ASME B107.14M, +/- 6% Accuracy.

Ergonomic multi-component handle, light and compact. Handle sizes proportioned to optimize torque range. Audible & perceptible click when torque setting has been attained. With Certificate of accuracy. Pkg. 1

Item No.	Range	mm	Inch	lbs.	pkg.
28522*	15-80(in/oz)	2.5 In.oz.	122-127	.33	
28524	5-10	.2 In.lbs.	122-127	.34	
28526	7.5-20	.5 In.lbs.	126-131	.42	
Item No.	Range	mm	Inch	lbs.	pkg.
28500*	.04 - .46	124	4.875"	.35	1

* +/- 10% (This unit only)



288 ESD Safe TORX® Interchangeable Blades For TorqueVario-S **TORX®** tip blades on narrow 5/32 Hex shafts. High alloy CVM steel, hardened, hard chromed.

Item No.	Size	mm	mm	Nm	lbs.	pkg.
28825	T5	175	4.0	0.4	.07	1
28827	T7	175	4.0	0.9	.07	1
28829	T9	175	4.0	2.5	.07	1



288 ESD Pentalobe Interchangeable Blades For TorqueVario-S Newton Meter Handle tip blades on narrow 5/32 Hex shafts.

Item No.	Size	mm	mm	lbs.	pkg.
28818	PL1	175	4.0	.07	1

Wiha TORX® Precision Series



267 TORX® Screwdriver, With

Precision Handle Blade high alloy chrome-vanadium-molybdenum steel.

Item							
No.	Size	mm	Inch	mm	Inch	lbs.	pkg.
26701	T1	40	1.6	120	4.7	.01	10
26702	T2	40	1.6	120	4.7	.02	10
26703	T3	40	1.6	120	4.7	.02	10
26704	T4	40	1.6	120	4.7	.02	10
26705	T5	40	1.6	120	4.7	.02	10
26706	T6	40	1.6	120	4.7	.02	10
26707	T7	40	1.6	120	4.7	.02	10
26708	T8	40	1.6	120	4.7	.03	10
26709	T9	50	2.0	145	5.7	.03	10
26710	T10	50	2.0	145	5.7	.03	10
26715	T15	60	2.4	170	6.7	.05	10
26720	T20	60	2.4	170	6.7	.05	10

*Metric dimensions actual - Inch dimensions approximate



26790 6 Pc. TORX® Screwdriver Set

Blade high alloy chrome-vanadium-molybdenum steel.

Item			
No.	TORX®:		lbs.
26790	T6, T7, T8 x 40mm		.30
	T9, T10 x 50mm		
	T15 x 60mm		



26792 7 Pc. TORX® Screwdriver Set

Blade high alloy chrome-vanadium-molybdenum steel.

Item			
No.	TORX®:		lbs.
26792	T5, T6, T7, T8 x 40mm		.33
	T9, T10 x 50mm		
	T15 x 60mm		



26791 8 Pcs. TORX® Screwdriver Set

Item No. T1, T2, T3, T4,
26791 T5, T6, T7, T8



26799 8 Pc. TORX® Screwdriver Set

Blade high alloy chrome-vanadium-molybdenum steel. Hard chrome finished.
In canvas storage pouch

Item	TORX®: T3, T4, T5,	
No.	T6, T7, T8 x 40mm	lbs.
26799	T9 x T10 x 50mm	.50

Wiha TORX® Pico Soft Grip



267 TORX® Driver, With Precision

Soft PicoFinish Handle Blade high alloy CVM tool steel, hardened, hard chrome finish.

Item						
No.	Size	mm	Inch	mm	Inch	Pkg.
26732	T1	40	1.6	134	5.3	10
26733	T2	40	1.6	134	5.3	10
26735	T3	40	1.6	134	5.3	10
26736	T4	40	1.6	134	5.3	10
26737	T5	40	1.6	134	5.3	10
26739	T6	40	1.6	140	5.5	10
26741	T7	40	1.6	140	5.5	10
26743	T8	40	1.6	140	5.5	10
26745	T9	50	2.0	150	5.9	10
26747	T10	50	2.0	150	5.9	10
26749	T15	60	2.4	160	6.3	10
26751	T20	60	2.4	160	6.3	10

*Metric dimensions actual - Inch dimensions approximate



26793 8 Pc. TORX® Precision Driver

Set, With Soft PicoFinish Handle Blade high alloy CVM steel, hardened, hard chromed. ChromTop finish on tip for a perfect fit.

Item	TORX®:		
No.	T1, T2, T3, T4,		lbs.
26793	T5, T6, T7, T8		.50



26796 8 Pc. TORX® Precision Driver

Set, Soft PicoFinish Handle Blade high alloy CVM steel, hardened, hard chromed. ChromTop finish on tip for a perfect fit.

Item	TORX®:	
No.	T5, T6, T7, T8 x 40mm	lbs. .57
26796	T9, T10 x 50mm, T15, T20 x 60mm	



91118

Rugged Polyester Canvas

Storage Pouch Holds 8 Precision Tools up to 170mm in length. Folding pouch. Has security flaps and velcro closer.

Item			
No.	Size	lbs.	pkg.
91118	14-1/2" W x 7-3/4" L	.13	1

ESD Safe Dissipative Precision Screwdrivers

Surface resistance of handles is $10^6 - 10^9$ Ohms



278 TORX® Screwdriver, With Precision ESD Safe Dissipative Handle Blade high alloy CVM steel. Hard chrome finished. Handle impact resistant, dissipative material. ESD standard IEC 61340-5-1.

Item	No.	Size	mm	Inch	mm	Inch	lbs.	pkg.
		T1	40	1.6	120	4.7	.03	10
		T2	40	1.6	120	4.7	.03	10
		T3	40	1.6	120	4.7	.03	10
		T4	40	1.6	120	4.7	.03	10
		T5	40	1.6	120	4.7	.03	10
		T6	40	1.6	120	4.7	.03	10
		T7	40	1.6	120	4.7	.03	10
		T8	40	1.6	120	4.7	.03	10
		T9	50	2.0	145	5.7	.04	10
		T10	50	2.0	145	5.7	.04	10
		T15	60	2.4	170	6.7	.07	10
		T20	60	2.4	170	6.7	.07	10

*Metric dimensions actual - Inch dimensions approximate



27890 Set 7 Pcs. TORX® Precision ESD Safe Dissipative Handle Blade high alloy CVM steel, hardened, hard chromed. Handle manufactured from impact resistant, dissipative material.

Item	TORX® :	lbs.
No.	T4, T5, T6, T7, T8, T9, T10	.31

ESD standard IEC 61340-5-1



27899 Set 8 Pcs. TORX® Precision ESD Safe Dissipative Handle Set In Pouch Blade high alloy CVM steel, hardened, hard chromed. Handle impact resistant, dissipative material. In storage pouch.

Item	TORX® :	lbs.
No.	T1, T2, T3, T4, T5, T6, T7	.47
	Chip Lifter	



278 TORX Plus® Screwdriver, With Precision ESD Safe Dissipative Handle Blade high alloy CVM steel, hardened, hard chromed. ESD standard IEC 61340-5-1.

Item	No.	Size	mm	Inch	mm	Inch	lbs.	pkg.
		IP4	40	1.6	120	4.7	.03	10
		IP5	40	1.6	120	4.7	.03	10
		IP6	40	1.6	120	4.7	.03	10
		IP7	40	1.6	120	4.7	.03	10
		IP8	40	1.6	120	4.7	.03	10
		IP9	50	2.0	145	5.7	.04	10
		IP10	50	2.0	145	5.7	.04	10
		IP15	60	2.4	170	6.7	.07	10

*Metric dimensions actual - Inch dimensions approximate



27894 Set 7 Pcs. TORX Plus® Precision ESD Safe Dissipative Handle

Item	TORX Plus® :	lbs.
No.	IP5, IP6, IP7, IP8	
27894	IP9, IP10, IP15	.27

ESD Safe SYS 4 Drive-Loc Handle & Blades



26961 ESD Safe Dissipative Precision Drive-Loc Handle Surface resistant 10^6-10^9 Ohms. 4 mm hex retainer for all SYSTEM 4 interchangeable blades. Ball retainer hold. 105mm/4.13" OAL

Item	No.	mm	Inch	mm	Inch	lbs.
		4.0	.1574	23	.91	.08



269 SYSTEM 4 TORX® Drive-Loc Reversible Locking Blades On 4mm Hex

Item	No.	Size	Size	lbs.
		T1	+ T2	.02
		T3	+ T4	.02
		T5	+ T6	.02
		T6	+ T8	.02
		T7	+ T9	.02
		T10	+ T15	.02
		T15	+ T20	.02

ESD Safe Precision Handles & Blades



28000 ESD Safe Dissipative Precision Handle with rotating control cap. Surface resistant 10^6-10^9 Ohms. 4 mm hex retainer for all SYSTEM 4 interchangeable blades. Tapered handle, high quality plastic, impact resistant. Ball retainer hold. 110mm/4.3" OAL

Item	No.	mm	Inch	mm	Inch	lbs.
		4.0	.1574	14.0	.55	.04



28001 ESD Safe Dissipative Precision Adjustable Handle with rotating control cap.

- Use in ESD sensitive applications. Surface resistant 10^6-10^9 Ohms.
- Collet lock allows for quick & easy adjustment.
- Holds blade securely in place. Accepts all SYSTEM 4 blades. 110mm/4.3" OAL

Item	No.	mm	Inch	mm	Inch	lbs.
		4.0	.1574	14.0	.55	.04



269 SYS 4 TORX® Reversible Blade High alloy chrome-vanadium-molybdenum steel, hardened, vapor chrome protected, Wiha vapor Chrome-Top finish on tips. 120mm/4.7" OAL

Item	No.	Size	Size	lbs.
		T6	+ T8	.03
		T7	+ T9	.03
		T10	+ T15	.03
		T15	+ T20	.03



269 SYS 4 TORX® Interchangeable Blade 120mm/4.7" OAL

Item	No.	Size	lbs.
		T3	.03
		T4	.03
		T5	.03

SYSTEM 4 Handles & Micro Bits

Bits CVM steel, hardened

Tips
Exact fit, precision machined

Tapered Handle
allows rapid rotation, requires less clearance. Static Dissipative $10^6 - 10^9$ ohms

Rotating Cap
for precise turning & control

Use bits directly in handle or with 4" bit extension



75801 SYS 4 ESD Safe  Dissipative Precision Bit Handle 110mm/4.3" OAL

Advantages:

- For working in ESD sensitive applications Surface resistant 10^6 - 10^9 Ohms
- Ball retainer holds bits securely in place
- Accepts all SYSTEM 4 Series bits

Item					
No.	mm	Inch	mm	Inch	lbs.
75801	4.0	.1574	14.0	.55	.06

Notes:

High alloy CVM steel, hardened, on 4 mm stock



757	SYSTEM 4 TORX ® Micro Bits				
Item					
No.	Size	mm	Inch	lbs.	
75701	T1	28	1.1	.01	
75702	T2	28	1.1	.01	
75703	T3	28	1.1	.01	
75704	T4	28	1.1	.01	
75705	T5	28	1.1	.01	
75706	T6	28	1.1	.01	
75707	T7	28	1.1	.01	
75708	T8	28	1.1	.01	
75709	T9	28	1.1	.01	
75710	T10	28	1.1	.01	
75715	T15	28	1.1	.01	
75720	T20	28	1.1	.01	



757	SYS 4 Security TORX ® Micro Bits				
Item					
No.	Size	mm	Inch	lbs.	
75735	T10s	28	1.1	.01	
75742	T20s	28	1.1	.01	

10 Bit Pack



756	SYSTEM 4 TORX ® Micro Bits				
Item					
No.	Size	mm	Inch	lbs.	
75660	T1	28	1.1	.06	
75661	T2	28	1.1	.06	
75662	T3	28	1.1	.06	
75663	T4	28	1.1	.06	
75664	T5	28	1.1	.06	
75665	T6	28	1.1	.06	
75666	T7	28	1.1	.06	
75667	T8	28	1.1	.07	
75668	T9	28	1.1	.07	
75669	T10	28	1.1	.07	
75670	T15	28	1.1	.08	
75671	T20	28	1.1	.08	

10 Bit Pack



756	SYS 4 Security TORX ® Micro Bits				
Item					
No.	Size	mm	Inch	lbs.	
75681	T10s	28	1.1	.07	
75683	T20s	28	1.1	.08	



75988 SYSTEM 4 **TORX® Micro Bit Replacement Pack, 10 Pcs.**

CVM steel, hardened, on 4 mm hex stock.

Item No. SYSTEM 4 Micro Bit Set

75988  **TORX®: T1, T2, T3, T4, T5, T6, T7, T8, T9, T10**

 lbs. .06



75093 SYS 4 Slotted, Phillips, **TORX® Compact ESD Precision Interchangeable Bit Set, 16 Pcs.** Wiha precision handle, bit extension & 14 interchangeable bits.

Item No. Combination Bit Set

75093 Set with ESD Safe Precision Handle

 **Slotted:** 1.5, 2.0, 2.5, 3.0mm

 **Phillips:** 00, 0, 1

lbs.  **TORX®: T6, T7, T8, T9, T10, T15, T20**

.17  100mm Bit Extension



75985 Micro Bit Handle Storage **TORX® Bit Set, 7 Pcs.** Wiha precision storage handle & 6 interchangeable bits.

Item No. Set with Precision Storage Handle

75985  **TORX®: T3, T4, T5, T6, T7, T8**

 lbs. .12

CushionGrip Stubby Bit Holders



38045 TORX® SoftFinish® CushionGrip Stubby Bit Holder with Wiha cushion grip handle and CVM tool steel shaft.
Includes The Following 1/4" Bits:
 lbs. **TORX®**: T8, T10, T15, T20, T25, T30



38047 Security TORX® SoftFinish® CushionGrip Stubby Bit Holder with Wiha cushion grip handle and CVM tool steel shaft.
Includes The Following 1/4" Bits: lbs. **TORX®**: T8s, T10s, T15s, T20s, T25s, T30s

For working in confined spaces



28103 Magnetic 1/4" Bit Holder With Wiha SoftFinish® Stubby Handle Stainless steel with strong magnet. Wiha-SoftFinish® handle multi-component, cushion grips.

Item					
No.	Inch	mm	Inch	lbs.	pkg.
28103	1/4"	57	2.2	.11	1

Wiha Cushion Grip Pop-Up Bit Holder Set



38042 Security TORX® Pop-Up Bit Screwdriver Set Wiha Cushion Grip handle, multi-component. Compact storage for 6 bits in the handle.
Includes The Following 75mm 1/4" Bits: lbs. **TORX®**: T10s, T15s, T20s, T25s, T27s, T30s

Wiha Pop-Up Bit Screwdriver Sets



38044 TORX® Pop-Up Bit Screwdriver Set with Wiha Cushion Grip handle, multi-component. Compact storage holds 12 bits.
Set includes the following 1/4" bits: lbs. **TORX®**: T5, T6, T7, T8, T9, T10, T15, T20, T25, T27, T30, T40



38046 Security TORX® Pop-Up Bit Screwdriver Set Wiha Cushion Grip handle, multi-component. Compact storage for 12 bits in the handle.
Includes The Following 1/4" Bits: lbs. **TORX®**: T5, T6, T7s, T8s, T9s, T10s, T15s, T20s, T25s, T27s, T30s, T40s

Wiha Insert Bit & Socket Set



72590 11 Piece TORX® Insert Bit Pack & Socket Set CVM S2 modified tool steel.
 1/4" to 3/8" Drive Socket
 1/4" Bits: T10, T15, T20, T25, T27, T30
 5/16" to 3/8" Drive Socket
 5/16" Bits: T40, T45, T50

Wiha Insert Bit Blister Pack



72595 10 Pack TORX® Insert Bit Pack CVM S2 modified tool steel.
 lbs. **TORX®**: T7, T8, T9, T10, T15, T20, T25, T27, T30, T40 x 1"

Wiha Insert Bit Selectors



79242 Bit-Selector With **TORX** Bits
Includes Universal Magnetic 1/4" Bit Holder
& The Following 10 Insert Bits:

lbs. **TORX**: T5, T6, T7, T8, T9,
.32 T10, T15, T20, T25, T30



79245 Bit-Selector With **TORX** Bits
Includes Auto Lock Magnetic 1/4" Bit Holder
& The Following 10 Insert Bits:

lbs. **TORX**: T7, T8, T9, T10,
.34 T15, T20, T25, T27, T30, T40



79247 Bit-Selector With Security **TORX** Bits, Includes Magnetic 1/4" Bit Holder
& The Following 10 Bits: lbs. .32

Security TORX:
T7s, T8s, T9s, T10s, T15s,
T20s, T25s, T27s, T30s, T40s



70190 Bit-Selector With Security **TORX** Bits, Includes The Following 7 Insert Bits:

Security TORX: lbs.
T7s, T8s, T9s,
T10s, T15s, T20s, T25s .21



71690 Bit-Selector With **TORXPlus** Bits
Set Includes Magnetic 1/4" Bit Holder
& The Following 10 Bits:

lbs. **TORXPlus**: IP7, IP8, IP9,
IP10, IP15, IP20, IP25
.31 IP27, IP30, IP40



71692 Bit-Selector With **TORXPlus** Bits
Set Includes Magnetic 1/4" Bit Holder
& The Following 10 Bits:

lbs. **TORXPlus**: IP3, IP4,
IP5, IP6, IP7, IP8, IP9,
.31 IP10, IP15, IP20

Wiha Power Bit Belt Packs



74985 Power Bit Belt Pack W/**TORX** Bits
Includes the following 10 bits: lbs. .28

TORX: T6, T7, T8, T9,
T10, T15, T20, T25, T27, T30



74981 Power Bit Belt Pack With
TORX Align Bits

Set includes the following 10 bits:

TORX Align: T6, T7, T8, T9,
T10, T15, T20, T25, T27, T30
lbs. .28



74987 Power Bit Belt Pack With Security
TORX Bits, Includes the following 10 bits:

Security TORX:
T7s, T8s, T9s,
lbs. T10s, T15s, T20s,
.29 T25s, T27s, T30s, T40s



74982 Power Bit Belt Pack W/**TORXPlus** Bits
Includes The Following 10 Bits:

lbs. **TORXPlus**: IP6, IP7,
IP8, IP9, IP10, IP15,
.28 IP20, IP25, IP27, IP30

Wiha XSelector Bit Sets



Includes Clicfix quick release holder

79445 XSelector Bit Set With **TORX** Bits
Set Includes Quick Release Holder
& the following 10 bits:

lbs. **TORX**: T7, T8, T9, T10, T15,
.29 T20, T25, T27, T30, T40



79447 XSelector Bit Set With Security
TORX Bits, Includes Quick Release Holder
& The Following 10 Bits: lbs. .27

Security TORX: T7s, T8s,
T9s, T10s, T15s, T20s, T25s,
T27s, T30s, T40s

XSelector
Pocket Sized
3 1/8" x 2 1/8" x 1/2"

Wiha Insert PokitPaks



71195 PokitPak - **TORX** Insert Bits In
Molded Case - Includes 6 - 1/4" Insert Bits
& Magnetic Bit Holder lbs. .16

TORX:
T8, T10, T15, T20, T25, T30



79283 PokitPak - **TORX** Align Insert
Bits In Molded Case -

Set Includes 6 - 1/4" Insert Bits

lbs. **TORX** Align: T10, T15,
.12 T20, T25, T30, T40

Magnetic




 Retainer out of stainless steel

384 1/4" Magnetic Bit Holding Drivers,

With Wiha SoftFinish® Handle Ergonomic cushion grip, magnetic, holds bit and screw. Shaft CVM steel, nickel-plated.

Item						
No.	Size	mm	Inch	mm	Inch	lbs.
38450	1/4"	125	5.0	240	9.46	.23
38460	1/4"	300	11.8	400	15.69	.37

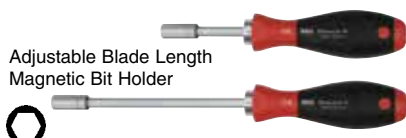

28489 Drive-Loc VI Bit Holder

High alloy CVM steel, through hardened, hard chrome finish. Wiha-SoftFinish® handle multi-component, cushion grips.

Item				
No.	Inch	Extends	lbs.	pkg.
28489	1/4"	1-3/4" to 4-7/8"	.36	1



48401	1/4" Bit holding Screwdriver,
-------	-------------------------------

With Wiha-Ergo 3K Handle Magnetic, holds bit & screw. Retainer out of stainless steel.


Item							
No.	Size	mm	Inch	mm	Inch	lbs.	pkg.
48401	1/4"	125	5.0	211	8.3	.24	1



48400 1/4" Bit holding Screwdriver.

With Wiha-Proturn Handle Magnetic, holds bit & screw. Retainer out of stainless steel.

Item							
No.	Size	mm	Inch	mm	Inch	lbs.	pkg.
48400	1/4"	125	5.0	243	9.6	.24	10

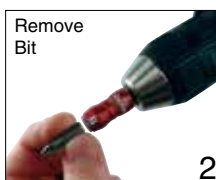

- Narrow Profile
- One handed bit changes
- Internal bit lock mechanism



71491 **ClicFix Bit Holder.**

Magnetic For Insert Bits Quick release

Item						
No.	Size	Size	mm	Inch	lbs.	pkg.
71491	1/4"	1/4"	75	2.9	.07	1

High Precision Tool Holder



Quick release tool holder for Drills, Countersinks & Power bits

71480 CentroFix Bit Holder

Item						
No.	Size	Size	mm	Inch	lbs.	pkg.
71480	1/4"	1/4"	60	2.4	.09	1




71494 **Stainless Steel Bit Holder,
1/4" For Insert Bits**

Internal C-ring for bit holding & magnet.

Item					
No.	Size	Size	mm	Inch	lbs.
71494	1/4"	1/4"	54	2.1"	.05

Wiha Terminator **TORX**® Impact Bits - Insert & Power

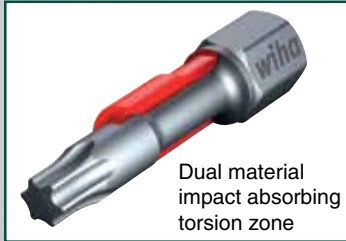Up To 30X Performance Over Standard Screwdriver Bits



Dual material
impact absorbing
torsion zone

Impact rated bits for long life in impact applications

Provide up to 30 times impact performance over standard bits

Standard 1/4" drive - No special adaptor required

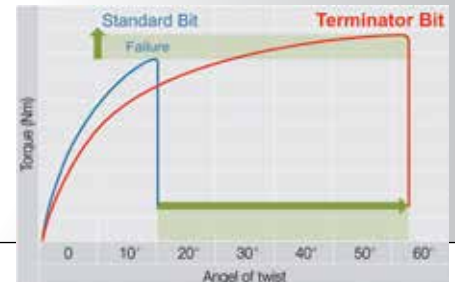
Wiha enhanced bi-material torsion zone

Precision machined exact fit tips

Wiha exclusive CVM tool steel

Guaranteed to out perform impact imposters

1/4" Drive Insert & Power Bits



10 pc.
bit pack!

765 **TORX**® Terminator Impact Bits,

1/4" Insert - 10 Bit Pack

Item No.	Size	mm	pkg.
76510	T10	29	10
76511	T15	29	10
76512	T20	29	10
76513	T25	29	10
76514	T27	29	10
76516	T30	29	10
76517	T40	29	10



76877 10 Pc. Bit Buddy Set With

Terminator Impact Insert Bits - 29mm

76877 Set includes the following bits:
 **Torx**®: T10, T15, T20 (2), T25 (2), T27, T30 (2), T40



10 pc.
bit pack!

765 **TORX**® Terminator Impact Bits,

1/4" Power - 10 Bit Pack

Item No.	Size	mm	pkg.
76553	T10	49	10
76554	T15	49	10
76555	T20	49	10
76556	T25	49	10
76557	T27	49	10
76558	T30	49	10
76559	T40	49	10



2 pack!

768 **TORX**® Terminator Impact Bits,

1/4" Insert - 2 Bit Pack

Item No.	Size	mm	pkg.
76810	T10	29	2
76811	T15	29	2
76812	T20	29	2
76813	T25	29	2
76814	T27	29	2
76816	T30	29	2
76817	T40	29	2



76895 8 Pc. Bit Buddy Set With

Terminator Impact Insert Bits - 29mm

76895 Set includes the following bits:
 **Torx**®: T10, T15, T20, T25, T27, T30, T40
 Includes magnetic bit holder



768 **TORX**® Terminator Impact Bits,

1/4" Power - 2 Bit Pack

Item No.	Size	mm	pkg.
76853	T10	49	2
76854	T15	49	2
76855	T20	49	2
76856	T25	49	2
76857	T27	49	2
76858	T30	49	2
76859	T40	49	2



Identification on bits allows
quick bit selection



76896 7 Pc. Bit Buddy Set With

Terminator Impact Power Bits - 49mm

76896 Set includes the following bits:
 **Torx**®: T10, T15, T20, T25, T27, T30, T40

TORX® 1/4" Insert Bits

TORX® Bits

The ideal multi-purpose bits for all around quality & performance
Made in Germany - Production Quality

Highly resistant to wear & tear for a long tool life

Impact resistant modified CVM, tool steel, hardened



Suitable for all applications for both manual & machine Hardness HRC 59-61



2 bit pack

715 TORX® Insert Bit Packs, 1"

CVM S2 modified tool steel.

Item No.	Size	mm	lbs.	pkg.
71548	T3	25	.03	2
71549	T4	25	.03	2
71550	T5	25	.03	2
71551	T6	25	.03	2
71552	T7	25	.03	2
71553	T8	25	.03	2
71554	T9	25	.03	2
71555	T10	25	.03	2
71556	T15	25	.03	2
71557	T20	25	.03	2
71558	T25	25	.03	2
71559	T27	25	.04	2
71560	T30	25	.04	2
71561	T40	25	.04	2



2 bit pack

777 TORX® Double End 1/4" Insert Bit Packs CVM S2 modified tool steel. 2 bit pack

Item No.	Size	mm	pkg.
77701	T6+T7	30	2
77702	T8+T9	30	2
77703	T10+T15	30	2
77704	T20+T25	30	2
77705	T27+T30	30	2

Torx® Profiles



10 Piece Contractor Grade Bits



Item No.	Size	mm	pkg.	lbs.
71523	T3	25	10	.12
71524	T4	25	10	.12
71505	T5	25	10	.12
71506	T6	25	10	.12
71507	T7	25	10	.12
71508	T8	25	10	.12
71509	T9	25	10	.12
71510	T10	25	10	.12
71515	T15	25	10	.12
71520	T20	25	10	.12
71525	T25	25	10	.12
71527	T27	25	10	.13
71530	T30	25	10	.14
71540	T40	25	10	.15

100 Piece Contractor Grade Bits



Item No.	Size	mm	pkg.	lbs.
72238	T15	25	100	1.5
72239	T20	25	100	1.5
72240	T25	25	100	1.5
72241	T27	25	100	1.5
72142	T30	25	100	1.5

250 Piece Contractor Grade Bits



Item No.	Size	mm	pkg.	lbs.
72338	T15	25	250	7.5
72339	T20	25	250	7.5
72340	T25	25	250	7.5
72341	T27	25	250	7.5
72342	T30	25	250	7.5

30 Piece Contractor Grade Bit Boxes



With a purchase of 10 bit boxes

Item No.	Size	mm	pkg.	lbs.
72572	T7	25	30	.36
72573	T8	25	30	.36
72574	T9	25	30	.36
72575	T10	25	30	.36
72576	T15	25	30	.36
72577	T20	25	30	.36
72578	T25	25	30	.36
72579	T27	25	30	.36
72580	T30	25	30	.36
72581	T40	25	30	.36

Wiha TORX® Bit Packs



71571 TORX® Insert Bit Packs, 1" CVM

S2 modified tool steel. Extra hard with natural finish. Exact fit machined tips. 6 pc. bit pack.

71571 Set includes the following bits:

TORX® Sizes:

T15, T20, T25, T27, wt. .08 T30, T40 x 1" (25mm)

71570 TORX® Insert Bit Packs, 1" CVM

S2 modified tool steel. Extra hard with natural finish. Exact fit machined tips. 6 pc bit pack.

71570 Set includes the following bits:

TORX® Sizes:

T5, T6, T7, T8, T9, wt. .07 T10 x 1" (25mm)

TORX® 1/4" Power Bits



745 TORX® Power Bit Packs, 2"				
Item No.	Size	mm	lbs.	
74525	T1	50	.05	
74527	T2	50	.05	
74530	T3	50	.05	
74540	T4	50	.05	
74559	T5	50	.05	
74501	T6	50	.05	
74502	T7	50	.05	
74503	T8	50	.05	
74504	T9	50	.05	
74506	T10	50	.05	
74508	T15	50	.05	
74510	T20	50	.05	
74514	T25	50	.06	
74515	T27	50	.06	
74516	T30	50	.06	
74518	T40	50	.06	

10 Piece Contractor Grade Bits



745 TORX® Power Bits				
1/4" Hex Drive, Length 2.0"/50mm. In clamshell				
Item No.	Size	mm	pkg.	lbs.
74511	T6	50	10	.18
74512	T7	50	10	.18
74513	T8	50	10	.18
74517	T9	50	10	.18
74519	T10	50	10	.18
74521	T15	50	10	.18
74523	T20	50	10	.18
74529	T25	50	10	.18
74531	T27	50	10	.18
74533	T30	50	10	.18
74535	T40	50	10	.18

15 Piece Contractor Grade Bit Boxes



With a purchase of 10 Bit boxes



745 TORX® Bits, 1/4" Bit Box Packs				
Item No.	Size	mm	pkg.	lbs.
74592	T15	50	15	.36
74593	T20	50	15	.36
74594	T25	50	15	.36
74596	T27	50	15	.36
74597	T30	50	15	.36

100 Piece Contractor Grade Bits



722 TORX® Bits, 1/4" Power Bits				
Item No.	Size	mm	pkg.	lbs.
72279	T15	50	100	1.5
72280	T20	50	100	1.5
72281	T25	50	100	1.5
72282	T27	50	100	1.5
72283	T30	50	100	1.5

250 Piece Contractor Grade Bits



723 TORX® Bits, 1/4" Power Bits				
Item No.	Size	mm	pkg.	lbs.
72379	T15	50	250	7.5
72381	T20	50	250	7.5
72382	T25	50	250	7.5
72383	T27	50	250	7.5
72384	T30	50	250	7.5



745 TORX® Power Bits				
1/4" Hex Drive, Length 2.75"/70mm				
Item No.	Size	mm	pkg.	lbs.
74536	T6	70	1	.02
74538	T7	70	1	.02
74542	T8	70	1	.02
74544	T9	70	1	.02
74546	T10	70	1	.02
74548	T15	70	1	.02
74551	T20	70	1	.03
74553	T25	70	1	.03
74556	T27	70	1	.04
74558	T30	70	1	.04
74561	T40	70	1	.04



745 TORX® Power Bits				
1/4" Hex Drive, Length 3.5"/90mm				
Item No.	Size	mm	pkg.	lbs.
74563	T6	90	1	.03
74565	T7	90	1	.03
74567	T8	90	1	.03
74569	T9	90	1	.03
74571	T10	90	1	.03
74573	T15	90	1	.03
74575	T20	90	1	.04
74577	T25	90	1	.04
74579	T27	90	1	.04
74581	T30	90	1	.04
74583	T40	90	1	.04



745 TORX® Power Bits				
1/4" Hex Drive, Length 6.0"/150mm				
Item No.	Size	mm	pkg.	lbs.
74580	T6	150	10	.04
74582	T7	150	10	.04
74584	T8	150	10	.04
74585	T9	150	10	.04
74586	T10	150	10	.04
74587	T15	150	10	.04
74588	T20	150	10	.04
74589	T25	150	10	.04
74590	T27	150	10	.04
74591	T30	150	10	.04

Wiha Double End TORX® Bits



744 TORX® Double End Bits				
1/4" Hex Drive, Length 2.56"/65mm				
Item No.	Size	Size	mm	pkg.
74413	T7	T7	65	10
74415	T8	T8	65	10
74417	T9	T9	65	10
74419	T10	T10	65	10
74431	T27	T27	65	10
74433	T30	T30	65	10
74435	T40	T40	65	10



744 TORX® Double End Bits				
1/4" Hex Drive, Length 2.56"/65mm				
Item No.	Size	Size	mm	lbs.
74461	T7	T7	65	.05
74462	T8	T8	65	.05
74463	T9	T9	65	.05
74464	T10	T10	65	.05
74465	T15	T15	65	.05
74468	T27	T27	65	.05
74469	T30	T30	65	.05
74470	T40	T40	65	.05

Wiha TORX® 5/16" Insert Bits

10 bit pack



725 TORX® Bits, 5/16"				
Item No.	Size	mm	pkg.	lbs.
72525	T25	35	10	.27
72527	T27	35	10	.27
72530	T30	35	10	.27
72540	T40	35	10	.28
72545	T45	35	10	.31
72550	T50	35	10	.32
72555	T55	35	10	.52
72570	T60	35	10	.52



725 TORX® Insert Bit Packs, 5/16"				
Item No.	Size	mm	lbs.	
72528	T25	35	.28	
72529	T27	35	.28	
72531	T30	35	.28	
72541	T40	35	.28	
72546	T45	35	.31	
72551	T50	35	.32	
72556	T55	35	.52	
72569	T60	35	.52	

Stainless Steel TORX® Bits

Stainless Steel

High-quality, non-rusting stainless steel, completely vacuum-hardened.



715 Stainless Steel TORX® Bits, 1/4"				
Item No.	Size	mm	pkg.	
71500	T8	25	10	
71502	T10	25	10	
71513	T40	25	10	



704 Stainless Steel TORX® Power Bits 1/4" Hex Drive, Length 2.0"/50mm				
Item No.	Size	mm	pkg.	
70411	T15	50	10	
70414	T25	50	10	
70416	T30	50	10	
70417	T40	50	10	

Wiha TORX® Align Insert Bits and Power Bits

Torx® Align Tapered For Snug Fit In Screw

Highly resistant to wear and tear for a long tool life



Impact resistant modified chrome-vanadium-molybdenum, tool steel, hardened

Made in Germany - Production Quality

Suitable for all applications for both manual and machine Hardness HRC 59-61



715 TORX® Align Bits, 1/4"				
Item No.	Size	mm	pkg.	lbs.
71536	T6	25	10	.12
71537	T7	25	10	.12
71538	T8	25	10	.12
71541	T10	25	10	.12
71542	T15	25	10	.12
71543	T20	25	10	.12
71544	T25	25	10	.13
71545	T27	25	10	.13
71546	T30	25	10	.14
71547	T40	25	10	.15

*Also Known As Torx Wedge Fit



733 TORX® Align Insert Bit Packs, 1"				
CVM S2 modified tool steel				
Item No.	Size	mm	lbs.	
73310	T6	25	.03	
73311	T7	25	.03	
73312	T8	25	.03	
73313	T9	25	.03	
73314	T10	25	.03	
73315	T15	25	.03	
73316	T20	25	.03	
73317	T25	25	.03	
73318	T27	25	.03	
73319	T30	25	.03	
73320	T40	25	.04	



747 TORX® Align Bits, 1/4" Hex Drive, Length 2.0"/50mm				
Item No.	Size	mm	pkg.	lbs.
74711	T6	50	10	.18
74714	T7	50	10	.18
74717	T8	50	10	.18
74721	T9	50	10	.18
74724	T10	50	10	.18
74728	T15	50	10	.20
74732	T20	50	10	.22
74736	T25	50	10	.22
74739	T27	50	10	.22
74742	T30	50	10	.22

*Also Known As Torx Wedge Fit



747 TORX® Align Power Bit Packs, 2"				
Item No.	Size	mm	lbs.	
74760	T6	50	.05	
74761	T7	50	.05	
74762	T8	50	.05	
74763	T9	50	.05	
74764	T10	50	.05	
74765	T15	50	.05	
74766	T20	50	.06	
74767	T25	50	.06	
74768	T27	50	.06	
74769	T30	50	.06	

Wiha Security TORX® Insert Bits and Power Bits

Security Torx®

Made in Germany - Production Quality

Impact resistant modified CVM tool steel, hardened

Highly resistant to wear and tear for a long tool life

Suitable for all applications for both manual & machine Hardness HRC 59-61



705 Security TORX® Power Bits, 1/4" Hex Drive, Length 2.0"/50mm

Item No.	Size	mm	pkg.	lbs.
70507	T7s	50	10	.18
70508	T8s	50	10	.18
70509	T9s	50	10	.18
70510	T10s	50	10	.19
70515	T15s	50	10	.19
70520	T20s	50	10	.21
70525	T25s	50	10	.23
70527	T27s	50	10	.23
70530	T30s	50	10	.23
70540	T40s	50	10	.23
70545	T45s	50	10	.33
70550	T50s	50	10	.37



2 bit pack

705 Security TORX® Power Bit Packs, 2"

Item No.	Size	mm	lbs.
70556	T7s	50	.07
70557	T8s	50	.07
70558	T9s	50	.07
70559	T10s	50	.07
70560	T15s	50	.07
70561	T20s	50	.07
70562	T25s	50	.07
70563	T27s	50	.07
70564	T30s	50	.07
70565	T40s	50	.07
70566	T45s	50	.07
70567	T50s	50	.07
70568	T55s	50	.07



701 Security TORX® Bits, 1/4"

Item No.	Size	mm	pkg.	lbs.
70127	T7s	25	10	.12
70128	T8s	25	10	.12
70129	T9s	25	10	.12
70135	T10s	25	10	.12
70139	T15s	25	10	.12
70142	T20s	25	10	.12
70148	T25s	25	10	.12
70160	T27s	25	10	.13
70163	T30s	25	10	.13
70168	T40s	25	10	.14



Made in Taiwan

745 Protturn Security TORX® Power Bits 1/4" Hex Drive, Length 3.0"/75mm

Item No.	Size	mm	pkg.	lbs.
74566	T10s	75	5	.01
74568	T15s	75	5	.01
74570	T20s	75	5	.01
74572	T25s	75	5	.02
74574	T27s	75	5	.02
74576	T30s	75	5	.03



5/16"

725 Security TORX® Bits, 5/16"

Item No.	Size	mm	pkg.	lbs.
72514	T25s	35	10	.26
72515	T27s	35	10	.27
72516	T30s	35	10	.28
72542	T40s	35	10	.28
72547	T45s	35	10	.32
72552	T50s	35	10	.34
72557	T55s	35	10	.52
72558	T60s	35	10	.65



2 bit pack

701 Security TORX® Insert Bit Packs, 1" CVM S2 modified tool steel.

Item No.	Size	mm	lbs.
70150	T7s	25	.03
70151	T8s	25	.03
70152	T9s	25	.03
70153	T10s	25	.03
70154	T15s	25	.03
70155	T20s	25	.03
70156	T25s	25	.03
70157	T27s	25	.03
70158	T30s	25	.03
70159	T40s	25	.03



705 Security TORX® Power Bits, 1/4" Hex Drive, Length 3.5"/90mm

Item No.	Size	mm	pkg.	lbs.
70533	T10s	90	5	.20
70534	T15s	90	5	.20
70535	T20s	90	5	.20
70536	T25s	90	5	.21
70537	T27s	90	5	.21
70538	T30s	90	5	.23
70539	T40s	90	5	.25



2 bit pack

725 Security TORX® Bits, 5/16" 2 Bit Pack

Item No.	Size	mm	lbs.
72559	T25s	35	.26
72560	T27s	35	.27
72561	T30s	35	.28
72562	T40s	35	.28
72563	T45s	35	.29
72564	T50s	35	.30
72567	T55s	35	.32
72568	T60s	35	.35

Wiha TORXPlus® Insert Bits and Power Bits

TORXPlus®

Made in Germany -
Production Quality

Highly resistant
to wear and
tear for a
long tool
life

Impact resistant modified
CVM, tool steel, hardened

Suitable for all applications for both
manual & machine Hardness HRC 59-61



716 TORXPlus® Insert Bit Packs, 1"

CVM S2 modified tool steel

Item No.	Size	mm	lbs.
71631	IP3	25	.03
71632	IP4	25	.03
71633	IP5	25	.03
71634	IP6	25	.03
71635	IP7	25	.03
71636	IP8	25	.03
71637	IP9	25	.03
71638	IP10	25	.03
71639	IP15	25	.03
71641	IP20	25	.03
71642	IP25	25	.03
71643	IP27	25	.03
71644	IP30	25	.03
71645	IP40	25	.04



716 TORXPlus® Insert Bits, 1/4" Hex, 1"

Item No.	Size	mm	pkg.	lbs.
71603	IP3	25	10	.12
71604	IP4	25	10	.12
71605	IP5	25	10	.12
71606	IP6	25	10	.12
71607	IP7	25	10	.12
71608	IP8	25	10	.12
71609	IP9	25	10	.12
71610	IP10	25	10	.12
71615	IP15	25	10	.12
71620	IP20	25	10	.12
71625	IP25	25	10	.12
71627	IP27	25	10	.13
71630	IP30	25	10	.13
71640	IP40	25	10	.15



746 TORXPlus® Power Bits, 1/4" Hex, 2"

Item No.	Size	mm	pkg.	lbs.
74601	IP5	50	10	.18
74602	IP6	50	10	.18
74603	IP7	50	10	.18
74604	IP8	50	10	.18
74608	IP9	50	10	.18
74612	IP10	50	10	.20
74616	IP15	50	10	.20
74620	IP20	50	10	.20
74624	IP25	50	10	.20
74628	IP27	50	10	.25
74632	IP30	50	10	.25
74636	IP40	50	10	.25

Wiha Ball End TORX® Bits



See additional Ball End TORX
Tools on Page 15



Wiha Security Pentalobe 5 Point Insert Bit



716 Security Pentalobe 5 Point Insert Bits, 1/4" Hex, 1" OAL

Item No.	Size	mm	pkg.	lbs.
71648	PLS8	25	1	.11
71650	PLS10	25	1	.11
71652	PLS15	25	1	.11
71654	PLS20	25	1	.12
71656	PLS25	25	1	.13
71657	PLS27	25	1	.13
71658	PLS30	25	1	.14
71660	PLS40	35	1	.14



XSelector
Pocket Sized
3 1/8" x 2 1/8" x 1/2"

79450 XSelector Bit Set With Security Pentalobe 5 Point Bits

Set Includes Quick Release Holder
lbs. and the following 7 bits:
.18 Security Pentalobe 5 Point Sizes:
PLS8, PLS10, PLS15, PLS20,
PLS25, PLS27, PLS30

Wiha TORX® MagicSpring Screw Holding Power Bits

Screw Holding TORX Bits



Stainless
rotary spring

745 TORX® MagicSpring Screw Holding Power Bits, 1/4" Hex Drive, 2.0"/50mm OAL

Item No.	Size	mm	pkg.	lbs.
74552	T10	50	2	.05
74554	T15	50	2	.05
74555	T20	50	2	.05
74557	T25	50	2	.05
74562	T30	50	2	.05
74564	T40	50	2	.05

Wiha Sockets



Set Screw
Replaceable
Bit

761 TORX® Sockets 1/4" Square Drive				
Item				
No.	Size	mm	lbs.	
76106	T6	38	.04	
76107	T7	38	.04	
76109	T8	38	.04	
76111	T9	38	.04	
76113	T10	38	.04	
76117	T15	38	.04	
76119	T20	38	.04	
76121	T25	38	.04	
76123	T27	38	.04	
76129	T30	38	.05	
76131	T40	38	.05	



763 TORX® Sockets 3/8" Square Drive, Set Screw Replaceable Bit. 1/4" bits				
Item				
No.	Size	mm	lbs.	
76312	T9	42	.09	
76314	T10	42	.09	
76316	T15	42	.09	
76318	T20	42	.09	
76322	T25	42	.09	
76324	T27	42	.09	
76326	T30	42	.09	
76328	T40	42	.09	



763 TORX® Sockets 3/8" Square Drive, Set Screw Replaceable Bit. 5/16" Bit. 2" OAL				
Item				
No.	Size	mm	lbs.	
76346	T40	51	.11	
76348	T45	51	.11	
76352	T50	51	.11	
76354	T55	51	.13	



716 TORXPlus® Sockets 1/4" Square Drive, Set Screw Replaceable Bit. 1/4" bits				
Item				
No.	Size	mm	lbs.	
71661	IP6	38	.04	
71662	IP7	38	.04	
71663	IP8	38	.04	
71664	IP9	38	.04	
71665	IP10	38	.04	
71666	IP15	38	.04	
71667	IP20	38	.04	
71668	IP25	38	.04	
71669	IP27	38	.04	
71670	IP30	38	.04	
71671	IP40	38	.04	



716 TORXPlus® Sockets 3/8" Square Drive, Set Screw Replaceable Bit. 1/4" bits				
Item				
No.	Size	mm	lbs.	
71673	IP9	42	.09	
71674	IP10	42	.09	
71675	IP15	42	.09	
71676	IP20	42	.09	
71677	IP25	42	.09	
71678	IP27	42	.09	
71680	IP30	42	.09	
71681	IP40	42	.09	



Set Screw
Replaceable
Bit

763 Security TORX® Sockets 1/4" Square drive, 1/4" bits				
Item				
No.	Size	mm		
76329	T7s	38		
76330	T8s	38		
76331	T9s	38		
76332	T10s	38		
76333	T15s	38		
76334	T20s	38		
76335	T25s	38		
76335	T27s	38		
76337	T30s	38		
76338	T40s	38		



Set Screw
Replaceable
Bit

701 Security TORX® Sockets 3/8" Square drive, 1/4" bits. 2" OAL				
Item				
No.	Size	mm	lbs.	
70107	T7s	42	.09	
70108	T8s	42	.09	
70109	T9s	42	.09	
70110	T10s	42	.09	
70113	T15s	42	.09	
70115	T20s	42	.09	
70117	T25s	42	.09	
70119	T27s	42	.09	
70121	T30s	42	.09	
70123	T40s	42	.09	



Set Screw
Replaceable
Bit

763 Security TORX® Sockets 3/8" Square drive, 5/16" bits				
Item				
No.	Size	mm		
76339	T40s	51		
76340	T45s	51		
76341	T50s	51		
76342	T55s	51		

1/2" Square Drive Sockets



Set Screw
Replaceable
Bit

764 TORX® Sockets 1/2" Square Drive					
Item					
No.	Size	mm	lbs.	pkg.	
76403	T30	59	.10	1	
76404	T40	59	.10	1	
76405	T45	59	.10	1	
76406	T50	59	.10	1	
76407	T55	59	.11	1	
76408	T60	59	.18	1	



Set Screw
Replaceable
Bit

764 Security TORX® Sockets 1/2" Square Drive					
Item					
No.	Size	mm	lbs.	pkg.	
76411	T40s	59	.11	1	
76412	T45s	59	.11	1	
76413	T50s	59	.11	1	
76414	T55s	59	.12	1	

Wiha Long Blade Sockets



771 TORX® Sockets				
1/4" Drive 6" Long Bit Socket				
Item No.	Size	Inch	lbs.	
77151	T8	6	.12	
77153	T9	6	.12	
77152	T10	6	.12	
77154	T15	6	.12	
77156	T20	6	.12	
77158	T25	6	.12	
77160	T27	6	.12	
77162	T30	6	.12	
77164	T40	6	.12	
77193 7 Pc. TORX® Socket Blade Set				
TORX®: T10, T15, T20, T25, T27, T30, T40				
wt. .69				



771 TORX® Sockets				
3/8" Drive 6" Long Bit Socket				
Item No.	Size	Inch	lbs.	
77101	T8	6	.12	
77103	T9	6	.12	
77105	T10	6	.12	
77107	T15	6	.12	
77109	T20	6	.12	
77111	T25	6	.12	
77113	T27	6	.12	
77115	T30	6	.12	
77117	T40	6	.12	
77195 9 Pc. TORX® Socket Blade Set				
TORX®: T8, T9, T10, T15, T20, T25, T27, T30, T40				
wt. 1.08				

Wiha External Sockets



773 TORX® External Sockets				
1/4" Square drive socket.				
Item No.	Size	mm	lbs.	
77304	E4	25	.03	
77305	E5	25	.03	
77306	E6	25	.03	
77308	E8	25	.04	

773 TORX® External Sockets				
3/8" Square drive socket.				
Item No.	Size	mm	lbs.	
77331	E8	28	.07	
77333	E10	28	.07	
77335	E12	28	.07	
77337	E14	28	.08	



773 TORX® External Sockets				
1/2" Square drive socket.				
Item No.	Size	mm	lbs.	
77341	E12	37	.12	
77343	E14	37	.12	
77345	E16	37	.14	
77347	E18	37	.14	
77349	E20	37	.15	
77353	E24	40	.24	



77390 22 pc. TORX® Set 1/4" Drive Socket				
Ratchet 5.5", extension 2" & 4", swivel & hand driver in steel box. Hard chromed and polished.				
Item No.	lbs.	Set includes the following:		
77390	2.14	E4, E5, E6, E7, E8, E10, T6, T7, T8, T9, T10, T15, T20, T25, T27, T30, T40		

Wiha Socket Sets On Molded Rails



76191 10 pc. TORX® Socket Set				
1/4" Square Drive Replaceable Bit Sockets. Bits CVM tool steel. OAL 1.5"				
Item No.	lbs.	Set Includes:		
76191	.49	T7, T8, T9, T10, T15, T20, T25, T27, T30, T40		



76194 6 pc. TORX® Socket Set				
1/4" Square Drive Replaceable Bit Sockets. Bits CVM tool steel.				
Item No.	lbs.	Set Includes:		
76194	.20	T10, T15, T20, T25, T27, T30		



76395 8 pc. TORX® Socket Set				
3/8" Square Drive Replaceable Bit Sockets. Bits CVM tool steel. OAL 1.5"				
Item No.	lbs.	Set Includes:		
76395	.75	T9, T10, T15, T20, T25, T27, T30, T40		



76396 8 pc. TORX® Socket Set				
3/8" Square Drive Replaceable Bit Sockets. 1/4" & 5/16" Bits CVM tool steel. OAL 1.65"				
Item No.	lbs.	Set Includes:		
76396	.87	1/4": T20, T25, T27, T30, T40 5/16": T45, T50, T55		



76490 6 pc. TORX® Socket Set				
1/2" Square Drive Replaceable Bit Sockets. Bits CVM tool steel.				
Item No.	lbs.	Set Includes:		
76490	1.06	T30, T40, T45, T50, T55, T60		

Wiha Socket Sets On Molded Rails

Security Torx®



70195 10 pc. Security TORX® Socket Set

1/4" Square drive replaceable bit sockets.

1/4" Bits CVM tool steel.

Item No.	Set Includes:
70195	lbs. T7s, T8s, T9s, .48 T10s, T15s, T20s, T25s, T27s, T30s, T40s



76397 9 pc. Security TORX® Socket Set

1/4" & 3/8" Square Drive Replaceable Bit

Sockets. 1/4" & 5/16" Bits CVM tool steel.

Item No.	Set Includes:
76397	lbs. 1/4": T10s, T15s, T20s, .85 T25s, T27s, T30s 3/8": T40s (1/4" bit) 3/8": T45s, T50s (5/16" bit)



76399 12 pc. Security TORX® Socket Set

Set 1/4" & 3/8" Square Drive Replaceable Bit

Sockets. 1/4" & 5/16" Bits CVM tool steel.

Item No.	Set Includes:
76399	lbs. 1/4": T7s, T8s, T10s, T15s, .80 T20s, T25s, T27s, T30s, T40s 5/16": T45s, T50s, T55s



71698 8 pc. TORXPlus® Socket Set On Rail, In Vinyl Pouch

1/4" & 3/8" Square Drive

Replaceable Bit Sockets. Bits CVM tool steel.

Item No.	Set Includes:
71698	lbs. 1/4": IP9, IP10, IP15, IP20 .60 3/8": IP25, IP27, IP30, IP40

Item No. Page

10810	10
10893	6
20756	11
20757	11
20758	11
20759	11
20760	11
20799	11
26701	23
26702	23
26703	23
26704	23
26705	23
26706	23
26707	23
26708	23
26709	23
26710	23
26715	23
26720	23
26721	19
26723	19
26725	19
26727	19
26729	19
26731	19
26732	23
26733	23
26735	23
26736	23
26737	23
26739	23
26741	23
26743	23
26745	23
26747	23
26749	23
26751	23
26790	23
26791	23
26792	23
26793	23
26796	23
26798	19
26799	23
26951	24
26952	24
26953	24
26954	24
26955	24
26956	24
26957	24
26961	24
26977	24
26978	24
26979	24
26980	24
26981	24
26982	24
26983	24
27801	24
27802	24
27803	24
27804	24
27805	24
27811	24
27817	24
27823	24
27829	24
27835	24
27841	24
27847	24
27850	24
27851	24
27852	24
27853	24
27854	24
27855	24

Item No. Page

27856	24
27857	24
27890	24
27894	24
27899	24
28000	24
28001	24
28103	26
28126	10
28127	10
28128	10
28129	10
28130	10
28132	10
28133	10
28134	10
28135	10
28136	10
28189	10
28197	10
28301	11
28339	11,21
28340	11,21
28341	11,21
28342	11,21
28343	11,21
28344	11,21
28349	21
28351	21
28352	21
28353	21
28354	21
28355	21
28356	21
28357	21
28358	21
28359	21
28360	21
28374	21
28375	21
28376	21
28377	21
28378	21
28379	21
28380	21
28381	21
28382	21
28383	21
28384	21
28385	21
28386	21
28387	21
28388	21
28389	21
28404	20
28408	20
28477	10
28485	10
28486	10
28487	10
28488	10
28489	28
28500	22
28501	20
28502	20
28506	20
28512	20
28522	22
28524	22
28526	22
28527	20
28528	20
28529	20
28530	20
28531	20
28532	20
28533	20
28550	20

Item No. Page

28551	20
28552	20
28553	20
28554	20
28561	20
28562	20
28563	20
28564	20
28565	20
28566	20
28567	20
28568	20
28569	20
28571	20
28572	20
28573	20
28574	20
28575	20
28576	20
28577	20
28578	20
28579	20
28597	22
28598	22
28599	22
28611	20
28612	20
28613	20
28614	20
28616	20
28617	20
28618	20
28619	20
28740	21
28741	21
28742	21
28750	21
28751	21
28752	21
28818	22
28825	22
28827	22
28829	22
28903	22
28904	22
28905	22
28906	22
28907	22
28908	22
28910	22
28911	22
28912	22
28913	22
28914	22
28915	22
28931	22
28933	22
28935	22
28937	22
28938	22
28939	22
28940	22
29232	21
29233	21
29234	21
29236	21
29237	21
29239	21
29242	21
29243	21
29244	21
29246	21
29247	21
29248	21
29249	21
29252	21
29253	21
29254	21

Item No. Page

29255	21
29256	21
32505	7
32511	7
32512	11
32513	11
32514	11
32515	11
32516	7
32517	11
32518	11
32519	11
32521	7
32526	7
32531	7
32536	7
32541	7
32546	7
32551	7
32556	7
32561	7
32566	7
32590	7
32592	7
32596	11
36106	18
36107	18
36108	18
36109	18
36110	18
36115	18
36120	18
36125	18
36127	18
36130	18
36140	18
36197	18
36199	18
36200	6
36201	5
36202	19
36203	19
36204	6
36205	8
36206	6
36207	19
36208	6
36209	6
36210	8
36211	17
36212	8
36214	17
36215	8
36216	15
36217	15
36218	6
36219	6
36220	8
36221	15
36222	15
36223	17
36224	6
36225	8
36226	15
36227	15
36228	17
36229	17
36230	8
36231	17
36232	17
36233	17
36234	19
36235	8
36236	15
36237	15
36238	17
36239	17
36240	8

38 Tools that work for you

Item No. Page	Item No. Page	Item No. Page	Item No. Page	Item No. Page	Item No. Page
36241 17	36346 12	36545 16	37026 14	52732 7	71506 30
36242 17	36350 12	36547 16	37027 16	52790 7	71507 30
36243 17	36352 12	36549 16	37029 14	52791 7	71508 30
36244 19	36355 12	36551 16	37032 14	70107 35	71509 30
36245 8	36357 12	36553 16	37036 14	70108 35	71510 30
36246 17	36360 12	36556 19	37055 14	70109 35	71512 32
36247 17	36390 12	36557 19	37056 14	70110 35	71513 32
36248 17	36391 12	36558 19	37057 14	70113 35	71515 30
36249 19	36392 12	36559 19	37058 14	70115 35	71516 30
36250 8	36393 12	36560 19	37059 14	70117 35	71517 30
36252 17	36394 12	36561 19	37060 14	70119 35	71518 30
36253 17	36395 11	36562 19	37061 14	70121 35	71520 30
36254 19	36396 11	36590 14	37062 14	70123 35	71521 30
36255 17	36397 11	36591 14	37063 16	70127 33	71522 30
36256 19	36398 11	36592 16	37064 16	70128 33	71523 30
36257 19	36399 12	36598 19	37065 16	70129 33	71524 30
36258 19	36409 13	36606 18	37066 16	70135 33	71525 30
36259 6	36410 13	36607 18	37067 16	70139 33	71527 30
36260 6	36415 13	36608 18	37068 16	70142 33	71530 30
36262 17	36417 13	36609 18	37069 16	70148 33	71536 32
36263 17	36420 13	36610 18	37070 16	70150 33	71537 32
36264 5	36422 13	36615 18	37090 14	70151 33	71538 32
36265 17	36425 13	36620 18	37091 14	70152 33	71540 30
36266 5	36427 13	36625 18	37092 16	70153 33	71541 32
36267 5	36430 13	36627 18	37106 18	70154 33	71542 32
36268 5	36432 13	36630 18	37107 18	70155 33	71543 32
36269 6	36435 13	36631 15	37108 18	70156 33	71544 32
36270 5	36437 13	36632 15	37109 18	70157 33	71545 32
36271 6	36440 13	36633 15	37110 18	70158 33	71546 32
36272 5	36442 13	36634 15	37115 18	70159 33	71547 32
36273 6	36445 13	36635 15	37120 18	70160 33	71548 31
36274 5	36450 13	36636 15	37125 18	70163 33	71549 31
36275 6	36452 13	36637 15	37127 18	70168 33	71550 31
36276 5	36461 17	36638 15	37130 18	70190 27	71551 31
36277 6	36463 17	36639 15	37140 18	70195 37	71552 31
36278 5	36466 17	36640 18	37190 18	70411 32	71553 31
36279 6	36469 17	36645 12	37192 18	70414 32	71554 31
36280 5	36472 17	36646 12	38042 26	70416 32	71555 31
36281 6	36474 17	36647 12	38044 26	70417 32	71556 31
36282 5	36476 17	36648 12	38045 26	70507 33	71557 31
36283 6	36478 17	36649 12	38046 26	70508 33	71558 31
36284 5	36480 13	36650 12	38047 26	70509 33	71559 31
36285 6	36481 13	36651 12	38450 28	70510 33	71560 31
36286 5	36482 13	36652 12	38460 28	70515 33	71561 31
36287 6	36483 13	36653 12	45504 9	70520 33	71563 30
36288 5	36484 13	36654 12	45505 8	70525 33	71564 30
36289 6	36486 13	36655 12	45506 8	70527 33	71565 30
36290 19	36487 13	36659 12	45508 9	70530 33	71566 30
36291 5	36490 13	36660 12	45509 9	70533 33	71567 30
36292 8	36492 13	36661 12	45511 8	70534 33	71568 30
36293 8	36494 13	36689 15	45516 8	70535 33	71569 30
36294 5	36496 17	36690 18	45521 8	70536 33	71570 31
36296 17	36497 13	36691 18	45525 9	70537 33	71571 31
36298 6	36511 14	36692 15	45526 8	70538 33	71576 30
36297 17	36513 14	36693 13	45527 9	70539 33	71578 30
36299 17	36514 14	36694 12	45530 9	70540 33	71582 30
36305 12	36516 14	36697 16	45531 8	70545 33	71585 30
36306 12	36517 14	36698 12	45536 8	70550 33	71587 30
36307 12	36518 14	36699 12	45540 9	70556 33	71588 30
36308 12	36519 14	37005 14	45541 8	70557 33	71603 34
36309 12	36521 14	37006 14	45546 8	70558 33	71604 34
36310 12	36522 14	37007 14	45550 9	70559 33	71605 34
36315 12	36523 14	37008 14	45551 8	70560 33	71606 34
36320 12	36524 16	37009 14	45556 8	70561 33	71607 34
36323 12	36526 16	37010 14	45561 8	70562 33	71608 34
36325 12	36527 16	37011 14	45589 8	70563 33	71609 34
36326 12	36528 16	37012 14	45591 8	70564 33	71610 34
36327 12	36529 16	37013 14	45592 8	70565 33	71615 34
36328 12	36531 16	37014 16	45593 9	70566 33	71620 34
36329 12	36532 16	37015 16	48400 9,28	70567 33	71625 34
36330 12	36533 16	37016 14	48401 9,28	70568 33	71627 34
36332 12	36534 14	37017 16	52711 7	71195 27	71630 34
36335 12	36536 14	37018 16	52713 7	71480 28	71631 34
36337 12	36537 14	37019 14	52716 7	71491 28	71632 34
36339 12	36538 14	37021 16	52719 7	71494 28	71633 34
36340 12	36539 16	37022 14	52722 7	71500 32	71634 34
36342 12	36541 16	37023 16	52726 7	71502 32	71635 34
36345 12	36543 16	37024 16	52729 7	71505 30	71636 34

Item No.	Page	Item No.	Page	Item No.	Page	Item No.	Page	Item No.	Page	Item No.	Page
71637	34	72556	32	74530	31	74628	34	76117	35	76856	29
71638	34	72557	33	74531	31	74632	34	76119	35	76857	29
71639	34	72558	32	74532	15	74636	34	76121	35	76858	29
71640	34	72559	33	74533	31	74659	34	76123	35	76859	29
71641	34	72560	33	74534	15	74660	34	76129	35	76877	29
71642	34	72561	33	74535	31	74661	34	76131	35	76895	29
71643	34	72562	33	74536	31	74662	34	76191	36	76896	29
71644	34	72563	33	74537	15	74663	34	76194	36	77101	36
71645	34	72564	33	74538	31	74664	34	76312	35	77103	36
71648	34	72567	33	74539	15	74665	34	76314	35	77105	36
71650	34	72568	33	74540	31	74666	34	76316	35	77107	36
71652	34	72569	32	74541	15	74667	34	76318	35	77109	36
71654	34	72570	32	74542	31	74668	34	76322	35	77111	36
71656	34	72572	30	74543	15	74669	34	76324	35	77113	36
71657	34	72573	30	74544	31	74670	34	76326	35	77115	36
71658	34	72574	30	74545	15	74711	32	76328	35	77117	36
71660	34	72575	30	74546	31	74714	32	76329	35	77151	36
71661	35	72576	30	74547	15	74717	32	76330	35	77152	36
71662	35	72577	30	74548	31	74721	32	76331	35	77153	36
71663	35	72578	30	74549	15	74724	32	76332	35	77154	36
71664	35	72579	30	74550	15	74728	32	76333	35	77156	36
71665	35	72580	30	74551	31	74732	32	76334	35	77158	36
71666	35	72581	30	74552	34	74736	32	76335	35	77160	36
71667	35	72590	26	74553	31	74739	32	76336	35	77162	36
71668	35	72595	26	74554	34	74742	32	76337	35	77164	36
71669	35	73310	32	74555	34	74760	32	76338	35	77193	36
71670	35	73311	32	74556	31	74761	32	76339	35	77195	36
71671	35	73312	32	74557	34	74762	32	76340	35	77304	36
71673	35	73313	32	74558	31	74763	32	76341	35	77305	36
71674	35	73314	32	74559	31	74764	32	76342	35	77306	36
71675	35	73315	32	74561	31	74765	32	76346	35	77308	36
71676	35	73316	32	74562	34	74766	32	76348	35	77331	36
71677	35	73317	32	74563	31	74767	32	76352	35	77333	36
71678	35	73318	32	74564	34	74768	32	76354	35	77335	36
71680	35	73319	32	74565	31	74769	32	76395	36	77337	36
71681	35	73320	32	74566	33	74981	27	76396	36	77341	36
71690	27	74413	31	74567	31	74982	27	76397	37	77343	36
71692	27	74415	31	74568	33	74985	27	76399	37	77345	36
71698	37	74417	31	74569	31	74987	27	76403	35	77347	36
72238	30	74419	31	74570	33	75093	25	76404	35	77349	36
72239	30	74431	31	74571	31	75660	25	76405	35	77353	36
72240	30	74433	31	74572	33	75661	25	76406	35	77390	36
72241	30	74435	31	74573	31	75662	25	76407	35	77701	30
72242	30	74461	31	74574	33	75663	25	76408	35	77702	30
72279	31	74462	31	74575	31	75664	25	76411	35	77703	30
72280	31	74463	31	74576	33	75665	25	76412	35	77704	30
72281	31	74464	31	74577	31	75666	25	76413	35	77705	30
72282	31	74465	31	74579	31	75667	25	76414	35	79242	27
72283	31	74468	31	74580	31	75668	25	76490	36	79245	27
72338	30	74469	31	74581	31	75669	25	76510	29	79247	27
72339	30	74470	31	74582	31	75670	25	76511	29	79283	27
72340	30	74501	31	74583	31	75671	25	76512	29	79445	27
72341	30	74502	31	74584	31	75679	25	76513	29	79447	27
72342	30	74503	31	74585	31	75681	25	76514	29	79450	34
72379	31	74504	31	74586	31	75683	25	76516	29	91118	23
72381	31	74505	15	74587	31	75701	25	76517	29		
72382	31	74506	31	74588	31	75702	25	76553	29		
72383	31	74508	31	74589	31	75703	25	76554	29		
72384	31	74510	31	74590	31	75704	25	76555	29		
72514	33	74511	31	74591	31	75705	25	76556	29		
72515	33	74512	31	74592	31	75706	25	76558	29		
72516	33	74513	31	74593	31	75707	25	76557	29		
72525	33	74514	31	74594	31	75708	25	76559	29		
72527	33	74515	31	74596	31	75709	25	76810	29		
72528	32	74516	31	74597	31	75710	25	76811	29		
72529	32	74517	31	74601	34	75715	25	76812	29		
72530	33	74518	31	74602	34	75720	25	76813	29		
72531	32	74519	31	74603	34	75728	25	76814	29		
72540	33	74520	15	74604	34	75735	25	76816	29		
72541	32	74521	31	74608	34	75742	25	76817	29		
72542	33	74522	15	74611	34	75801	25	76853	29		
72545	32	74523	31	74612	34	75985	25	76854	29		
72546	32	74524	15	74613	34	75988	25	76855	29		
72547	33	74525	31	74614	34	76106	35				
72550	32	74526	15	74616	34	76107	35				
72551	32	74527	31	74617	34	76109	35				
72552	33	74528	15	74620	34	76111	35				
72555	32	74529	31	74624	34	76113	35				



Prop65 WARNING: This product could expose you to chemicals including Vinyl Chloride, Ethylene Glycol, Ni or CrVI, which are known to the state of California to cause cancer or reproductive harm. For more information go to www.P65warnings.ca.gov/

MANUFACTURING
EXCELLENCE
AWARD
BESTES KMU
2014

WIHA – WINNER OF THE
MX AWARD 2014.
GERMANY'S BEST SME.

wiha 
Tools that work for you

PROFESSIONAL TORX® TOOLS



(800) 494-6104
fax: (800) 494-7456
cservice@wihatools.com
www.wihatools.com

Catalog Item No. 99914 .wo
version - 3/1/19

Subject to change
without notice

©2019 Willi Hahn Corporation

®Torx is a registered trademark of
Acument Intellectual Properties LLC.



Wiha Quality Tools

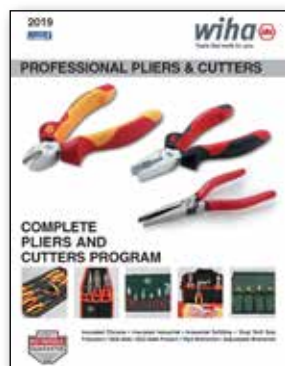
1348 Dundas Circle
Monticello, MN 55362
tel: 763.295.6591
fax: 763.295.6598

Wiha Tools Canada Ltd.

www.wihatools.ca
Brampton, ONT L6T 4X4
tel: 866.494.0096 or 763.295.6591
fax: 763.295.6598



To:



99977.wo - Pliers/Crimpers Catalog



99934.wo - Hex Tools Catalog



99001.wo - TorqueControl Catalog



99951.wo - Bits Catalog



99919.wo - Insulated Catalog



99002.wo - Screwdrivers Catalog



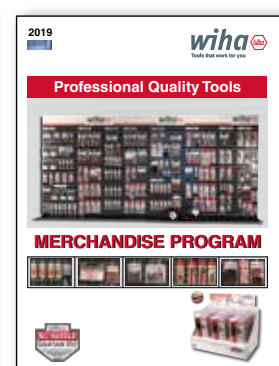
99004.wo - Shop Tools Catalog



99006.wo - Tech Tools Catalog



99945.wo - ESD Catalog



99007.wo - Merchandise Catalog

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Wiha:

76853	76895	76896	76856	76512	71524	76553	76855	76817	71512	76516	76556	71548	76812	74669
76194	70564	74462	74508	74510	38047	74987	76340	77113	76336	76339	76411	72552	72564	72576
74539	74541	74982	76333	76342	76399	77101	72547	73314	73316	72577	74537	72556	73311	74522
74528	74549	76330	76332	76414	71680	71671	71674	71675	71677	74557	71503	71637	74768	74463
74664	74760	74763	74555	70565	71596	74468	74504	74516	74661	74465	74466	74501	70558	71501
70416	74552	70561	70567	74767	70411	74564	71670	73319	74505	74543	76331	76816	72527	72557
72575	77391	74464	74665	74762	73317	72578	76334	70563	71681					