

2024

Wiha
Tools that work for you

Heavy Duty Tool Hauler Backpack Sets



4 NEW
Sets!



◆ External YKK zip pockets keep tools and materials easily accessible and safe



◆ Zipper front pocket allows easy access to important gear



◆ Rear Compartment with padded laptop sleeve for safety and security

2024

Heavy Duty Tool Hauler Backpack Sets

Apprentice Electrician



Insulated cushion grip screwdrivers for comfort and control and Industrial brushed finished pliers & cutters, premium quality tool steel for strength and durability. Each certified to VDE 0682/part 201, EN/IEC 60900, ASTM F-1505, NFPA70E & CSA standards. 1000 volt rated, individually tested.

16 Piece | Insulated Heavy Duty Backpack Apprentice Electrician Tool Set

Model #91870

9.5" Insulated NE Style Lineman's Pliers
8.0" Insulated Long Nose Pliers
8.0" Insulated Heavy Duty Diagonal Cutters
7.25" Insulated Wire Stripping Pliers 10-20 AWG
Slotted | 4.5, 6.5mm Phillips | #1, #2 Square | #2
Insulated PicoFinish® Precision Screwdrivers
Slotted | 2.5, 3.0, 3.5mm Phillips | #0
25 Ft. Tape Measure, 20 oz. Claw Hammer, 9" Torpedo Level



Journeyman Electrician



Insulated cushion grip screwdrivers for comfort and control and Industrial brushed finished pliers & cutters, premium quality tool steel for strength and durability. Each certified to VDE 0682/part 201, EN/IEC 60900, ASTM F-1505, NFPA70E & CSA standards. 1000 volt rated, individually tested.

30 Piece | Insulated Heavy Duty Backpack Journeyman's Electrician Tool Set

Model #91871

9.5" Insulated NE Style Lineman's Pliers
8.0" Insulated Long Nose Pliers
8.0" Insulated Heavy Duty Diagonal Cutters
8.0" Insulated Cable Cutters
10.0" Insulated Water Pump Pliers
10.0" Auto Grip Pliers
7.25" Insulated Wire Stripping Pliers 10-20 AWG



Slotted | 4.0, 4.5, 6.5mm
Phillips | #1, #2 Square | #1, #2
SAE Nut Drivers | 1/4, 5/16, 3/8"
Insulated PicoFinish® Precision Screwdrivers
Slotted | 2.5, 3.0, 3.5mm Phillips | #0, #1
Extra Heavy Duty SoftFinish® Slotted Screwdriver | 8.0mm
Nut Setters | 1/4, 5/16, 3/8"
25 Ft. Tape Measure, 20 oz. Claw Hammer, 9" Torpedo Level
6" Cat. IV Voltage Detector 50-1000 Volts

Fully
adjustable
shoulder
straps for
maximum
comfort



Professional Mobile Tool Solutions



► Master Electrician



Insulated cushion grip screwdrivers for comfort and control and Industrial brushed finished pliers & cutters, premium quality tool steel for strength and durability. Each certified to VDE 0682/part 201, EN/IEC 60900, ASTM F-1505, NFPA70E & CSA standards. 1000 volt rated, individually tested.

59 Piece | Insulated Heavy Duty Backpack Master Electrician's Tool Set

Model #91872

9.5" Insulated NE Style Lineman's Pliers
8.0" Insulated Long Nose Pliers
8.0" Insulated Heavy Duty Diagonal Cutters
8.0" Insulated Cable Cutters
10.0" Insulated Water Pump Pliers
10.0" Auto Grip Pliers
7.25" Insulated Wire Stripping Pliers 10-20 AWG



Slotted | 4.0, 4.5, 5.5, 6.5mm
Phillips | #1, #2 Square | #1, #2
Xeno Slotted/Phillips Terminal | #1, #2
SAE Nut Drivers | 7/32, 1/4, 5/16, 3/8, 7/16, 1/2"
Insulated PicoFinish® Precision Screwdrivers
Slotted | 2.5, 3.0, 3.5mm Phillips | #00, #0, #1
22 Pc. ErgoStar Ball End Hex SAE & Metric L-keys
SAE | .050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8"
Metric | 1.5, 2.0, 2.5, 3.0, 4.0, 5.0, 6.0, 8.0, 10.0mm
Extra Heavy Duty SoftFinish® Slotted Screwdriver | 8.0mm
Nut Setters | 1/4, 5/16, 3/8"
25 Ft. Tape Measure, 20 oz. Claw Hammer, 9" Torpedo Level
6" Cat. IV Voltage Detector 50-1000 Volts



► Industrial MRO



Industrial brushed finished pliers & cutters, induction hardened cutting edges and jaws for superior sharpness and longevity. SoftFinish® cushion grip screwdrivers for maximum power and comfort. Exact fit precision machined tips for reduced cam-out and premium quality tool steel for strength and durability.


80 Piece | Industrial Heavy Duty Backpack MRO Tool Set

Model #91873

5.0" Flush Cutters w/Return Spring
7.0" Combination Pliers
8.0" BiCut Compound Cutters
8.0" Industrial Long Nose Pliers
8.0" High Leverage End Cutting Nippers
9.5" Industrial NE Style Lineman's Pliers w/Crimpers
10.0" Auto Grip Pliers



SoftFinish® Screwdrivers Slotted | 4.5, 6.0mm & Phillips | #1
Extra Heavy Duty SoftFinish® Screwdrivers SLT | 8.0mm & PH | #2
CentroFix Bit Holder & Stubby SoftFinish® Bit Holder
11in1 Multi-Driver SLT 3/16", 1/4" | PH #1, #2 | SQ #1, #2 | TORX T20, T25
Nut Driver 1/4, 5/16, 3/8"
32 Piece GoBox™ Bit Set SLT, PH, SQ, TORX, SAE/Metric Hex,
1/4" Bit Holder, 1/4" Hex to 1/4" Sq. Adapter, 1/4" Bit Ratchet-72Tooth
22 Pc. ErgoStar Ball End Hex SAE & Metric L-keys
SAE | .050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8"
Metric | 1.5, 2.0, 2.5, 3.0, 4.0, 5.0, 6.0, 8.0, 10.0mm
Color Coded SAE Nut Setters | 1/4, 5/16, 3/8, 7/16, 1/2, 9/16"
Magnetizer/Demagnetizer, 25 Ft. Tape Measure,
35 oz. Dead Blow Hammer, 6.5" Shears, 10" Adjustable Wrench

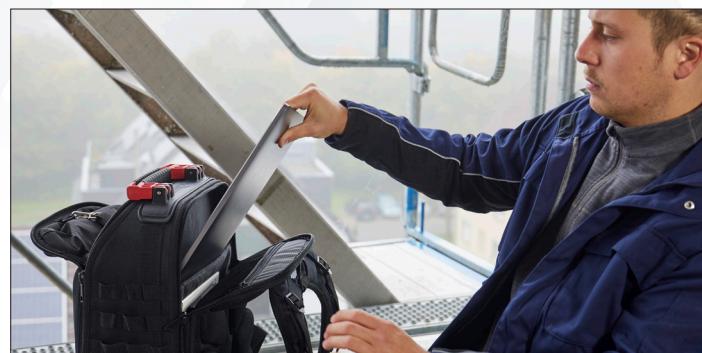

Heavy Duty Tool Hauler Backpack

Extremely robust, extremely ergonomic and extremely flexible



Heavy Duty Tool Hauler Backpack

77 storage and 30 flexible attachment options for tools or other utensils

External Zip Pockets keep tools and materials easily accessible and safe

Rear Compartment with padded laptop sleeve provides safety and security

Adjustable shoulder straps optimizes fit for maximum comfort

Durable water proof base keeps pack upright and gear dry on the job site

Zipper front pocket allows easy access to important gear



Heavy Duty Tool Hauler Backpack

Model #91869

21" H x 15.25" L x 10.25" W

Splash proof upper 1680D pack-cloth fabric with PU coating and YKK zippers



Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Wiha](#):

[91870](#) [91871](#) [91873](#) [91872](#)