

2024

wiha 
Tools that work for you

Premium Mobile Tool Kit

SKU #92100

194
PIECES

Available
2024!



**Unmatched
Capabilites**

**Professional Mobile Tool Solutions:
All New Wiha Premium Mobile Tool Kit**

Tools in Tow Wherever You Go: All New Wiha Premium Mobile Tool Kit



12 Nut Setters
SAE & Metric



Voltage Tester
Category IV
12-1000V AC
w/Flash Light



10.25" Pliers Wrench



8" BiCut Compound
Diagonal Cutters



Purpose-Built Rolling Case

- Fully Waterproof
- Collapsible Pull Handle
- Dual Latches
- Lock Points

Case external dimensions:
23" x 14.21" x 9.37"




L-key Sets
SAE, Metric & TORX®



SoddFinish®
cushion grip
screwdrivers



3/8" Drive Sockets
Standard & Deep

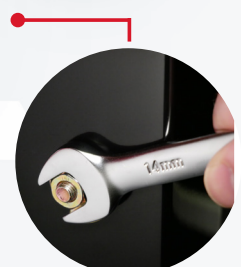

Combination
Wrenches
SAE & Metric



Professional Mobile Tool Solutions: All New Wiha Premium Mobile Tool Kit

Wiha's 194 Piece Premium Mobile Tool Kit is designed to make your work easier, allowing you to accomplish more and go farther.

With a wide range of essential tools, including Screwdrivers, Pliers, Cutters, Sockets, Wrenches, L-Keys, Bits, Level, Tape Measure, Hammer, and Voltage Detector, you're well-equipped for any task. The impact-resistant and waterproof case ensures the durability of your tools, protecting them during transit and ensuring they're always organized and ready.

2024 NEW KIT

wiha 
Tools that work for you

#92100
Premium
Mobile Tool Kit

**194
PIECES**



GoBox™ Sets -

36 Piece ESD Safe Precision Micro Bit Set
32 Piece TerminatorBlue Impact Bit Set with
Mini Ratchet

Nut Setters -

6 Pc. Color Coded Magnetic Nut Setter SAE Set
6 Pc. Color Coded Magnetic Nut Setter Metric Set

CentroFix Blade Holder

Magnetic Torpedo Level 9"

25 Foot DualMax Tape Measure

Claw Hammer 20 oz

Non-Contact Voltage Tester Category IV

12-1000V AC with Flash Light



L-Keys -

22 Piece ErgoStar Ball End Hex Inch/Metric
13 Piece Torx Rust Free Finish

SoftFinish® Screwdrivers -

XHD Slotted 8.0mm
XHD Phillips #2
Slotted 4.5mm | 6.5 | 8.0mm
Phillips #1 | #2

11inOne Multi-Driver

CentroFix Blade Holder



Pliers & Cutters -

Auto Grip V-Jaw Tongue and Groove Pliers 10"

Pliers Wrench 10.25"

High Leverage Combination Pliers 8"

BiCut Compound Diagonal Cutters 8"

Wire Combination Strippers/Crimpers 8.25"

Flush Cutters with Return Spring

Long Nose Pliers w/ Cutters 8"

NE Style Lineman's Pliers with Crimpers 9.5"



Combination Wrenches -

8" | 10" | 12" | 13" | 14" | 15mm
5/16" | 3/8" | 7/16" | 1/2" | 9/16" | 5/8"

3/8" Drive Standard Sockets 12 Point-

1/4" | 5/16" | 3/8" | 7/16" | 1/2" | 9/16" | 5/8"
3/4" | 13/16" | 7/8"
6/8" | 10" | 12" | 13" | 14" | 15" | 16" | 17" | 19" | 22mm

3/8" Drive Deep Sockets 12 Point -

1/4" | 5/16" | 3/8" | 7/16" | 1/2" | 9/16" | 5/8"
3/4" | 13/16" | 7/8"
8" | 10" | 12" | 13" | 14" | 15" | 16" | 17" | 19" | 22mm

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Wiha:](#)

[92100](#)