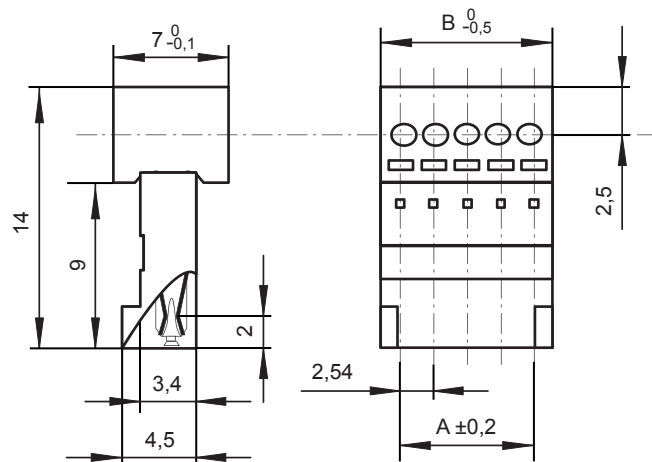
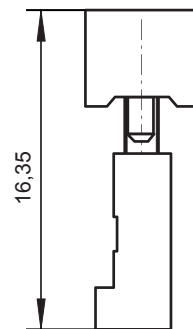


12345

After cabling



Before cabling



TECHNICAL CHARACTERISTICS

MATERIAL  
INSULATOR: PBT  
FLAMMABILITY RATING: UL94V0  
COLOR: BLACK  
METAL: PHOSPHOR BRONZE  
PLATING: TIN  
QUALITY CLASS: 25 MATING CYCLES

ENVIRONMENTAL  
OPERATING TEMPERATURE: -40°C UP TO +125°C  
COMPLIANCE: LEAD FREE AND ROHS

 

ELECTRICAL  
CURRENT RATING: 3 A  
WORKING VOLTAGE: 50 VAC  
WITHSTANDING VOLTAGE: 500 VAC/MIN  
INSULATION RESISTANCE: >1000 MΩ  
CONTACT RESISTANCE: 20 mΩ MAX

MECHANICAL  
STRANDED WIRE: 28-26 AWG

PACKAGING  
TUBES

A = (nb. pin-1) x pitch

B = (nb. pin x pitch)

RoHS Compliant				<div>PROJECTION:</div> <div></div>	<div>GENERAL TOLERANCE</div> <div>±0,1</div>	<div> WÜRTH ELEKTRONIK</div>		D
G								
F								
E								
D	17-JUN-16	DESCRIPTION	AK	APPROVAL: BBu	UNIT: MM	DESCRIPTION: 2.54 MM AUTOCOM SINGLE ROW FEMALE RIGHT ANGLED IDC RECEPTACLE FOR AWG#28-26 WITH DISCRETE WIRES ON LOCKING SIDE	SIZE <b>A4</b>	
C	07-DEC-15	MECHANICAL / PACK	AK		SCALE:			
B	20-OCT-15	UPDATE	AK		SHEET: 1/2			
A	19-SEP-14	PDF	AK		WERI PART NO: 661 0xx 152 022			
REV	DATE	FILE	BY		DRAW: AK			



# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Wurth Elektronik:](#)

[661003152022](#) [661003152122](#) [661003152222](#)