
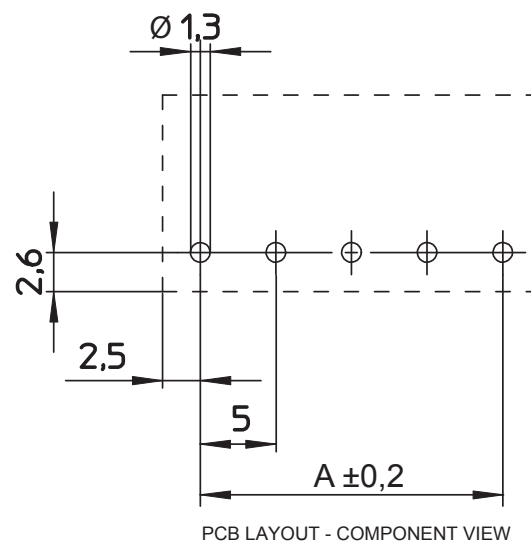


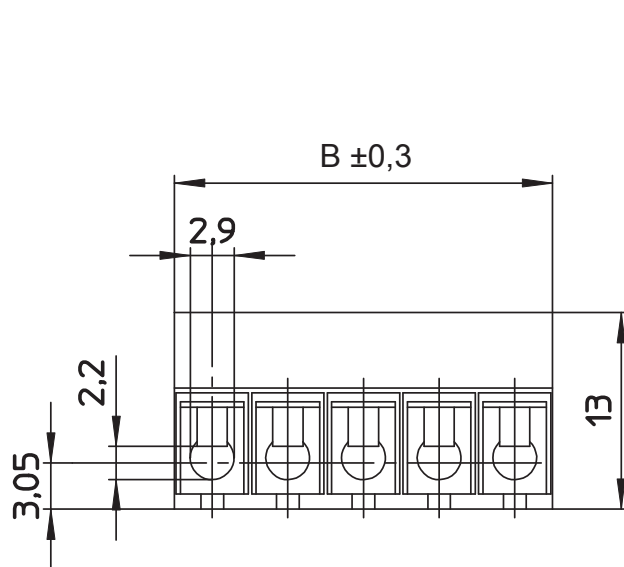

TECHNICAL CHARACTERISTICS

MATERIAL
INSULATOR: PC
FLAMMABILITY RATING: UL94V0
COLOR: GREY
METAL HOUSING: COPPER ALLOY / Ni+Sn
TERMINAL SCREW: STEEL / Zn
WIRE GUARD: COPPER ALLOY / Sn

ENVIRONMENTAL
OPERATING TEMPERATURE: -30°C UP TO +120°C
COMPLIANCE: LEAD FREE AND ROHS

ELECTRICAL	UL	VDE
CURRENT RATING:	16A	24A
WORKING VOLTAGE:	300VAC	450VAC
WITHSTANDING VOLTAGE:	1,6KV	2,5KV
CONTACT RESISTANCE:	20 mΩ MAX	

STANDARD

UL CERTIFIED: E150931 CAT. N°: CZZ (1)
CE CERTIFIED: 40021377 TYPE: CZZ

MECHANICAL

SOLID WIRE: 30-14 AWG / 0,05-2,08 mm²
STRANDED WIRE: 30-14 AWG / 0,05-2,08 mm²
TORQUE: 4Lb.In / 0,5 Nm



WIRE STRIPE LENGTH: 7 mm
SCREW: M3
PITCH: 5 mm

SOLDERING
JEDEC LEAD FREE WAVE SOLDERING

 
PACKAGING
BOX

A = (nb. pin-1) x pitch

B = (nb. pin x pitch)

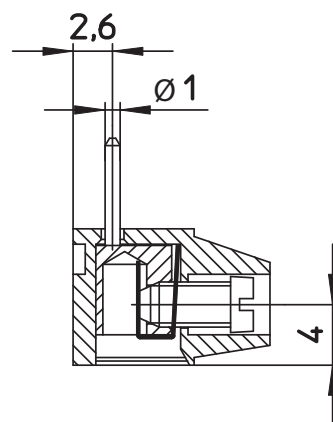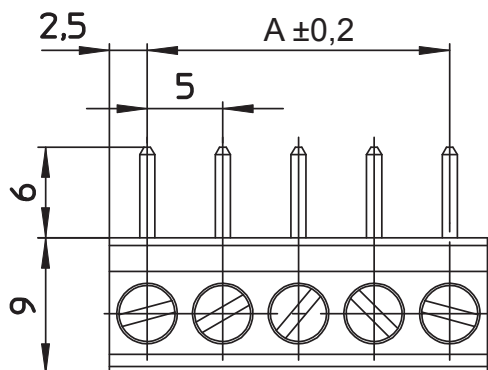

RoHS Compliant

				PROJECTION: 	GENERAL TOLERANCE ±0,1	 WÜRTH ELEKTRONIK		
G								
F								
E								
D								
C				APPROVAL: QL	UNIT: MM	DESCRIPTION: SERIE 1367 - 5.00 MM - VERTICAL CABLE ENTRY WITH PRESSURE CLAMP - GLOW WIRE PLASTIC - WR-TBL	SIZE	
B					SCALE:			
A	25-AUG-14	PDF	AK		SHEET: 1/2			WERI PART NO: 691 136 700 0xx
REV	DATE	FILE	BY		DRAW: AK			
							A4	

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Würth Elektronik:](#)

[691136700004](#) [691136700005](#) [691136700006](#) [691136700007](#) [691136700008](#) [691136700010](#)