


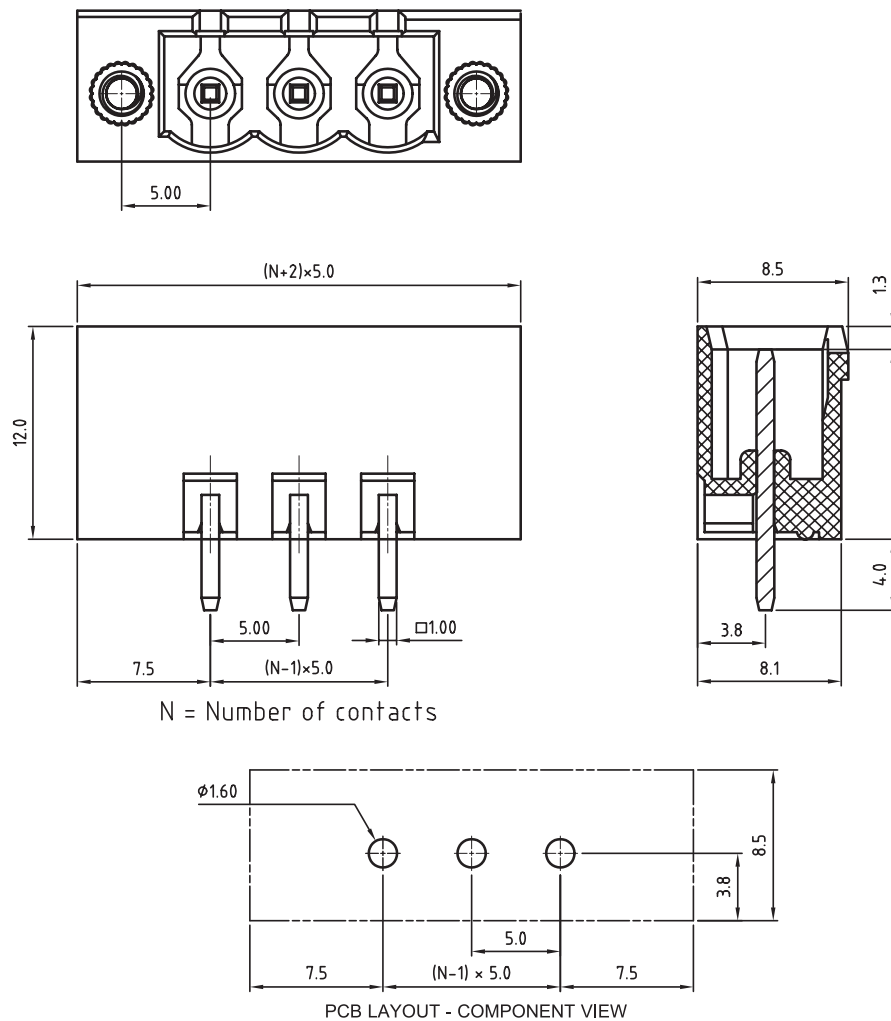

TECHNICAL CHARACTERISTICS

MATERIAL

INSULATOR: PBT
FLAMABILITY RATING: UL94-V0
COLOR: GREEN
CONTACT: BRASS
SOLDER TAIL PLATING: TIN
FLANGES SCREW NUT: BRASS M2.5

ENVIRONMENTAL

OPERATING TEMPERATURE: -40 UP TO 105°C
COMPLIANCE: LEAD FREE AND ROHS

ELECTRICAL

	cULus	VDE
CURRENT RATING:	20A	20A
WORKING VOLTAGE:	300VAC	300VAC
WITHSTANDING VOLTAGE:	1.6KV	2.5KV
CONTACT RESISTANCE:	20 mOhm max	

STANDARD

ULus CERTIFIED E315414 / MODEL NUMBER 3187
CE CERTIFIED 40023195 / MODEL NUMBER 3187

MECHANICAL

PITCH: 5.00MM

SOLDERING: WAVE PROCESS ONLY

PACKAGING: BOX

SERIE 3187

RoHS Compliant				PROJECTION: 	GENERAL TOLERANCE .X = ± 0.2 .XX = ± 0.15		DESCRIPTION: SERIE 3187 - 5.00MM CLOSE VERTICAL PCB HEADER WITH FLANGES WR-TBL WERI PART NO: 691 318 700 0xx	SIZE A4
G								
F								
E								
D								
C				APPROVAL: RJ	UNIT: MM			
B	13-OCT-09	STANDARD	JP					
A	04-NOV-08	PDF	JP					
REV	DATE	FILE	BY					

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Wurth Elektronik:](#)

[691318700004](#)