


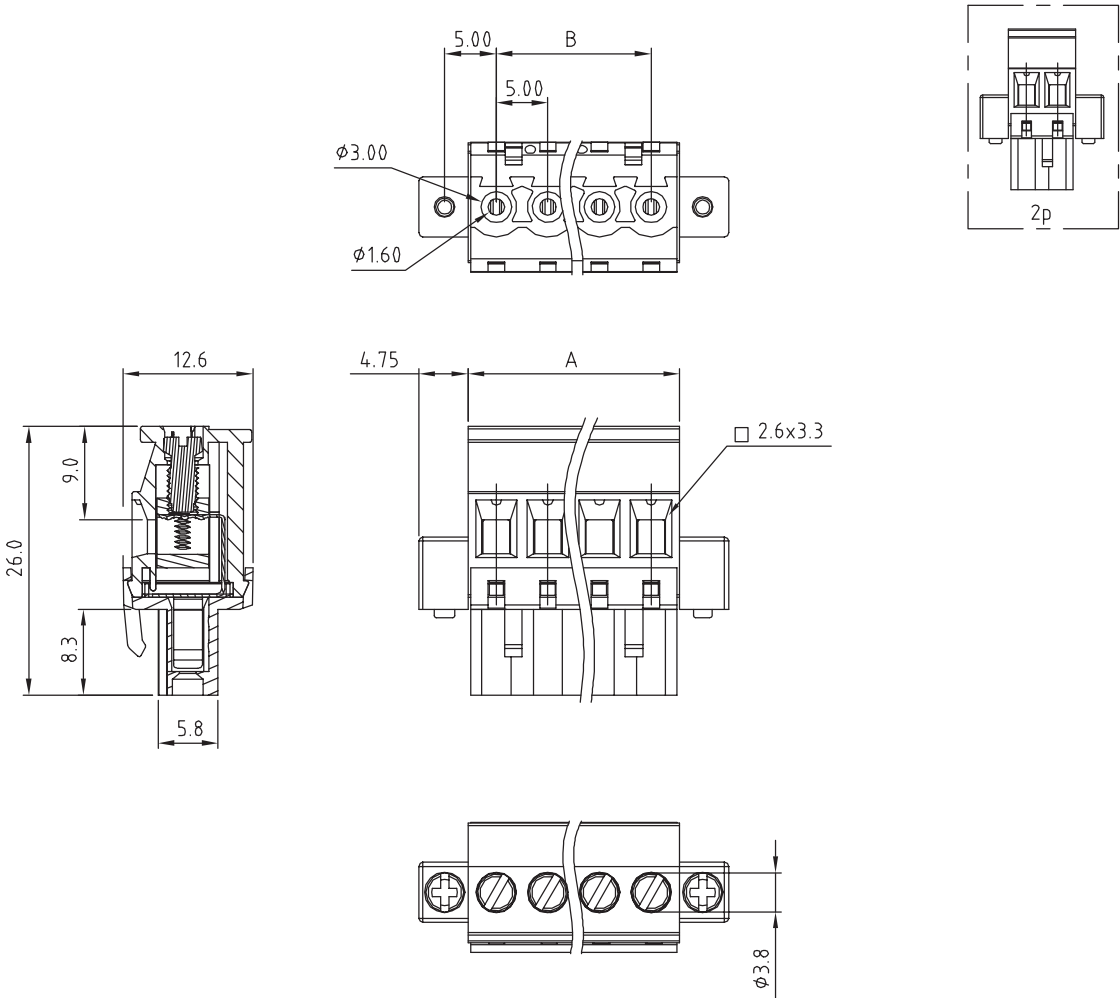

TECHNICAL CHARACTERISTICS

MATERIAL
INSULATOR: PA 66
FLAMMABILITY RATING: UL94-V0
COLOR: GREEN
METAL HOUSING: BRASS (CuZn)
TERMINAL SCREW: STEEL ZINC PLATING
TERMINAL SCREW SLOT TYPE: "-"
CONTACT: BRASS
WIRE GUARD: PhBz TIN PLATED
FLANGES SCREW: STEEL M2.5

ENVIRONMENTAL
OPERATING TEMPERATURE: -40 UP TO 105°C
COMPLIANCE: LEAD FREE AND ROHS

ELECTRICAL	cULus	VDE
CURRENT RATING:	15 A	17 A
WORKING VOLTAGE:	300 VAC	300 VAC
WITHSTANDING VOLTAGE:	1.6 KV	2.5 KV
CONTACT RESISTANCE:	20 mOhm max	

STANDARD
ULus CERTIFIED E315414
CE CERTIFIED 40023402

MECHANICAL
SOLID WIRE: 24-12 AWG / 0.2-3.0 MM²
STRANDED WIRE: 24-12 AWG / 0.2-3.0 MM²
TORQUE: 3.5 Lb-In / 0.4 Nm

WIRE STRIPE LENGTH: 6-7 MM
SCREW: M3.0
PITCH: 5.00 MM

PACKAGING
BOX

DIMENSION
A = (NB. PINS -1) x PITCH
B = NB. PINS x PITCH

RoHS Compliant				PROJECTION: 	GENERAL TOLERANCE .X = +/- 0.2 .XX = +/- 0.15	 WÜRTH ELEKTRONIK	DESCRIPTION: SERIE 3407 - 5.00MM HORIZONTAL CABLE ENTRY PLUG WITH FLANGES & HOOK ON WIRE SIDE - WR-TBL	SIZE A4
G								
F								
E								
D	20-APR-16	DRAWING	AK	APPROVAL: FBr	UNIT: MM	WERI PART NO: 691 340 700 0xx		
C	21-OCT-09	SCREW	JP					
B	13-OCT-09	STANDARD	JP					
A	04-NOV-08	PDF	JP					
REV	DATE	FILE	BY					
					SCALE:			
					SHEET: 1/2			
					DRAW: MARVIN			

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Wurth Elektronik:](#)

[691340700007](#)