



1

2

3

4

5

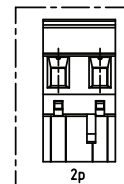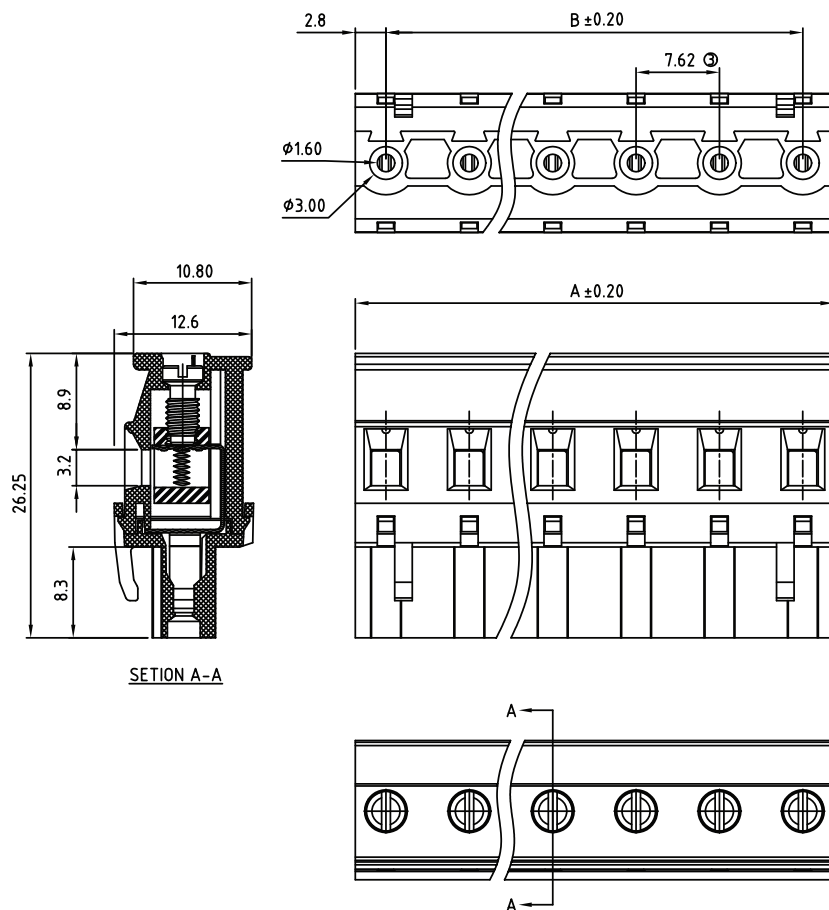

## TECHNICAL CHARACTERISTICS

MATERIAL  
INSULATOR: PA 66  
FLAMMABILITY RATING: UL94-V0  
COLOR: GREEN  
METAL HOUSING: BRASS (CuZn)  
TERMINAL SCREW: STEEL ZINC PLATING  
TERMINAL SCREW SLOT TYPE: "-"  
WIRE GUARD: PhBz TIN PLATED

ENVIRONMENTAL  
OPERATING TEMPERATURE: -40 UP TO 105°C  
COMPLIANCE: LEAD FREE AND ROHS

ELECTRICAL  
CURRENT RATING: 15 A  
WORKING VOLTAGE: 300 VAC  
WITHSTANDING VOLTAGE: 1.6 KV  
CONTACT RESISTANCE: 20 mOhm max

STANDARD  
ULus CERTIFIED E315414

MECHANICAL  
SOLID WIRE: 24-12 AWG / 0.205-3.31 MM²  
STRANDED WIRE: 24-12 AWG / 0.205-3.31 MM²  
TORQUE: 4.3 Lb-In / 0.49 Nm

WIRE STRIPE LENGTH: 6-7 MM  
SCREW: M3.0  
PITCH: 7.62 MM

PACKAGING  
BOX

DIMENSION  
A = (NB. PINS -1) x PITCH  
B = (NB. PINS x PITCH) -2.02

RoHS Compliant

PROJECTION:



GENERAL TOLERANCE

.X =  $\pm 0.2$ .XX =  $\pm 0.15$ 

APPROVAL: FBr

UNIT: MM

SCALE:

SHEET: 1/2

DRAW: MARVIN

DESCRIPTION: SERIE 3524 - 7.62MM HORIZONTAL CABLE ENTRY PLUG  
WITH HOOK ON WIRE SIDE - WR-TBL

WERI PART NO: 691 352 410 0xx

SIZE

A4



# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Wurth Elektronik:](#)

[691352410004](#)