
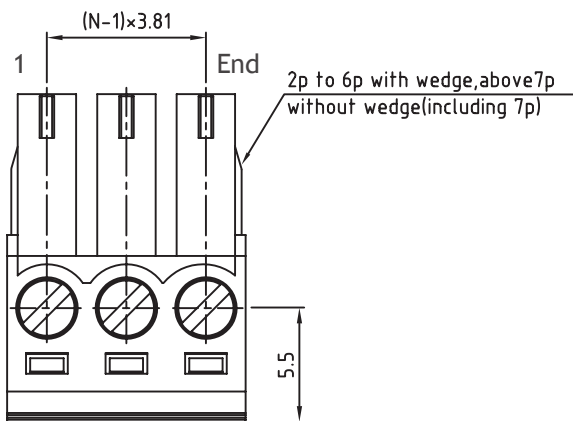
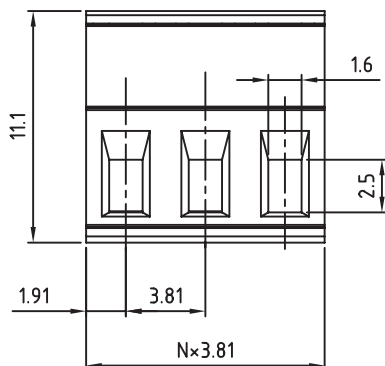


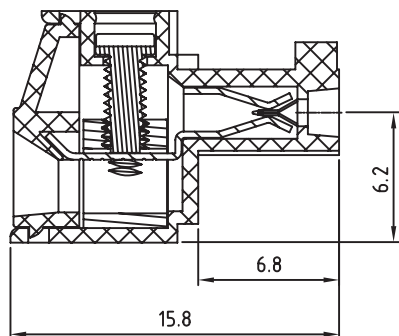

TECHNICAL CHARACTERISTICS

MATERIAL

INSULATOR: PA 66
FLAMABILITY RATING: UL94-V0
COLOR: GREEN
METAL HOUSING: BRASS (CuZn)
TERMINAL SCREW: STEEL ZINC PLATING "-" SLOT TYPE
WIRE GUARD: PhBz TIN PLATED

ENVIRONMENTAL

OPERATING TEMPERATURE: -40 UP TO 105°C
COMPLIANCE: LEAD FREE AND ROHS

ELECTRICAL

	cULus	VDE
CURRENT RATING:	10A	10.5A
WORKING VOLTAGE:	300VAC	300VAC
WITHSTANDING VOLTAGE:	1.6KV	2.5KV
CONTACT RESISTANCE:	20 mOhm MAX	

STANDARD

ULus CERTIFIED E315414
CE CERTIFIED 40023195

MECHANICAL

SOLID WIRE:	26-16 AWG / 0.129-1.31 MM²
STRANDED WIRE:	26-16 AWG / 0.129-1.31 MM²
TORQUE:	3.0 Lb.In / 0.34 Nm

WIRE STRIPE LENGTH: 6-7 MM

SCREW: M2
PITCH: 3.81 MM

PACKAGING
BOX

RoHS Compliant

PROJECTION:



GENERAL TOLERANCE

.X = ± 0.2

.XX = ± 0.15



APPROVAL: FBr

UNIT: MM

SCALE:

SHEET: 1/2

DRAW: MARVIN

DESCRIPTION: SERIE 361 - 3.81MM VERTICAL CABLE ENTRY PLUG
- WR-TBL

WERI PART NO: 691 361 300 0xx

SIZE

A4

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Wurth Elektronik:](#)

[691361300024](#)