


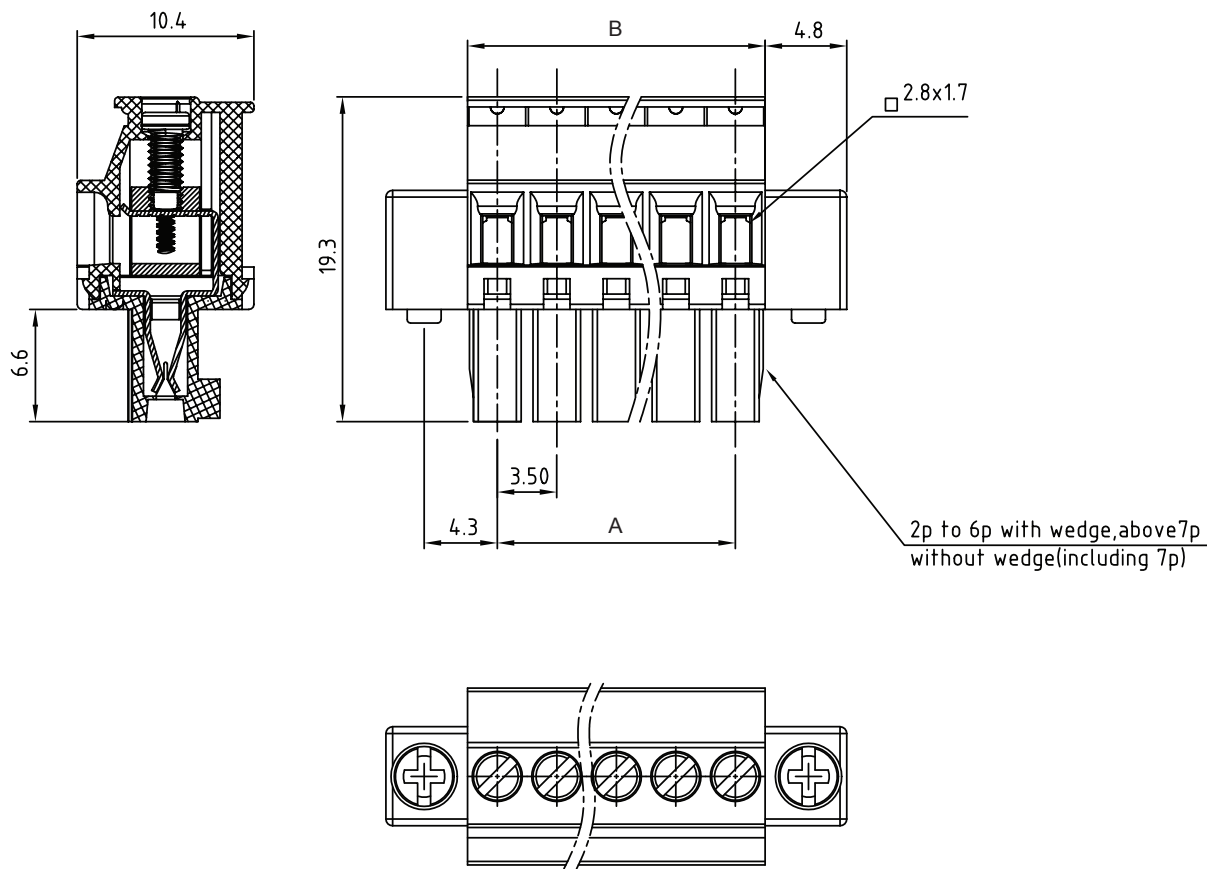

TECHNICAL CHARACTERISTICS

MATERIAL
INSULATOR: PA 66
FLAMMABILITY RATING: UL94-V0
COLOR: GREEN
METAL HOUSING: BRASS (CuZn)
TERMINAL SCREW: STEEL ZINC PLATING
TERMINAL SCREW SLOT TYPE: "-" & "+"
WIRE GUARD: PbZn TIN PLATED
FLANGES SCREW: STEEL M2.5

ENVIRONMENTAL
OPERATING TEMPERATURE: -40 UP TO 105°C
COMPLIANCE: LEAD FREE AND ROHS

ELECTRICAL	cULus	VDE
CURRENT RATING:	8 A	10 A
WORKING VOLTAGE:	300 VAC	300 VAC
WITHSTANDING VOLTAGE:	1.6 KV	2.5 KV
CONTACT RESISTANCE:	20 mOhm max	

STANDARD
ULus CERTIFIED E315414
CE CERTIFIED 40023402

MECHANICAL
SOLID WIRE: 26-16 AWG / 0.129-1.31 MM²
STRANDED WIRE: 26-16 AWG / 0.129-1.31 MM²
TORQUE: 1.7 Lb-In / 0.2 Nm

WIRE STRIPE LENGTH: 6-7 MM
SCREW: M2.0
PITCH: 3.5 MM

PACKAGING
BOX

DIMENSION
A = (NB. PINS - 1) x PITCH
B = NB. PINS x PITCH

RoHS Compliant				PROJECTION: 	GENERAL TOLERANCE .X = $\pm$ 0.2 .XX = $\pm$ 0.15	 WÜRTH ELEKTRONIK		
G								
F								
E								
D	01-APR-16	DRAWING	AK	APPROVAL: FBr	UNIT: MM	DESCRIPTION: SERIE 3671 - 3.50MM HORIZONTAL CABLE ENTRY PLUG WITH FLANGES & HOOK ON BACK SIDE - WR-TBL		SIZE A4
C	21-OCT-09	SCREW	JP		SCALE:			
B	12-OCT-09	STANDARD	JP		SHEET: 1/2	WERI PART NO: 691 367 110 0xx		
A	31-OCT-08	PDF	JP		DRAW: MARVIN			
REV	DATE	FILE	BY					

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Wurth Elektronik:](#)

[691367110002](#)