




1

2

3

4

5

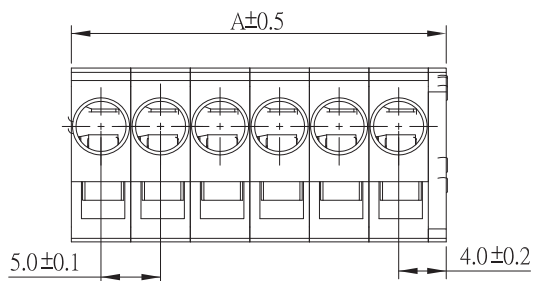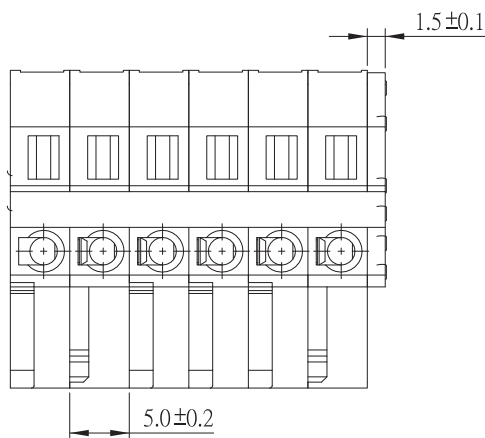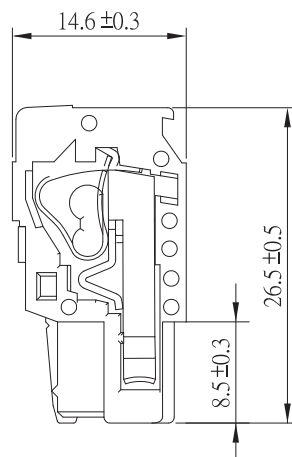

## TECHNICAL CHARACTERISTICS

## MATERIAL

INSULATOR: PA 66

FLAMMABILITY RATING: UL94-V0

COLOR: GREY

CONTACT MATERIAL: PHOSPHOR BRONZE - TIN PLATED

WIRE GUARD: STAINLESS STRIP STEEL

## ENVIRONMENTAL

OPERATING TEMPERATURE: -40 UP TO 115°C

COMPLIANCE: LEAD FREE AND ROHS

## ELECTRICAL

cULus

CURRENT RATING: 16A

WORKING VOLTAGE: 300VAC

WITHSTANDING VOLTAGE: 2.0KV

INSULATION RESISTANCE: 2000 MOhm

CONTACT RESISTANCE: 20 mOhm

## STANDARD

ULus CERTIFIED E315414

## MECHANICAL

SOLID WIRE: 28-12 AWG / 0.081-3.31 MM<sup>2</sup>STRANDED WIRE: 28-12 AWG / 0.081-3.31 MM<sup>2</sup>

WIRE STRIPE LENGTH: 8-9 MM

PITCH: 5.0 MM

## PACKAGING

 
BOX

## DIMENSION

A = 5 x (NB POLES - 1) + 6.5

RoHS Compliant

PROJECTION:



GENERAL TOLERANCE

.X =  $\pm 0.2$ .XX =  $\pm 0.15$ 

APPROVAL: FBr

UNIT: MM

SCALE:

SHEET: 1/2

DRAW: QL

DESCRIPTION: SERIE 369B - 5,00MM SCREWLESS CABLE ENTRY PLUG  
- WR-TBL

WERI PART NO: 691 369 700 0xxB

SIZE

A4



# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Wurth Elektronik:](#)

[691369700002B](#)