

CUSTOMER TERMINAL	RoHS	LEAD(Pb)-FREE
Sn96%, Ag4%	Yes	Yes

more than you expect




ELECTRICAL SPECIFICATIONS @ 25°C unless otherwise noted:

PARAMETER	TEST CONDITIONS	VALUE
D.C. RESISTANCE	1-4 @20°C	128 mOhms max.
INDUCTANCE	1-4 1kHz, 100mVAC, Ls	696.0uH ±10%

GENERAL SPECIFICATIONS:

OPERATING TEMPERATURE RANGE: -40°C to +125°C including temp rise.

CURRENT RATING: 2A

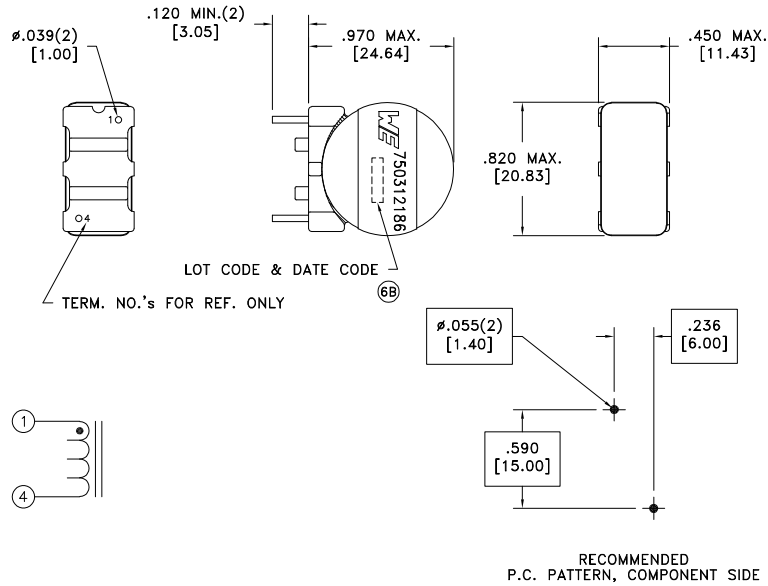

Wire insulation & RoHS status not affected by wire color.  
Wire insulation color may vary depending on availability.

DETAILS SUBJECT TO CHANGE

REV.	DATE	Packaging Specifications		Tolerances unless otherwise specified: Angles: $\pm 1^\circ$ Fractions: $\pm 1/64$	DRAWING TITLE	PART NO.
6D	3/21	Method: Tray		Decimals: $\pm .005$ [.13]	<b>INDUCTOR</b>	<b>750312186</b>
6C	6/20	PKG-0119		Fractions: $\pm .001$ [.03]		
6B	7/14	www.we-online.com/midcom		This drawing is dual dimensioned. Dimensions in brackets are in millimeters.	eiSos p/n: 750312186	SPECIFICATION SHEET 1 OF 1
6A	5/11	SEE REVISION SHEET FOR REVISION LEVEL				



# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Wurth Elektronik:](#)

[750312186](#)