



CUSTOMER TERMINAL	RoHS	LEAD(Pb)-FREE
Sn96%, Ag4%	Yes	Yes

more than you expect


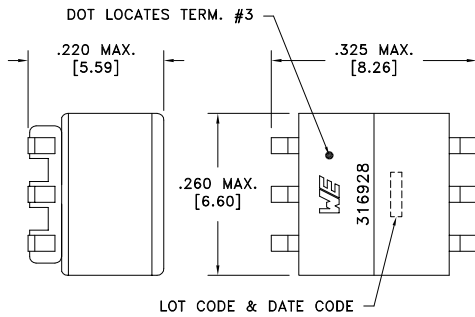


TERM. NO.'s FOR REF. ONLY

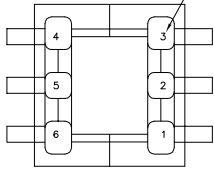

**ELECTRICAL SPECIFICATIONS @ 25°C unless otherwise noted:**

PARAMETER	TEST CONDITIONS	VALUE
D.C. RESISTANCE	1-3 @20°C	0.159 ohms ±10%
D.C. RESISTANCE	4-6 @20°C	1.03 ohms ±10%
INDUCTANCE	4-6 10kHz, 100mVAC, Ls	239uH ±8%
DIELECTRIC	3-4 500VAC, 1 second	500VAC, 1 minute
TURNS RATIO	(4-6):(3-1)	4.5:1, ±1%
TURNS RATIO	(4-6):(2-1)	9:1, ±1%

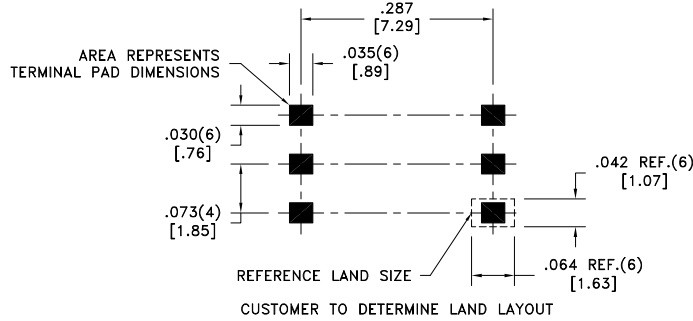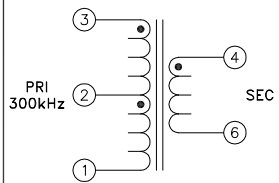

6B

GENERAL SPECIFICATIONS:

OPERATING TEMPERATURE RANGE: -40°C to +125°C including temp rise.

Safety standard undefined.

Wire insulation & RoHS status not affected by wire color.  
Wire insulation color may vary depending on availability.

REV.	DATE	Packaging Specifications Method: <b>Tape &amp; Reel</b> PKG-0637 www.we-online.com/midcom		Tolerances unless otherwise specified: Angles: ±1° Fractions: ±1/64 Decimals: ±.005 [.13] Footprint: ±.005 [.13]	DRAWING TITLE <b>TRANSFORMER</b>	PART NO. <b>750316928</b>
6B	2/18			This drawing is dual dimensioned. Dimensions in brackets are in millimeters.	eiSos p/n: 750316928	SPECIFICATION SHEET 1 OF 1
6A	9/17	SEE REVISION SHEET FOR REVISION LEVEL				

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Wurth Elektronik:](#)

[750316928](#)