
 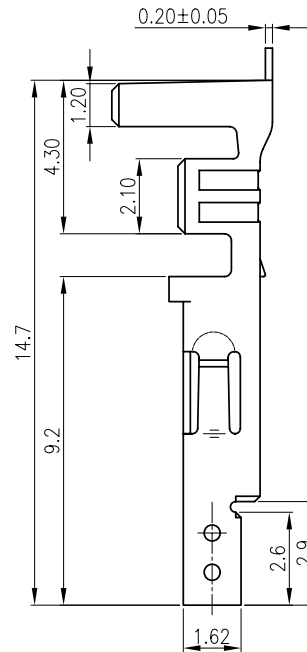

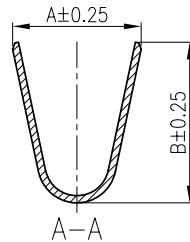
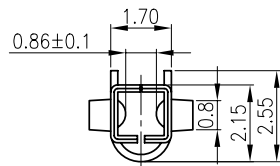


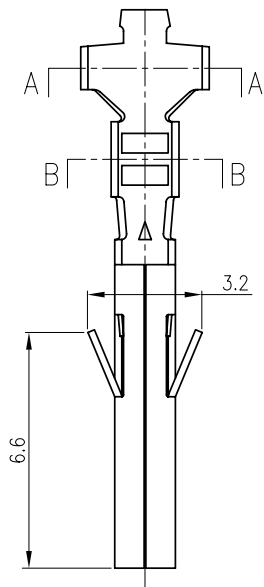

TECHNICAL CHARACTERISTICS

MATERIAL

CONTACT MATERIAL: COPPER ALLOY
CONTACT TYPE: STAMPED
CONTACT PLATING: TIN
QUALITY CLASS: 25 MATING CYCLES
PITCH: FOR 4.20MM

ENVIRONMENTAL

OPERATING TEMPERATURE: -40 UP TO 105°C
COMPLIANCE: LEAD FREE AND ROHS

ELECTRICAL

CURRENT RATING: 6 TO 9A
WORKING VOLTAGE: 600V AC
INSULATOR RESISTANCE: >1000 MOHM
DIELECTRIC WITHSTANDING VOLTAGE: 1500V AC/MN
CONTACT RESISTANCE: 20 MOHM MAX

WIRE DIMENSION

64900113722 AWG 22-16

DIMENSION


ORDER CODE	AWG	A	B	C	D
64900113722	22-16	4.00	4.40	2.50	2.25

PACKAGING

BULK/LOOSE DELIVERY IN A BAG
EACH CONTACT SEPARATED FROM EACH OTHER
NOT ON A REEL
100PCS/PER BAG. MULTIPLE OF 100PCS ONLY
1PCS OF 64900113722DEC=1 CRIMP CONTACT
SO 1 BAG MEANS 100 PCS OF 64900113722DEC

RoHS Compliant

 PROJECTION:



GENERAL TOLERANCE

.X = ± 0.2

.XX = ± 0.15



APPROVAL: RJ

UNIT: MM

SCALE:

SHEET: 1/1

DRAW: MIKE

DESCRIPTION: 4.2MM FEMALE CRIMP TERMINAL 22-16 AWG

WERI PART NO: 649 001 137 22 DEC

SIZE

A4

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Wurth Elektronik:](#)

[64900113722DEC](#)