




CUSTOMER TERMINAL	RoHS	LEAD(Pb)--FREE
Sn 96%, Ag 4%	Yes	Yes

more than you expect



ELECTRICAL SPECIFICATIONS @ 25° C unless otherwise noted:

PARAMETER	TEST CONDITIONS	VALUE
D.C. RESISTANCE	5-8 @20°C	1.40 ohms ±10%
D.C. RESISTANCE	10-9 @20°C	0.115 ohms ±10%
INDUCTANCE	5-8 10kHz, 100mV, Ls	1.80mH ±10%
SATURATION CURRENT	5-8 20% rolloff from initial	750mA
DIELECTRIC	8-10 1500VAC, 1 second	
URNS RATIO	(5-8):(10-9)	15:1, ±1%

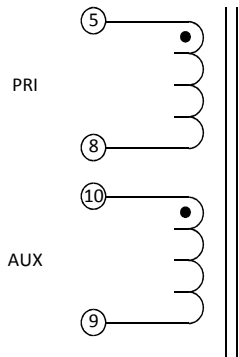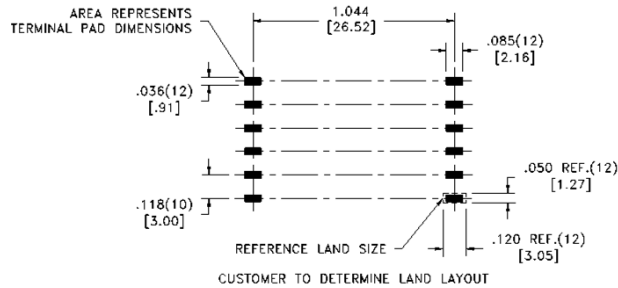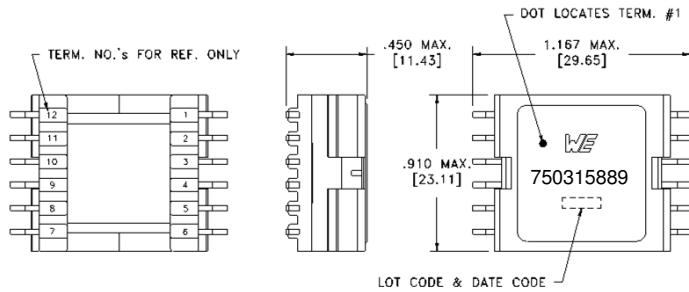

GENERAL SPECIFICATIONS:

OPERATING TEMPERATURE RANGE: -40°C to +125°C including temp rise.

- Functional insulation only

Wire insulation & RoHS status not affected by wire color. Wire insulation color may vary depending on availability.

DFM	SP	Packaging Specifications		Tolerances unless otherwise specified: Angles: ±1° Decimals: ±.005 [13] Fractions: ±1/64 Footprint: ±.005 [13]	DRAWING TITLE INDUCTOR	PART NO. 750315889
DATE	11/4/2015	Method: Tape & Reel		This drawing is dual dimensioned. Dimensions in brackets are in millimeters.		
ENG	KLM	PKG-0868				
REV.	00					
DATE	11/13/2015	www.we-online.com/midcom				SPECIFICATION SHEET 1 OF 1

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Wurth Elektronik:](#)

[750315889](#)