



All Larsen NMOHF (high frequency 27 MHz to 6 GHz) mounts convert from low frequency applications to high frequency applications and back by pulling or replacing the center pin and insulator.

NMOHF mounts require a 3/4" hole for mounting and include 17' of coax. NMOHF mounts accommodate roof surfaces from 0.1" to .03". NMOHFTHK (thick) mounts accommodates roof surfaces up to 1/2" thick.

NMO 3/4" HIGH FREQUENCY MOUNTS

| Model | Coax | Connector |
|----------------|---------------------------|---------------|
| *NMOKHFCX | CX (RG-58A/U) | No Conn |
| *NMOKHFCXFME | CX (RG-58A/U) | FME CRIMP |
| *NMOKHFCXMPL | CX (RG-58A/U) | MPL |
| *NMOKHFCXPL | CX (RG-58A/U) | PL-259 |
| *NMOKHFDS | DS (RG-58A/U Dual Shield) | No Conn |
| NMOKHFUD | UD (RG-58U Dual Shield) | No Conn |
| *NMOKHFUDFME | UD (RG-58U Dual Shield) | FME |
| *NMOKHFUDMPL | UD (RG-58U Dual Shield) | MPL |
| *NMOKHFUDSMA | UD (RG-58U Dual Shield) | SMA |
| *NMOKHFUDTNC | UD (RG-58U Dual Shield) | TNC |
| *NMOKHF200SMAI | LMR200 | SMA Installed |



NMO 3/4" HIGH FREQUENCY MID-SIZE MOUNTS

| Model | Coax | Connector |
|---------------|-------------------------------------|-----------|
| *NMOKHF MIDCX | CX (RG-58A/U) | No Conn |
| *NMOKHF MIDDS | DS (RG-58A/U Dual Shield, Low Loss) | No Conn |
| *NMOKHF MIDUD | UD (RG-58U, Dual Shield) | No Conn |



NMO 3/4" HIGH FREQUENCY THICK MOUNTS

| Model | Coax | Connector |
|--------------|---------------------------|-----------|
| *NMOKHFCXTHK | CX (RG-58A/U) | No Conn |
| *NMOKHFDSTHK | DS (RG-58A/U Dual Shield) | No Conn |

If your antenna has a "tab" or "pin" connector, use the NMOHF mount in the low frequency configuration - leave the center pin and insulator in place as it arrives from the factory.


If your antenna has a "high frequency" (HF) connector, use the NMOHF mount in the high frequency configuration - remove the center pin and insulator.



NMO 3/4" STANDARD MOUNTS

NMO 3/4" standard mounts require a 3/4" hole for mounting and include 17' of coax.

| Model | Coax | Connector |
|------------|---------------------------|-----------|
| NMOKNOCONN | CX (RG-58A/U) | No Conn |
| *NMOK | CX (RG-58A/U) | PL-259 |
| *NMOKFME | CX (RG-58A/U) | FME |
| *NMOKMPL | CX (RG-58A/U) | MPL Crimp |
| *NMOKDS | DS (RG-58A/U Dual Shield) | No Conn |
| *NMOKDSFME | DS (RG-58A/U Dual Shield) | FME |
| NMOKUD | UD (RG-58U Dual Shield) | No Conn |
| *NMOKUDFME | UD (RG-58U Dual Shield) | FME |
| *NMOKUDPL | UD (RG-58U Dual Shield) | PL-259T |
| *NMOKUDTNC | UD (RG-58U Dual Shield) | TNC |

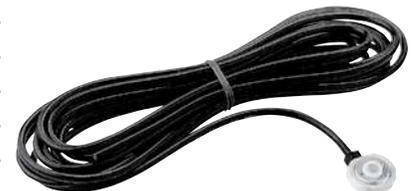



*MADE IN THE USA

CABLE ASSEMBLIES/MOUNTS



NMO HIGH FREQUENCY MOUNTS

| Model | Thickness | Cable |
|-----------|----------------------------------|--------------|
| NMOHF | 0.761-2.54 mm Standard | Not included |
| NMOHF MID | 0.761 - 5.90 mm Mid-Thickness | Not included |
| NMOHF THK | 1.6 - 12.7 mm Greatest Thickness | Not included |

All Larsen NMOHF (high frequency 27 MHz to 6 GHz) mounts convert from low frequency applications to high frequency applications and back by pulling or replacing the center pin and insulator.



NMO HIGH FREQUENCY MAGNETIC MOUNTS

NMOHF round magnetic mounts have the following specifications:

Size: 3.5" Diameter
Cable Length: 12'
Pull Strength: 80 lbs

| Model | Coax | Connector |
|------------------|---------------------------|-----------|
| *NMOMMRNOCONN | CX (RG-58A/U) | No Conn |
| *NMOMMR | CX (RG-58A/U) | 58FCP |
| *NMOMMRFME | CX (RG-58A/U) | FME Crimp |
| *NMOMMRPL | CX (RG-58A/U) | PL-259 |
| *NMOMMRMPL | CX (RG-58A/U) | MPL Crimp |
| *NMOMMRTNC | CX (RG-58A/U) | TNC Crimp |
| *NMOMMRBNC | CX (RG-58A/U) | BNC Crimp |
| *NMOMMRN | CX (RG-58A/U) | N Crimp |
| *NMOMMRDS | DS (RG-58A/U Dual Shield) | No Conn |
| *NMOMMRDSFME | DS (RG-58A/U Dual Shield) | FME |
| *NMOMMRDSMPL | DS (RG-58A/U Dual Shield) | MPL Crimp |
| *NMOMMRDSN | DS (RG-58A/U Dual Shield) | N Crimp |
| *NMOMMRDSSMA | DS (RG-58A/U Dual Shield) | SMA |
| *NMOMMRDSSMAR/P | DS (RG-58A/U Dual Shield) | SMARP |
| *NMOMMRDSPL | DS (RG-58A/U Dual Shield) | PL-259T |
| *NMOMMRDSTNC | DS (RG-58A/U Dual Shield) | TNC |
| *NMOMMT200NOCONN | LMR200 | No Conn |
| *NMOMMR200SMA | LMR200 | SMA |
| *NMOMMR200N | LMR200 | N |

NMO 3/8" THICK MOUNTS

NMO3/8" mounts have the following specifications:

Mounting: 3/4" hole
Mounting Surface: 0.15" to 0.22" thickness
Cable Length: 17'



| Model | Coax | Connector |
|--------------|---------------------------|-----------|
| *NMOKCX38THK | CX (RG-58A/U) | No Conn |
| *NMOKUD38THK | DS (RG-58A/U Dual Shield) | No Conn |



All Larsen NMOHF (high frequency 27 MHz to 6 GHz) mounts convert from low frequency applications to high frequency applications and back by pulling or replacing the center pin and insulator.

GPS LTE DIRECT MOUNTS

NMOHFGPS mounts have the following specifications:

| | | | |
|----------------------|---------------------------------------|------------------|----------------------|
| Frequency: | 1575.4 - 1576.4 MHz | Gain: | 5 dBic |
| Polarization: | Right-Hand Circular / Vertical | LNA Gain: | 26 dB ± 2 dB |
| Cable: | 16.4' RG-174 (GPS) | VSWR: | Less than 2:1 |
| | 16.4' RG-58 (NMOHF) | Size: | .5 x 2 x 4.5 |
| Voltage: | 3 or 5 V DC | Color: | Black |
| Mounting: | 5/8" Hole | | |



| Model | Connectors |
|-------------------|------------------|
| *NMOHFGPSFMENOCNN | FME/No Connector |
| *NMOHFGPSFMESMA | FME/SMA |
| *NMOHFGPSNOCNN | No Connectors |
| *NMOHFGPSSMASMA | SMA/SMA |

NOTE: Specifications listed refer to GPS performance. Additional antenna specifications are dependent on the antenna mounted on the NMO side.

NMO SQUARE MAGNETIC MOUNTS

NMO square magnetic mounts have the following specifications:

| | |
|-----------------------|------------------|
| Size: | 3.5" x 3" |
| Cable Length: | 12' |
| Pull Strength: | 50 lbs |

| Model | Coax | Connector |
|--------------|---------------------------|-----------|
| *NMOMMNOCONN | CX (RG-58A/U) | No Conn |
| *NMOMMMPL | CX (RG-58A/U) | MPL |
| *NMOMM | CX (RG-58A/U) | 58FCP |
| *NMOMMBNC | CX (RG-58A/U) | BNC |
| *NMOMMPL | CX (RG-58A/U) | PL-259 |
| *NMOMMFME | CX (RG-58A/U) | FME |
| *NMOMMDSFME | DS (RG-58A/U Dual Shield) | FME |



NMO TRUNK LID MOUNTS

NMO trunk lid mounts have the following specifications:

Size: 2.5" x 2"

| Model | Coax | Cable Length | Connector |
|------------------|---------------|--------------|-----------|
| *NMOTLP | CX (RG-58A/U) | 17 ft. | PL-259 |
| *NMOTLPFME | CX (RG-58A/U) | 17 ft. | FME |
| *NMOHFTLP200NF | LMR-200 | 17 ft. | N-Female |
| *NMOHFTLP200NF12 | LMR-200 | 12 ft. | N-Female |





*MADE IN THE USA

CABLE ASSEMBLIES/MOUNTS



LM MOUNTS

| Model | Coax | Connector |
|------------|---------------------------|-----------|
| *LMKNOCONN | CX (RG-58A/U) | No Conn |
| *LMKFME | CX (RG-58A/U) | FME |
| *LMK | CX (RG-58A/U) | PL-259 |
| *LMKDS | DS (RG-58A/U Dual Shield) | No Conn |
| *LMKDSFME | DS (RG-58A/U Dual Shield) | FME |
| LMKUD | UD (RG-58U Dual Shield) | No Conn |
| LMKUDFME | UD (RG-58U Dual Shield) | FME |



LMMM MAGNETIC MOUNTS

LM magnetic mounts have the following specifications:

Size: 3.5" x 3" **Cable Length:** 12'
Type: 5/16" x 24 THDS **Pull Strength:** 50 lbs

| Model | Coax | Connector |
|--------------|---------------------------|-----------|
| *LMMMFMFME | CX (RG-58A/U) | FME Crimp |
| *LMMMFMPL | CX (RG-58A/U) | MPL Crimp |
| *LMMM | CX (RG-58A/U) | 58FCP |
| *LMMMFM BNC | CX (RG-58A/U) | BNC Crimp |
| *LMMMFMPL | CX (RG-58A/U) | PL-259 |
| *LMMMFMDS | DS (RG-58A/U Dual Shield) | No Conn |
| *LMMMFMDSFME | DS (RG-58A/U Dual Shield) | FME |



LM TRUNK LID MOUNTS

LM trunk lid mounts have the following specifications:

Size: 2.5" x 2" **Cable Length:** 17'
Type: 5/16" x 24 THDS

| Model | Coax | Connector |
|----------|---------------------------|------------------|
| *LMTLP | CX (RG-58A/U) | PL-259 |
| *LMTLPDS | DS (RG-58A/U Dual Shield) | Order Separately |



PO MOUNTS

| Model | Coax | Connector |
|------------|---------------|-----------|
| *POKNOCONN | CX (RG-58A/U) | No Conn |



PO MAGNETIC MOUNTS

PO magnetic mounts have the following specifications:

Size: 3.5" x 3" **Cable Length:** 12'
Type: SO-239 Female **Pull Strength:** 50 lbs

| Model | Coax | Connector |
|-------|---------------|-----------|
| *POMM | CX (RG-58A/U) | 58FCP |

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Pulse:

[NMOK25NOCONN](#) [NMOKDS](#) [NMOKNOCONN](#) [NMOKUDTNC](#) [NMOMMRDSSMAR/P](#) [LMB](#) [LMKUD](#) [LMMM](#)
[NMOB](#) [NMOK](#) [NMOKFME](#) [NMOKHF200NOCONN](#) [NMOKHFCX](#) [NMOKHFCXMPL](#) [NMOKHFCXTHK](#) [NMOKHFDS](#)
[NMOKHFUDFME25](#) [NMOKHFUDMPL](#) [NMOKMPL](#) [NMOKUD25MPL](#) [NMOKUDFME](#) [NMOKUDNOCONN30](#)
[NMOKUDPL](#) [NMOMMR](#) [NMOMMR200N](#) [NMOMMR200SMA](#) [NMOMMRBNC](#) [NMOMMRDSN](#) [NMOMMRFME](#)
[NMOMMRN](#) [LMB1/4](#) [LMK](#) [LMK1/4](#) [LMKDS](#) [LMKDSFME](#) [LMKFME](#) [LMKNOCONN](#) [LMKUDFME](#) [LMMMBNC](#)
[LMMMDS](#) [LMMMDSFME](#) [LMMMFME](#) [LMMMPL](#) [LMMPL](#) [LMTLP](#) [LMTLPDS](#) [NMOKDSFME](#)
[NMOKHF195THK40NC](#) [NMOKHF200RPSMAI](#) [NMOKHFCXFME](#) [NMOKHFCXPL](#) [NMOKHFDSTHK](#)
[NMOKHFDSTHKFME](#) [NMOKHFUD35](#) [NMOKHFUDSMA](#) [NMOKHFUDSMARP](#) [NMOKHFUDTNC](#) [NMOKHFUDTNCI](#)
[NMOKUDMPLI](#) [NMOKUDSMAI](#) [NMOKUDSMBI](#) [NMOMM](#) [NMOMMBNC](#) [NMOMMDSFME](#) [NMOMMFME](#)
[NMOMMPL](#) [NMOMMNOCONN](#) [NMOMMPL](#) [NMOMMR200RPSMA](#) [NMOMMR240NOCONN](#) [NMOMMRDS](#)
[NMOMMRDSFME](#) [NMOMMRDSMPL](#) [NMOMMRDSPL](#) [NMOMMRNOCONN](#) [NMOMMRTNC](#) [NMOMMRUDNOCONN](#)
[NMOTLP](#) [NMOTLPFME](#) [POKNOCONN](#) [POMM](#) [NMOKHF195](#) [NMOKHF195SMAI](#)