


GPS DIRECT MOUNT
GPSDM02-12

Series : ANTENNA

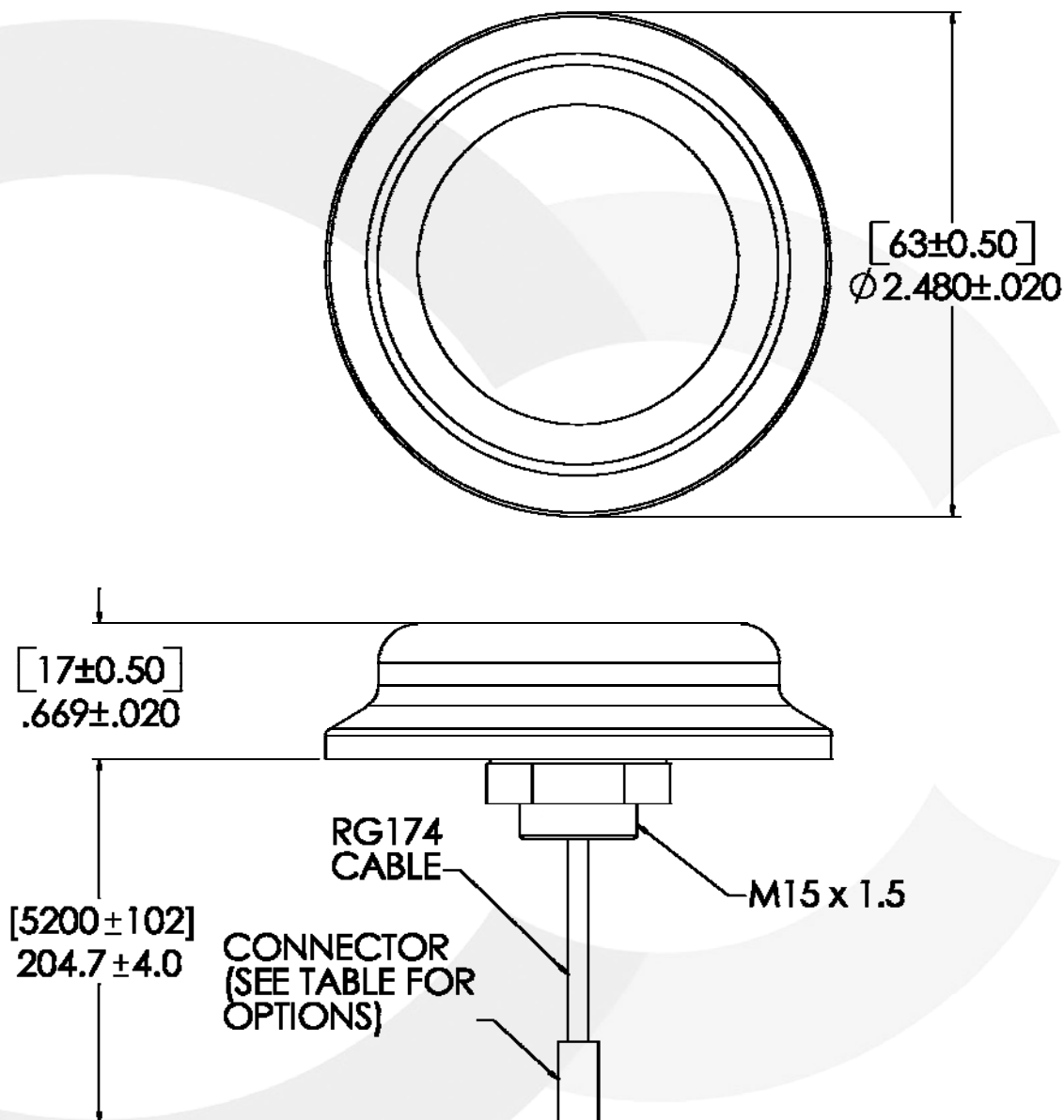

MODEL	CONNECTOR
GPSDM02	MCX
GPSDM04	MMCX
GPSDM06	SMB
GPSDM08	SMA
GPSDM10	BNC
GPSDM12	No Conn

All dimensions are in inches
 [] dimensions in mm

Issue : 0710

In the effort to improve our products, we reserve the right to make changes judged to be necessary.

GPS DIRECT MOUNT**GPSDM02-12**

Series : ANTENNA

ELECTRICAL SPECIFICATIONS

Frequency : 1575.42 MHz

Nominal Impedance : 50 Ω

VSWR : 2:1 Max

Gain @ Zenith: +5 dBic

Gain @ 10° Elevation: -1 dBic

Polarization : **Right Hand Circular**

Voltage: 5 V DC

Connector type : **SMA, SMB, MCX,
MMCX, BNC**Cable type : **RG-174**

Length : 17 Feet

MECHANICAL SPECIFICATIONSPlastic radome : **Polycarbonate-polyester
plastic blend**Color : **Black or White**

Diameter: 2.5 inches

Height :07 inches

Mounting Type: **Bolt mount requiring 3/8"
to 3/4" hole**Optional Mounting: **Die cut double sided tape
on bottom of antenna****ENVIRONMENTAL SPECIFICATIONS**

Operating temperature : -30 to +80 ° C

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Pulse:

GPSDM02