


PMR209MC6220M220R300PS

aka P409CP224M250DH221LW0P

Capacitor, film, 0.22 uF, +/-20% Tol, -40/+85C, RC(x2), 630V@85C,
Lead Spacing=20.3 mm

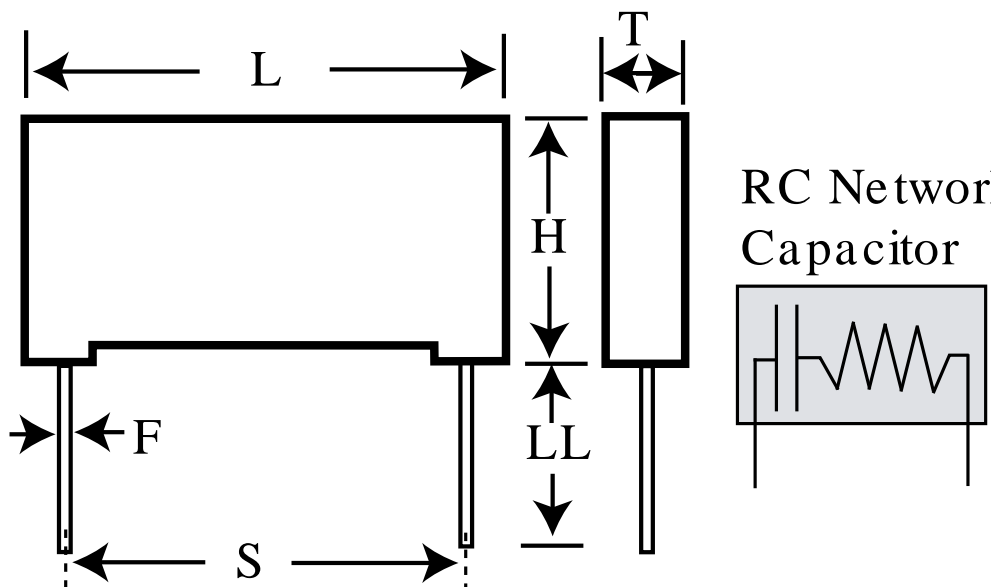

Dimensions (mm)

Specifications

ID	Dimension	Tolerance	Manufacturer:	KEMET
L	24	max	Brand:	Rifa
H	16.5	max	Capacitance:	0.22 uF
T	11.3	max	Temperature Range:	-40/+85C
S	20.3	+/-0.4	Rated Temperature:	85C
LL	30	nom	Voltage @ rated temp:	630V
F	0.8	nom	Voltage AC:	250VAC
			Tolerance:	+/-20%
			Body Type:	Radial Molded
			Construction:	Wound
			Application:	RC(x2)
			Electrical Name (Other):	Resistor
			Electrical Value (Other):	220
			Electrical Units (Other):	Ohms
			Insulation Resistance:	3 GOhm
			UL_1283:	250V
			IEC_60384-14:	250V
			Miscellaneous Electrical:	PMR209
			Package Kind:	Bulk
			Package Quantity:	150

Notes:

-Capacitor and Resistor are in series inside of case

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

KEMET:

[PMR209MC6220M220R300PS](#)