



RWP Series Datasheet

SMD | Power Metal Film Resistors | Metal Film
Epoxy Encapsulation

ORDERING CODE - Example

New SAP Part Nr.:

RWP	502	J	K	-	13-	100R	AA
Serie	Size	Tol.	Pack-Code	TCR	Package type	R Value	Special
	502 = 5020	F = $\pm 1\%$ J = $\pm 5\%$	K = Blister Tape	- Base on spec.	13- = 13 inch (Reel diameter)		AA = Standard

Historical VTM Part Nr.:

RWP	5020	J	K	-	13	100R
Type	Size	Tol.	K = Blister tape reel	TC	Reel diam.	R Value

APPLICATIONS

- Consumer & Electronics
- Industrial
- Power & Energy


FEATURES

- Suitable for automatic pick and place
- All welded construction
- Small package size
- Moulded encapsulation
- RoHS & REACH Compliant


ELECTRICAL SPECIFICATIONS

Type			RWP502
Historical Part Number			RWP5020
Nominal Power Rating	P ₂₅ P ₇₀	[W]	2,2 1,6
Resistance Range		[Ω]	10R ... 1M
E-Series			E96
Tolerances		±[%]	F = 1% J = 5%
Temperature Coefficient		±[10 ⁻⁶ K ⁻¹]	50 200
Working Temperature Range		[°C]	-55 ... +200
Thermal Resistance		[KW ⁻¹]	90
Max. Working Voltage		[V] _{RMS}	500
Dielectric Withstanding Voltage IEC115-1 clause 4.7 (1[min])		[V] _{RMS}	1000
Insulation Resistance IEC115-1 clause 4.6		[MΩ]	>1000

DIMENSIONS [mm]

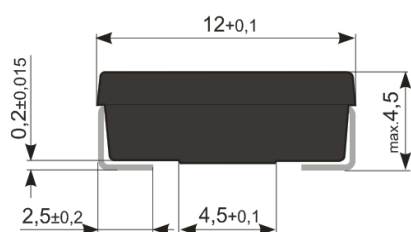

SOLDER PAD

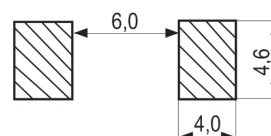


RWP Series Datasheet

PERFORMANCE DATA


Type		RWP502
Historical Part Number		RWP5020
Derating Linear	[°C]	70...200 (0W)
Climatic Category		55/200/56
Endurance <i>IEC60115-1 clause 4.25</i> ($P_{70\%}$ @ 70[°C], 1000[h])	±[%]	1,5
Damp Heat, Steady State <i>IEC60115-1 clause 4.24</i> (40[°C], 93[% r.h.], 56[d])	±[%]	1,5
Climatic Sequence <i>IEC60115-1 clause 4.23</i>	±[%]	1,0
Resistance to Soldering Heat <i>IEC60115-1 clause 4.18</i> (260 ^{±5} [°C], 3,5 ^{±1} [s])	±[%]	0,25
Short Time Overload <i>IEC60115-1 clause 4.13</i>	±[%]	1,0
Temperature Shock <i>IEC60115-1 clause 4.19</i>	±[%]	0,25
Board-bending Test		No interruption
Solderability <i>IEC60068-2-20</i> (245 ^{±5} [°C] 3 ^{±0,5} [s])		Solder bath method (> 95% coverage)
Marking <i>IEC60062</i>		Printed in clear (Type – Value – Tolerance)

PULSE PERFORMANCE

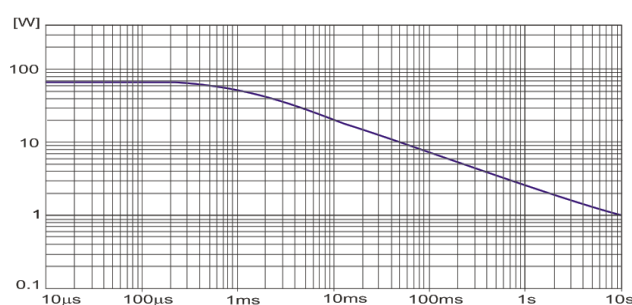


PERFORMANCE GRAPHS

Temperature Rise

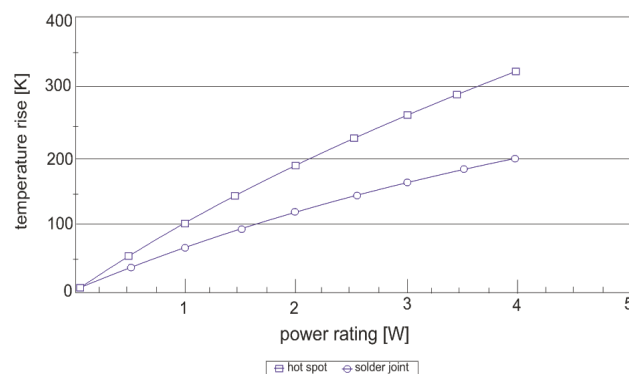


RWP Series Datasheet

Derating – P₂₅

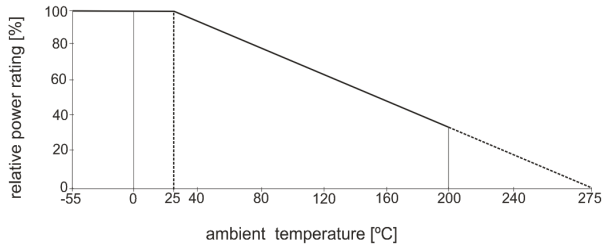


Derating – P₇₀

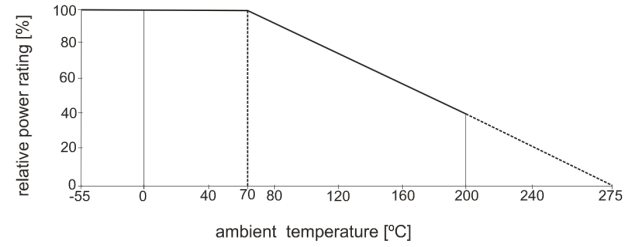


PACKAGING


The standard packaging for RWP, dimensions below.

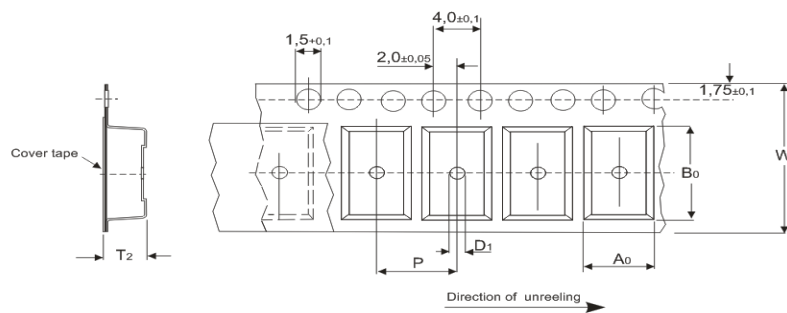

Type	A0	B0	W	D1	P	T2
RWP502	5,4	12,4	24	1,5	8	5

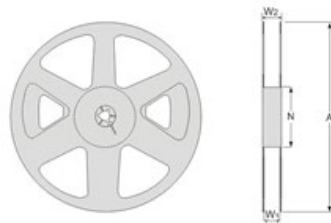

Type	W1	W2	N	A
RWP502	25,4	29,5	90	330

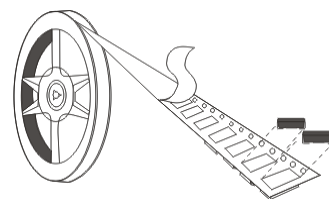

Type	Packaging	Pieces
RWP502	13(inch) Blister tape	1500

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

YAGEO:

[RWP502FK-13-100KAA](#) [RWP502FK-13-430RAA](#) [RWP502FK-13-680RAA](#) [RWP502JK-13-5K6AA](#) [RWP502FK-13-100RAA](#) [RWP502FK-13-102KAA](#) [RWP502FK-13-102RAA](#) [RWP502FK-13-105KAA](#) [RWP502FK-13-105RAA](#) [RWP502FK-13-10K2AA](#) [RWP502FK-13-10K7AA](#) [RWP502FK-13-10R2AA](#) [RWP502FK-13-10RAA](#) [RWP502FK-13-110KAA](#) [RWP502FK-13-110RAA](#) [RWP502FK-13-113KAA](#) [RWP502FK-13-113RAA](#) [RWP502FK-13-115KAA](#) [RWP502FK-13-115RAA](#) [RWP502FK-13-118KAA](#) [RWP502FK-13-118RAA](#) [RWP502FK-13-11K5AA](#) [RWP502FK-13-11K8AA](#) [RWP502FK-13-11KAA](#) [RWP502FK-13-11R3AA](#) [RWP502FK-13-11R5AA](#) [RWP502FK-13-11R8AA](#) [RWP502FK-13-11RAA](#) [RWP502FK-13-121KAA](#) [RWP502FK-13-121RAA](#) [RWP502FK-13-124KAA](#) [RWP502FK-13-124RAA](#) [RWP502FK-13-127KAA](#) [RWP502FK-13-127RAA](#) [RWP502FK-13-12K1AA](#) [RWP502FK-13-12K4AA](#) [RWP502FK-13-12R1AA](#) [RWP502FK-13-12R4AA](#) [RWP502FK-13-12R7AA](#) [RWP502FK-13-130KAA](#) [RWP502FK-13-130RAA](#) [RWP502FK-13-133KAA](#) [RWP502FK-13-133RAA](#) [RWP502FK-13-137KAA](#) [RWP502FK-13-137RAA](#) [RWP502FK-13-13KAA](#) [RWP502FK-13-13R3AA](#) [RWP502FK-13-13R7AA](#) [RWP502FK-13-13RAA](#) [RWP502FK-13-140KAA](#) [RWP502FK-13-140RAA](#) [RWP502FK-13-143KAA](#) [RWP502FK-13-143RAA](#) [RWP502FK-13-147KAA](#) [RWP502FK-13-147RAA](#) [RWP502FK-13-14K3AA](#) [RWP502FK-13-14K7AA](#) [RWP502FK-13-14KAA](#) [RWP502FK-13-14R3AA](#) [RWP502FK-13-14R7AA](#) [RWP502FK-13-14RAA](#) [RWP502FK-13-150KAA](#) [RWP502FK-13-150RAA](#) [RWP502FK-13-154KAA](#) [RWP502FK-13-154RAA](#) [RWP502FK-13-158KAA](#) [RWP502FK-13-158RAA](#) [RWP502FK-13-15K4AA](#) [RWP502FK-13-15K8AA](#) [RWP502FK-13-15KAA](#) [RWP502FK-13-15R4AA](#) [RWP502FK-13-15R8AA](#) [RWP502FK-13-15RAA](#) [RWP502FK-13-162KAA](#) [RWP502FK-13-162RAA](#) [RWP502FK-13-165KAA](#) [RWP502FK-13-165RAA](#) [RWP502FK-13-169KAA](#) [RWP502FK-13-169RAA](#) [RWP502FK-13-16K2AA](#) [RWP502FK-13-16R2AA](#) [RWP502FK-13-16R5AA](#) [RWP502FK-13-16R9AA](#) [RWP502FK-13-174KAA](#) [RWP502FK-13-174RAA](#) [RWP502FK-13-178KAA](#) [RWP502FK-13-178RAA](#) [RWP502FK-13-17R4AA](#) [RWP502FK-13-17R8AA](#) [RWP502FK-13-182KAA](#) [RWP502FK-13-182RAA](#) [RWP502FK-13-187KAA](#) [RWP502FK-13-187RAA](#) [RWP502FK-13-18R2AA](#) [RWP502FK-13-18R7AA](#) [RWP502FK-13-191KAA](#) [RWP502FK-13-191RAA](#) [RWP502FK-13-196KAA](#) [RWP502FK-13-196RAA](#) [RWP502FK-13-19R1AA](#)