

ZOM Series Datasheet

Zero – Ohm | Moulded Jumper

ORDERING CODE - Example

New SAP Part Nr.:

ZOM	065	-	T	-	52-	OR	AA
Type	Wire diameter	Tol.	Pack-Code	TC	Forming type	R Value	Special
	065 = 0,65[mm]	Based on spec.	T = Tape Ammo pack R = Tape in Reel	Based on spec.	52- = Inner taping dim.		AA = Standard

Historical VTM Part Nr.:

ZOM	0207	T	OR
Type	Style	Pack-Code	R Value

APPLICATIONS



Automotive



Power & Energy



Computer & Peripherals

FEATURES

High insulation voltage

Tape and reel packing

Compatible for automatic insertion

RoHS & REACH Compliant


ELECTRICAL SPECIFICATIONS

Type / Wire diameter		ZOM065
Historical Part Number		ZOM0207
Resistance Range	[Ω]	OR
Current rating	[A]	10
Working Temperature Range	[°C]	-55 ... +175
Dielectric Withstanding Voltage IEC115-1 clause 4.7 (1[min])	[V] _{RMS}	1000

PERFORMANCE DATA


Cross-section area of conductor	[mm ²]	0,28
Conductor resistance	[mΩ/cm]	0,54
Marking		one color-band: black

DIMENSIONS [mm]

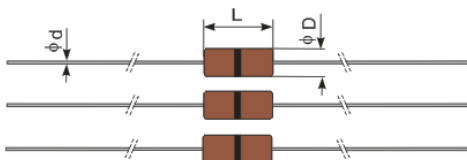

Type	Historical P/N:	L ±0,2	ØD ±0,2	Ød ±0,05
ZOM065	ZOM0207	6,4	2,3	0,65

PACKAGING

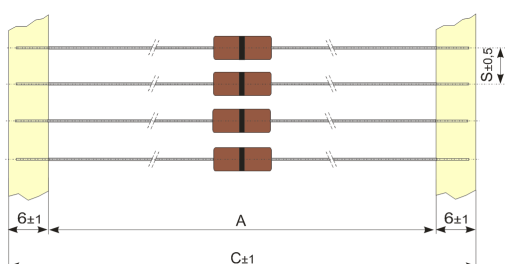

New P/N Type	Historical P/N:	Pack Code	Pieces	A	C	S
ZOM065	ZOM0207	T = Taped Ammo R = Tape Reel	2000 5000	52	65	5

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

YAGEO:

ZOM065-T-52-0RAA