

SPECIFICATIONS

Insulation Resistance:	100MΩ min.
Current Rating:	1.5A max.
Voltage Rating:	30V AC
Contact Resistance:	30mΩ max.
Withstanding Voltage:	100V AC for 1 minute
Operating Temp. Range:	0°C to +50°C



MATERIALS AND FINISH

Insulator:	PBT, UL94V-0 Rated
Contact Area:	Phosphor Bronze and Brass
Shell:	Stainless Steel
Latch:	Stainless Steel

FEATURE

- RoHS2011/65/EU

OUTLINE DIMENSIONS

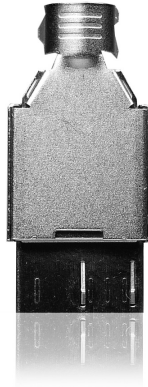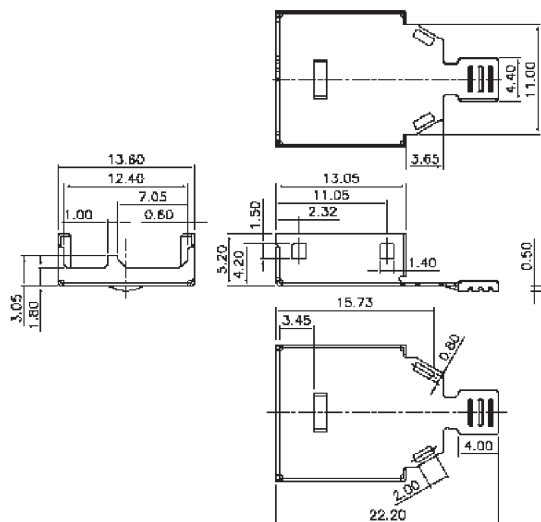

PART NUMBER

USB-3.0MC - 10B - P - BL - BU



Series No.

No of Pins = 10 Type B

Solder Plug Type

BL = 15μ" Au Plating Selective

Bulk Packaging

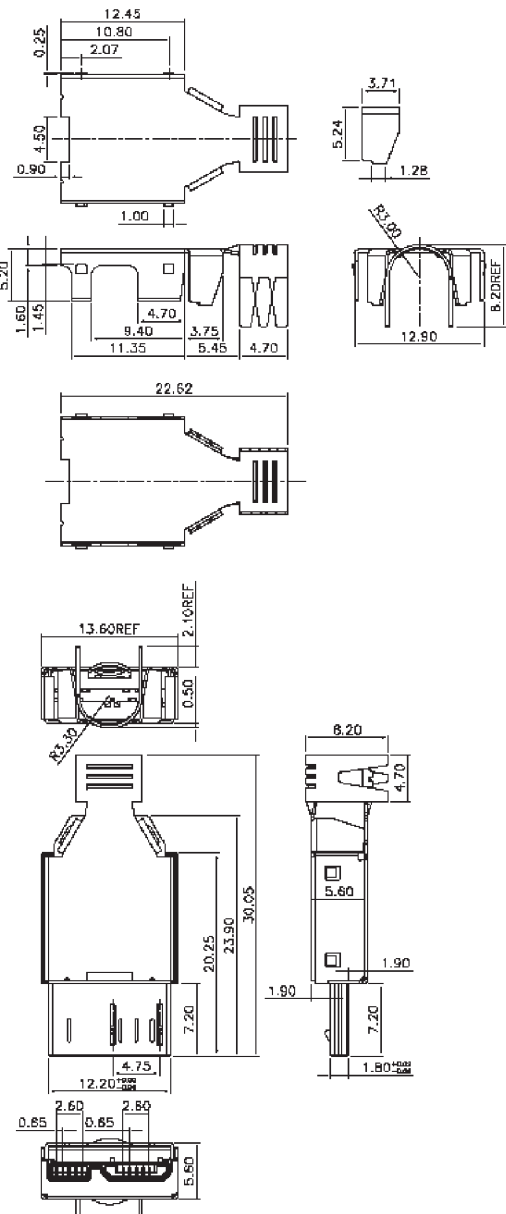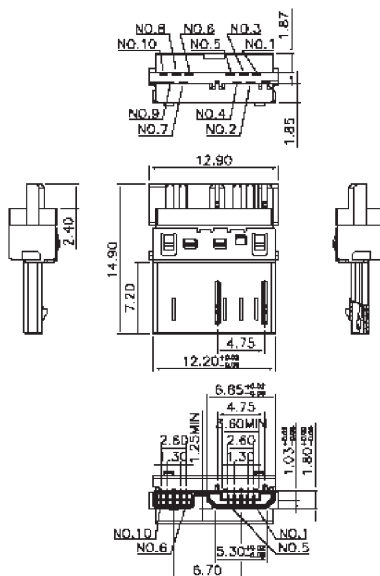

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Yamaichi Electronics:](#)

[USB-3.0MC-10B-P-BL-BU](#)