


DC Power Cord

172-0172

KOBI CONN

DC Power Cord

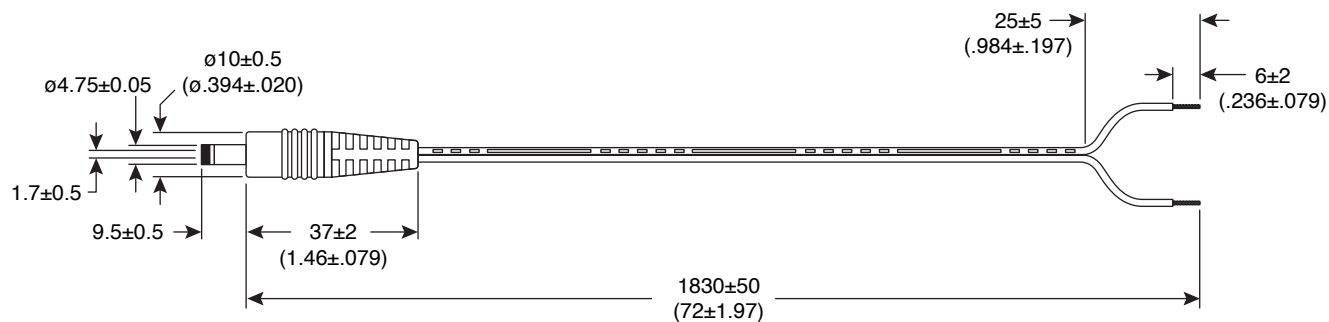

DIMENSIONS: mm (In.)

SPECIFICATIONS

Type:	24 AWG
Temperature:	60° C
Voltage Rating:	300 VDC
Resistance:	0.15 ohm per meter

Date Last Revised: 10-19-05

Available from Mouser Electronics
1-800-346-6873
www.mouser.com

KC-300325

172-0172

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Kobiconn:](#)

[172-0172](#)