


6P/4C Modular Jack

154-7623D4

KOBI CONN

6P/4C Modular Jack

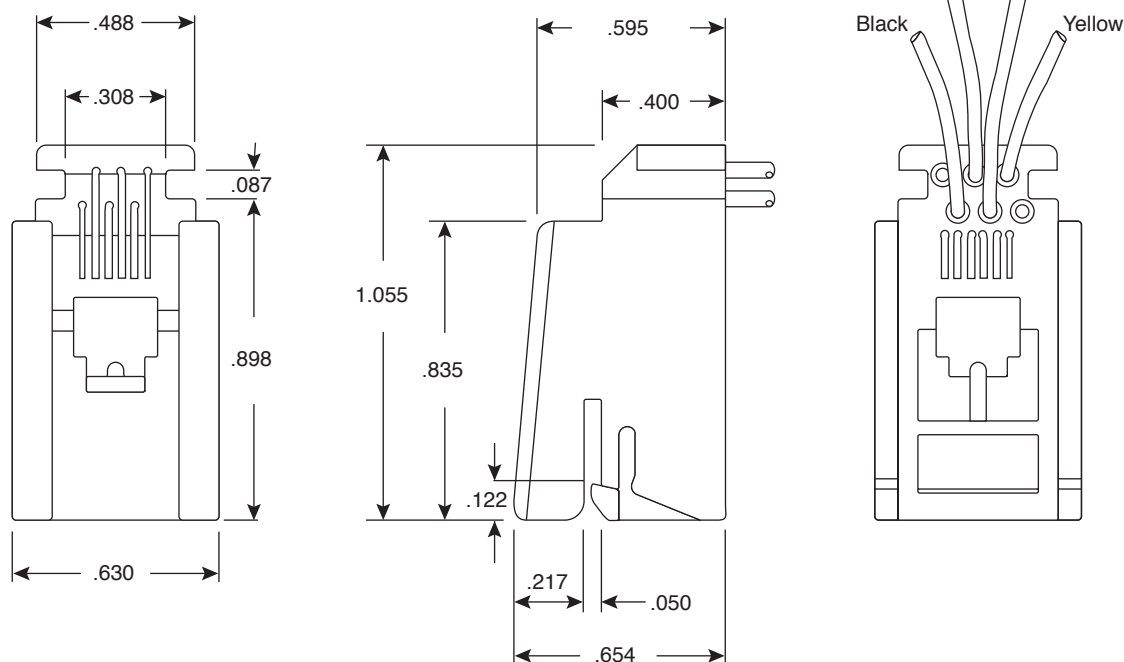

Dimensions: In.

SPECIFICATIONS

Housing:	ABS Resin
Contact:	ø.45mm (ø.018), Phosphor Bronze Alloy
Wire:	26AWG
Wire Insulation:	PVC
Wire O.D.:	1.105mm
Insulation Resistance:	10MΩ min.
Contact Resistance:	20mΩ max.
Dielectric Strength:	1000Vrms 60Hz
Retention Strength:	7.7Kgs Between Jack and Plug
Crimp Tensile Strength:	2.27Kgs

Date Last Revised: 10-15-05

Available from Mouser Electronics
1-800-346-6873
www.mouser.com

KC-300610

154-7623D4

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Kobiconn:](#)

[154-7623D4](#)