


PCB Modular Jacks

KOBICONN

154-UL6441, 154-UL6641, 154-UL6661, 154-UL6881

PCB Modular Jacks

154-UL6441, 154-UL6641, 154-UL6661, 154-UL6881

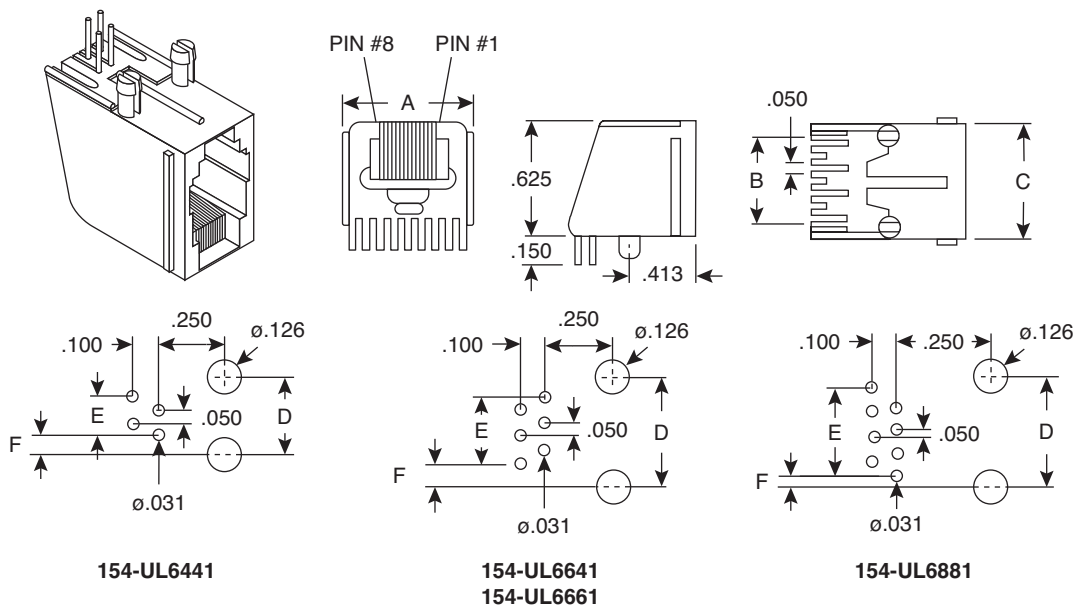

Dimensions: In.

MOUSERSTOCK NO.	Dimensions (In)					
	A	B	C	D	E	F
154-UL6441	.540	.150	.440	.300	.150	.075
154-UL6641	.620	.250	.520	.400	.250	.075
154-UL6661	.620	.250	.520	.400	.250	.075
154-UL6881	.700	.350	.600	.450	.350	.050

SPECIFICATIONS	
Type:	Flanged PCB Modular
Housing:	25% Glass Filled Nylon
Contact:	50μ Gold Over Nickel Plated, .014" Phosphor Bronze
Current Rating:	1.5A
Voltage Rating:	150V max.
Breakdown Voltage:	500VAC for 1 Minute
Insulation Resistance:	10MΩ

Date Last Revised: 6/26/12

Available from Mouser Electronics
1-800-346-6873
www.mouser.com

KC-300616

Specifications are subject to change without notice. No liability or warranty implied by this information. Environmental compliance based on producer documentation.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Kobiconn:

[154-UL6641](#) [154-UL6881](#) [154-UL6661](#) [154-UL6441](#)