




LoRa 868/915/923 Right-Angle Stick Antenna

LoRa 868/915/923 Stright Stick Antenna

Product Number: WTH43006

Part Number: 122040004



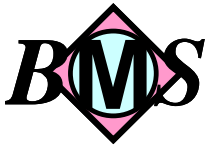

Applications:

Antenna units is used with or in Handheld system, Automobile, Recreational, Marine, etc

It is very suitable for the antenna being attached to the glass window or being put into the device which cover is plastic. And, then, antenna be connected to system by a RF coaxial cable.


Antenna unit has good performance in VSWR, gain, and patterns, so that it can give systems a good communication quality.

Specification:

Characteristic Parameters	Specification
LoRa System Band	868/915/923 MHz
Frequency Band	824 - 960 MHz
Reflecion Coefficient	< -10 dB typ.
VSWR	< 2. typ
Gain	2 dBi typ.
Polarization	Vertical typ.
Maximum Input power	5 W
connector	Straight SMA Male
House	Black
Size	antenna body: 61mm*Φ 9.2mm
Storage Temperature	-40 °C to 85 °C
Operating Temp.	-40 °C to 75 °C




Reflection Coefficient:

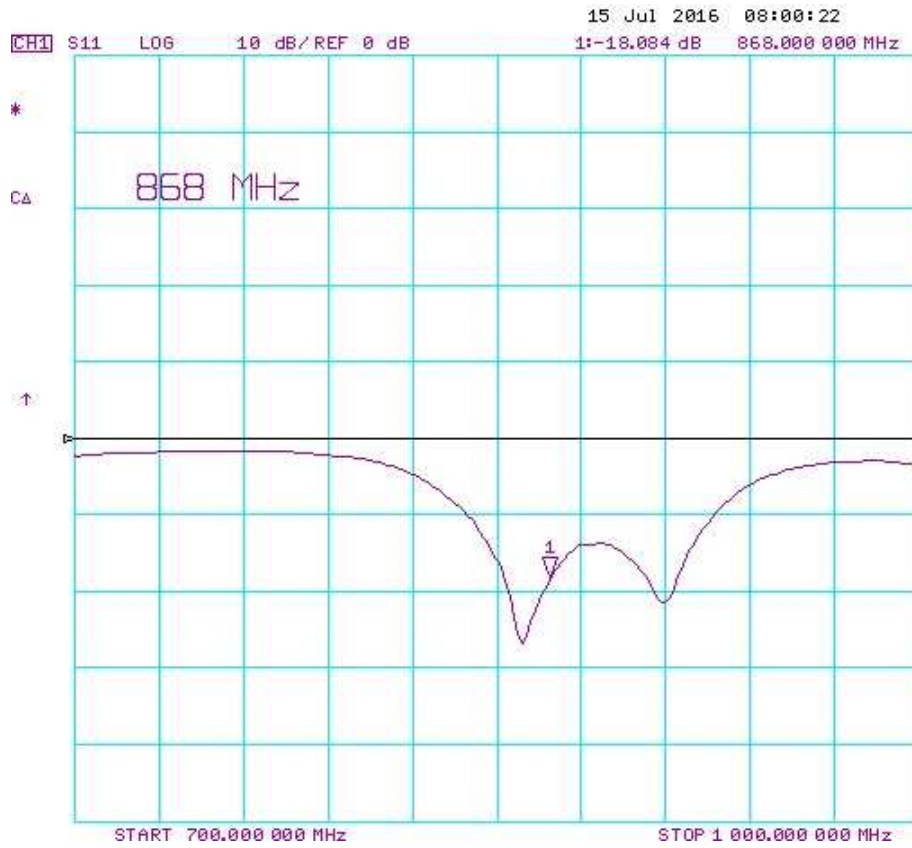

Antenna dimension: unit:mm



LoRa 868/915/923 Right-Angle Stick Antenna

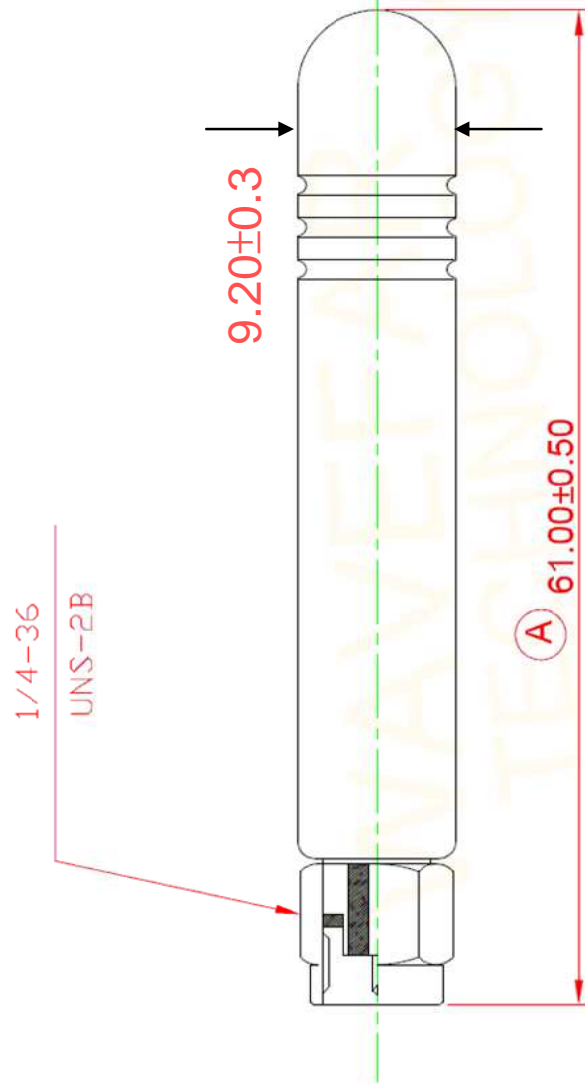

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[ADLINK Technology:](#)

[LoRa Node Kit\(US\)](#)