

# RK-608B

## Wallmount Industrial Chassis supports 10-slot Backplane



### Specifications

<b>Dimensions</b>	13 in x 6.9 in x 16.5 in (330 mm x 175 mm x 418 mm) (W x H x D)
<b>Drive Bays</b>	Two 5.25" and two 3.5" front accessible drive bays
<b>Construction</b>	Heavy-duty steel
<b>Color</b>	Beige
<b>Cooling Fans</b>	In: one 120 mm x 120 mm x 25 mm ball bearing fan (85 CFM)
<b>Front Panel</b>	LEDs: HDD active and system power System reset switch and ATX power switch Two USB and one PS/2 keyboard connector
<b>Backplane</b>	10-slot passive backplane
<b>Power Supply</b>	PS2 form factor ATX power supply
<b>Carton Size</b>	20.9 in x 13.2 in x 18.1 in (530 mm x 335 mm x 460 mm)
<b>Weight</b>	Net 7.8 kg (17.2 lb)

### Backplane Options

Model Name	PICMG® SBC	PCIe x1	PCIe x4	PCIe x16	PCI	ISA	PSU Connector
HPCI-9S7U	2	--	--	--	7	1	ATX/AT
HPCI-8S4	2	--	--	--	4	4	ATX/AT
EBP-7E2	1	--	1	1	4	--	ATX
EBP-9E2	1	--	1	1	6	--	ATX

### Mechanical Layout



### Features

- Supports 10 slot PICMG backplane
- Two 5.25" and two 3.5" external drive bays, one internal 3.5" drive bay
- Upper cover with captive screw
- Drive bay with shock and vibration resistant design
- Replaceable and easy-to-clean air filter
- 12cm cooling fan (85CFM)
- Two USB and one PS/2 keyboard connectors on front panel

### Power Supply Options


Model Number	Watt	Input Range	Output (Max.)						
			+5 V	+3.3 V	+12 V1	+12 V2	-12 V	-5 V	+5 Vsb
APS930XA-ATX12	300 W	Universal	16 A	19 A	17 A	17 A	0.5 A	0.3 A	3 A
APS-946XA-EPS12	460 W	Universal	20 A	24 A	16 A	16 A	0.5 A	0.3 A	3 A

### Ordering Information

Model Number	Color	Description
RK-608B-E	Beige	Wallmount industrial chassis supports 10-slot backplane

### Dimensions

Units: mm

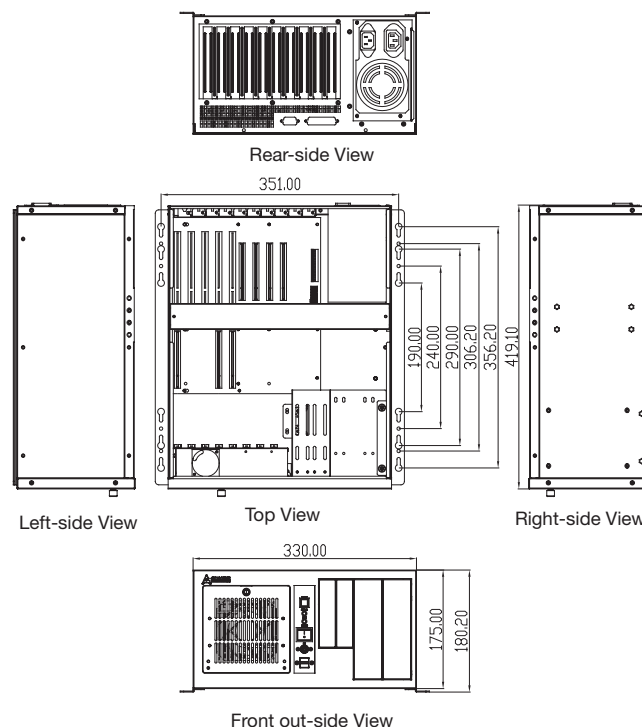

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[ADLINK Technology:](#)

[RK-608B-E](#)