


Dimensions (In.)

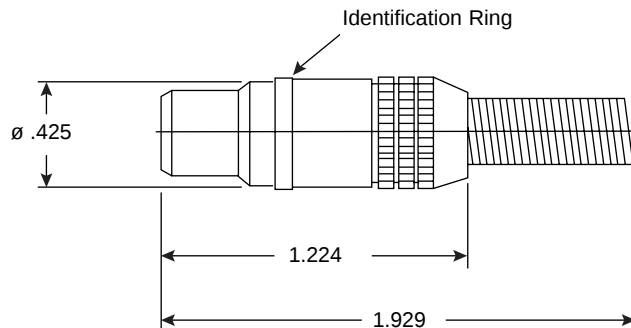

Specifications:

- Maximum cable size: 5.5m (.216")
- Ratings: 5A @ 200VDC/150 VAC maximum
- Insulation resistance: 100MΩ @ 500VDC
- Center contact: silver and flash gold plated brass
- Ground contact: nickel and flash gold plated brass
- Insulation: noryl SE1
- Cable clamp: silver and flash gold plated brass
- Spring: nickel and flash gold plated spring steel
- Cap: nickel and flash gold plated brass

Mouser Stock No.	Description
164-3400	Nickel plated
164-3401	Nickel plated (black ID ring)
164-3402	Nickel plated (blue ID ring)
164-3405	Nickel plated (red ID ring)
164-3406	Nickel plated (white ID ring)
164-3407	Nickel plated (yellow ID ring)
164-3410	Flash gold plated
164-3411	Flash gold plated (black ID ring)
164-3412	Flash gold plated (blue ID ring)
164-3415	Flash gold plated (red ID ring)
164-3416	Flash gold plated (white ID ring)
164-3417	Flash gold plated (yellow ID ring)
164-3420	Flash gold socket assy/black chrome cap & spring
164-3421	Flash gold socket assy/black chrome cap & spring (black ID ring)
164-3422	Flash gold socket assy/black chrome cap & spring (blue ID ring)
164-3425	Flash gold socket assy/black chrome cap & spring (red ID ring)
164-3426	Flash gold socket assy/black chrome cap & spring (white ID ring)
164-3427	Flash gold socket assy/black chrome cap & spring (yellow ID ring)

Your source for quality electronics. Toll-free full service

(800) 346-6873

<http://www.mouser.com>

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Deltron:](#)

[341-0000](#) [342-0000](#)