

174-3330	174-3336	174-3342	174-3350	174-3356
174-3331	174-3337	174-3345	174-3351	174-3357
174-3332	174-3340	174-3346	174-3352	
174-3335	174-3341	174-3347	174-3355	

Phono  
Plugs


**MOUSER STOCK NO.**

174-3330, 3331, 3332, 3335, 3336, 3337, 3340, 3341, 3342, 3345, 3346, 3347,  
3350, 3351, 3352, 3355, 3356, 3357


Phono Plugs

**8-** 0417129

**Date:** 3-5-97

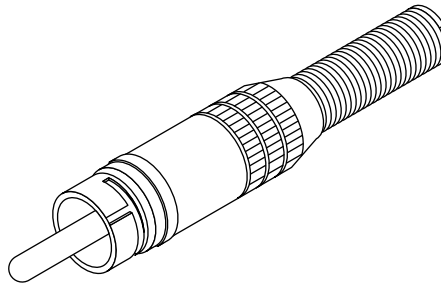

**Dimensions (In.)**

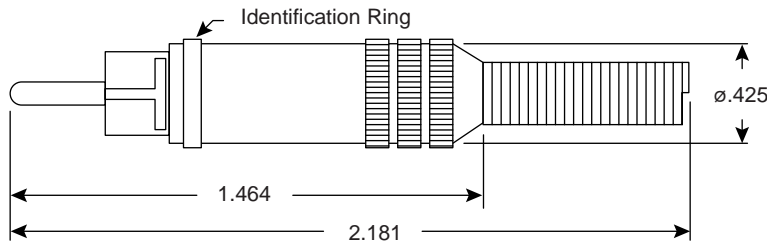

**Specifications:**

- Type: professional RCA; solid pin
- Maximum cable size: 5.5mm (.216")
- Current ratings: 5A @ 200VDC/150VAC max.
- Insulation resistance: 100MΩ @ 500VDC
- Insulation: noryl SE1
- Center contact: silver or gold plated brass
- Ground contact & cable clamp: nickel or gold plated brass
- Cap: nickel or black chrome plated brass

Mouser Stock No.	Body & Spring Plating	ID Ring Color
174-3330 174-3331 174-3332 174-3335 174-3336 174-3337	Nickel	--- Black Blue Red White Yellow
174-3340 174-3341 174-3342 174-3345 174-3346 174-3347	Flash Gold	--- Black Blue Red White Yellow
174-3350 174-3351 174-3352 174-3355 174-3356 174-3357	Black Chrome  Pin Assy = Flash Gold	--- Black Blue Red White Yellow

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Deltron:](#)

[333-0000](#) [334-0000](#) [335-0000](#)