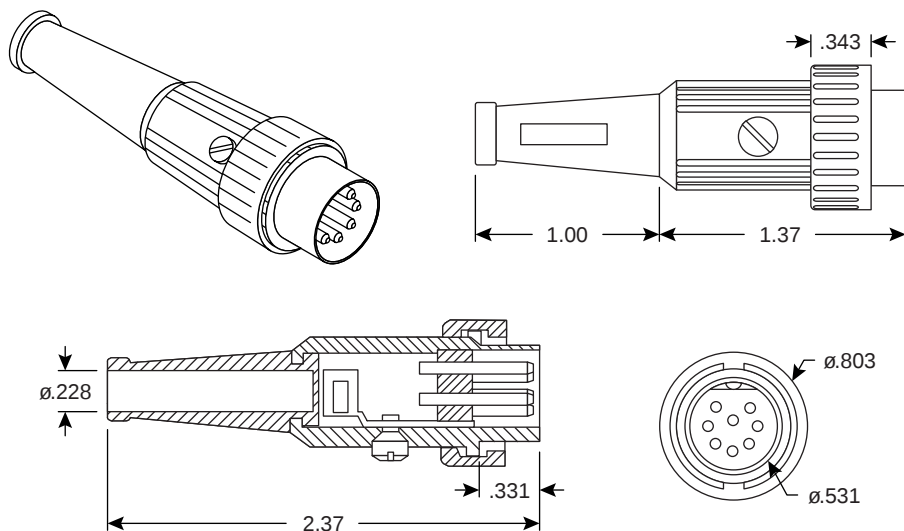


Dimensions (In.)

Specifications:

- Type: ring lock DIN
- Working voltage: 100VDC or AC peak
- Test voltage: 1000VDC
- Insulation resistance: 100GΩ min. @ 100VDC
- Current: 4A
- Contact resistance: 10mΩ max.
- Capacity(mated): 3pF
- Temperature range: -25°~+70°C
- Locking ring life: 10,000 operations @ .369 ft/lbs
- Housing: nickel plated zinc alloy
- Molding: nylon
- Locking ring: polyester, black
- Contacts: silver plated brass
- Cable clamp: zinc plated mild steel
- Grommet: PVC, black

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Deltron:](#)

[592-0601](#)